


# Separate units $\varnothing$ 22: Heads

IP 66  
 To be combined with a clip and electrical blocks (p. 48)  
 With locking ring  
 Plastic chrome bezel- Black bezel on request (form p. 79)  
 Conform to IEC 60947-5-1

 Characteristics (p. 94)  
 Cross reference list (p. 311)

## ▶ SELECTOR SWITCHES - NON ILLUMINATED (CONTINUED)


WITH KEY

3 positions

Cat. No.



L21NA00

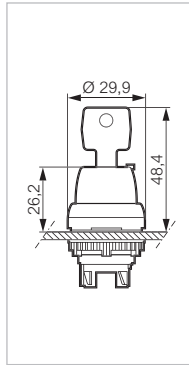

Key free in position:

Supplied with 2 keys profile n° 455

**Stay-put positions - 45°**

● Black



0

**L21NA00**

**Spring return from left to 0 - 45°**

● Black



0

**L21NB00**

**Spring return from right to 0 - 45°**

● Black



0

**L21NC00**

**Spring return to 0 - 45°**

● Black



0

**L21ND00**

**Stay-put positions - 45°**

● Black



1 - 2

**L21NE00**

**Spring return from right to 0 - 45°**

● Black



1

**L21NJ00**

**Stay-put positions - 90°**

● Black



1 - 0 - 2

**L21NK00**

**Stay-put positions - 90°**

● Black



0

**L21NL00**

Key profile n° 1424 A and others (form p. 79)