

## TECHNICAL SPECIFICATIONS


<b>Material:</b>	Zinc, Nickel Plated
<b>Operating Temperature:</b>	-40°C to +120°C
<b>Cable Entry:</b>	45° Side Entry
<b>Thumbscrews:</b>	UNC 4-40 (Standard) M2,5 or M3 on request
<b>Cable O.D.:</b>	Up to 13mm (Size 9-37) Up to 17mm (Size 50)
<b>Accessories:</b>	See page 186-190
<b>Assembly Instruction:</b>	See page 197



### Features:


- Available in sizes 9-15-25-37-50
- Excellent EMI Shielding
- Re-openable
- Strain relief inserts ensure a secure termination
- Metalized (RAHI) grommets on request. see page 186

**NEW: Size 50 now available**

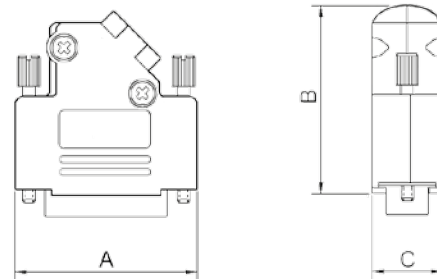


Size MHD45ZK	Dim A	Dim B	Dim C
9-way	31,0	36,3	14,5
15-way	39,5	40,3	14,5
25-way	53,2	40,3	14,5
37-way	69,7	40,3	14,5
50-way	67,4	44,9	17,4

### Grommet Sizes / D45ZK50:

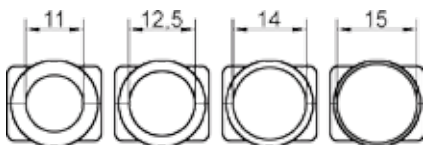

### Grommet Sizes / D45ZK09-37:

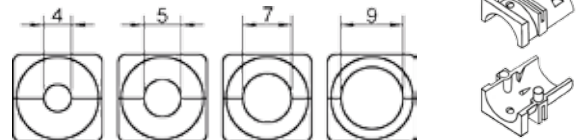

## Ordering information:

Size:	P/N - Kitted:	Product Code:
9-way	6560-0106-11	MHD45ZK-9-RA-K
15-way	6560-0106-12	MHD45ZK-15-RA-K
25-way	6560-0106-13	MHD45ZK-25-RA-K
37-way	6560-0106-14	MHD45ZK-37-RA-K
50-way	6560-0106-15	MHD45ZK-50-RA-K

Size:	P/N - BULK:	Product Code:
9-way	6561-0106-11	MHD45ZK-9-RA
15-way	6561-0106-12	MHD45ZK-15-RA
25-way	6561-0106-13	MHD45ZK-25-RA
37-way	6561-0106-14	MHD45ZK-37-RA
50-way	6561-0106-15	MHD45ZK-50-RA