



### Self Adhesive / Screw Fixing Cable Tie Mounts


#### • Q-mount Series QM

Q-mounts allow a “4-way” entry for Q-ties and are available in a screwable or self adhesive version. Due of the special design of the mounting base, they offer a perfect solution in combination with the Q-tie cable ties. The Q-mount keeps the Q-tie in place during pre-assembly and ensures that the Q-tie does not slip out even in difficult situations, for example vertical mounting positions.




Q-mount QM, 4-way entry, adhesive/screwable.

Please find more Q-Series products for your system solution on page 81 and 508.

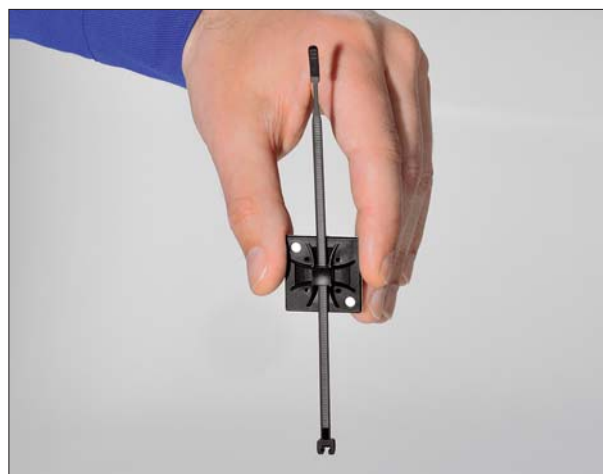

The Q-mount base locks the Q-tie in vertical position, your hands are free to apply the cables.

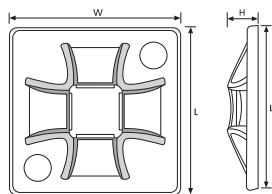

Mounting Base Q-mount

Synthetic rubber	
Base material	PE foam
Temperature range	at least -40°C to +60°C



Material Data	
Material	Polyamide 6.6 (PA66)
Colour	Natural (NA), Black (BK)
Operating Temperature	-40 °C to +105 °C Continuous, (+105 °C for 500 h)
Flammability	UL94 V2 (excluding adhesive)



#### Technical Table

Article-No.	Type	Length (L)	Width (W)	Height (H)	Fixing Hole Ø (FH)	Strap Width max. (G)	Material	Colour	Adhesive
151-10901	QM20	20.0	20.0	3.7	3.1	4.0	PA66	Natural (NA)	–
151-10902	QM30	30.0	30.0	4.5	4.1	5.1	PA66	Natural (NA)	–
151-10903	QM40	40.0	40.0	5.5	4.1	8.4	PA66	Natural (NA)	–
151-10904	QM20A	20.0	20.0	3.7	3.1	4.0	PA66	Natural (NA)	Synthetic rubber
151-10905	QM30A	30.0	30.0	4.5	4.1	5.1	PA66	Natural (NA)	Synthetic rubber
151-10906	QM40A	40.0	40.0	5.5	4.1	8.4	PA66	Natural (NA)	Synthetic rubber
151-10911	QM20	20.0	20.0	3.7	3.1	4.0	PA66	Black (BK)	–
151-10912	QM30	30.0	30.0	4.5	4.1	5.1	PA66	Black (BK)	–
151-10913	QM40	40.0	40.0	5.5	4.1	8.4	PA66	Black (BK)	–
151-10914	QM20A	20.0	20.0	3.7	3.1	4.0	PA66	Black (BK)	Synthetic rubber
151-10915	QM30A	30.0	30.0	4.5	4.1	5.1	PA66	Black (BK)	Synthetic rubber
151-10916	QM40A	40.0	40.0	5.5	4.1	8.4	PA66	Black (BK)	Synthetic rubber

All dimensions in mm. Subject to technical changes.