



Cable Tie with quick release mechanism Speedy-Click

• SpeedyTie

Features and Benefits


The SpeedyTie can be used many times because of its removable, patented trigger. Also this is a heavy duty releasable tie that can bear loads of up to 888N (200lbs). With a length of 750mm it suits a wide variety of applications and is easy to handle even when wearing work gloves. Any excess tail can be easily 'tucked away' in a second slot on the head. These ties are available in 'high visibility' yellow and in weatherproof black.



Patented quick release mechanism for quick and easy application.

Application

The versatility of the SpeedyTie means that it is suitable for a multitude of applications. Originally developed for the 'offshore' industries, other uses include: construction, electrical installations, scaffolding sheet installations, exhibitions, trade fairs, and many more.

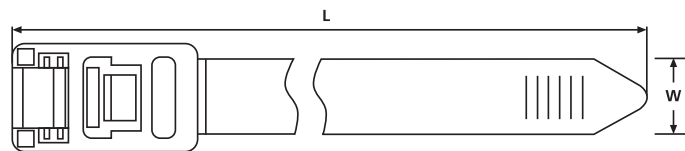


SpeedyTie



SpeedyTie - Quick and easy.



Excess Tails can be neatly tucked away.

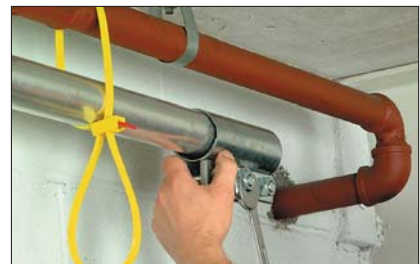


SpeedyTie is particularly suited for temporary but safe bundling or fixing.

Material Data	
Material	Polyamide 6.6 (PA66)
Operating Temperature	-40 °C to +85 °C Continuous, (+105 °C for 500 h)
Flammability	UL94 V2



Material Data	
Material	Polyamide 6.6 High Imp. Mod. scan black (PA66HIR(S))
Operating Temperature	-40 °C to +80 °C Continuous, (+105 °C for 500 h)
Flammability	UL94 HB

 

Technical Table

Article-No.	Type	Length (L)	Width (W)	Bundle Ø max.	Min. Tensile Strength (N)	Colour	Material	Pack Cont.
Bulk pack								
115-00000	RTT750HR	750	13.0	210	888	Yellow (YE), Red (RD)*	PA66	25
Small pack								
115-00001	RTT750HR	750	13.0	210	888	Yellow (YE), Red (RD)*	PA66	5
115-00030	RTT750HR	750	13.0	210	888	Black (BK), Black (BK)*	PA66HIR(S)	5

All dimensions in mm. Subject to technical changes.

*Fastener