

RJ45 connector - VS-PPC-C1-MNNA-8Q5-EMC - 1403367

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://download.phoenixcontact.com>)



Push/pull connector (version 14), metal EMC, with 8-pos. RJ45 QUICKON connector insert, with QUICKON fast connection technology, for 26 ... 24 AWG 1-wire and 7-wire conductors, for 5.0 mm ... 8.0 mm cable diameter

Push/pull EMC connector



EtherCAT
Technology Group

SERCOS
the automation bus

Ethernet

Key commercial data

package_quantity	1
GTIN	4046356708326

Technical data

Mechanical characteristics

Standards/specifications	IEC PAS 61076-3-117
Number of positions	8
Connection profile	RJ45 8(8)
Locking type	Push Pull
Shielded	Yes
Insertion/withdrawal cycles	≥ 500
Connection method	IDC fast connection
Connection cross section AWG	(solid)
Connection cross section AWG	(stranded)
Max. cable diameter	5 mm ... 8 mm
External cable diameter	5 mm ... 8 mm
Cable exit	Straight
Color	silver

Ambient conditions

Ambient temperature (operation)	-40 °C ... 70 °C
Degree of protection	IP65/67

Material data

Inflammability class according to UL 94	V0
Housing material	Zinc die-cast
Housing surface material	Nickel-plated
Contact carrier material	PC
Contact material	Copper alloy

RJ45 connector - VS-PPC-C1-MNNA-8Q5-EMC - 1403367

Technical data

Material data

Contact surface material	Gold over nickel
Material, O-ring	NBR
Cable seal material	TPE
Material housing intermediate seal	NBR

Electrical characteristics

Number of positions	8
Nominal voltage U_N	50 V
Nominal current I_N	1.75 A
Transmission characteristics (category)	CAT5 (IEC 11801:2002), CAT5e (TIA 568B:2001)
Rated current	1.75 A
Surge voltage category	I
Pollution degree	2

classifications

eCl@ss

eCl@ss 4.0	27140816
eCl@ss 4.1	27140816
eCl@ss 5.0	27189239
eCl@ss 5.1	27189239
eCl@ss 6.0	27260708
eCl@ss 7.0	27144001
eCl@ss 8.0	27144001

ETIM

ETIM 3.0	EC000007
ETIM 4.0	EC001121
ETIM 5.0	EC002641

UNSPSC

UNSPSC 6.01	31261501
UNSPSC 7.0901	31261501
UNSPSC 11	31261501
UNSPSC 12.01	31261501
UNSPSC 13.2	31261501

RJ45 connector - VS-PPC-C1-MNNA-8Q5-EMC - 1403367


accessories

VS-CABLE-STRIP-VARIO - 1657407



Drawings

Dimensioned drawing

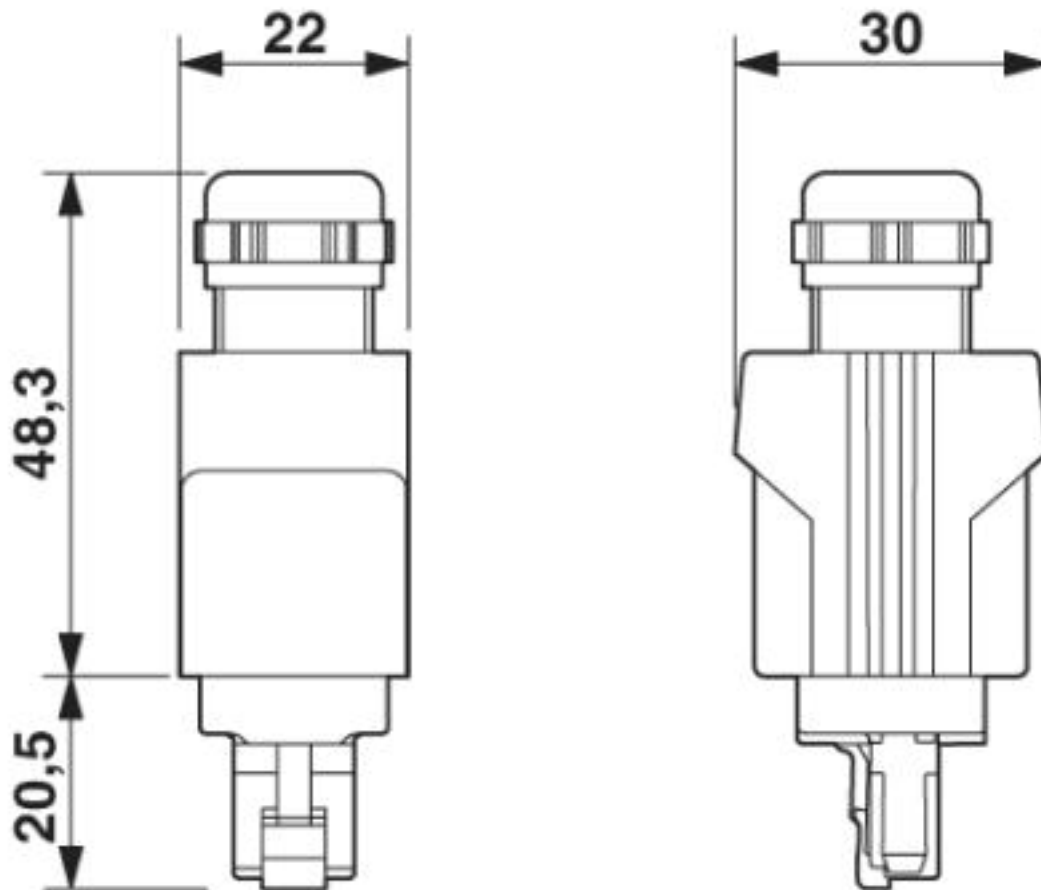

RJ45 push/pull EMC connector, IP65/67

© Phoenix Contact 2013 - all rights reserved
<http://www.phoenixcontact.com>