

RJ45 connector - VS-PPC-C1-RJ45-MNNA-PG9-4Q5-B - 1405141

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://download.phoenixcontact.com>)



RJ45 connector, IP67, with push-pull interlocking, metal housing, CAT5e, 4-pos., with QUICKON fast connection technology, for 1-wire and 7-wire conductors AWG 26 ... 22, for cable cross section 5.0 mm ... 8.0 mm



Key commercial data

package_quantity	1
GTIN	4046356325929

Technical data

Mechanical characteristics

Standards/specifications	IEC PAS 61076-3-117
Number of positions	4
Connection profile	RJ45 8(4)
Locking type	Push Pull
Shielded	Yes
Insertion/withdrawal cycles	≥ 500
Connection method	IDC fast connection
Conductor cross section	0.13 mm ² ... 0.32 mm ² (solid)
Conductor cross section	0.14 mm ² ... 0.36 mm ² (stranded)
Connection cross section AWG	26 ... 22 (solid)
Connection cross section AWG	26 ... 22 (stranded)
External cable diameter	5 mm ... 8 mm
Cable exit	Straight
Color	silver

Ambient conditions

Ambient temperature (operation)	-40 °C ... 70 °C
Degree of protection	IP65/67

Material data

Inflammability class according to UL 94	V0
Housing material	Zinc die-cast
Housing surface material	Nickel-plated
Contact carrier material	PC

RJ45 connector - VS-PPC-C1-RJ45-MNNA-PG9-4Q5-B - 1405141

Technical data

Material data

Contact material	Copper alloy
Contact surface material	Gold over nickel
Material	Metal
Material, O-ring	NBR
Cable seal material	TPE
Material housing intermediate seal	NBR

Electrical characteristics

Number of positions	4
Transmission characteristics (category)	CAT5 (IEC 11801:2002), CAT5e (TIA 568B:2001)
Rated current	1.75 A
Surge voltage category	I
Pollution degree	2

classifications

eCl@ss

eCl@ss 4.0	272607xx
eCl@ss 4.1	27260701
eCl@ss 5.0	27260701
eCl@ss 5.1	27260701
eCl@ss 6.0	27260708
eCl@ss 7.0	27440312
eCl@ss 8.0	27440312

ETIM

ETIM 3.0	EC001121
ETIM 4.0	EC001121
ETIM 5.0	EC002641

UNSPSC

UNSPSC 6.01	31261501
UNSPSC 7.0901	31261501
UNSPSC 11	31261501
UNSPSC 12.01	31261501
UNSPSC 13.2	31261501

RJ45 connector - VS-PPC-C1-RJ45-MNNA-PG9-4Q5-B - 1405141


accessories

VS-CABLE-STRIP-VARIO - 1657407



Drawings

Dimensioned drawing

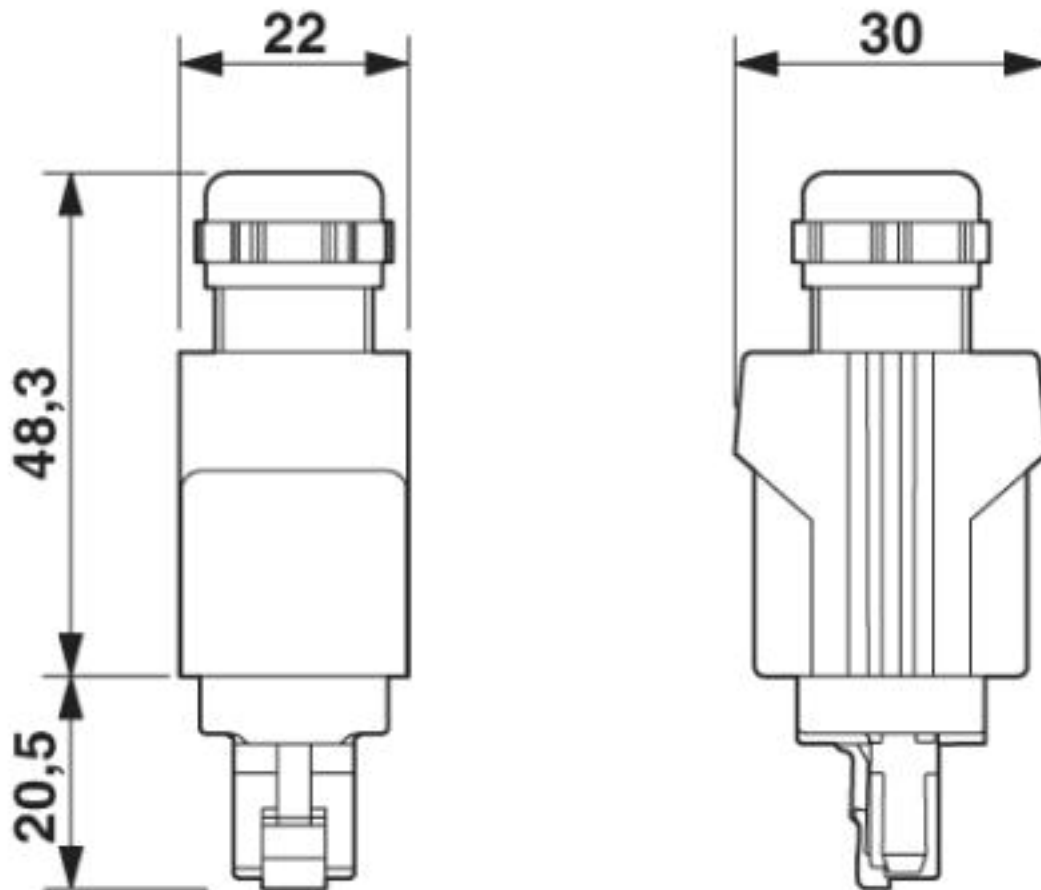

Push-pull RJ45 connector IP65/67

© Phoenix Contact 2013 - all rights reserved
<http://www.phoenixcontact.com>