

# Valve connectors - SACC-VB-3CON-M16/B-1L-SV 24V - 1452204

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://download.phoenixcontact.com>)



Valve connector, 3-pos., construction B, 1 LED, with protective circuit, screw connection, M16 cable gland

## Key commercial data

|                  |               |
|------------------|---------------|
| package_quantity | 1             |
| GTIN             | 4046356536370 |

## Technical data

### Dimensions

|                   |               |
|-------------------|---------------|
| External diameter | 6 mm ... 8 mm |
|-------------------|---------------|

### Ambient conditions

|                                 |                               |
|---------------------------------|-------------------------------|
| Ambient temperature (operation) | -25 °C ... 60 °C (valve plug) |
| Degree of protection            | IP65                          |

### General

|                              |  |
|------------------------------|--|
| Rated current at 40°C        | 1.5 A  |
| Rated voltage                | 24 V   |
| Number of positions          | 3  |
| Contact resistance           | ≤ 4 MΩ                                       |
| Insulation resistance        | > 2 GΩ                                       |
| Standards/regulations        | Valve connector EN 175301-803                |
| Status display               | Yellow LED                                   |
| Protective circuit/component | Varistor                                     |
| Surge voltage category       | II   |
| Pollution degree             | 3  |
| Connection method            | Screw connection                             |
| Conductor cross section      | 0.25 mm <sup>2</sup> ... 1.5 mm <sup>2</sup> |
| AWG conductor cross section  | 24 ... 16                                    |
| Torque                       | 1.8 Nm ± 0.2 (Pressure screw)                |
| Torque                       | 0.6 Nm (Central screw)                       |
| Torque                       | 0.2 Nm ± 0.1 (Contact screw)                 |

### Material

|   |    |
|---|----|
| Inflammability class according to UL 94 | HB |
|---|----|

# Valve connectors - SACC-VB-3CON-M16/B-1L-SV 24V - 1452204

## Technical data

### Material

|                                     |      |
|-------------------------------------|------|
| Valve plug contact material         | CuZn |
| Valve plug contact surface material | CuSn |
| Material housing valve plug         | PA   |
| Sealing material                    | NBR  |

## classifications

### eCl@ss

|            |          |
|------------|----------|
| eCl@ss 4.0 | 27140815 |
| eCl@ss 4.1 | 27140815 |
| eCl@ss 5.0 | 27143423 |
| eCl@ss 5.1 | 27143423 |
| eCl@ss 6.0 | 27143423 |
| eCl@ss 7.0 | 27449001 |
| eCl@ss 8.0 | 27449001 |

### ETIM

|          |          |
|----------|----------|
| ETIM 4.0 | EC002062 |
| ETIM 5.0 | EC002062 |

 
### UNSPSC

|               |          |
|---------------|----------|
| UNSPSC 6.01   | 31251501 |
| UNSPSC 7.0901 | 31251501 |
| UNSPSC 11     | 31251501 |
| UNSPSC 12.01  | 31251501 |
| UNSPSC 13.2   | 31251501 |

## approvals

GOST /

### Approval details



## accessories

### Cable by the meter

# Valve connectors - SACC-VB-3CON-M16/B-1L-SV 24V - 1452204

accessories


SAC-3P-100,0-PUR/0,5 - 1457393



---


## Drawings

Dimensioned drawing

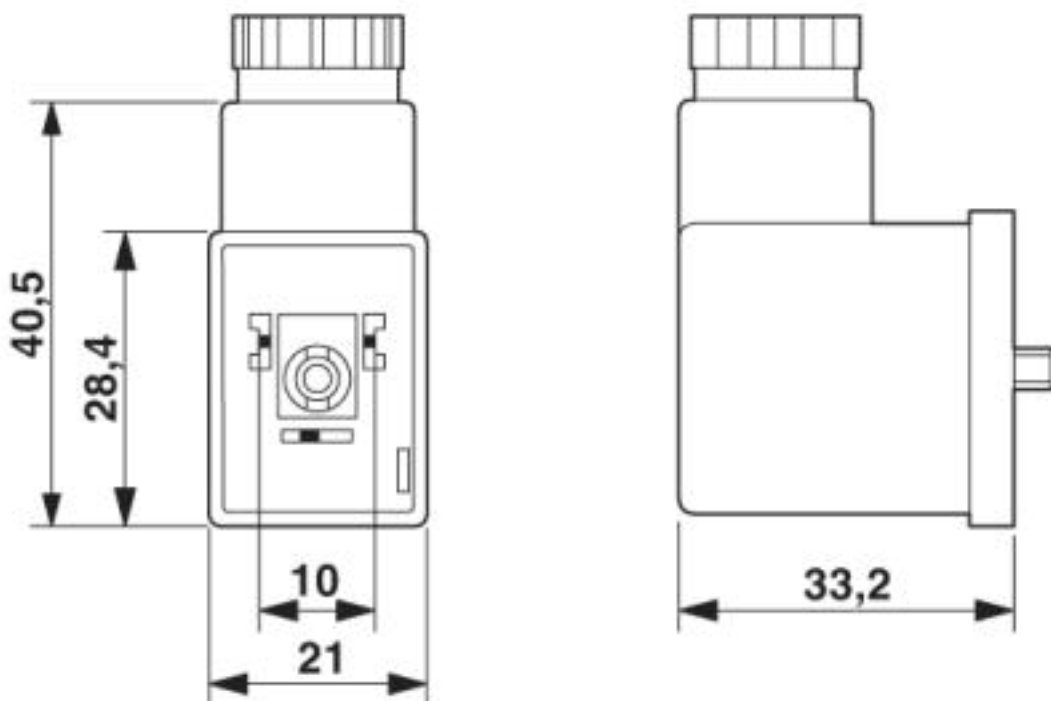

# Valve connectors - SACC-VB-3CON-M16/B-1L-SV 24V - 1452204

Circuit diagram

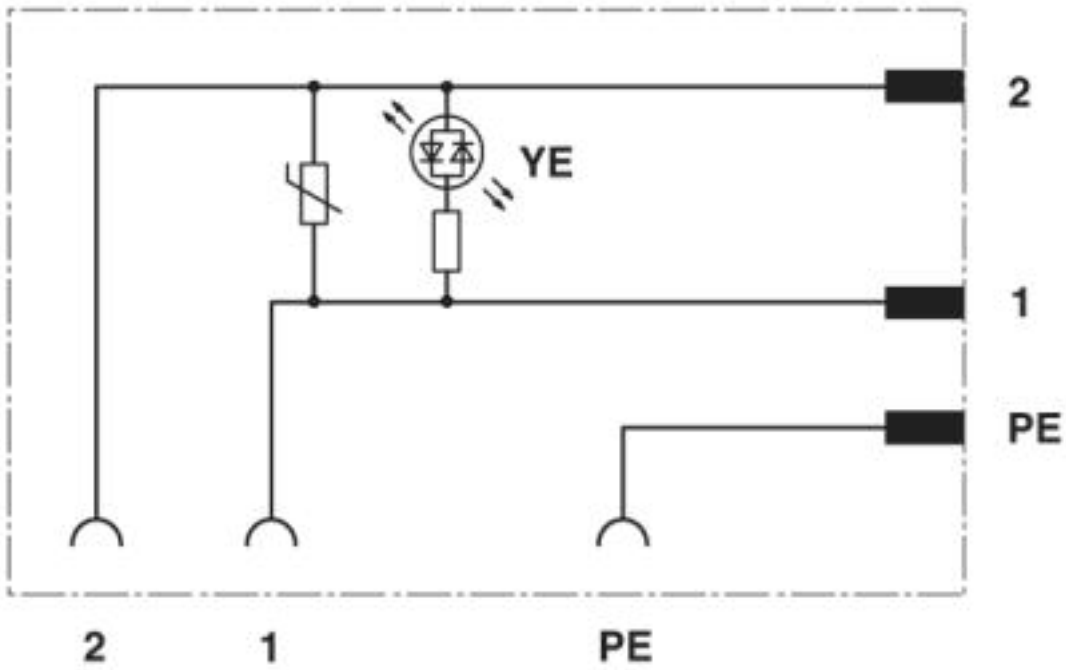

© Phoenix Contact 2013 - all rights reserved  
<http://www.phoenixcontact.com>