

T box - DC-B 6-HTC-M20-M20-M - 1581049

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://download.phoenixcontact.com>)



DUPLICON, aluminum T-box, type B6, IP67 protection, 2 x M20 cable screw connection thread (without cable screw connection)

Key commercial data

package_quantity	10
GTIN	4046356154833

Technical data

Dimensions

Height	72 mm
Width	81 mm
Length	81 mm

Ambient conditions

Ambient temperature (operation)	-40 °C ... 125 °C
---------------------------------	-------------------

General

Design	DC-B6
Housing type	Box mounting bases
Color	pearl gray
Locking type	For double locking latch
No. of cable exits	2
Cable exit	Lateral
Screw connection	None
Type of the screw connection	With M20 thread
Protective cover	No
Housing material	Aluminum die-cast
Housing surface material	EMC-conductive

classifications

eCl@ss

eCl@ss 4.0	272607xx
eCl@ss 4.1	27260701
eCl@ss 5.0	27143424

T box - DC-B 6-HTC-M20-M20-M - 1581049

classifications

eCl@ss

eCl@ss 5.1	27143424
eCl@ss 6.0	27143424
eCl@ss 7.0	27440209
eCl@ss 8.0	27440209

ETIM

ETIM 3.0	EC000437
ETIM 4.0	EC000437
ETIM 5.0	EC000437

UNSPSC

UNSPSC 6.01	31261502
UNSPSC 7.0901	31261502
UNSPSC 11	31261502
UNSPSC 12.01	31261502
UNSPSC 13.2	31261502

approvals

VDE Gutachten mit Fertigungsüberwachung /

Approval details

VDE Gutachten mit Fertigungsüberwachung 	
Nominal voltage UN	690 V
Nominal current IN	25 A
mm²/AWG/kcmil	

accessories

Protective cover

DC-B 6-CT-P - 1581078



Full screw connection

T box - DC-B 6-HTC-M20-M20-M - 1581049

accessories

HC-M-KV-M20(9-13) - 1690561



HC-M-KV-M20(11-16) - 1645998



Device marking


EML (26,5X12)R SR - 0816854



Drawings

T box - DC-B 6-HTC-M20-M20-M - 1581049

Dimensioned drawing

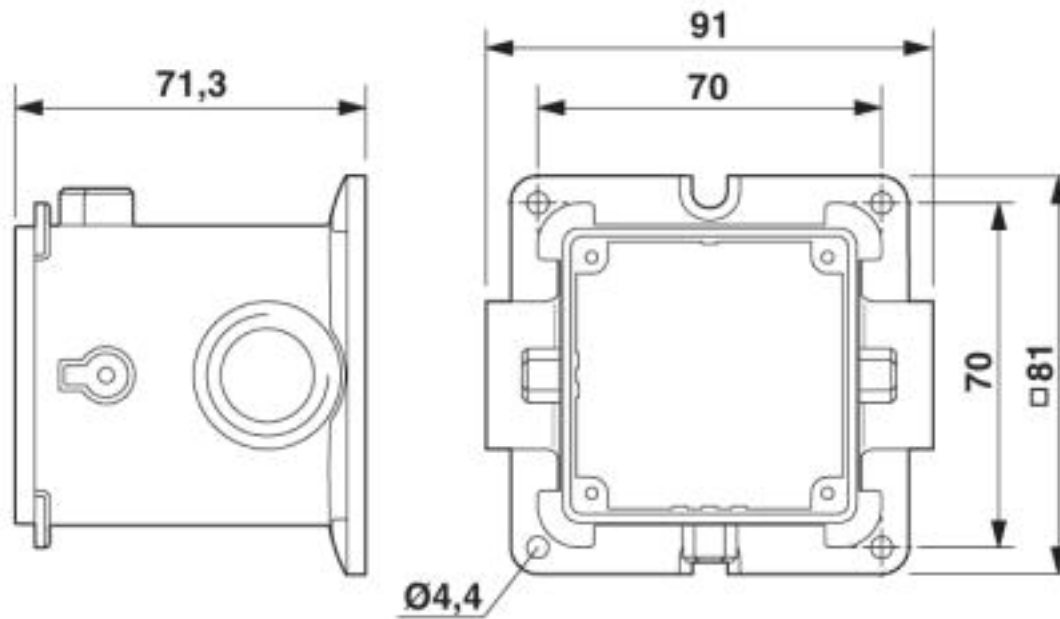

Dimensional drawing

© Phoenix Contact 2013 - all rights reserved
<http://www.phoenixcontact.com>