

Sleeve housing - VC-K-T2-Z-FK-7,5X29,5 - 1607680

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://download.phoenixcontact.com>)



Sleeve housing, plastic, type: VC2, with 7.5 x 29.5 mm flat cable outlet, locking screws with positive/negative head,

The illustration shows version VC-K-T3-Z

Key commercial data

package_quantity	10
GTIN	4017918944070

Technical data

Dimensions

Height	65 mm
--------	-------

Ambient conditions

Degree of protection	IP54
Ambient temperature (operation)	-40 °C ... 80 °C

General

Design	VC2
Degree of protection	IP54
Inflammability class according to UL 94	V0
Locking type	Screw locking, cylinder head
Fixing screws	M4
Tightening torque, mounting screw	1.5 Nm ± 0.3 Nm
Type of the screw connection	7.5 x 29.5 mm
Pg screw connection	None
Cable exit	Straight
Housing material	PA
Seal material	EPDM
Ambient temperature (operation)	-40 °C ... 80 °C

classifications

eCl@ss

eCl@ss 4.0	27140816
eCl@ss 4.1	27140816

Sleeve housing - VC-K-T2-Z-FK-7,5X29,5 - 1607680

classifications

eCl@ss

eCl@ss 5.0	27143424
eCl@ss 5.1	27143424
eCl@ss 6.0	27143424
eCl@ss 7.0	27440209
eCl@ss 8.0	27440209

ETIM

ETIM 2.0	EC000007
ETIM 3.0	EC000007
ETIM 4.0	EC000437
ETIM 5.0	EC000437


UNSPSC

UNSPSC 6.01	31261501
UNSPSC 7.0901	31261501
UNSPSC 11	31261501
UNSPSC 12.01	31261501
UNSPSC 13.2	31261501

approvals

GOST /

 
Approval details



Drawings

Sleeve housing - VC-K-T2-Z-FK-7,5X29,5 - 1607680

Dimensioned drawing

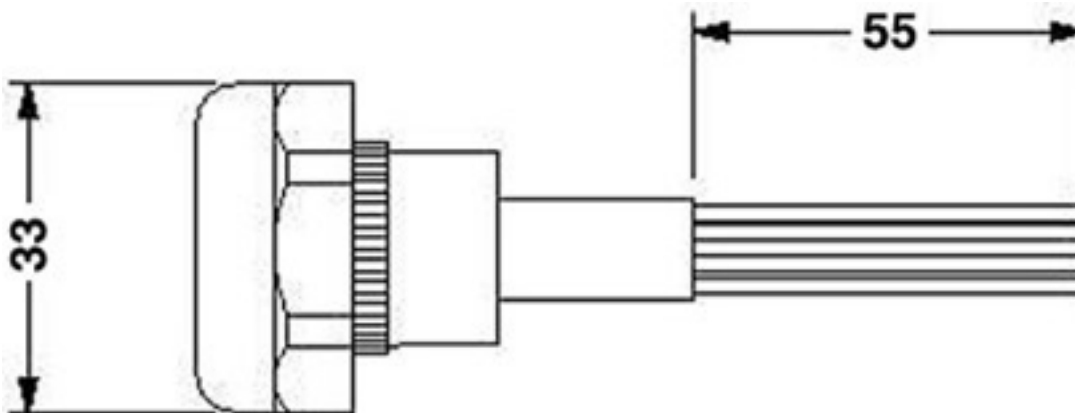

© Phoenix Contact 2013 - all rights reserved
<http://www.phoenixcontact.com>