


Socket strip - SFL (2,8-0,8)F32/ZD - 2285328

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://download.phoenixcontact.com>)

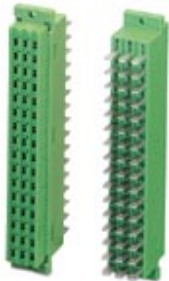

Flat connector socket, Number of positions: 32, Pitch: 0 mm, Connection method: Slip-on connection, Color: green, Contact surface: Tin

The illustration shows the version SFL (2,8-0,8) F 48

Key commercial data

package_quantity	10
GTIN	4017918055929

Technical data

Dimensions

Length	14.8 mm
Height	28.6 mm
Width	95 mm
Pitch	0 mm
Hole diameter	2.8 mm

General

Range of articles	SFL (2,8-0,8)
Insulating material group	II
Rated surge voltage (III/3)	2.5 kV
Nominal cross section	0 mm ²
Insulating material	PA-F
Inflammability class according to UL 94	HB
Number of positions	32

classifications

eCl@ss

eCl@ss 4.0	272607xx
eCl@ss 4.1	27260701
eCl@ss 5.0	27260701
eCl@ss 5.1	27260701
eCl@ss 6.0	27260704
eCl@ss 7.0	27440490

Socket strip - SFL (2,8-0,8)F32/ZD - 2285328

classifications

eCl@ss

eCl@ss 8.0	27440490
------------	----------

ETIM

ETIM 3.0	EC000516
ETIM 4.0	EC002498
ETIM 5.0	EC000516


UNSPSC

UNSPSC 6.01	30211810
UNSPSC 7.0901	39121409
UNSPSC 11	39121409
UNSPSC 12.01	39121409
UNSPSC 13.2	39121409

approvals

GOST /

 Approval details



accessories

Insulating sleeve


PT/FS 2,8 - 1406700



Drawings

Socket strip - SFL (2,8-0,8)F32/ZD - 2285328

Dimensioned drawing

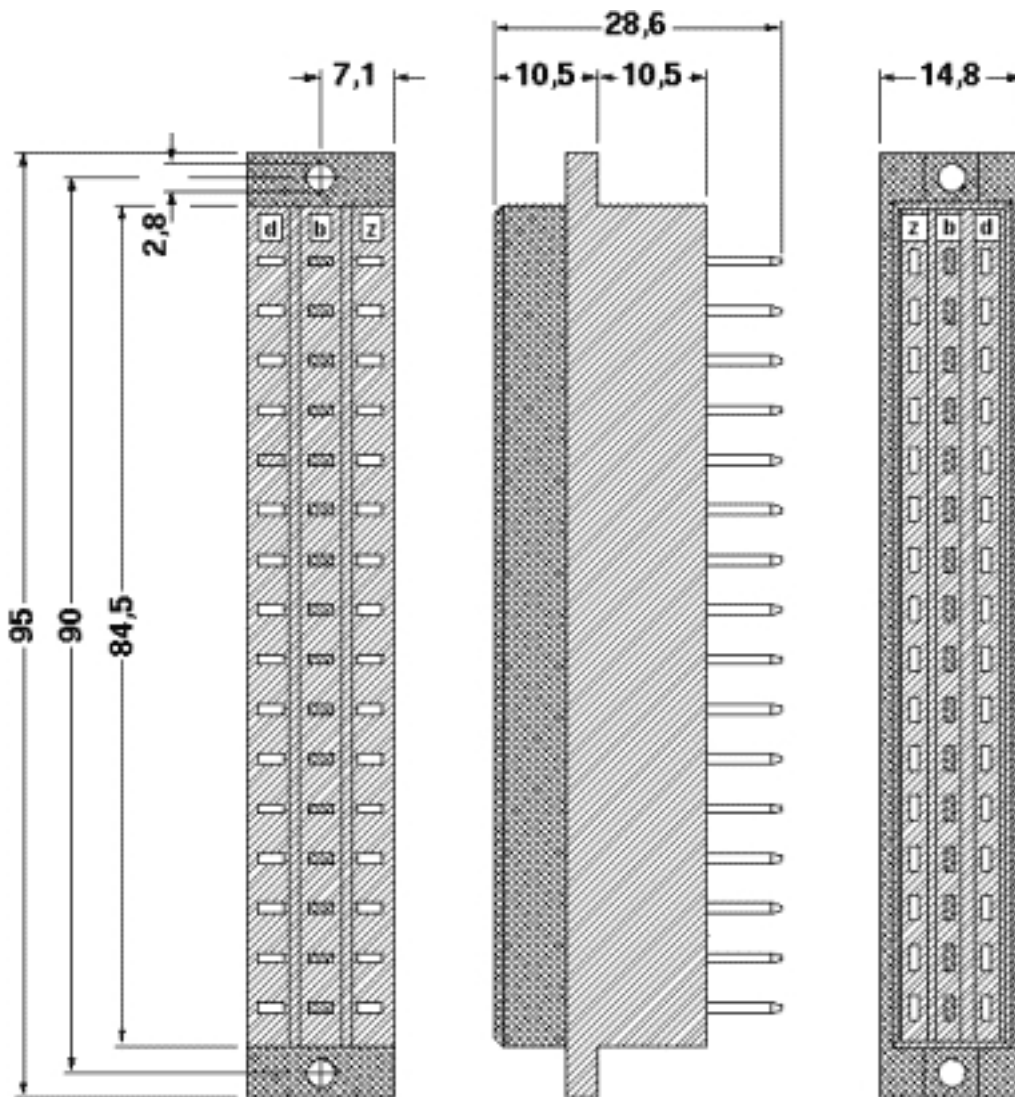

© Phoenix Contact 2013 - all rights reserved
<http://www.phoenixcontact.com>