

Interface module - UM 45-D15SUB/B/ZFKDS - 2293679

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://download.phoenixcontact.com>)



VARIOFACE module, with spring-cage connection and D-Subminiature socket strip, for mounting on NS 35/7.5, 15-pos.

The illustration shows version UM 45-D 37SUB/S/ZFKDS

Product Features

- ✓ 9 to 50-pos.
- ✓ Spring-cage connection technology
- ✓ According to IEC 60807-2
- ✓ 1:1 connection



Key commercial data

package_quantity	1
GTIN	4017918120573

Technical data

Dimensions

Width	65 mm
Height	45 mm
Depth	50 mm

Ambient conditions

Ambient temperature (operation)	-20 °C ... 50 °C
Ambient temperature (storage/transport)	-20 °C ... 70 °C

General

Nominal voltage U_N	125 V AC/DC
Max. current carrying capacity per branch	2.5 A
Max. current carrying capacity per branch	1.5 A (with even load on all branches)
Number of positions	15
Status display	No
Test voltage	800 V (50 Hz, 1 min.)
Mounting position	Any
Standards/regulations	IEC 60664

Interface module - UM 45-D15SUB/B/ZFKDS - 2293679

Technical data

General

Standards/regulations	DIN EN 50178
Standards/regulations	IEC 62103
Pollution degree	2
Surge voltage category	II
Rated surge voltage	1.2 kV
Rated insulation voltage	125 V

Connection data for connection 1

Connection name	PCB connection
Connection in acc. with standard	IEC / EN
Connection method	Spring-cage connection
Conductor cross section solid min.	0.2 mm ²
Conductor cross section solid max.	2.5 mm ²
Conductor cross section stranded min.	0.2 mm ²
Conductor cross section stranded max.	1.5 mm ²
Conductor cross section AWG/kcmil min.	24
Conductor cross section AWG/kcmil max	14
Stripping length	8 mm

Connection data for connection 2

Connection name	D-SUB connection
Number of connections	1
Connection method	D-SUB socket strip
Number of positions	15

classifications

eCl@ss

eCl@ss 4.0	27250313
eCl@ss 4.1	27250313
eCl@ss 5.0	27250313
eCl@ss 5.1	27250313
eCl@ss 6.0	27242608
eCl@ss 7.0	27141152
eCl@ss 8.0	27141152

ETIM

ETIM 2.0	EC001434
ETIM 3.0	EC001604
ETIM 4.0	EC001604
ETIM 5.0	EC002780

UNSPSC

UNSPSC 6.01	30211824
-------------	----------

Interface module - UM 45-D15SUB/B/ZFKDS - 2293679

classifications

UNSPSC

UNSPSC 7.0901	39121421
UNSPSC 11	39121421
UNSPSC 12.01	39121421
UNSPSC 13.2	39121421

approvals

GOST /

Approval details



accessories

Screwdriver tools

SZF 0-0,4X2,5 - 1204504



System cable

CABLE-D15SUB/B/S/ 50/KONFEK/S - 2302052



CABLE-D15SUB/B/S/100/KONFEK/S - 2302065



Interface module - UM 45-D15SUB/B/ZFKDS - 2293679

accessories

CABLE-D15SUB/B/S/150/KONFEK/S - 2302078



CABLE-D15SUB/B/S/200/KONFEK/S - 2302081



CABLE-D15SUB/B/S/300/KONFEK/S - 2302094



CABLE-D15SUB/B/S/400/KONFEK/S - 2302104



CABLE-D15SUB/B/S/600/KONFEK/S - 2302117



CABLE D-SUB-S/.../.../... - 2302340



Interface module - UM 45-D15SUB/B/ZFKDS - 2293679

accessories

CABLE D-SUB-S-S/.../.../... - 2302434



CABLE-D-15SUB/M/OE/0,25/S/0,5M - 2926438



CABLE-D-15SUB/M/OE/0,25/S/1,0M - 2926441



CABLE-D-15SUB/M/OE/0,25/S/1,5M - 2926454



CABLE-D-15SUB/M/OE/0,25/S/2,0M - 2926467



Interface module - UM 45-D15SUB/B/ZFKDS - 2293679

accessories

CABLE-D-15SUB/M/OE/0,25/S/3,0M - 2926470



CABLE-D-15SUB/M/OE/0,25/S/4,0M - 2926483



CABLE-D-15SUB/M/OE/0,25/S/6,0M - 2926496




CABLE-D-15SUB-M-OE-0,25-S/... - 2900910



Drawings

Interface module - UM 45-D15SUB/B/ZFKDS - 2293679

Circuit diagram

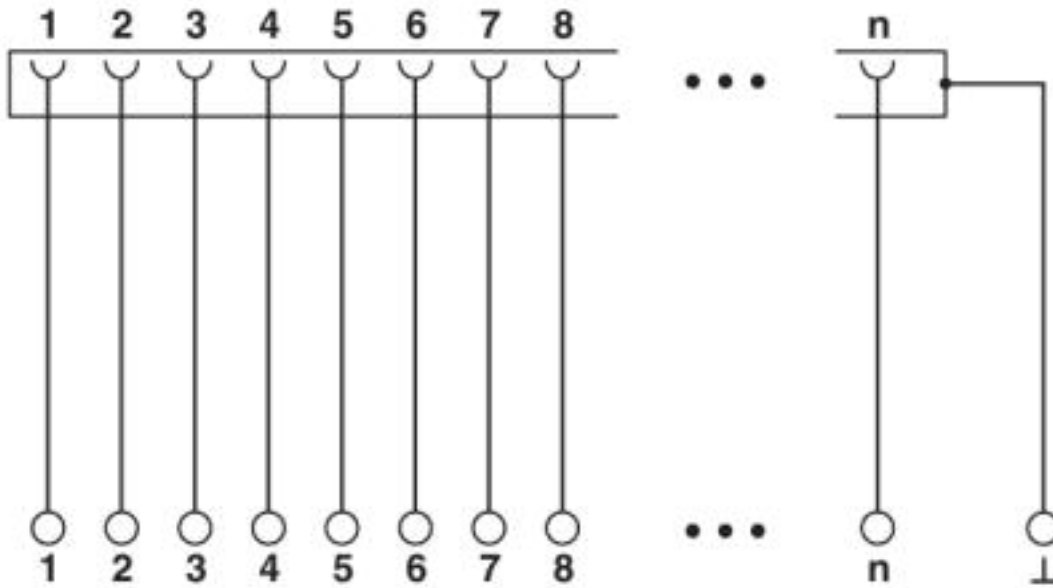

© Phoenix Contact 2013 - all rights reserved
<http://www.phoenixcontact.com>