

Electronic housing - UM-BEFE 35 - 2955564

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://download.phoenixcontact.com>)



Base element with snap-on foot, for mounting on NS 32 or NS 35/7.5 DIN rail, with ribs, L = 35 mm

The illustration shows a combination of versions UM-SE, UM 16,5 BE, UM-BE 35, UM-BEFE 35, UM-SE-A 73 and UM-A/U 73 CM

Key commercial data

package_quantity	10
GTIN	4017918085537

Technical data

General

Housing material	Polyamide
Color	green

Ambient conditions

Ambient temperature (operation)	-40 °C ... 105 °C
--	-------------------

Dimensions

Width	35 mm
--------------	-------

Technical data

Inflammability class according to UL 94	V0
--	----

classifications

eCl@ss

eCl@ss 4.0	27180401
eCl@ss 4.1	27180401
eCl@ss 5.0	27180506
eCl@ss 5.1	27180506
eCl@ss 6.0	27180802
eCl@ss 7.0	27182701
eCl@ss 8.0	27182701

ETIM

Electronic housing - UM-BEFE 35 - 2955564

classifications

ETIM

ETIM 2.0	EC001031
ETIM 3.0	EC001031
ETIM 4.0	EC001031
ETIM 5.0	EC000721


UNSPSC

UNSPSC 6.01	31261501
UNSPSC 7.0901	31261501
UNSPSC 11	31261501
UNSPSC 12.01	31261501
UNSPSC 13.2	31261501

approvals

UL Recognized /

 
Approval details



Drawings

Electronic housing - UM-BEFE 35 - 2955564

Dimensioned drawing

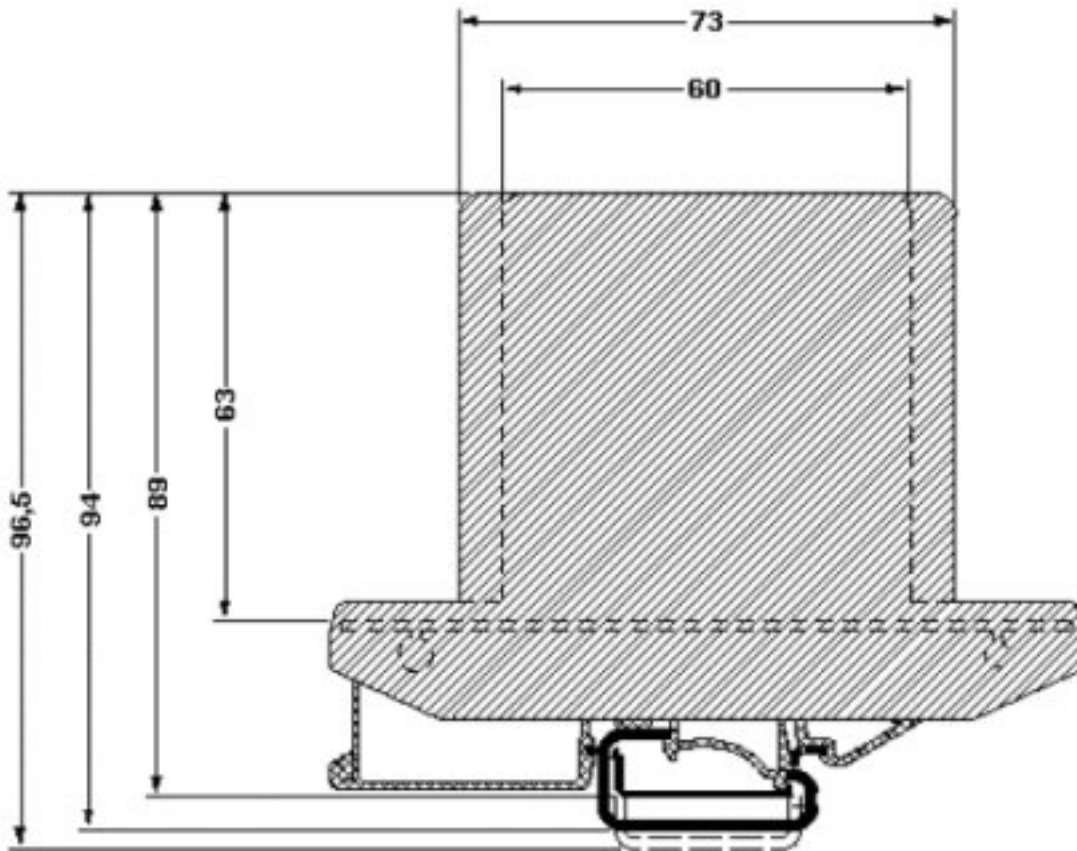

Electronic housing - UM-BEFE 35 - 2955564

Dimensioned drawing

