

Knife disconnect terminal block - ST 2,5-TWIN-MT/1P - 3040766

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://download.phoenixcontact.com>)



Knife disconnect terminal block, Connection type: Spring-cage/plug-in connection, Cross section: 0.08 mm² - 4 mm², AWG: 28 - 12, Nominal current: 20 A, Nominal voltage: 400 V, Length: 81 mm, Width: 5.2 mm, Color: gray, Assembly: NS 35/7,5, NS 35/15

Product Features

- ✓ Design width of just 5.2 mm
- ✓ Tested for railway applications

Key commercial data

package_quantity	50
GTIN	4017918907310

Technical data

General

Number of levels	1
Number of connections	2
Color	gray
Insulating material	PA
Inflammability class according to UL 94	V0
Area of application	Railway industry
Area of application	Mechanical engineering
Area of application	Plant engineering

General

Maximum load current	16 A (with 4 mm ² conductor cross section)
Rated surge voltage	6 kV
Pollution degree	3
Surge voltage category	III
Insulating material group	I
Connection in acc. with standard	IEC 61984
Nominal current I _N	20 A
Nominal voltage U _N	400 V
Open side panel	ja

Dimensions

Width	5.2 mm
-------	--------

Knife disconnect terminal block - ST 2,5-TWIN-MT/1P - 3040766

Technical data

Dimensions

Length	81 mm
Height NS 35/7,5	36.5 mm
Height NS 35/15	44 mm

Connection data

Conductor cross section solid min.	0.08 mm ²
Conductor cross section solid max.	4 mm ²
Conductor cross section stranded min.	0.08 mm ²
Conductor cross section stranded max.	2.5 mm ²
Conductor cross section AWG/kcmil min.	28
Conductor cross section AWG/kcmil max	12
Conductor cross section stranded, with ferrule without plastic sleeve min.	0.14 mm ²
Conductor cross section stranded, with ferrule without plastic sleeve max.	2.5 mm ²
Conductor cross section stranded, with ferrule with plastic sleeve min.	0.14 mm ²
Conductor cross section stranded, with ferrule with plastic sleeve max.	2.5 mm ²
2 conductors with same cross section, stranded, TWIN ferrules with plastic sleeve, max.	0.5 mm ²
Connection method	Spring-cage/plug-in connection
Minimum stripping length	8 mm
Maximum stripping length	10 mm
Internal cylindrical gage	A3

classifications

eCl@ss

eCl@ss 4.0	27141117
eCl@ss 4.1	27141117
eCl@ss 5.0	27141120
eCl@ss 5.1	27141120
eCl@ss 6.0	27141120
eCl@ss 7.0	27141120
eCl@ss 8.0	27141120

ETIM

ETIM 2.0	EC000902
ETIM 3.0	EC000902
ETIM 4.0	EC000902
ETIM 5.0	EC000902

UNSPSC

UNSPSC 6.01	30211811
-------------	----------

Knife disconnect terminal block - ST 2,5-TWIN-MT/1P - 3040766

classifications

UNSPSC

UNSPSC 7.0901	39121410
UNSPSC 11	39121410
UNSPSC 12.01	39121410
UNSPSC 13.2	39121410

approvals

CSA / UL Recognized / cUL Recognized / LR / GL / BV / DNV / RS / GOST / GOST / cULus Recognized /

Approval details

CSA 	
Usegroups	B
Nominal voltage UN	300 V
Nominal current IN	20 A
mm²/AWG/kcmil	28-12

UL Recognized 			
Usegroups	B	C	D
Nominal voltage UN	300 V	300 V	600 V
Nominal current IN	20 A	20 A	5 A
mm²/AWG/kcmil	28-12	28-12	28-12

cUL Recognized 			
Usegroups	B	C	D
Nominal voltage UN	300 V	300 V	600 V
Nominal current IN	20 A	20 A	5 A
mm²/AWG/kcmil	28-12	28-12	28-12

LR

GL

BV

Knife disconnect terminal block - ST 2,5-TWIN-MT/1P - 3040766

approvals

DNV

RS

GOST 



cULus Recognized  US

accessories

End cover

D-ST 2,5-QUATTRO/ 2P - 3040083



DP PS-5 - 3036725



Partition plate

ATP-ST QUATTRO - 3030815



Knife disconnect terminal block - ST 2,5-TWIN-MT/1P - 3040766

accessories

Coding element

PC - 3040588



Screwdriver tools

SZF 1-0,6X3,5 - 1204517



Documentation

ST-IL - 3039900



Bridge

FBS 2-5 - 3030161



FBS 3-5 - 3030174



Knife disconnect terminal block - ST 2,5-TWIN-MT/1P - 3040766

accessories

FBS 4-5 - 3030187



FBS 5-5 - 3030190



FBS 10-5 - 3030213



FBS 20-5 - 3030226



FBS 50-5 - 3038930



Knife disconnect terminal block - ST 2,5-TWIN-MT/1P - 3040766

accessories

FBS 2-5 BU - 3036877



FBS 3-5 BU - 3036880



FBS 4-5 BU - 3036893



FBS 5-5 BU - 3036903



FBS 10-5 BU - 3036916



FBS 20-5 BU - 3036929



Knife disconnect terminal block - ST 2,5-TWIN-MT/1P - 3040766

accessories

FBS 50-5 BU - 3032114



FBS 2-5 GY - 3038969



FBS 3-5 GY - 3038972



FBS 4-5 GY - 3038985



FBS 5-5 GY - 3038998



Knife disconnect terminal block - ST 2,5-TWIN-MT/1P - 3040766

accessories

FBS 10-5 GY - 3039007



FBS 20-5 GY - 3038671



FBS 50-5 GY - 3032127



Mounting rail

NS 35/ 7,5 PERF 2000MM - 0801733



NS 35/ 7,5 UNPERF 2000MM - 0801681



Knife disconnect terminal block - ST 2,5-TWIN-MT/1P - 3040766

accessories

NS 35/ 7,5 WH PERF 2000MM - 1204119



NS 35/ 7,5 WH UNPERF 2000MM - 1204122



NS 35/ 7,5 AL UNPERF 2000MM - 0801704



NS 35/ 7,5 ZN PERF 2000MM - 1206421



NS 35/ 7,5 ZN UNPERF 2000MM - 1206434



NS 35/ 7,5 CU UNPERF 2000MM - 0801762



Knife disconnect terminal block - ST 2,5-TWIN-MT/1P - 3040766

accessories

NS 35/ 7,5 CAP - 1206560



Terminal marking

ZB 5 :UNBEDRUCKT - 1050004



UC-TM 5 - 0818108



UCT-TM 5 - 0828734



ZBF 5:UNBEDRUCKT - 0808642



Knife disconnect terminal block - ST 2,5-TWIN-MT/1P - 3040766

accessories

UC-TMF 5 - 0818153



UCT-TMF 5 - 0828744



Labeled terminal marker

ZB 5 CUS - 0824962



UC-TM 5 CUS - 0824581



UCT-TM 5 CUS - 0829595



Knife disconnect terminal block - ST 2,5-TWIN-MT/1P - 3040766

accessories

ZBF 5 CUS - 0825025



UC-TMF 5 CUS - 0824638



UCT-TMF 5 CUS - 0829658



Insulating sleeve

ISH 2,5/0,2 - 3002843



ISH 2,5/0,5 - 3002856



Knife disconnect terminal block - ST 2,5-TWIN-MT/1P - 3040766

accessories

ISH 2,5/1,0 - 3002869



Test plug terminal block

PAI-4-FIX-5/6 BU - 3035975



PAI-4-FIX-5/6 OG - 3035974



PAI-4-FIX-5/6 YE - 3035977



PAI-4-FIX-5/6 RD - 3035976



Knife disconnect terminal block - ST 2,5-TWIN-MT/1P - 3040766

accessories

PAI-4-FIX-5/6 GN - 3035978



PAI-4-FIX-5/6 BK - 3035980



PAI-4-FIX-5/6 GY - 3035982



PAI-4-FIX-5/6 VT - 3035979



PAI-4-FIX-5/6 BN - 3035981



PS-5 - 3030983



Knife disconnect terminal block - ST 2,5-TWIN-MT/1P - 3040766

accessories

PS-5/2,3MM RD - 3038723



Knife

P-DI - 3036783



P-DI GY - 3047390



P-FIX - 3038956



Component plug terminal block

P-CO - 3036796



Knife disconnect terminal block - ST 2,5-TWIN-MT/1P - 3040766

accessories

P-CO 1N4007/R-L - 3032457




P-CO 1N4007/L-R - 3032460



Drawings


Diagram

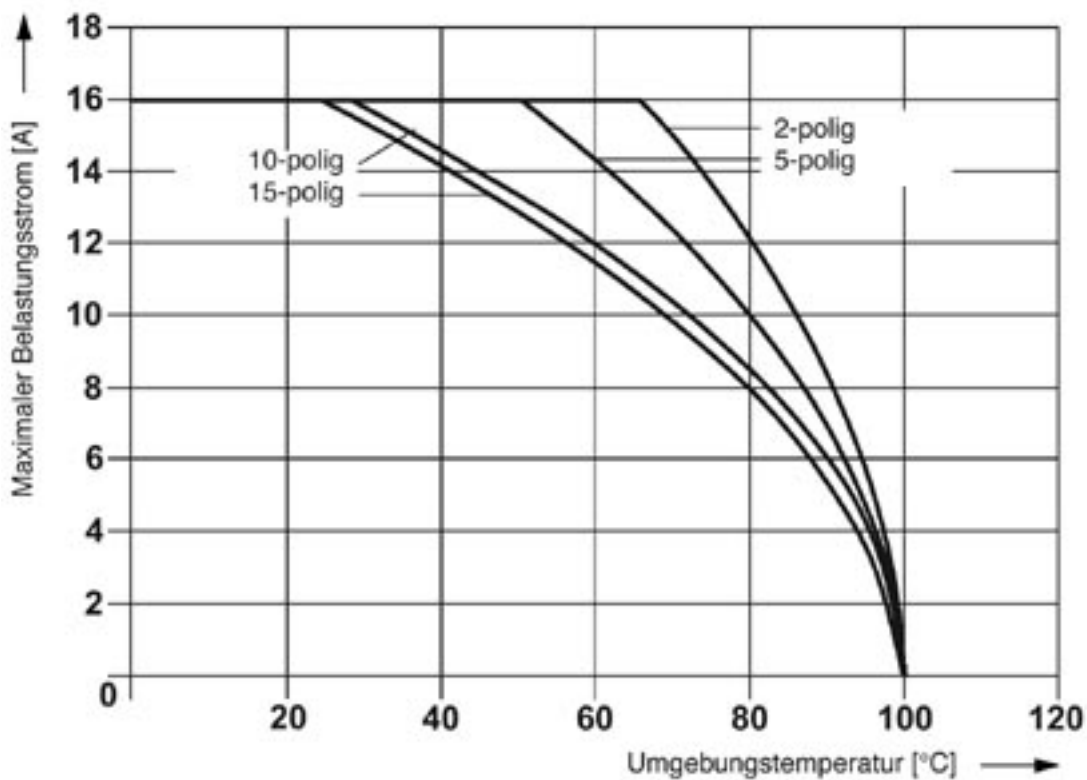

Applies to all male connector variants SP...

Knife disconnect terminal block - ST 2,5-TWIN-MT/1P - 3040766

Circuit diagram

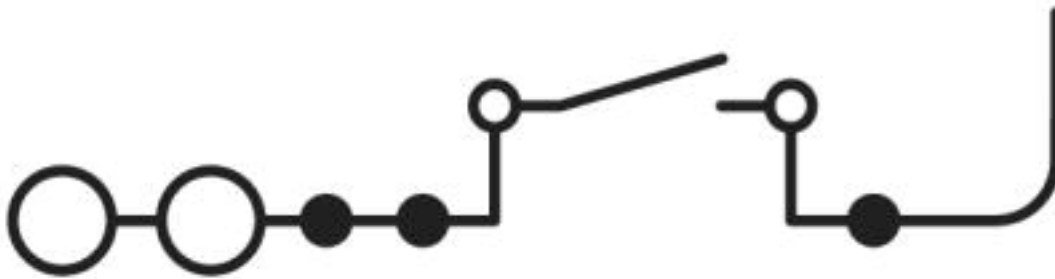

© Phoenix Contact 2013 - all rights reserved
<http://www.phoenixcontact.com>