

Multi-level terminal block - ST 2,5-4L/2P-Z - 3041998

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://download.phoenixcontact.com>)



Multi-level terminal block, Connection method: Spring-cage/plug-in connection, Cross section: 0.08 mm² - 4 mm², AWG: 28 - 12, Width: 5.2 mm, Color: gray, Mounting type: NS 35/7,5, NS 35/15

The illustration shows the version without engagement pin

Product Features

- ☒ Can be labeled at each terminal point
- ☒ Design width of just 5.2 mm
- ☒ Four feed-through levels

Key commercial data

package_quantity	50
GTIN	4017918980535

Technical data

General

Number of levels	4
Number of connections	6
Color	gray
Insulating material	PA
Inflammability class according to UL 94	V0

General

Rated surge voltage	4 kV
Pollution degree	3
Surge voltage category	III
Insulating material group	I
Connection in acc. with standard	IEC 61984
Nominal current I _N	24 A
Nominal voltage U _N	500 V
Open side panel	ja

Dimensions

Width	5.2 mm
Length	120.5 mm
Height NS 35/7,5	59 mm

Multi-level terminal block - ST 2,5-4L/2P-Z - 3041998

Technical data

Dimensions

Height NS 35/15	66.5 mm
------------------------	---------

Connection data

Conductor cross section solid min.	0.08 mm ²
Conductor cross section solid max.	4 mm ²
Conductor cross section stranded min.	0.08 mm ²
Conductor cross section stranded max.	2.5 mm ²
Conductor cross section AWG/kcmil min.	28
Conductor cross section AWG/kcmil max	12
Conductor cross section stranded, with ferrule without plastic sleeve min.	0.14 mm ²
Conductor cross section stranded, with ferrule without plastic sleeve max.	2.5 mm ²
Conductor cross section stranded, with ferrule with plastic sleeve min.	0.14 mm ²
Conductor cross section stranded, with ferrule with plastic sleeve max.	2.5 mm ²
2 conductors with same cross section, stranded, TWIN ferrules with plastic sleeve, max.	0.5 mm ²
Connection method	Spring-cage/plug-in connection
Minimum stripping length	8 mm
Maximum stripping length	10 mm
Internal cylindrical gage	A3

classifications

eCl@ss

eCl@ss 4.0	27141117
eCl@ss 4.1	27141117
eCl@ss 5.0	27141120
eCl@ss 5.1	27141120
eCl@ss 6.0	27141120
eCl@ss 7.0	27141120
eCl@ss 8.0	27141120

ETIM

ETIM 2.0	EC000897
ETIM 3.0	EC000897
ETIM 4.0	EC000897
ETIM 5.0	EC000897

UNSPSC

UNSPSC 6.01	30211811
UNSPSC 7.0901	39121410
UNSPSC 11	39121410

Multi-level terminal block - ST 2,5-4L/2P-Z - 3041998

classifications

UNSPSC

UNSPSC 12.01	39121410
UNSPSC 13.2	39121410

approvals

CSA / UL Recognized / cUL Recognized / GOST / GOST / cULus Recognized /

Approval details

CSA 	
Usegroups	B
Nominal voltage UN	300 V
Nominal current IN	10 A
mm²/AWG/kcmil	28-12

UL Recognized 		
Usegroups	B	D
Nominal voltage UN	300 V	300 V
Nominal current IN	10 A	10 A
mm²/AWG/kcmil	28-12	28-12

cUL Recognized 		
Usegroups	B	D
Nominal voltage UN	300 V	300 V
Nominal current IN	10 A	10 A
mm²/AWG/kcmil	28-12	28-12

GOST 	
---	--



Multi-level terminal block - ST 2,5-4L/2P-Z - 3041998

approvals

cULus Recognized  US

accessories

End cover

D-ST 2,5-4L/2P - 3041927



DP PS-5 - 3036725



Screwdriver tools

SZF 1-0,6X3,5 - 1204517



Bridge

FBS-PV PT 2,5-4L - 3012318



Multi-level terminal block - ST 2,5-4L/2P-Z - 3041998

accessories

FBS 2-5 - 3030161



FBS 3-5 - 3030174



FBS 4-5 - 3030187



FBS 5-5 - 3030190



FBS 10-5 - 3030213



FBS 20-5 - 3030226



Multi-level terminal block - ST 2,5-4L/2P-Z - 3041998

accessories

FBS 50-5 - 3038930



Flange

PT 2,5-4L/2P-FS - 3012312



Documentation

ST-IL - 3039900



Cable housing

PH CP-H 2,5/2 - 3012332



PH CP-H 2,5/3 - 3012333



Multi-level terminal block - ST 2,5-4L/2P-Z - 3041998

accessories

PH CP-H 2,5/4 - 3012334



PH CP-H 2,5/5 - 3012335



Cable tie

WT-HF 2,5X98 BK - 3240733



Mounting rail

NS 35/ 7,5 PERF 2000MM - 0801733



NS 35/ 7,5 UNPERF 2000MM - 0801681



Multi-level terminal block - ST 2,5-4L/2P-Z - 3041998

accessories

NS 35/ 7,5 WH PERF 2000MM - 1204119



NS 35/ 7,5 WH UNPERF 2000MM - 1204122



NS 35/ 7,5 AL UNPERF 2000MM - 0801704



NS 35/ 7,5 ZN PERF 2000MM - 1206421



NS 35/ 7,5 ZN UNPERF 2000MM - 1206434



NS 35/ 7,5 CU UNPERF 2000MM - 0801762



Multi-level terminal block - ST 2,5-4L/2P-Z - 3041998

accessories

NS 35/ 7,5 CAP - 1206560



NS 35/15 PERF 2000MM - 1201730



NS 35/15 UNPERF 2000MM - 1201714



NS 35/15 WH PERF 2000MM - 0806602



NS 35/15 WH UNPERF 2000MM - 1204135



Multi-level terminal block - ST 2,5-4L/2P-Z - 3041998

accessories

NS 35/15 AL UNPERF 2000MM - 1201756



NS 35/15 ZN PERF 2000MM - 1206599



NS 35/15 ZN UNPERF 2000MM - 1206586



NS 35/15 CU UNPERF 2000MM - 1201895



NS 35/15 CAP - 1206573



NS 35/15-2,3 UNPERF 2000MM - 1201798



Multi-level terminal block - ST 2,5-4L/2P-Z - 3041998

accessories

Terminal marking

ZB 5 :UNBEDRUCKT - 1050004



UC-TM 5 - 0818108



UCT-TM 5 - 0828734



ZBF 5:UNBEDRUCKT - 0808642



UC-TMF 5 - 0818153



Multi-level terminal block - ST 2,5-4L/2P-Z - 3041998

accessories

UCT-TMF 5 - 0828744



Labeled terminal marker

ZB 5 CUS - 0824962



UC-TM 5 CUS - 0824581



UCT-TM 5 CUS - 0829595



ZBF 5 CUS - 0825025



Multi-level terminal block - ST 2,5-4L/2P-Z - 3041998

accessories

UC-TMF 5 CUS - 0824638



UCT-TMF 5 CUS - 0829658



Test plug terminal block

MPS-MT - 0201744



PAI-4-FIX-5/6 BU - 3035975



PAI-4-FIX-5/6 OG - 3035974



Multi-level terminal block - ST 2,5-4L/2P-Z - 3041998

accessories

PAI-4-FIX-5/6 YE - 3035977



PAI-4-FIX-5/6 RD - 3035976



PAI-4-FIX-5/6 GN - 3035978



PAI-4-FIX-5/6 BK - 3035980



PAI-4-FIX-5/6 GY - 3035982



PAI-4-FIX-5/6 VT - 3035979



Multi-level terminal block - ST 2,5-4L/2P-Z - 3041998

accessories

PAI-4-FIX-5/6 BN - 3035981



PS-5 - 3030983



PS-5/2,3MM RD - 3038723



Insulating sleeve

MPS-IH WH - 0201663



MPS-IH RD - 0201676



Multi-level terminal block - ST 2,5-4L/2P-Z - 3041998

accessories

MPS-IH BU - 0201689



MPS-IH YE - 0201692



MPS-IH GN - 0201702



MPS-IH GY - 0201728



MPS-IH BK - 0201731



ISH 2,5/0,2 - 3002843



Multi-level terminal block - ST 2,5-4L/2P-Z - 3041998

accessories

ISH 2,5/0,5 - 3002856



ISH 2,5/1,0 - 3002869



Planning and marking software

CLIP-PROJECT ADVANCED - 5146040



CLIP-PROJECT PROFESSIONAL - 5146053



End block

CLIPFIX 35 - 3022218



Multi-level terminal block - ST 2,5-4L/2P-Z - 3041998

accessories

CLIPFIX 35-5 - 3022276




E/NS 35 N - 0800886




Drawings

Diagram

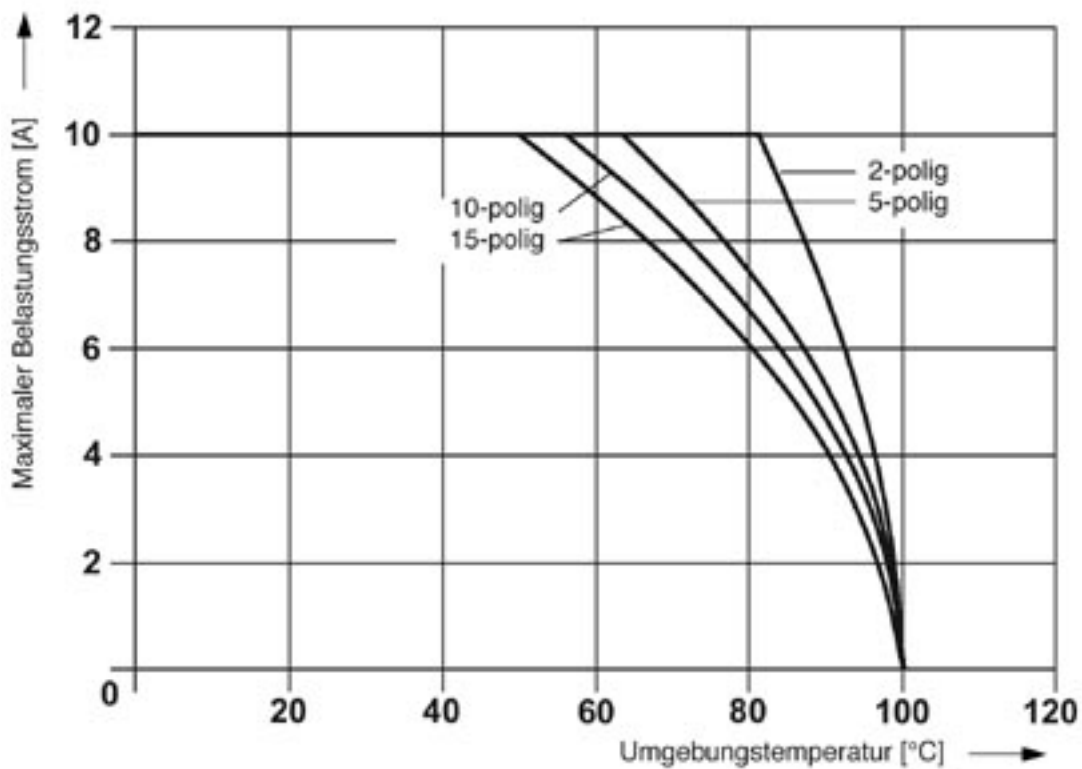

Multi-level terminal block - ST 2,5-4L/2P-Z - 3041998

Circuit diagram

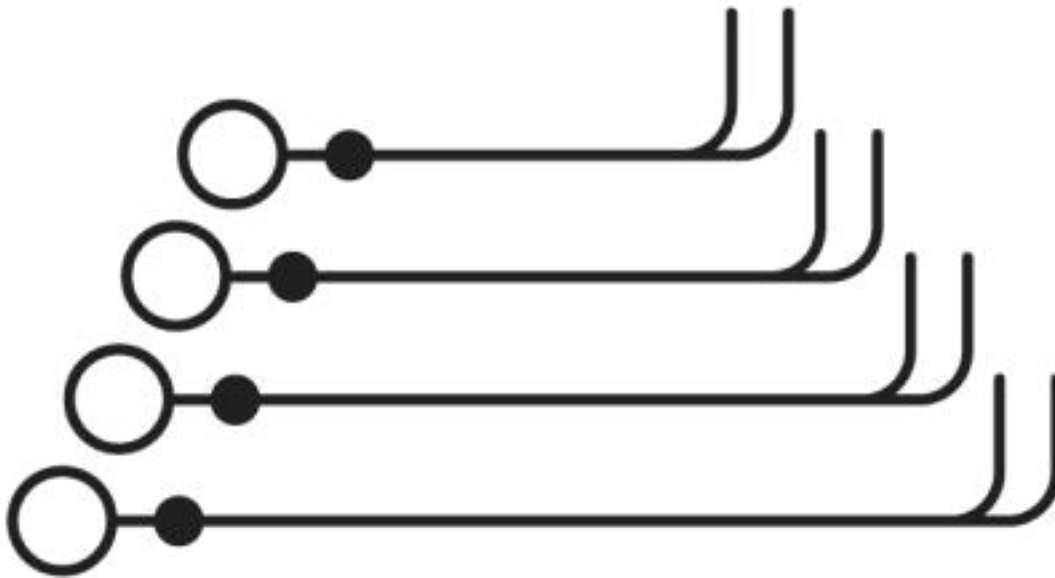

© Phoenix Contact 2013 - all rights reserved
<http://www.phoenixcontact.com>