

Protective conductor double-level terminal block - UTTB 2,5/2P-PE - 3060380

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://download.phoenixcontact.com>)



Protective conductor double-level terminal block, Cross section: 0.14 mm² - 4 mm², AWG: 26 - 12, Connection type: Screw/plug-in connection, Width: 5.2 mm, Color: green-yellow, Mounting type: NS 35/7,5, NS 35/15

Product Features

- ☒ Potential routing on two levels

Key commercial data

package_quantity	50
GTIN	4046356132190

Technical data

General

Number of levels	2
Number of connections	4
Color	green-yellow
Insulating material	PA
Inflammability class according to UL 94	V0

General

Maximum load current	22 A (with 4 mm ² conductor cross section)
Rated surge voltage	6 kV
Pollution degree	3
Surge voltage category	III
Insulating material group	I
Connection in acc. with standard	IEC 61984
Open side panel	ja

Dimensions

Width	5.2 mm
Length	74.3 mm
Height NS 35/7,5	65 mm
Height NS 35/15	72.5 mm
End cover width	2.2 mm

Connection data

Protective conductor double-level terminal block - UTTB 2,5/2P-PE - 3060380

Technical data

Connection data

Connection method	Screw/plug-in connection
Stripping length	9 mm
Internal cylindrical gage	A3
Tightening torque, min	0.5 Nm
Tightening torque max	0.6 Nm
Conductor cross section solid min.	0.14 mm ²
Conductor cross section solid max.	4 mm ²
Conductor cross section stranded min.	0.14 mm ²
Conductor cross section stranded max.	4 mm ²
Conductor cross section AWG/kcmil min.	26
Conductor cross section AWG/kcmil max	12
Conductor cross section stranded, with ferrule without plastic sleeve min.	0.14 mm ²
Value	0.14 mm ²
Conductor cross section stranded, with ferrule without plastic sleeve max.	2.5 mm ²
Value	2.5 mm ²
Conductor cross section stranded, with ferrule with plastic sleeve min.	0.14 mm ²
Value	0.14 mm ²
Conductor cross section stranded, with ferrule with plastic sleeve max.	2.5 mm ²
Value	2.5 mm ²
2 conductors with same cross section, solid min.	0.14 mm ²
2 conductors with same cross section, solid max.	1.5 mm ²
2 conductors with same cross section, stranded min.	0.14 mm ²
2 conductors with same cross section, stranded max.	1.5 mm ²
2 conductors with same cross section, stranded, ferrules without plastic sleeve, min.	0.14 mm ²
Value	0.14 mm ²
2 conductors with same cross section, stranded, ferrules without plastic sleeve, max.	1.5 mm ²
Value	1.5 mm ²
2 conductors with same cross section, stranded, TWIN ferrules with plastic sleeve, min.	0.5 mm ²
Value	0.5 mm ²
2 conductors with same cross section, stranded, TWIN ferrules with plastic sleeve, max.	1.5 mm ²
Value	1.5 mm ²

classifications

eCl@ss

Protective conductor double-level terminal block - UTTB 2,5/2P-PE - 3060380

classifications

eCl@ss

eCl@ss 4.0	27141118
eCl@ss 4.1	27141118
eCl@ss 5.0	27141118
eCl@ss 5.1	27141118
eCl@ss 6.0	27141141
eCl@ss 7.0	27141141
eCl@ss 8.0	27141141

ETIM

ETIM 2.0	EC000901
ETIM 3.0	EC000901
ETIM 4.0	EC000901
ETIM 5.0	EC000901

UNSPSC

UNSPSC 6.01	30211811
UNSPSC 7.0901	39121410
UNSPSC 11	39121410
UNSPSC 12.01	39121410
UNSPSC 13.2	39121410

approvals

GOST / GOST /

Approval details



accessories

Screwdriver tools

Protective conductor double-level terminal block - UTTB 2,5/2P-PE - 3060380

accessories

SZS 0,6X3,5 - 1205053



Marker pen

X-PEN 0,35 - 0811228



End cover

D-UTTB 2,5/4 2P - 3060393



DP PS-5 - 3036725



Partition plate

DP-UTTB 2,5/4 - 3047303



Protective conductor double-level terminal block - UTTB 2,5/2P-PE - 3060380

accessories

Partition plate

ATP-UTTB 2,5/4 - 3047316



Flange

UTTB 2,5/2P-F - 3060474



Coding element

PC - 3040588



Bridge

FBS 2-5 - 3030161



Protective conductor double-level terminal block - UTTB 2,5/2P-PE - 3060380

accessories

FBS 3-5 - 3030174



FBS 4-5 - 3030187



FBS 5-5 - 3030190



FBS 10-5 - 3030213



FBS 20-5 - 3030226



Protective conductor double-level terminal block - UTTB 2,5/2P-PE - 3060380

accessories

FBS 50-5 - 3038930



Mounting rail

NS 35/ 7,5 PERF 2000MM - 0801733



NS 35/ 7,5 UNPERF 2000MM - 0801681



NS 35/ 7,5 WH PERF 2000MM - 1204119



NS 35/ 7,5 WH UNPERF 2000MM - 1204122



Protective conductor double-level terminal block - UTTB 2,5/2P-PE - 3060380

accessories

NS 35/ 7,5 AL UNPERF 2000MM - 0801704



NS 35/ 7,5 ZN PERF 2000MM - 1206421



NS 35/ 7,5 ZN UNPERF 2000MM - 1206434



NS 35/ 7,5 CU UNPERF 2000MM - 0801762



NS 35/ 7,5 CAP - 1206560



Protective conductor double-level terminal block - UTTB 2,5/2P-PE - 3060380

accessories

NS 35/15 PERF 2000MM - 1201730



NS 35/15 UNPERF 2000MM - 1201714



NS 35/15 WH PERF 2000MM - 0806602



NS 35/15 WH UNPERF 2000MM - 1204135



NS 35/15 AL UNPERF 2000MM - 1201756



Protective conductor double-level terminal block - UTTB 2,5/2P-PE - 3060380

accessories

NS 35/15 ZN PERF 2000MM - 1206599



NS 35/15 ZN UNPERF 2000MM - 1206586



NS 35/15 CU UNPERF 2000MM - 1201895



NS 35/15 CAP - 1206573



NS 35/15-2,3 UNPERF 2000MM - 1201798



Terminal marking

Protective conductor double-level terminal block - UTTB 2,5/2P-PE - 3060380

accessories

ZB 5 :UNBEDRUCKT - 1050004



UC-TM 5 - 0818108



UCT-TM 5 - 0828734



Labeled terminal marker

ZB 5 CUS - 0824962



UC-TM 5 CUS - 0824581



Protective conductor double-level terminal block - UTTB 2,5/2P-PE - 3060380

accessories

UCT-TM 5 CUS - 0829595



Test plug terminal block

MPS-MT - 0201744



PAI-4-FIX-5/6 BU - 3035975



PAI-4-FIX-5/6 OG - 3035974



PAI-4-FIX-5/6 YE - 3035977



Protective conductor double-level terminal block - UTTB 2,5/2P-PE - 3060380

accessories

PAI-4-FIX-5/6 RD - 3035976



PAI-4-FIX-5/6 GN - 3035978



PAI-4-FIX-5/6 BK - 3035980



PAI-4-FIX-5/6 GY - 3035982



PAI-4-FIX-5/6 VT - 3035979



Protective conductor double-level terminal block - UTTB 2,5/2P-PE - 3060380

accessories

PAI-4-FIX-5/6 BN - 3035981



PS-5 - 3030983



PS-5/2,3MM RD - 3038723



Insulating sleeve

MPS-IH WH - 0201663



MPS-IH RD - 0201676



Protective conductor double-level terminal block - UTTB 2,5/2P-PE - 3060380

accessories

MPS-IH BU - 0201689



MPS-IH YE - 0201692



MPS-IH GN - 0201702



MPS-IH GY - 0201728



MPS-IH BK - 0201731



End block

Protective conductor double-level terminal block - UTTB 2,5/2P-PE - 3060380

accessories

CLIPFIX 35 - 3022218



CLIPFIX 35-5 - 3022276




E/NS 35 N - 0800886



Drawings

Protective conductor double-level terminal block - UTTB 2,5/2P-PE - 3060380

Circuit diagram

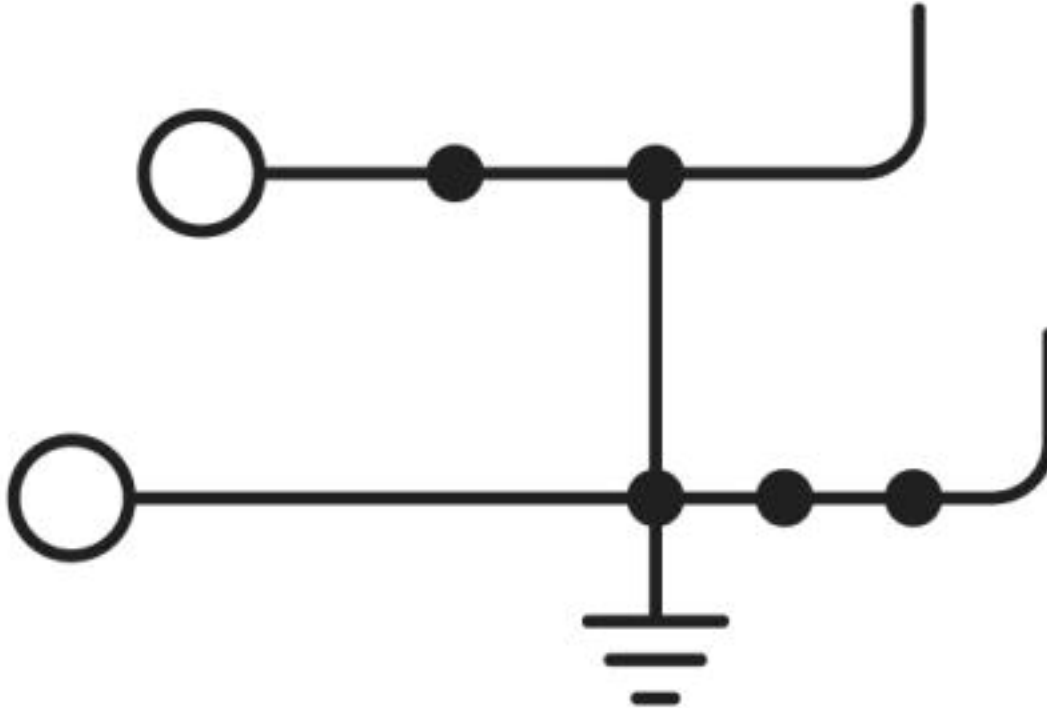

© Phoenix Contact 2013 - all rights reserved
<http://www.phoenixcontact.com>