

SEMI-CONDUCTOR CONTACTOR 3RF2 AC 51 10 A
40 DEGREES C 48-460 V / 24 V DC SCREW
TERMINAL



Main circuit:		
Operating current		
	• at AC-1 at 400 V Rated value	A 10.5
	• at AC-51 Rated value	A 10.5
Operating current minimum	mA	101
Rate of voltage rise at the thyristor for main contacts maximum permissible	V/μs	1 000
I2t value maximum	A²·s	200

Certificates/ approvals:

General Product Approval			EMC	Declaration of Conformity	Test Certificates
					Typprüfbescheinigung/Werkszeugnis
CSA	UL		C-TICK	EG-Konf.	

Test Certificates	other
spezielle Prüfbescheinigungen	Umweltbestätigung

Further information

Short-circuit protection, design of the fuse link

https://www.automation.siemens.com/cd-static/material/info/3RF23_eng.pdf

Information- and Downloadcenter (Catalogs, Brochures,...)

<http://www.siemens.com/industrial-controls/catalogs>

Industry Mall (Online ordering system)

<http://www.siemens.com/industrymall>

Cax online generator



<http://support.automation.siemens.com/WW/CAXorder/default.aspx?lang=en&mlfb=3RF23101AA040KN0>

Service&Support (Manuals, Certificates, Characteristics, FAQs,...)

<https://support.industry.siemens.com/cs/ww/en/ps/3RF23101AA040KN0>

Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, EPLAN macros, ...)

http://www.automation.siemens.com/bilddb/cax_de.aspx?mlfb=3RF23101AA040KN0&lang=en

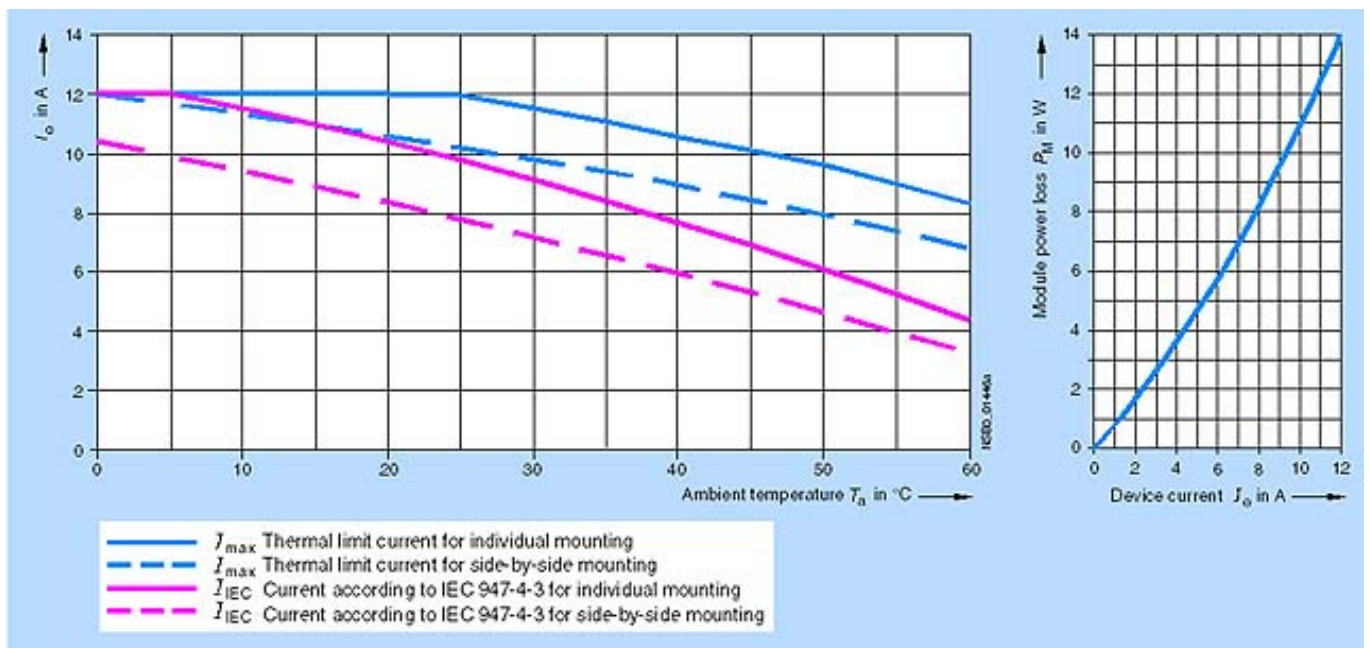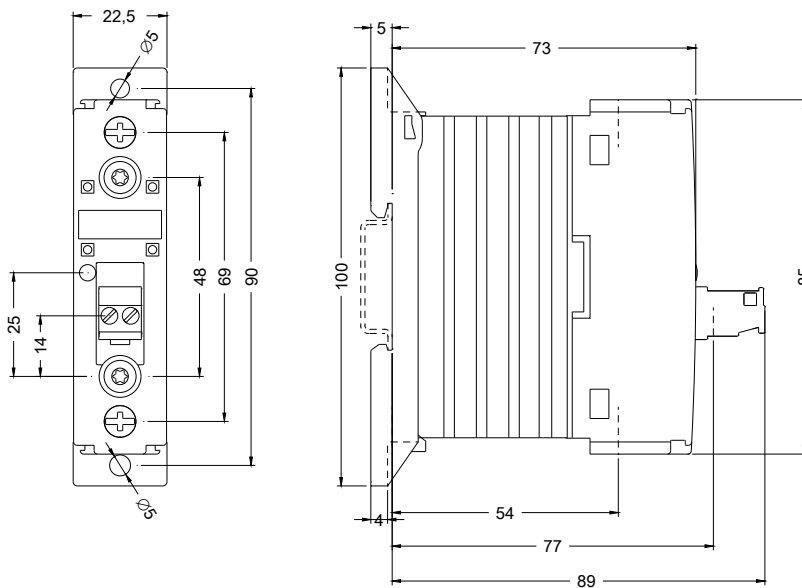

last modified:

17.07.2015