



SURGE SUPPRESSOR, DIODE COMBINATION, DC 24 V, FOR MOTOR CONTACTORS SZ S0,

General technical data:		
product brand name		SIRIUS
Product designation		surge suppressor
Size of contactor		S0
Design of the surge suppressor		with diode assemblies
Ambient temperature		
• during storage	°C	-40 ... +80
• during operation	°C	-25 ... +60
Control circuit/ Control:		
Type of voltage of the control supply voltage		DC
Control supply voltage 1		
• for DC		
— Rated value	V	24
Installation/ mounting/ dimensions:		
mounting position		any
Mounting type		clip-on
Width	mm	30
Height	mm	19
Depth	mm	12
Certificates/ approvals:		
Certificate of suitability		CE / UL / CSA / CCC

General Product Approval	Declaration of Conformity	Test Certificates	Shipping Approval
--------------------------	---------------------------	-------------------	-------------------



[Special Test Certificate](#)



### Shipping Approval



### other

[Confirmation](#)

[Environmental Confirmations](#)



### Further information



**Information- and Downloadcenter (Catalogs, Brochures,...)**  
<http://www.siemens.com/industrial-controls/catalogs>

**Industry Mall (Online ordering system)**  
<http://www.siemens.com/industrymall>

**Cax online generator**  
<http://support.automation.siemens.com/WW/CAXorder/default.aspx?lang=en&mlfb=3RT29261ER00>

**Service&Support (Manuals, Certificates, Characteristics, FAQs,...)**  
<https://support.industry.siemens.com/cs/ww/en/ps/3RT29261ER00>

**Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, EPLAN macros, ...)**  
[http://www.automation.siemens.com/bilddb/cax\\_de.aspx?mlfb=3RT29261ER00&lang=en](http://www.automation.siemens.com/bilddb/cax_de.aspx?mlfb=3RT29261ER00&lang=en)

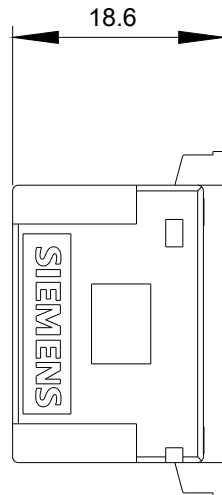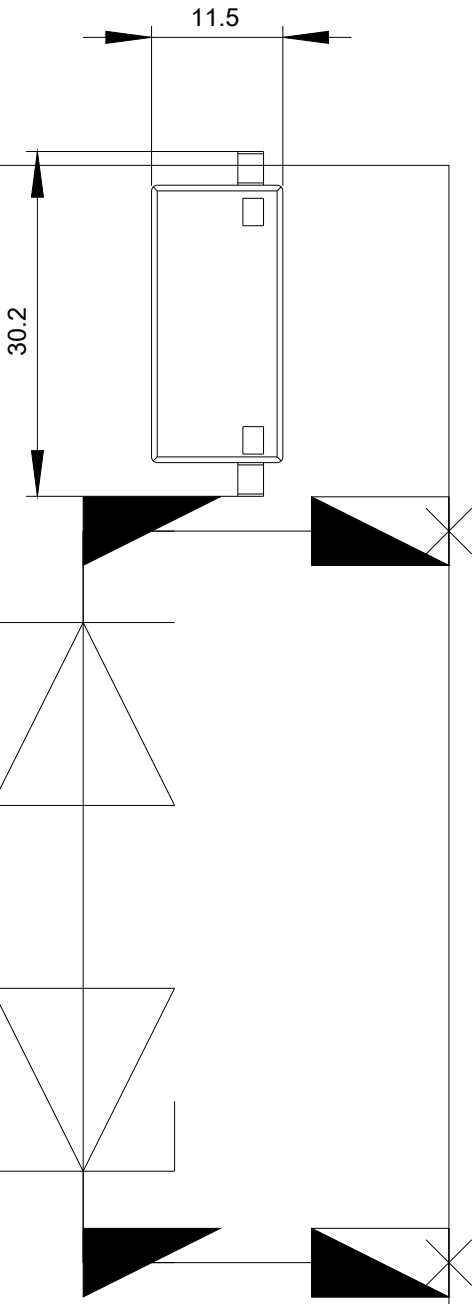

last modified:

27.04.2015