



Data sheet | Item number: 2003-499

Test plug adapter N/L; for 2003-6641 and 2003-6640 Multilevel Installation
Terminal Blocks; for vertical test slot; 2-pole

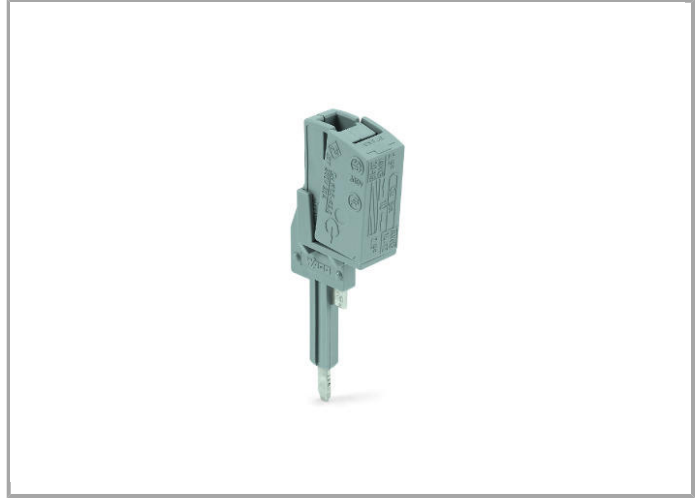


www.wago.com/2003-499



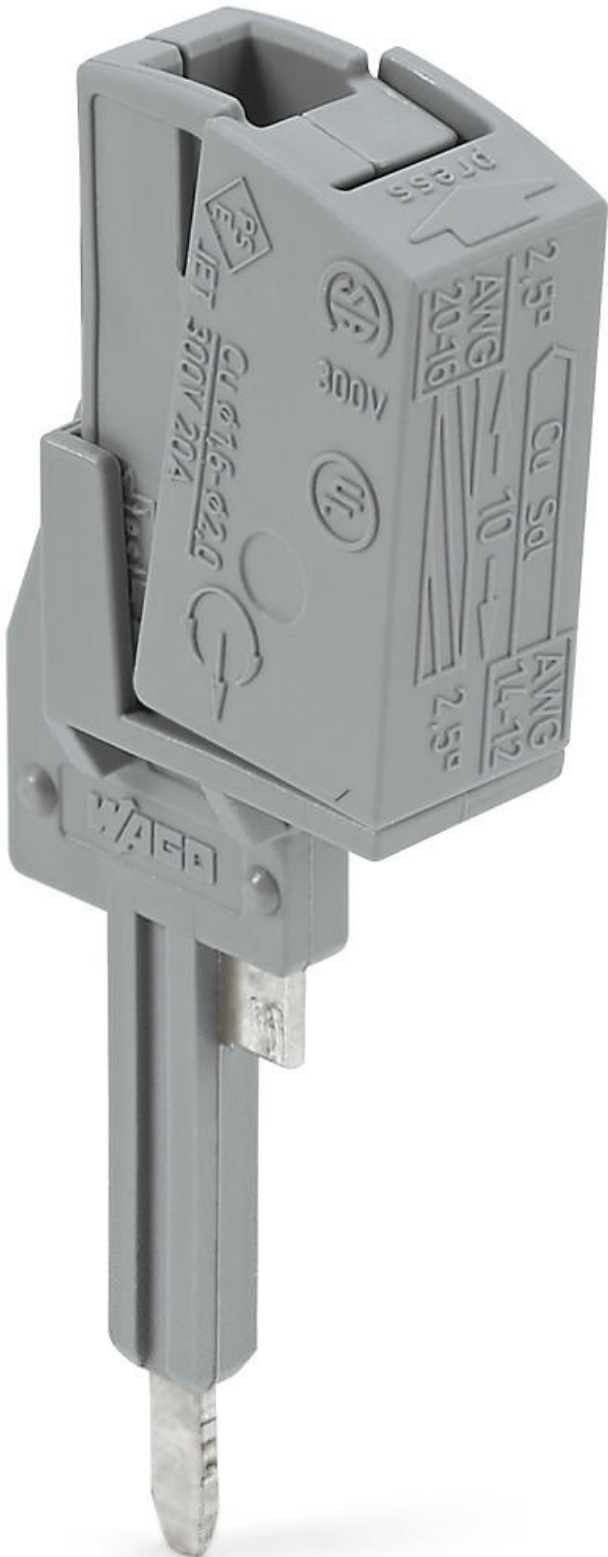

RoHS 
Compliant

BOMcheck.net

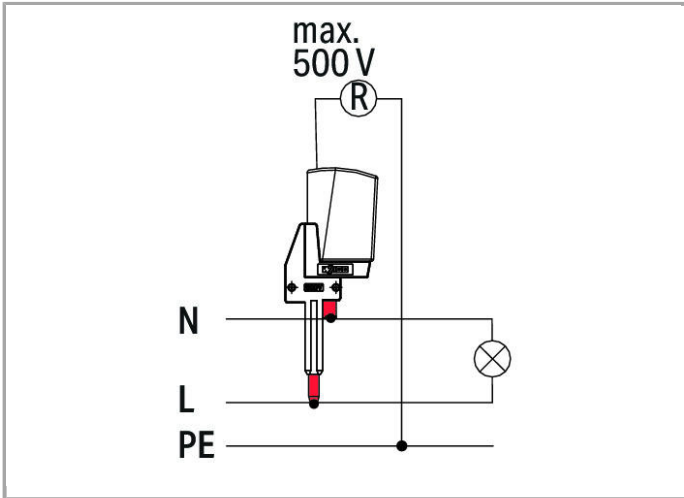Color: **Data****Electrical data****Ratings per IEC/EN 60664-1**

Rated voltage (III / 3)	500 V
Rated impulse voltage (III / 3)	6 kV
Rated current	16 A

Connection data

Connection technology	CAGE CLAMP®
Solid conductor	0.5 ... 2.5 mm ² / 20 ... 16 AWG
Stranded conductor	0.5 ... 1.5 mm ² / 20 ... 16 AWG
Fine-stranded conductor	0.5 ... 2.5 mm ² / 20 ... 16 AWG
Strip length	9 ... 11 mm / 0.35 ... 0.43 Inch
Total number of connection points	1
Total number of potentials	1
Type of wiring	Side-entry wiring

Material Data

Color	gray
Fire load	0.065 MJ
Weight	3.328 g



Commercial data

Country of origin	DE
GTIN	4050821322115
Customs Tariff No.	85366990990
Product Group	22 (TOPJOB S)

Downloads

Documentation

Bid Text

2003-499	Oct 26, 2017	DOC 24.1 kB	Download
----------	--------------	----------------	----------

Subject to changes.