


Data sheet | Item number: 2004-435

Push-in type jumper bar; insulated; from 1 to 5; Nominal current 32 A

[www.wago.com/2004-435](http://www.wago.com/2004-435)

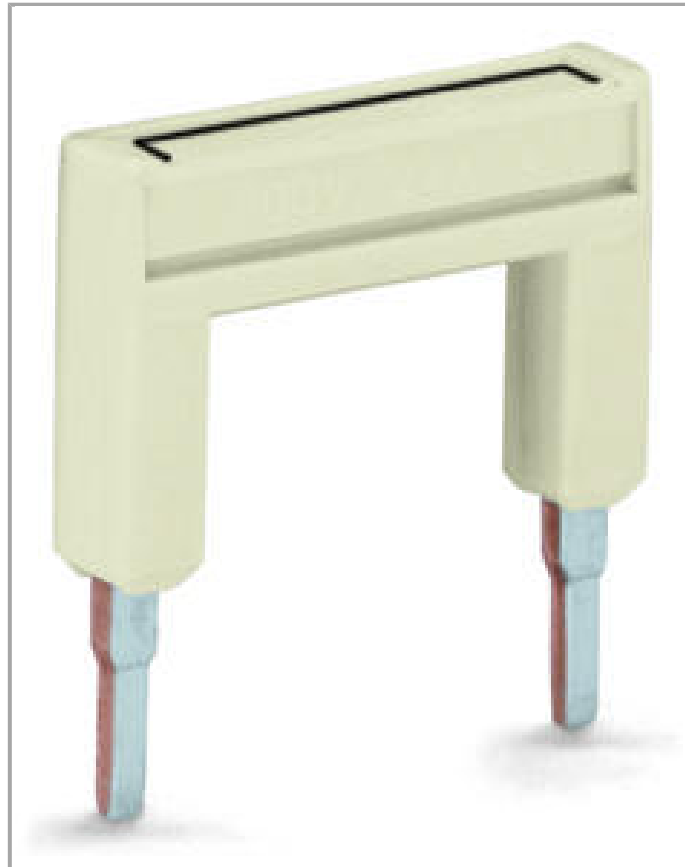

RoHS  Compliant

[BOMcheck.net](https://www.bomcheck.net)

Color:

## Data

### Electrical data

Rated current (Ex e II)	30 A
-------------------------	------

### Ratings per IEC/EN 60664-1

Rated voltage (III / 3)	800 V
-------------------------	-------

Rated current	32 A
---------------	------

### Geometrical Data

Width	29 mm / 1.142 inch
-------	--------------------



Height	19 mm / 0.748 inch
Depth	4.1 mm / 0.161 inch

**Material Data**

Color	light gray
Fire load	0.015 MJ
Weight	2.452 g

**Commercial data**

Country of origin	DE
GTIN	4044918583091
Customs Tariff No.	85366990990
Product Group	22 (TOPJOB S)

**Downloads****Documentation****Bid Text**

2004-435	Oct 26, 2017	DOC 24.1 kB	Download
----------	--------------	----------------	----------

**smartDATA****CAD data**

3D Download 2004-435	URL	Download
----------------------	-----	----------

**Product family****TOPJOB® S**

TOPJOB® S: In various industrial applications and modern building installations, WAGO's wide and versatile range of rail-mount terminal blocks provides more than just reliable electrical connections.

[Learn more about the product family.](#)

[Show all products from the family](#)

Subject to changes.