



## Data sheet | Item number: 2020-1201

1-conductor/1-pin carrier terminal block; for DIN-rail 35 x 15 and 35 x 7.5;  
Push-in CAGE CLAMP®

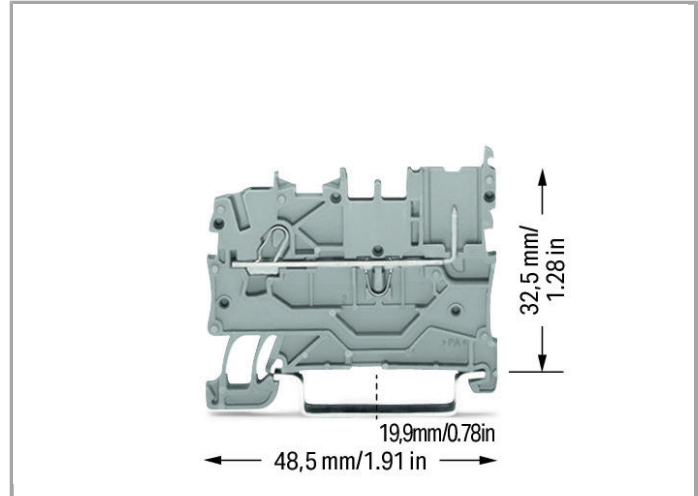

[www.wago.com/2020-1201](http://www.wago.com/2020-1201)

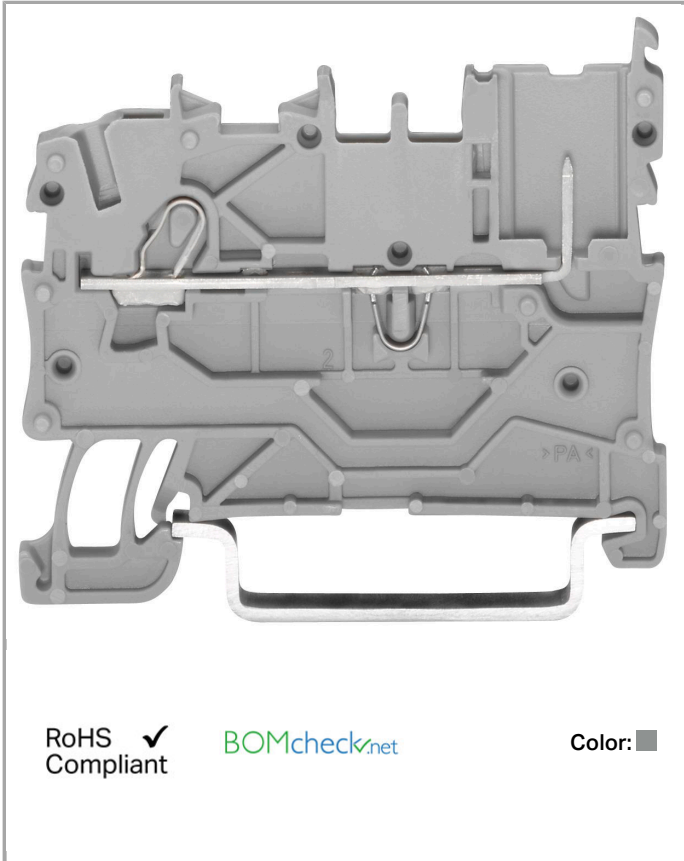

RoHS  
Compliant ✓

[BOMcheck.net](http://BOMcheck.net)

Color: ■

### Data

#### Electrical data

#### Ratings per IEC/EN 60664-1

Rated voltage (III / 3)	500 V
Rated impulse voltage (III / 3)	6 kV
Rated current	13.5 A
Legend (ratings)	(III / 3) ≙ Overvoltage category III / Pollution degree 3

#### Approvals per UL 1059

Rated voltage UL (Use Group B)	300 V
Rated current UL (Use Group B)	15 A
Rated voltage UL (Use Group C)	300 V
Rated current UL (Use Group C)	15 A
Rated voltage UL (Use Group D)	300 V



Rated current UL (Use Group D)	15 A
--------------------------------	------

### Approvals per CSA

Rated voltage CSA (Use Group B)	300 V
Rated current CSA (Use Group B)	10 A
Rated voltage CSA (Use Group C)	300 V
Rated current CSA (Use Group C)	10 A

### Connection data

Connection technology	Push-in CAGE CLAMP®
Actuation type	Operating tool Push-in
Connectable conductor materials	Copper Aluminum
Nominal cross section	1 mm <sup>2</sup>
Solid conductor	0.14 ... 1.5 mm <sup>2</sup> / 24 ... 16 AWG
Solid conductor, push-in termination	0.5 ... 1.5 mm <sup>2</sup> / 20 ... 16 AWG
Fine-stranded conductor	0.14 ... 1.5 mm <sup>2</sup> / 24 ... 16 AWG
Fine-stranded conductor with ferrule, push-in termination, from	0.5 mm <sup>2</sup> / 20 AWG
Strip length	9 ... 11 mm / 0.35 ... 0.43 Inch
Total number of connection points	1
Total number of potentials	1
Number of levels	1
Type of wiring	Front-entry wiring

### Geometrical Data

Width	3.5 mm / 0.138 inch
Height from upper-edge of DIN-35 rail	32.5 mm / 1.28 inch
Depth	48.5 mm / 1.909 inch

### Mechanical data

Design	horizontal
Type of mounting	DIN-35 rail
Marking level	Center/side marking

### Material Data

Color	gray
Insulating material	Polyamide 66 (PA 66)
Fire load	0.082 MJ
Weight	3.62 g

## Commercial data




Country of origin	CN
GTIN	4050821145387
Customs Tariff No.	85366990990
Product Group	18 (X-COM-System)

## Approvals / Certificates

### Country specific Approvals

Logo	Approval	Certificate name
	CSA DEKRA Certification B.V.	2516073
	KEMA/KEUR DEKRA Certification B.V.	71-100670

### Ship Approvals

















Logo	Approval	Certificate name
	ABS American Bureau of Shipping	14-HG1293677-PDA
	BV Bureau Veritas S.A.	38586/A0 BV
	LR Lloyds Register	91/20112 (E9)

















### UL-Approvals














Logo	Approval	Certificate name
	UL Underwriters Laboratories Inc.	E45172

## Compatible products


Jumper

	<b>Item no.: 2000-402</b> Push-in type jumper bar; insulated; 2-way; Nominal current 14 A	<a href="http://www.wago.com/2000-402">www.wago.com/2000-402</a>
	<b>Item no.: 2000-402/000-005</b> Push-in type jumper bar; insulated; 2-way; Nominal current 14 A	<a href="http://www.wago.com/2000-402/000-005">www.wago.com/2000-402/000-005</a>
	<b>Item no.: 2000-402/000-006</b> Push-in type jumper bar; insulated; 2-way; Nominal current 14 A	<a href="http://www.wago.com/2000-402/000-006">www.wago.com/2000-402/000-006</a>
	<b>Item no.: 2000-402/000-018</b> Push-in type jumper bar; insulated; 2-way; Nominal current 14 A	<a href="http://www.wago.com/2000-402/000-018">www.wago.com/2000-402/000-018</a>
	<b>Item no.: 2000-403</b> Push-in type jumper bar; insulated; 3-way; Nominal current 14 A	<a href="http://www.wago.com/2000-403">www.wago.com/2000-403</a>
	<b>Item no.: 2000-403/000-005</b> Push-in type jumper bar; insulated; 3-way; Nominal current 14 A	<a href="http://www.wago.com/2000-403/000-005">www.wago.com/2000-403/000-005</a>
	<b>Item no.: 2000-403/000-006</b> Push-in type jumper bar; insulated; 3-way; Nominal current 14 A	<a href="http://www.wago.com/2000-403/000-006">www.wago.com/2000-403/000-006</a>
	<b>Item no.: 2000-404</b> Push-in type jumper bar; insulated; 4-way; Nominal current 14 A	<a href="http://www.wago.com/2000-404">www.wago.com/2000-404</a>
	<b>Item no.: 2000-404/000-005</b> Push-in type jumper bar; insulated; 4-way; Nominal current 14 A	<a href="http://www.wago.com/2000-404/000-005">www.wago.com/2000-404/000-005</a>
	<b>Item no.: 2000-404/000-006</b> Push-in type jumper bar; insulated; 4-way; Nominal current 14 A	<a href="http://www.wago.com/2000-404/000-006">www.wago.com/2000-404/000-006</a>
	<b>Item no.: 2000-405</b> Push-in type jumper bar; insulated; 5-way; Nominal current 14 A	<a href="http://www.wago.com/2000-405">www.wago.com/2000-405</a>
	<b>Item no.: 2000-405/000-005</b> Push-in type jumper bar; insulated; 5-way; Nominal current 14 A	<a href="http://www.wago.com/2000-405/000-005">www.wago.com/2000-405/000-005</a>
	<b>Item no.: 2000-405/000-006</b> Push-in type jumper bar; insulated; 5-way; Nominal current 14 A	<a href="http://www.wago.com/2000-405/000-006">www.wago.com/2000-405/000-006</a>
	<b>Item no.: 2000-405/011-000</b> Star point jumper; insulated; 3-way (1-3-5); IN = IN terminal block	<a href="http://www.wago.com/2000-405/011-000">www.wago.com/2000-405/011-000</a>
	<b>Item no.: 2000-406</b> Push-in type jumper bar; insulated; 6-way; Nominal current 14 A	<a href="http://www.wago.com/2000-406">www.wago.com/2000-406</a>
	<b>Item no.: 2000-406/000-005</b> Push-in type jumper bar; insulated; 6-way; Nominal current 14 A	<a href="http://www.wago.com/2000-406/000-005">www.wago.com/2000-406/000-005</a>




	<b>Item no.: 2000-406/000-006</b> Push-in type jumper bar; insulated; 6-way; Nominal current 14 A	<a href="http://www.wago.com/2000-406/000-006">www.wago.com/2000-406/000-006</a>
	<b>Item no.: 2000-406/020-000</b> Delta jumper; insulated; 1-2 3-4 5-6; IN = IN terminal block	<a href="http://www.wago.com/2000-406/020-000">www.wago.com/2000-406/020-000</a>
	<b>Item no.: 2000-407</b> Push-in type jumper bar; insulated; 7-way; Nominal current 14 A	<a href="http://www.wago.com/2000-407">www.wago.com/2000-407</a>
	<b>Item no.: 2000-407/000-005</b> Push-in type jumper bar; insulated; 7-way; Nominal current 14 A	<a href="http://www.wago.com/2000-407/000-005">www.wago.com/2000-407/000-005</a>
	<b>Item no.: 2000-407/000-006</b> Push-in type jumper bar; insulated; 7-way; Nominal current 14 A	<a href="http://www.wago.com/2000-407/000-006">www.wago.com/2000-407/000-006</a>
	<b>Item no.: 2000-408</b> Push-in type jumper bar; insulated; 8-way; Nominal current 14 A	<a href="http://www.wago.com/2000-408">www.wago.com/2000-408</a>
	<b>Item no.: 2000-408/000-005</b> Push-in type jumper bar; insulated; 8-way; Nominal current 14 A	<a href="http://www.wago.com/2000-408/000-005">www.wago.com/2000-408/000-005</a>
	<b>Item no.: 2000-408/000-006</b> Push-in type jumper bar; insulated; 8-way; Nominal current 14 A	<a href="http://www.wago.com/2000-408/000-006">www.wago.com/2000-408/000-006</a>
	<b>Item no.: 2000-409</b> Push-in type jumper bar; insulated; 9-way; Nominal current 14 A	<a href="http://www.wago.com/2000-409">www.wago.com/2000-409</a>
	<b>Item no.: 2000-409/000-005</b> Push-in type jumper bar; insulated; 9-way; Nominal current 14 A	<a href="http://www.wago.com/2000-409/000-005">www.wago.com/2000-409/000-005</a>
	<b>Item no.: 2000-409/000-006</b> Push-in type jumper bar; insulated; 9-way; Nominal current 14 A	<a href="http://www.wago.com/2000-409/000-006">www.wago.com/2000-409/000-006</a>
	<b>Item no.: 2000-410</b> Push-in type jumper bar; insulated; 10-way; Nominal current 14 A	<a href="http://www.wago.com/2000-410">www.wago.com/2000-410</a>
	<b>Item no.: 2000-410/000-005</b> Push-in type jumper bar; insulated; 10-way; Nominal current 14 A	<a href="http://www.wago.com/2000-410/000-005">www.wago.com/2000-410/000-005</a>
	<b>Item no.: 2000-410/000-006</b> Push-in type jumper bar; insulated; 10-way; Nominal current 14 A	<a href="http://www.wago.com/2000-410/000-006">www.wago.com/2000-410/000-006</a>
	<b>Item no.: 2000-433</b> Push-in type jumper bar; insulated; from 1 to 3; Nominal current 14 A	<a href="http://www.wago.com/2000-433">www.wago.com/2000-433</a>
	<b>Item no.: 2000-433/000-005</b> Push-in type jumper bar; insulated; from 1 to 3; Nominal current 14 A	<a href="http://www.wago.com/2000-433/000-005">www.wago.com/2000-433/000-005</a>

	<b>Item no.: 2000-433/000-006</b> Push-in type jumper bar; insulated; from 1 to 3; Nominal current 14 A	<a href="http://www.wago.com/2000-433/000-006">www.wago.com/2000-433/000-006</a>
	<b>Item no.: 2000-434</b> Push-in type jumper bar; insulated; from 1 to 4; Nominal current 14 A	<a href="http://www.wago.com/2000-434">www.wago.com/2000-434</a>
	<b>Item no.: 2000-435</b> Push-in type jumper bar; insulated; from 1 to 5; Nominal current 14 A	<a href="http://www.wago.com/2000-435">www.wago.com/2000-435</a>
	<b>Item no.: 2000-436</b> Push-in type jumper bar; insulated; from 1 to 6; Nominal current 14 A	<a href="http://www.wago.com/2000-436">www.wago.com/2000-436</a>
	<b>Item no.: 2000-437</b> Push-in type jumper bar; insulated; from 1 to 7; Nominal current 14 A	<a href="http://www.wago.com/2000-437">www.wago.com/2000-437</a>
	<b>Item no.: 2000-438</b> Push-in type jumper bar; insulated; from 1 to 8; Nominal current 14 A	<a href="http://www.wago.com/2000-438">www.wago.com/2000-438</a>
	<b>Item no.: 2000-439</b> Push-in type jumper bar; insulated; from 1 to 9; Nominal current 14 A	<a href="http://www.wago.com/2000-439">www.wago.com/2000-439</a>
	<b>Item no.: 2000-440</b> Push-in type jumper bar; insulated; from 1 to 10; Nominal current 14 A	<a href="http://www.wago.com/2000-440">www.wago.com/2000-440</a>
	<b>Item no.: 2009-402</b> Push-in type wire jumper; insulated; wire length 60 mm; Conductor cross section 0.75 mm <sup>2</sup> ; suitable for 2000 and 2020 Series rail-mounted terminal blocks	<a href="http://www.wago.com/2009-402">www.wago.com/2009-402</a>
	<b>Item no.: 2009-404</b> Push-in type wire jumper; insulated; wire length 110 mm; Conductor cross section 0.75 mm <sup>2</sup> ; suitable for 2000 and 2020 Series rail-mounted terminal blocks	<a href="http://www.wago.com/2009-404">www.wago.com/2009-404</a>
	<b>Item no.: 2009-406</b> Push-in type wire jumper; insulated; wire length 250 mm; Conductor cross section 0.75 mm <sup>2</sup> ; suitable for 2000 and 2020 Series rail-mounted terminal blocks	<a href="http://www.wago.com/2009-406">www.wago.com/2009-406</a>
	<b>Item no.: 210-103</b> Wire commoning chain; insulated; 50 connections	<a href="http://www.wago.com/210-103">www.wago.com/210-103</a>
	<b>Item no.: 210-123</b> Wire commoning chain; insulated; 50 connections	<a href="http://www.wago.com/210-123">www.wago.com/210-123</a>

#### Protective Warning Marker

	<b>Item no.: 2000-115</b> Protective warning marker; with high-voltage symbol, black; for 5 terminal blocks	<a href="http://www.wago.com/2000-115">www.wago.com/2000-115</a>
--	--	--

#### tools

	<b>Item no.: 210-647</b> Operating tool with partially insulated shaft; Blade (2.5 x 0.4) mm; short	<a href="http://www.wago.com/210-647">www.wago.com/210-647</a>
	<b>Item no.: 210-648</b> Operating tool with partially insulated shaft; Blade (2.5 x 0.4) mm; short; angled	<a href="http://www.wago.com/210-648">www.wago.com/210-648</a>
	<b>Item no.: 210-719</b> Operating tool with partially insulated shaft; Type 1, blade (2.5 x 0.4) mm	<a href="http://www.wago.com/210-719">www.wago.com/210-719</a>

#### Coding



Item no.: 2020-100

Carrier with 6 coding pins; for coding of female plugs; for carrier terminal blocks

[www.wago.com/2020-100](http://www.wago.com/2020-100)

## ferrule



Item no.: 216-241

Ferrule; Sleeve for 0.5 mm<sup>2</sup> / AWG 22; insulated; electro-tin plated; electrolytic copper; gastight crimped; acc. to DIN 46228, Part 4/09.90[www.wago.com/216-241](http://www.wago.com/216-241)

Item no.: 216-242

Ferrule; Sleeve for 0.75 mm<sup>2</sup> / AWG 20; insulated; electro-tin plated; electrolytic copper; gastight crimped; acc. to DIN 46228, Part 4/09.90[www.wago.com/216-242](http://www.wago.com/216-242)

Item no.: 216-243

Ferrule; Sleeve for 1 mm<sup>2</sup> / AWG 18; insulated; electro-tin plated; electrolytic copper; gastight crimped; acc. to DIN 46228, Part 4/09.90[www.wago.com/216-243](http://www.wago.com/216-243)

## General accessories



Item no.: 2020-161

Start module for 1-conductor female connector; with integrated end plate; 1.5 mm<sup>2</sup>; 1-pole[www.wago.com/2020-161](http://www.wago.com/2020-161)

Item no.: 2020-164

Start module for 1-conductor female connector; with integrated end plate; 1.5 mm<sup>2</sup>; 1-pole[www.wago.com/2020-164](http://www.wago.com/2020-164)

Item no.: 2020-167

Start module for 1-conductor female connector; 1.5 mm<sup>2</sup>; 1-pole[www.wago.com/2020-167](http://www.wago.com/2020-167)

Item no.: 2020-181

End module for 1-conductor female connector; 1.5 mm<sup>2</sup>; 1-pole[www.wago.com/2020-181](http://www.wago.com/2020-181)

Item no.: 2020-184

End module for 1-conductor female connector; 1.5 mm<sup>2</sup>; 1-pole[www.wago.com/2020-184](http://www.wago.com/2020-184)

Item no.: 2020-187

End module for 1-conductor female connector; 1.5 mm<sup>2</sup>; 1-pole[www.wago.com/2020-187](http://www.wago.com/2020-187)

Item no.: 2020-261

Start module for 2-conductor female connector; with integrated end plate; 1.5 mm<sup>2</sup>; 1-pole[www.wago.com/2020-261](http://www.wago.com/2020-261)

Item no.: 2020-264

Start module for 2-conductor female connector; with integrated end plate; 1.5 mm<sup>2</sup>; 1-pole[www.wago.com/2020-264](http://www.wago.com/2020-264)

Item no.: 2020-267

Start module for 2-conductor female connector; 1.5 mm<sup>2</sup>; 1-pole[www.wago.com/2020-267](http://www.wago.com/2020-267)

Item no.: 2020-281

End module for 2-conductor female connector; 1.5 mm<sup>2</sup>; 1-pole[www.wago.com/2020-281](http://www.wago.com/2020-281)

Item no.: 2020-284

End module for 2-conductor female connector; 1.5 mm<sup>2</sup>; 1-pole[www.wago.com/2020-284](http://www.wago.com/2020-284)

Item no.: 2020-287

End module for 2-conductor female connector; 1.5 mm<sup>2</sup>; 1-pole[www.wago.com/2020-287](http://www.wago.com/2020-287)












 



 
## Marking accessories











Item no.: 2009-110












Marking strips; on reel; not stretchable; plain; snap-on type








 
[www.wago.com/2009-110](http://www.wago.com/2009-110)





	<b>Item no.: 2009-113</b> WMB-Inline; for smartPRINTER; on reel; plain; snap-on type	<a href="http://www.wago.com/2009-113">www.wago.com/2009-113</a>
	<b>Item no.: 2009-113/000-002</b> WMB-Inline; for smartPRINTER; on reel; plain; snap-on type	<a href="http://www.wago.com/2009-113/000-002">www.wago.com/2009-113/000-002</a>
	<b>Item no.: 2009-113/000-005</b> WMB-Inline; for smartPRINTER; on reel; plain; snap-on type	<a href="http://www.wago.com/2009-113/000-005">www.wago.com/2009-113/000-005</a>
	<b>Item no.: 2009-113/000-006</b> WMB-Inline; for smartPRINTER; on reel; plain; snap-on type	<a href="http://www.wago.com/2009-113/000-006">www.wago.com/2009-113/000-006</a>
	<b>Item no.: 2009-113/000-007</b> WMB-Inline; for smartPRINTER; on reel; plain; snap-on type	<a href="http://www.wago.com/2009-113/000-007">www.wago.com/2009-113/000-007</a>
	<b>Item no.: 2009-113/000-012</b> WMB-Inline; for smartPRINTER; on reel; plain; snap-on type	<a href="http://www.wago.com/2009-113/000-012">www.wago.com/2009-113/000-012</a>
	<b>Item no.: 2009-113/000-017</b> WMB-Inline; for smartPRINTER; on reel; plain; snap-on type	<a href="http://www.wago.com/2009-113/000-017">www.wago.com/2009-113/000-017</a>
	<b>Item no.: 2009-113/000-023</b> WMB-Inline; for smartPRINTER; on reel; plain; snap-on type	<a href="http://www.wago.com/2009-113/000-023">www.wago.com/2009-113/000-023</a>
	<b>Item no.: 2009-113/000-024</b> WMB-Inline; for smartPRINTER; on reel; plain; snap-on type	<a href="http://www.wago.com/2009-113/000-024">www.wago.com/2009-113/000-024</a>
	<b>Item no.: 793-3501</b> WMB marking card; as card; plain; snap-on type	<a href="http://www.wago.com/793-3501">www.wago.com/793-3501</a>
<b>Carrier rail</b>		
	<b>Item no.: 210-112</b> Steel carrier rail; 35 x 7.5 mm; 1 mm thick; 2 m long; slotted; according to EN 60715; "Hole width 25 mm	<a href="http://www.wago.com/210-112">www.wago.com/210-112</a>
	<b>Item no.: 210-113</b> Steel carrier rail; 35 x 7.5 mm; 1 mm thick; 2 m long; unslotted; according to EN 60715	<a href="http://www.wago.com/210-113">www.wago.com/210-113</a>
	<b>Item no.: 210-114</b> Steel carrier rail; 35 x 15 mm; 1.5 mm thick; 2 m long; unslotted; similar to EN 60715	<a href="http://www.wago.com/210-114">www.wago.com/210-114</a>
	<b>Item no.: 210-115</b> Steel carrier rail; 35 x 7.5 mm; 1 mm thick; 2 m long; slotted; according to EN 60715; "Hole width 18 mm	<a href="http://www.wago.com/210-115">www.wago.com/210-115</a>
	<b>Item no.: 210-118</b> Steel carrier rail; 35 x 15 mm; 2.3 mm thick; 2 m long; unslotted; according to EN 60715	<a href="http://www.wago.com/210-118">www.wago.com/210-118</a>
	<b>Item no.: 210-196</b> Aluminum carrier rail; 35 x 8.2 mm; 1.6 mm thick; 2 m long; unslotted; similar to EN 60715	<a href="http://www.wago.com/210-196">www.wago.com/210-196</a>







	<b>Item no.: 210-197</b> Steel carrier rail; 35 x 15 mm; 1.5 mm thick; 2 m long; slotted; similar to EN 60715	<a href="http://www.wago.com/210-197">www.wago.com/210-197</a>
	<b>Item no.: 210-198</b> Copper carrier rail; 35 x 15 mm; 2.3 mm thick; 2 m long; unslotted; according to EN 60715	<a href="http://www.wago.com/210-198">www.wago.com/210-198</a>
<b>Female plug</b>		
	<b>Item no.: 2020-102</b> 1-conductor female plug; 1.5 mm <sup>2</sup> ; 2-pole	<a href="http://www.wago.com/2020-102">www.wago.com/2020-102</a>
	<b>Item no.: 2020-102/122-000</b> 1-conductor female plug; Locking lever; 1.5 mm <sup>2</sup> ; 2-pole	<a href="http://www.wago.com/2020-102/122-000">www.wago.com/2020-102/122-000</a>
	<b>Item no.: 2020-102/132-000</b> 1-conductor female plug; Strain relief plate; 1.5 mm <sup>2</sup> ; 2-pole	<a href="http://www.wago.com/2020-102/132-000">www.wago.com/2020-102/132-000</a>
	<b>Item no.: 2020-102/142-000</b> 1-conductor female plug; Strain relief plate; 1.5 mm <sup>2</sup> ; 2-pole	<a href="http://www.wago.com/2020-102/142-000">www.wago.com/2020-102/142-000</a>
	<b>Item no.: 2020-103</b> 1-conductor female plug; 1.5 mm <sup>2</sup> ; 3-pole	<a href="http://www.wago.com/2020-103">www.wago.com/2020-103</a>
	<b>Item no.: 2020-103/000-036</b> 1-conductor female plug; 1.5 mm <sup>2</sup> ; 3-pole	<a href="http://www.wago.com/2020-103/000-036">www.wago.com/2020-103/000-036</a>
	<b>Item no.: 2020-103/000-037</b> 1-conductor female plug; 1.5 mm <sup>2</sup> ; 3-pole	<a href="http://www.wago.com/2020-103/000-037">www.wago.com/2020-103/000-037</a>
	<b>Item no.: 2020-103/000-038</b> 1-conductor female plug; 1.5 mm <sup>2</sup> ; 3-pole	<a href="http://www.wago.com/2020-103/000-038">www.wago.com/2020-103/000-038</a>
	<b>Item no.: 2020-103/000-039</b> 1-conductor female plug; 1.5 mm <sup>2</sup> ; 3-pole	<a href="http://www.wago.com/2020-103/000-039">www.wago.com/2020-103/000-039</a>
	<b>Item no.: 2020-103/122-000</b> 1-conductor female plug; Locking lever; 1.5 mm <sup>2</sup> ; 3-pole	<a href="http://www.wago.com/2020-103/122-000">www.wago.com/2020-103/122-000</a>
	<b>Item no.: 2020-103/132-000</b> 1-conductor female plug; Strain relief plate; 1.5 mm <sup>2</sup> ; 3-pole	<a href="http://www.wago.com/2020-103/132-000">www.wago.com/2020-103/132-000</a>
	<b>Item no.: 2020-103/142-000</b> 1-conductor female plug; Strain relief plate; 1.5 mm <sup>2</sup> ; 3-pole	<a href="http://www.wago.com/2020-103/142-000">www.wago.com/2020-103/142-000</a>
	<b>Item no.: 2020-104</b> 1-conductor female plug; 1.5 mm <sup>2</sup> ; 4-pole	<a href="http://www.wago.com/2020-104">www.wago.com/2020-104</a>

	<b>Item no.: 2020-104/000-036</b> 1-conductor female plug; 1.5 mm <sup>2</sup> ; 4-pole	<a href="http://www.wago.com/2020-104/000-036">www.wago.com/2020-104/000-036</a>
	<b>Item no.: 2020-104/000-037</b> 1-conductor female plug; 1.5 mm <sup>2</sup> ; 4-pole	<a href="http://www.wago.com/2020-104/000-037">www.wago.com/2020-104/000-037</a>
	<b>Item no.: 2020-104/000-038</b> 1-conductor female plug; 1.5 mm <sup>2</sup> ; 4-pole	<a href="http://www.wago.com/2020-104/000-038">www.wago.com/2020-104/000-038</a>
	<b>Item no.: 2020-104/000-039</b> 1-conductor female plug; 1.5 mm <sup>2</sup> ; 4-pole	<a href="http://www.wago.com/2020-104/000-039">www.wago.com/2020-104/000-039</a>
	<b>Item no.: 2020-104/124-000</b> 1-conductor female plug; Locking lever; 1.5 mm <sup>2</sup> ; 4-pole	<a href="http://www.wago.com/2020-104/124-000">www.wago.com/2020-104/124-000</a>
	<b>Item no.: 2020-104/133-000</b> 1-conductor female plug; Strain relief plate; 1.5 mm <sup>2</sup> ; 4-pole	<a href="http://www.wago.com/2020-104/133-000">www.wago.com/2020-104/133-000</a>
	<b>Item no.: 2020-104/143-000</b> 1-conductor female plug; Strain relief plate; 1.5 mm <sup>2</sup> ; 4-pole	<a href="http://www.wago.com/2020-104/143-000">www.wago.com/2020-104/143-000</a>
	<b>Item no.: 2020-105</b> 1-conductor female plug; 1.5 mm <sup>2</sup> ; 5-pole	<a href="http://www.wago.com/2020-105">www.wago.com/2020-105</a>
	<b>Item no.: 2020-105/000-036</b> 1-conductor female plug; 1.5 mm <sup>2</sup> ; 5-pole	<a href="http://www.wago.com/2020-105/000-036">www.wago.com/2020-105/000-036</a>
	<b>Item no.: 2020-105/000-037</b> 1-conductor female plug; 1.5 mm <sup>2</sup> ; 5-pole	<a href="http://www.wago.com/2020-105/000-037">www.wago.com/2020-105/000-037</a>
	<b>Item no.: 2020-105/000-038</b> 1-conductor female plug; 1.5 mm <sup>2</sup> ; 5-pole	<a href="http://www.wago.com/2020-105/000-038">www.wago.com/2020-105/000-038</a>
	<b>Item no.: 2020-105/000-039</b> 1-conductor female plug; 1.5 mm <sup>2</sup> ; 5-pole	<a href="http://www.wago.com/2020-105/000-039">www.wago.com/2020-105/000-039</a>
	<b>Item no.: 2020-105/124-000</b> 1-conductor female plug; Locking lever; 1.5 mm <sup>2</sup> ; 5-pole	<a href="http://www.wago.com/2020-105/124-000">www.wago.com/2020-105/124-000</a>
	<b>Item no.: 2020-105/133-000</b> 1-conductor female plug; Strain relief plate; 1.5 mm <sup>2</sup> ; 5-pole	<a href="http://www.wago.com/2020-105/133-000">www.wago.com/2020-105/133-000</a>
	<b>Item no.: 2020-105/143-000</b> 1-conductor female plug; Strain relief plate; 1.5 mm <sup>2</sup> ; 5-pole	<a href="http://www.wago.com/2020-105/143-000">www.wago.com/2020-105/143-000</a>








	<b>Item no.: 2020-106</b> 1-conductor female plug; 1.5 mm <sup>2</sup> ; 6-pole	<a href="http://www.wago.com/2020-106">www.wago.com/2020-106</a>
	<b>Item no.: 2020-106/000-036</b> 1-conductor female plug; 1.5 mm <sup>2</sup> ; 6-pole	<a href="http://www.wago.com/2020-106/000-036">www.wago.com/2020-106/000-036</a>
	<b>Item no.: 2020-106/000-037</b> 1-conductor female plug; 1.5 mm <sup>2</sup> ; 6-pole	<a href="http://www.wago.com/2020-106/000-037">www.wago.com/2020-106/000-037</a>
	<b>Item no.: 2020-106/000-038</b> 1-conductor female plug; 1.5 mm <sup>2</sup> ; 6-pole	<a href="http://www.wago.com/2020-106/000-038">www.wago.com/2020-106/000-038</a>
	<b>Item no.: 2020-106/000-039</b> 1-conductor female plug; 1.5 mm <sup>2</sup> ; 6-pole	<a href="http://www.wago.com/2020-106/000-039">www.wago.com/2020-106/000-039</a>
	<b>Item no.: 2020-106/124-000</b> 1-conductor female plug; Locking lever; 1.5 mm <sup>2</sup> ; 6-pole	<a href="http://www.wago.com/2020-106/124-000">www.wago.com/2020-106/124-000</a>
	<b>Item no.: 2020-106/133-000</b> 1-conductor female plug; Strain relief plate; 1.5 mm <sup>2</sup> ; 6-pole	<a href="http://www.wago.com/2020-106/133-000">www.wago.com/2020-106/133-000</a>
	<b>Item no.: 2020-106/143-000</b> 1-conductor female plug; Strain relief plate; 1.5 mm <sup>2</sup> ; 6-pole	<a href="http://www.wago.com/2020-106/143-000">www.wago.com/2020-106/143-000</a>
	<b>Item no.: 2020-107</b> 1-conductor female plug; 1.5 mm <sup>2</sup> ; 7-pole	<a href="http://www.wago.com/2020-107">www.wago.com/2020-107</a>
	<b>Item no.: 2020-107/000-036</b> 1-conductor female plug; 1.5 mm <sup>2</sup> ; 7-pole	<a href="http://www.wago.com/2020-107/000-036">www.wago.com/2020-107/000-036</a>
	<b>Item no.: 2020-107/000-037</b> 1-conductor female plug; 1.5 mm <sup>2</sup> ; 7-pole	<a href="http://www.wago.com/2020-107/000-037">www.wago.com/2020-107/000-037</a>
	<b>Item no.: 2020-107/000-038</b> 1-conductor female plug; 1.5 mm <sup>2</sup> ; 7-pole	<a href="http://www.wago.com/2020-107/000-038">www.wago.com/2020-107/000-038</a>
	<b>Item no.: 2020-107/000-039</b> 1-conductor female plug; 1.5 mm <sup>2</sup> ; 7-pole	<a href="http://www.wago.com/2020-107/000-039">www.wago.com/2020-107/000-039</a>
	<b>Item no.: 2020-107/124-000</b> 1-conductor female plug; Locking lever; 1.5 mm <sup>2</sup> ; 7-pole	<a href="http://www.wago.com/2020-107/124-000">www.wago.com/2020-107/124-000</a>
	<b>Item no.: 2020-107/134-000</b> 1-conductor female plug; Strain relief plate; 1.5 mm <sup>2</sup> ; 7-pole	<a href="http://www.wago.com/2020-107/134-000">www.wago.com/2020-107/134-000</a>

	<b>Item no.: 2020-107/144-000</b> 1-conductor female plug; Strain relief plate; 1.5 mm <sup>2</sup> ; 7-pole	<a href="http://www.wago.com/2020-107/144-000">www.wago.com/2020-107/144-000</a>
	<b>Item no.: 2020-108</b> 1-conductor female plug; 1.5 mm <sup>2</sup> ; 8-pole	<a href="http://www.wago.com/2020-108">www.wago.com/2020-108</a>
	<b>Item no.: 2020-108/000-036</b> 1-conductor female plug; 1.5 mm <sup>2</sup> ; 8-pole	<a href="http://www.wago.com/2020-108/000-036">www.wago.com/2020-108/000-036</a>
	<b>Item no.: 2020-108/000-037</b> 1-conductor female plug; 1.5 mm <sup>2</sup> ; 8-pole	<a href="http://www.wago.com/2020-108/000-037">www.wago.com/2020-108/000-037</a>
	<b>Item no.: 2020-108/000-038</b> 1-conductor female plug; 1.5 mm <sup>2</sup> ; 8-pole	<a href="http://www.wago.com/2020-108/000-038">www.wago.com/2020-108/000-038</a>
	<b>Item no.: 2020-108/000-039</b> 1-conductor female plug; 1.5 mm <sup>2</sup> ; 8-pole	<a href="http://www.wago.com/2020-108/000-039">www.wago.com/2020-108/000-039</a>
	<b>Item no.: 2020-108/124-000</b> 1-conductor female plug; Locking lever; 1.5 mm <sup>2</sup> ; 8-pole	<a href="http://www.wago.com/2020-108/124-000">www.wago.com/2020-108/124-000</a>
	<b>Item no.: 2020-108/134-000</b> 1-conductor female plug; Strain relief plate; 1.5 mm <sup>2</sup> ; 8-pole	<a href="http://www.wago.com/2020-108/134-000">www.wago.com/2020-108/134-000</a>
	<b>Item no.: 2020-108/144-000</b> 1-conductor female plug; Strain relief plate; 1.5 mm <sup>2</sup> ; 8-pole	<a href="http://www.wago.com/2020-108/144-000">www.wago.com/2020-108/144-000</a>
	<b>Item no.: 2020-109</b> 1-conductor female plug; 1.5 mm <sup>2</sup> ; 9-pole	<a href="http://www.wago.com/2020-109">www.wago.com/2020-109</a>
	<b>Item no.: 2020-109/000-036</b> 1-conductor female plug; 1.5 mm <sup>2</sup> ; 9-pole	<a href="http://www.wago.com/2020-109/000-036">www.wago.com/2020-109/000-036</a>
	<b>Item no.: 2020-109/000-037</b> 1-conductor female plug; 1.5 mm <sup>2</sup> ; 9-pole	<a href="http://www.wago.com/2020-109/000-037">www.wago.com/2020-109/000-037</a>
	<b>Item no.: 2020-109/000-038</b> 1-conductor female plug; 1.5 mm <sup>2</sup> ; 9-pole	<a href="http://www.wago.com/2020-109/000-038">www.wago.com/2020-109/000-038</a>
	<b>Item no.: 2020-109/000-039</b> 1-conductor female plug; 1.5 mm <sup>2</sup> ; 9-pole	<a href="http://www.wago.com/2020-109/000-039">www.wago.com/2020-109/000-039</a>
	<b>Item no.: 2020-109/124-000</b> 1-conductor female plug; Locking lever; 1.5 mm <sup>2</sup> ; 9-pole	<a href="http://www.wago.com/2020-109/124-000">www.wago.com/2020-109/124-000</a>










 
**Item no.: 2020-109/134-000**1-conductor female plug; Strain relief plate; 1.5 mm<sup>2</sup>; 9-pole[www.wago.com/2020-109/134-000](http://www.wago.com/2020-109/134-000)**Item no.: 2020-109/144-000**1-conductor female plug; Strain relief plate; 1.5 mm<sup>2</sup>; 9-pole[www.wago.com/2020-109/144-000](http://www.wago.com/2020-109/144-000)**Item no.: 2020-110**1-conductor female plug; 1.5 mm<sup>2</sup>; 10-pole[www.wago.com/2020-110](http://www.wago.com/2020-110)**Item no.: 2020-110/000-036**1-conductor female plug; 1.5 mm<sup>2</sup>; 10-pole[www.wago.com/2020-110/000-036](http://www.wago.com/2020-110/000-036)**Item no.: 2020-110/000-037**1-conductor female plug; 1.5 mm<sup>2</sup>; 10-pole[www.wago.com/2020-110/000-037](http://www.wago.com/2020-110/000-037)**Item no.: 2020-110/000-038**1-conductor female plug; 1.5 mm<sup>2</sup>; 10-pole[www.wago.com/2020-110/000-038](http://www.wago.com/2020-110/000-038)**Item no.: 2020-110/000-039**1-conductor female plug; 1.5 mm<sup>2</sup>; 10-pole[www.wago.com/2020-110/000-039](http://www.wago.com/2020-110/000-039)**Item no.: 2020-110/125-000**1-conductor female plug; Locking lever; 1.5 mm<sup>2</sup>; 10-pole[www.wago.com/2020-110/125-000](http://www.wago.com/2020-110/125-000)**Item no.: 2020-110/135-000**1-conductor female plug; Strain relief plate; 1.5 mm<sup>2</sup>; 10-pole[www.wago.com/2020-110/135-000](http://www.wago.com/2020-110/135-000)**Item no.: 2020-110/145-000**1-conductor female plug; Strain relief plate; 1.5 mm<sup>2</sup>; 10-pole[www.wago.com/2020-110/145-000](http://www.wago.com/2020-110/145-000)**Item no.: 2020-111**1-conductor female plug; 1.5 mm<sup>2</sup>; 11-pole[www.wago.com/2020-111](http://www.wago.com/2020-111)**Item no.: 2020-111/000-036**1-conductor female plug; 1.5 mm<sup>2</sup>; 11-pole[www.wago.com/2020-111/000-036](http://www.wago.com/2020-111/000-036)**Item no.: 2020-111/000-037**1-conductor female plug; 1.5 mm<sup>2</sup>; 11-pole[www.wago.com/2020-111/000-037](http://www.wago.com/2020-111/000-037)**Item no.: 2020-111/000-038**1-conductor female plug; 1.5 mm<sup>2</sup>; 11-pole[www.wago.com/2020-111/000-038](http://www.wago.com/2020-111/000-038)**Item no.: 2020-111/000-039**1-conductor female plug; 1.5 mm<sup>2</sup>; 11-pole[www.wago.com/2020-111/000-039](http://www.wago.com/2020-111/000-039)





 




 

	<b>Item no.: 2020-111/125-000</b> 1-conductor female plug; Locking lever; 1.5 mm <sup>2</sup> ; 11-pole	<a href="http://www.wago.com/2020-111/125-000">www.wago.com/2020-111/125-000</a>
	<b>Item no.: 2020-111/135-000</b> 1-conductor female plug; Strain relief plate; 1.5 mm <sup>2</sup> ; 11-pole	<a href="http://www.wago.com/2020-111/135-000">www.wago.com/2020-111/135-000</a>
	<b>Item no.: 2020-111/145-000</b> 1-conductor female plug; Strain relief plate; 1.5 mm <sup>2</sup> ; 11-pole	<a href="http://www.wago.com/2020-111/145-000">www.wago.com/2020-111/145-000</a>
	<b>Item no.: 2020-112</b> 1-conductor female plug; 1.5 mm <sup>2</sup> ; 12-pole	<a href="http://www.wago.com/2020-112">www.wago.com/2020-112</a>
	<b>Item no.: 2020-112/000-036</b> 1-conductor female plug; 1.5 mm <sup>2</sup> ; 12-pole	<a href="http://www.wago.com/2020-112/000-036">www.wago.com/2020-112/000-036</a>
	<b>Item no.: 2020-112/000-037</b> 1-conductor female plug; 1.5 mm <sup>2</sup> ; 12-pole	<a href="http://www.wago.com/2020-112/000-037">www.wago.com/2020-112/000-037</a>
	<b>Item no.: 2020-112/000-038</b> 1-conductor female plug; 1.5 mm <sup>2</sup> ; 12-pole	<a href="http://www.wago.com/2020-112/000-038">www.wago.com/2020-112/000-038</a>
	<b>Item no.: 2020-112/000-039</b> 1-conductor female plug; 1.5 mm <sup>2</sup> ; 12-pole	<a href="http://www.wago.com/2020-112/000-039">www.wago.com/2020-112/000-039</a>
	<b>Item no.: 2020-112/125-000</b> 1-conductor female plug; Locking lever; 1.5 mm <sup>2</sup> ; 12-pole	<a href="http://www.wago.com/2020-112/125-000">www.wago.com/2020-112/125-000</a>
	<b>Item no.: 2020-112/135-000</b> 1-conductor female plug; Strain relief plate; 1.5 mm <sup>2</sup> ; 12-pole	<a href="http://www.wago.com/2020-112/135-000">www.wago.com/2020-112/135-000</a>
	<b>Item no.: 2020-112/145-000</b> 1-conductor female plug; Strain relief plate; 1.5 mm <sup>2</sup> ; 12-pole	<a href="http://www.wago.com/2020-112/145-000">www.wago.com/2020-112/145-000</a>
	<b>Item no.: 2020-113</b> 1-conductor female plug; 1.5 mm <sup>2</sup> ; 13-pole	<a href="http://www.wago.com/2020-113">www.wago.com/2020-113</a>
	<b>Item no.: 2020-113/000-036</b> 1-conductor female plug; 1.5 mm <sup>2</sup> ; 13-pole	<a href="http://www.wago.com/2020-113/000-036">www.wago.com/2020-113/000-036</a>
	<b>Item no.: 2020-113/000-037</b> 1-conductor female plug; 1.5 mm <sup>2</sup> ; 13-pole	<a href="http://www.wago.com/2020-113/000-037">www.wago.com/2020-113/000-037</a>
	<b>Item no.: 2020-113/000-038</b> 1-conductor female plug; 1.5 mm <sup>2</sup> ; 13-pole	<a href="http://www.wago.com/2020-113/000-038">www.wago.com/2020-113/000-038</a>

**Item no.: 2020-113/000-039**1-conductor female plug; 1.5 mm<sup>2</sup>; 13-pole[www.wago.com/2020-113/000-039](http://www.wago.com/2020-113/000-039)**Item no.: 2020-113/125-000**1-conductor female plug; Locking lever; 1.5 mm<sup>2</sup>; 13-pole[www.wago.com/2020-113/125-000](http://www.wago.com/2020-113/125-000)**Item no.: 2020-113/135-000**1-conductor female plug; Strain relief plate; 1.5 mm<sup>2</sup>; 13-pole[www.wago.com/2020-113/135-000](http://www.wago.com/2020-113/135-000)**Item no.: 2020-113/145-000**1-conductor female plug; Strain relief plate; 1.5 mm<sup>2</sup>; 13-pole[www.wago.com/2020-113/145-000](http://www.wago.com/2020-113/145-000)**Item no.: 2020-114**1-conductor female plug; 1.5 mm<sup>2</sup>; 14-pole[www.wago.com/2020-114](http://www.wago.com/2020-114)**Item no.: 2020-114/000-036**1-conductor female plug; 1.5 mm<sup>2</sup>; 14-pole[www.wago.com/2020-114/000-036](http://www.wago.com/2020-114/000-036)**Item no.: 2020-114/000-037**1-conductor female plug; 1.5 mm<sup>2</sup>; 14-pole[www.wago.com/2020-114/000-037](http://www.wago.com/2020-114/000-037)**Item no.: 2020-114/000-038**1-conductor female plug; 1.5 mm<sup>2</sup>; 14-pole[www.wago.com/2020-114/000-038](http://www.wago.com/2020-114/000-038)**Item no.: 2020-114/000-039**1-conductor female plug; 1.5 mm<sup>2</sup>; 14-pole[www.wago.com/2020-114/000-039](http://www.wago.com/2020-114/000-039)**Item no.: 2020-114/125-000**1-conductor female plug; Locking lever; 1.5 mm<sup>2</sup>; 14-pole[www.wago.com/2020-114/125-000](http://www.wago.com/2020-114/125-000)**Item no.: 2020-114/135-000**1-conductor female plug; Strain relief plate; 1.5 mm<sup>2</sup>; 14-pole[www.wago.com/2020-114/135-000](http://www.wago.com/2020-114/135-000)**Item no.: 2020-114/145-000**1-conductor female plug; Strain relief plate; 1.5 mm<sup>2</sup>; 14-pole[www.wago.com/2020-114/145-000](http://www.wago.com/2020-114/145-000)**Item no.: 2020-115**1-conductor female plug; 1.5 mm<sup>2</sup>; 15-pole[www.wago.com/2020-115](http://www.wago.com/2020-115)**Item no.: 2020-115/000-036**1-conductor female plug; 1.5 mm<sup>2</sup>; 15-pole[www.wago.com/2020-115/000-036](http://www.wago.com/2020-115/000-036)**Item no.: 2020-115/000-037**1-conductor female plug; 1.5 mm<sup>2</sup>; 15-pole[www.wago.com/2020-115/000-037](http://www.wago.com/2020-115/000-037)

	<b>Item no.: 2020-115/000-038</b> 1-conductor female plug; 1.5 mm <sup>2</sup> ; 15-pole	<a href="http://www.wago.com/2020-115/000-038">www.wago.com/2020-115/000-038</a>
	<b>Item no.: 2020-115/000-039</b> 1-conductor female plug; 1.5 mm <sup>2</sup> ; 15-pole	<a href="http://www.wago.com/2020-115/000-039">www.wago.com/2020-115/000-039</a>
	<b>Item no.: 2020-115/125-000</b> 1-conductor female plug; Locking lever; 1.5 mm <sup>2</sup> ; 15-pole	<a href="http://www.wago.com/2020-115/125-000">www.wago.com/2020-115/125-000</a>
	<b>Item no.: 2020-115/135-000</b> 1-conductor female plug; Strain relief plate; 1.5 mm <sup>2</sup> ; 15-pole	<a href="http://www.wago.com/2020-115/135-000">www.wago.com/2020-115/135-000</a>
	<b>Item no.: 2020-115/145-000</b> 1-conductor female plug; Strain relief plate; 1.5 mm <sup>2</sup> ; 15-pole	<a href="http://www.wago.com/2020-115/145-000">www.wago.com/2020-115/145-000</a>
	<b>Item no.: 2020-202</b> 2-conductor female connector; 1.5 mm <sup>2</sup> ; 2-pole	<a href="http://www.wago.com/2020-202">www.wago.com/2020-202</a>
	<b>Item no.: 2020-202/122-000</b> 2-conductor female connector; Locking lever; 1.5 mm <sup>2</sup> ; 2-pole	<a href="http://www.wago.com/2020-202/122-000">www.wago.com/2020-202/122-000</a>
	<b>Item no.: 2020-202/132-000</b> 2-conductor female connector; Strain relief plate; 1.5 mm <sup>2</sup> ; 2-pole	<a href="http://www.wago.com/2020-202/132-000">www.wago.com/2020-202/132-000</a>
	<b>Item no.: 2020-202/142-000</b> 2-conductor female connector; Strain relief plate; 1.5 mm <sup>2</sup> ; 2-pole	<a href="http://www.wago.com/2020-202/142-000">www.wago.com/2020-202/142-000</a>
	<b>Item no.: 2020-203</b> 2-conductor female connector; 1.5 mm <sup>2</sup> ; 3-pole	<a href="http://www.wago.com/2020-203">www.wago.com/2020-203</a>
	<b>Item no.: 2020-203/000-036</b> 2-conductor female connector; 1.5 mm <sup>2</sup> ; 3-pole	<a href="http://www.wago.com/2020-203/000-036">www.wago.com/2020-203/000-036</a>
	<b>Item no.: 2020-203/000-037</b> 2-conductor female connector; 1.5 mm <sup>2</sup> ; 3-pole	<a href="http://www.wago.com/2020-203/000-037">www.wago.com/2020-203/000-037</a>
	<b>Item no.: 2020-203/000-038</b> 2-conductor female connector; 1.5 mm <sup>2</sup> ; 3-pole	<a href="http://www.wago.com/2020-203/000-038">www.wago.com/2020-203/000-038</a>
	<b>Item no.: 2020-203/000-039</b> 2-conductor female connector; 1.5 mm <sup>2</sup> ; 3-pole	<a href="http://www.wago.com/2020-203/000-039">www.wago.com/2020-203/000-039</a>
	<b>Item no.: 2020-203/122-000</b> 2-conductor female connector; Locking lever; 1.5 mm <sup>2</sup> ; 3-pole	<a href="http://www.wago.com/2020-203/122-000">www.wago.com/2020-203/122-000</a>



	<b>Item no.: 2020-203/132-000</b> 2-conductor female connector; Strain relief plate; 1.5 mm <sup>2</sup> ; 3-pole	<a href="http://www.wago.com/2020-203/132-000">www.wago.com/2020-203/132-000</a>
	<b>Item no.: 2020-203/142-000</b> 2-conductor female connector; Strain relief plate; 1.5 mm <sup>2</sup> ; 3-pole	<a href="http://www.wago.com/2020-203/142-000">www.wago.com/2020-203/142-000</a>
	<b>Item no.: 2020-204</b> 2-conductor female connector; 1.5 mm <sup>2</sup> ; 4-pole	<a href="http://www.wago.com/2020-204">www.wago.com/2020-204</a>
	<b>Item no.: 2020-204/000-036</b> 2-conductor female connector; 1.5 mm <sup>2</sup> ; 4-pole	<a href="http://www.wago.com/2020-204/000-036">www.wago.com/2020-204/000-036</a>
	<b>Item no.: 2020-204/000-037</b> 2-conductor female connector; 1.5 mm <sup>2</sup> ; 4-pole	<a href="http://www.wago.com/2020-204/000-037">www.wago.com/2020-204/000-037</a>
	<b>Item no.: 2020-204/000-038</b> 2-conductor female connector; 1.5 mm <sup>2</sup> ; 4-pole	<a href="http://www.wago.com/2020-204/000-038">www.wago.com/2020-204/000-038</a>
	<b>Item no.: 2020-204/000-039</b> 2-conductor female connector; 1.5 mm <sup>2</sup> ; 4-pole	<a href="http://www.wago.com/2020-204/000-039">www.wago.com/2020-204/000-039</a>
	<b>Item no.: 2020-204/124-000</b> 2-conductor female connector; Locking lever; 1.5 mm <sup>2</sup> ; 4-pole	<a href="http://www.wago.com/2020-204/124-000">www.wago.com/2020-204/124-000</a>
	<b>Item no.: 2020-204/133-000</b> 2-conductor female connector; Strain relief plate; 1.5 mm <sup>2</sup> ; 4-pole	<a href="http://www.wago.com/2020-204/133-000">www.wago.com/2020-204/133-000</a>
	<b>Item no.: 2020-204/143-000</b> 2-conductor female connector; Strain relief plate; 1.5 mm <sup>2</sup> ; 4-pole	<a href="http://www.wago.com/2020-204/143-000">www.wago.com/2020-204/143-000</a>
	<b>Item no.: 2020-205</b> 2-conductor female connector; 1.5 mm <sup>2</sup> ; 5-pole	<a href="http://www.wago.com/2020-205">www.wago.com/2020-205</a>
	<b>Item no.: 2020-205/000-036</b> 2-conductor female connector; 1.5 mm <sup>2</sup> ; 5-pole	<a href="http://www.wago.com/2020-205/000-036">www.wago.com/2020-205/000-036</a>
	<b>Item no.: 2020-205/000-037</b> 2-conductor female connector; 1.5 mm <sup>2</sup> ; 5-pole	<a href="http://www.wago.com/2020-205/000-037">www.wago.com/2020-205/000-037</a>
	<b>Item no.: 2020-205/000-038</b> 2-conductor female connector; 1.5 mm <sup>2</sup> ; 5-pole	<a href="http://www.wago.com/2020-205/000-038">www.wago.com/2020-205/000-038</a>
	<b>Item no.: 2020-205/000-039</b> 2-conductor female connector; 1.5 mm <sup>2</sup> ; 5-pole	<a href="http://www.wago.com/2020-205/000-039">www.wago.com/2020-205/000-039</a>

	<b>Item no.: 2020-205/124-000</b> 2-conductor female connector; Locking lever; 1.5 mm <sup>2</sup> ; 5-pole	<a href="http://www.wago.com/2020-205/124-000">www.wago.com/2020-205/124-000</a>
	<b>Item no.: 2020-205/133-000</b> 2-conductor female connector; Strain relief plate; 1.5 mm <sup>2</sup> ; 5-pole	<a href="http://www.wago.com/2020-205/133-000">www.wago.com/2020-205/133-000</a>
	<b>Item no.: 2020-205/143-000</b> 2-conductor female connector; Strain relief plate; 1.5 mm <sup>2</sup> ; 5-pole	<a href="http://www.wago.com/2020-205/143-000">www.wago.com/2020-205/143-000</a>
	<b>Item no.: 2020-206</b> 2-conductor female connector; 1.5 mm <sup>2</sup> ; 6-pole	<a href="http://www.wago.com/2020-206">www.wago.com/2020-206</a>
	<b>Item no.: 2020-206/000-036</b> 2-conductor female connector; 1.5 mm <sup>2</sup> ; 6-pole	<a href="http://www.wago.com/2020-206/000-036">www.wago.com/2020-206/000-036</a>
	<b>Item no.: 2020-206/000-037</b> 2-conductor female connector; 1.5 mm <sup>2</sup> ; 6-pole	<a href="http://www.wago.com/2020-206/000-037">www.wago.com/2020-206/000-037</a>
	<b>Item no.: 2020-206/000-038</b> 2-conductor female connector; 1.5 mm <sup>2</sup> ; 6-pole	<a href="http://www.wago.com/2020-206/000-038">www.wago.com/2020-206/000-038</a>
	<b>Item no.: 2020-206/000-039</b> 2-conductor female connector; 1.5 mm <sup>2</sup> ; 6-pole	<a href="http://www.wago.com/2020-206/000-039">www.wago.com/2020-206/000-039</a>
	<b>Item no.: 2020-206/124-000</b> 2-conductor female connector; Locking lever; 1.5 mm <sup>2</sup> ; 6-pole	<a href="http://www.wago.com/2020-206/124-000">www.wago.com/2020-206/124-000</a>
	<b>Item no.: 2020-206/133-000</b> 2-conductor female connector; Strain relief plate; 1.5 mm <sup>2</sup> ; 6-pole	<a href="http://www.wago.com/2020-206/133-000">www.wago.com/2020-206/133-000</a>
	<b>Item no.: 2020-206/143-000</b> 2-conductor female connector; Strain relief plate; 1.5 mm <sup>2</sup> ; 6-pole	<a href="http://www.wago.com/2020-206/143-000">www.wago.com/2020-206/143-000</a>
	<b>Item no.: 2020-207</b> 2-conductor female connector; 1.5 mm <sup>2</sup> ; 7-pole	<a href="http://www.wago.com/2020-207">www.wago.com/2020-207</a>
	<b>Item no.: 2020-207/000-036</b> 2-conductor female connector; 1.5 mm <sup>2</sup> ; 7-pole	<a href="http://www.wago.com/2020-207/000-036">www.wago.com/2020-207/000-036</a>
	<b>Item no.: 2020-207/000-037</b> 2-conductor female connector; 1.5 mm <sup>2</sup> ; 7-pole	<a href="http://www.wago.com/2020-207/000-037">www.wago.com/2020-207/000-037</a>
	<b>Item no.: 2020-207/000-038</b> 2-conductor female connector; 1.5 mm <sup>2</sup> ; 7-pole	<a href="http://www.wago.com/2020-207/000-038">www.wago.com/2020-207/000-038</a>



**Item no.: 2020-207/000-039**  
2-conductor female connector; 1.5 mm<sup>2</sup>; 7-pole

[www.wago.com/2020-207/000-039](http://www.wago.com/2020-207/000-039)

**Item no.: 2020-207/124-000**  
2-conductor female connector; Locking lever; 1.5 mm<sup>2</sup>; 7-pole

[www.wago.com/2020-207/124-000](http://www.wago.com/2020-207/124-000)

**Item no.: 2020-207/134-000**  
2-conductor female connector; Strain relief plate; 1.5 mm<sup>2</sup>; 7-pole

[www.wago.com/2020-207/134-000](http://www.wago.com/2020-207/134-000)



**Item no.: 2020-207/144-000**  
2-conductor female connector; Strain relief plate; 1.5 mm<sup>2</sup>; 7-pole

[www.wago.com/2020-207/144-000](http://www.wago.com/2020-207/144-000)

**Item no.: 2020-208**  
2-conductor female connector; 1.5 mm<sup>2</sup>; 8-pole

[www.wago.com/2020-208](http://www.wago.com/2020-208)

**Item no.: 2020-208/000-036**  
2-conductor female connector; 1.5 mm<sup>2</sup>; 8-pole

[www.wago.com/2020-208/000-036](http://www.wago.com/2020-208/000-036)

**Item no.: 2020-208/000-037**  
2-conductor female connector; 1.5 mm<sup>2</sup>; 8-pole

[www.wago.com/2020-208/000-037](http://www.wago.com/2020-208/000-037)

**Item no.: 2020-208/000-038**  
2-conductor female connector; 1.5 mm<sup>2</sup>; 8-pole

[www.wago.com/2020-208/000-038](http://www.wago.com/2020-208/000-038)

**Item no.: 2020-208/000-039**  
2-conductor female connector; 1.5 mm<sup>2</sup>; 8-pole

[www.wago.com/2020-208/000-039](http://www.wago.com/2020-208/000-039)

**Item no.: 2020-208/124-000**  
2-conductor female connector; Locking lever; 1.5 mm<sup>2</sup>; 8-pole

[www.wago.com/2020-208/124-000](http://www.wago.com/2020-208/124-000)

**Item no.: 2020-208/134-000**  
2-conductor female connector; Strain relief plate; 1.5 mm<sup>2</sup>; 8-pole

[www.wago.com/2020-208/134-000](http://www.wago.com/2020-208/134-000)



**Item no.: 2020-208/144-000**  
2-conductor female connector; Strain relief plate; 1.5 mm<sup>2</sup>; 8-pole

[www.wago.com/2020-208/144-000](http://www.wago.com/2020-208/144-000)

**Item no.: 2020-209**  
2-conductor female connector; 1.5 mm<sup>2</sup>; 9-pole

[www.wago.com/2020-209](http://www.wago.com/2020-209)



**Item no.: 2020-209/000-036**  
2-conductor female connector; 1.5 mm<sup>2</sup>; 9-pole

[www.wago.com/2020-209/000-036](http://www.wago.com/2020-209/000-036)



**Item no.: 2020-209/000-037**  
2-conductor female connector; 1.5 mm<sup>2</sup>; 9-pole

[www.wago.com/2020-209/000-037](http://www.wago.com/2020-209/000-037)



**Item no.: 2020-209/000-038**  
2-conductor female connector; 1.5 mm<sup>2</sup>; 9-pole

[www.wago.com/2020-209/000-038](http://www.wago.com/2020-209/000-038)



**Item no.: 2020-209/000-039**  
2-conductor female connector; 1.5 mm<sup>2</sup>; 9-pole

[www.wago.com/2020-209/000-039](http://www.wago.com/2020-209/000-039)

**Item no.: 2020-209/124-000**  
2-conductor female connector; Locking lever; 1.5 mm<sup>2</sup>; 9-pole

[www.wago.com/2020-209/124-000](http://www.wago.com/2020-209/124-000)

**Item no.: 2020-209/134-000**  
2-conductor female connector; Strain relief plate; 1.5 mm<sup>2</sup>; 9-pole

[www.wago.com/2020-209/134-000](http://www.wago.com/2020-209/134-000)



**Item no.: 2020-209/144-000**  
2-conductor female connector; Strain relief plate; 1.5 mm<sup>2</sup>; 9-pole

[www.wago.com/2020-209/144-000](http://www.wago.com/2020-209/144-000)

**Item no.: 2020-210**  
2-conductor female connector; 1.5 mm<sup>2</sup>; 10-pole

[www.wago.com/2020-210](http://www.wago.com/2020-210)

**Item no.: 2020-210/000-036**  
2-conductor female connector; 1.5 mm<sup>2</sup>; 10-pole

[www.wago.com/2020-210/000-036](http://www.wago.com/2020-210/000-036)

**Item no.: 2020-210/000-037**  
2-conductor female connector; 1.5 mm<sup>2</sup>; 10-pole

[www.wago.com/2020-210/000-037](http://www.wago.com/2020-210/000-037)

**Item no.: 2020-210/000-038**  
2-conductor female connector; 1.5 mm<sup>2</sup>; 10-pole

[www.wago.com/2020-210/000-038](http://www.wago.com/2020-210/000-038)

**Item no.: 2020-210/000-039**  
2-conductor female connector; 1.5 mm<sup>2</sup>; 10-pole

[www.wago.com/2020-210/000-039](http://www.wago.com/2020-210/000-039)

**Item no.: 2020-210/125-000**  
2-conductor female connector; Locking lever; 1.5 mm<sup>2</sup>; 10-pole

[www.wago.com/2020-210/125-000](http://www.wago.com/2020-210/125-000)

**Item no.: 2020-210/135-000**  
2-conductor female connector; Strain relief plate; 1.5 mm<sup>2</sup>; 10-pole

[www.wago.com/2020-210/135-000](http://www.wago.com/2020-210/135-000)



**Item no.: 2020-210/145-000**  
2-conductor female connector; Strain relief plate; 1.5 mm<sup>2</sup>; 10-pole







[www.wago.com/2020-210/145-000](http://www.wago.com/2020-210/145-000)



**Item no.: 2020-211**  
2-conductor female connector; 1.5 mm<sup>2</sup>; 11-pole



[www.wago.com/2020-211](http://www.wago.com/2020-211)

**Item no.: 2020-211/000-036**  
2-conductor female connector; 1.5 mm<sup>2</sup>; 11-pole




[www.wago.com/2020-211/000-036](http://www.wago.com/2020-211/000-036)

	<b>Item no.: 2020-211/000-037</b> 2-conductor female connector; 1.5 mm <sup>2</sup> ; 11-pole	<a href="http://www.wago.com/2020-211/000-037">www.wago.com/2020-211/000-037</a>
	<b>Item no.: 2020-211/000-038</b> 2-conductor female connector; 1.5 mm <sup>2</sup> ; 11-pole	<a href="http://www.wago.com/2020-211/000-038">www.wago.com/2020-211/000-038</a>
	<b>Item no.: 2020-211/000-039</b> 2-conductor female connector; 1.5 mm <sup>2</sup> ; 11-pole	<a href="http://www.wago.com/2020-211/000-039">www.wago.com/2020-211/000-039</a>
	<b>Item no.: 2020-211/125-000</b> 2-conductor female connector; Locking lever; 1.5 mm <sup>2</sup> ; 11-pole	<a href="http://www.wago.com/2020-211/125-000">www.wago.com/2020-211/125-000</a>
	<b>Item no.: 2020-211/135-000</b> 2-conductor female connector; Strain relief plate; 1.5 mm <sup>2</sup> ; 11-pole	<a href="http://www.wago.com/2020-211/135-000">www.wago.com/2020-211/135-000</a>
	<b>Item no.: 2020-211/145-000</b> 2-conductor female connector; Strain relief plate; 1.5 mm <sup>2</sup> ; 11-pole	<a href="http://www.wago.com/2020-211/145-000">www.wago.com/2020-211/145-000</a>
	<b>Item no.: 2020-212</b> 2-conductor female connector; 1.5 mm <sup>2</sup> ; 12-pole	<a href="http://www.wago.com/2020-212">www.wago.com/2020-212</a>
	<b>Item no.: 2020-212/000-036</b> 2-conductor female connector; 1.5 mm <sup>2</sup> ; 12-pole	<a href="http://www.wago.com/2020-212/000-036">www.wago.com/2020-212/000-036</a>
	<b>Item no.: 2020-212/000-037</b> 2-conductor female connector; 1.5 mm <sup>2</sup> ; 12-pole	<a href="http://www.wago.com/2020-212/000-037">www.wago.com/2020-212/000-037</a>
	<b>Item no.: 2020-212/000-038</b> 2-conductor female connector; 1.5 mm <sup>2</sup> ; 12-pole	<a href="http://www.wago.com/2020-212/000-038">www.wago.com/2020-212/000-038</a>
	<b>Item no.: 2020-212/000-039</b> 2-conductor female connector; 1.5 mm <sup>2</sup> ; 12-pole	<a href="http://www.wago.com/2020-212/000-039">www.wago.com/2020-212/000-039</a>
	<b>Item no.: 2020-212/125-000</b> 2-conductor female connector; Locking lever; 1.5 mm <sup>2</sup> ; 12-pole	<a href="http://www.wago.com/2020-212/125-000">www.wago.com/2020-212/125-000</a>
	<b>Item no.: 2020-212/135-000</b> 2-conductor female connector; Strain relief plate; 1.5 mm <sup>2</sup> ; 12-pole	<a href="http://www.wago.com/2020-212/135-000">www.wago.com/2020-212/135-000</a>
	<b>Item no.: 2020-212/145-000</b> 2-conductor female connector; Strain relief plate; 1.5 mm <sup>2</sup> ; 12-pole	<a href="http://www.wago.com/2020-212/145-000">www.wago.com/2020-212/145-000</a>
	<b>Item no.: 2020-213</b> 2-conductor female connector; 1.5 mm <sup>2</sup> ; 13-pole	<a href="http://www.wago.com/2020-213">www.wago.com/2020-213</a>



<b>Item no.: 2020-213/000-036</b> 2-conductor female connector; 1.5 mm <sup>2</sup> ; 13-pole	<a href="http://www.wago.com/2020-213/000-036">www.wago.com/2020-213/000-036</a>	
<b>Item no.: 2020-213/000-037</b> 2-conductor female connector; 1.5 mm <sup>2</sup> ; 13-pole	<a href="http://www.wago.com/2020-213/000-037">www.wago.com/2020-213/000-037</a>	
<b>Item no.: 2020-213/000-038</b> 2-conductor female connector; 1.5 mm <sup>2</sup> ; 13-pole	<a href="http://www.wago.com/2020-213/000-038">www.wago.com/2020-213/000-038</a>	
<b>Item no.: 2020-213/000-039</b> 2-conductor female connector; 1.5 mm <sup>2</sup> ; 13-pole	<a href="http://www.wago.com/2020-213/000-039">www.wago.com/2020-213/000-039</a>	
<b>Item no.: 2020-213/125-000</b> 2-conductor female connector; Locking lever; 1.5 mm <sup>2</sup> ; 13-pole	<a href="http://www.wago.com/2020-213/125-000">www.wago.com/2020-213/125-000</a>	
<b>Item no.: 2020-213/135-000</b> 2-conductor female connector; Strain relief plate; 1.5 mm <sup>2</sup> ; 13-pole	<a href="http://www.wago.com/2020-213/135-000">www.wago.com/2020-213/135-000</a>	
	<b>Item no.: 2020-213/145-000</b> 2-conductor female connector; Strain relief plate; 1.5 mm <sup>2</sup> ; 13-pole	<a href="http://www.wago.com/2020-213/145-000">www.wago.com/2020-213/145-000</a>
<b>Item no.: 2020-214</b> 2-conductor female connector; 1.5 mm <sup>2</sup> ; 14-pole	<a href="http://www.wago.com/2020-214">www.wago.com/2020-214</a>	
<b>Item no.: 2020-214/000-036</b> 2-conductor female connector; 1.5 mm <sup>2</sup> ; 14-pole	<a href="http://www.wago.com/2020-214/000-036">www.wago.com/2020-214/000-036</a>	
<b>Item no.: 2020-214/000-037</b> 2-conductor female connector; 1.5 mm <sup>2</sup> ; 14-pole	<a href="http://www.wago.com/2020-214/000-037">www.wago.com/2020-214/000-037</a>	
<b>Item no.: 2020-214/000-038</b> 2-conductor female connector; 1.5 mm <sup>2</sup> ; 14-pole	<a href="http://www.wago.com/2020-214/000-038">www.wago.com/2020-214/000-038</a>	
<b>Item no.: 2020-214/000-039</b> 2-conductor female connector; 1.5 mm <sup>2</sup> ; 14-pole	<a href="http://www.wago.com/2020-214/000-039">www.wago.com/2020-214/000-039</a>	
<b>Item no.: 2020-214/125-000</b> 2-conductor female connector; Locking lever; 1.5 mm <sup>2</sup> ; 14-pole	<a href="http://www.wago.com/2020-214/125-000">www.wago.com/2020-214/125-000</a>	
<b>Item no.: 2020-214/135-000</b> 2-conductor female connector; Strain relief plate; 1.5 mm <sup>2</sup> ; 14-pole	<a href="http://www.wago.com/2020-214/135-000">www.wago.com/2020-214/135-000</a>	
	<b>Item no.: 2020-214/145-000</b> 2-conductor female connector; Strain relief plate; 1.5 mm <sup>2</sup> ; 14-pole	<a href="http://www.wago.com/2020-214/145-000">www.wago.com/2020-214/145-000</a>

	<b>Item no.: 2020-215</b> 2-conductor female connector; 1.5 mm <sup>2</sup> ; 15-pole	<a href="http://www.wago.com/2020-215">www.wago.com/2020-215</a>
	<b>Item no.: 2020-215/000-036</b> 2-conductor female connector; 1.5 mm <sup>2</sup> ; 15-pole	<a href="http://www.wago.com/2020-215/000-036">www.wago.com/2020-215/000-036</a>
	<b>Item no.: 2020-215/000-037</b> 2-conductor female connector; 1.5 mm <sup>2</sup> ; 15-pole	<a href="http://www.wago.com/2020-215/000-037">www.wago.com/2020-215/000-037</a>
	<b>Item no.: 2020-215/000-038</b> 2-conductor female connector; 1.5 mm <sup>2</sup> ; 15-pole	<a href="http://www.wago.com/2020-215/000-038">www.wago.com/2020-215/000-038</a>
	<b>Item no.: 2020-215/000-039</b> 2-conductor female connector; 1.5 mm <sup>2</sup> ; 15-pole	<a href="http://www.wago.com/2020-215/000-039">www.wago.com/2020-215/000-039</a>
	<b>Item no.: 2020-215/125-000</b> 2-conductor female connector; Locking lever; 1.5 mm <sup>2</sup> ; 15-pole	<a href="http://www.wago.com/2020-215/125-000">www.wago.com/2020-215/125-000</a>
	<b>Item no.: 2020-215/135-000</b> 2-conductor female connector; Strain relief plate; 1.5 mm <sup>2</sup> ; 15-pole	<a href="http://www.wago.com/2020-215/135-000">www.wago.com/2020-215/135-000</a>
	<b>Item no.: 2020-215/145-000</b> 2-conductor female connector; Strain relief plate; 1.5 mm <sup>2</sup> ; 15-pole	<a href="http://www.wago.com/2020-215/145-000">www.wago.com/2020-215/145-000</a>

## check

	<b>Item no.: 2009-174</b> Test plug adapter; for 4 mm Ø test plugs; for testing TOPJOB®S rail-mounted terminal blocks	<a href="http://www.wago.com/2009-174">www.wago.com/2009-174</a>
	<b>Item no.: 2009-182</b> Testing tap; for max. 2.5 mm <sup>2</sup> ; tool-free connection for individual test wires 0.08 - 2.5 mm	<a href="http://www.wago.com/2009-182">www.wago.com/2009-182</a>
	<b>Item no.: 859-500</b> Test pin; 1 mm Ø; with solder connection for test wire	<a href="http://www.wago.com/859-500">www.wago.com/859-500</a>

## End plate

	<b>Item no.: 2020-1291</b> End and intermediate plate; 1 mm thick	<a href="http://www.wago.com/2020-1291">www.wago.com/2020-1291</a>
	<b>Item no.: 2020-1292</b> End and intermediate plate; 1 mm thick	<a href="http://www.wago.com/2020-1292">www.wago.com/2020-1292</a>

Downloads

Documentation

Bid Text



2020-1201

Aug 14, 2018

DOCX  
15.4 kB

Download

---

### smartDATA

#### CAD data

3D Download 2020-1201

URL

Download

---

### Product family

**X-COM S-Mini**

[Show all products from the family](#)

Subject to changes.