



Data sheet | Item number: 2022-1204

1-conductor/1-pin carrier terminal block; for DIN-rail 35 x 15 and 35 x 7.5;
2.5 mm²; Push-in CAGE CLAMP®

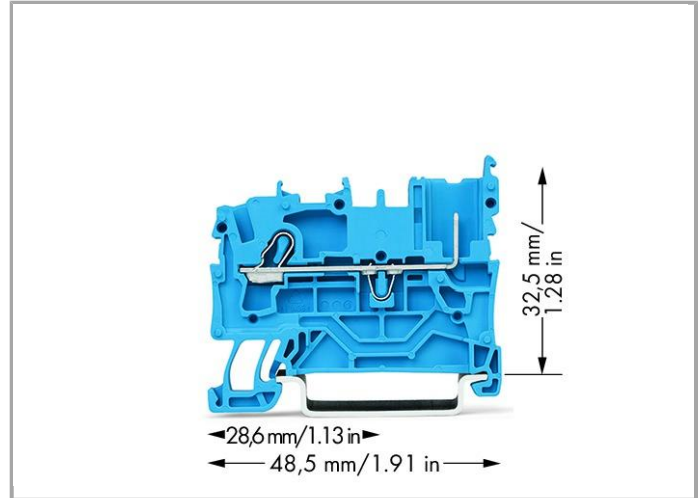

www.wago.com/2022-1204

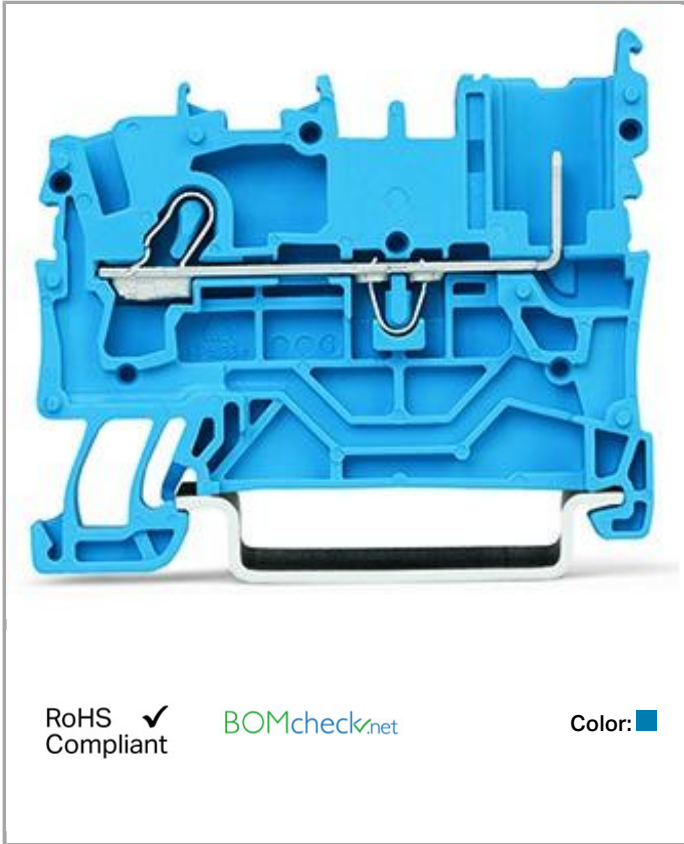

RoHS Compliant

BOMcheck.net

Color:

Data

Electrical data

Ratings per IEC/EN 60664-1

| | |
|---------------------------------|---|
| Rated voltage (III / 3) | 690 V |
| Rated impulse voltage (III / 3) | 6 kV |
| Rated current | 24 A |
| Rated current (2) | 32 A |
| Legend (ratings) | (III / 3) ± Overvoltage category III / Pollution degree 3 |

Connection data

| | |
|---------------------------------|---------------------------|
| Connection technology | Push-in CAGE CLAMP® |
| Actuation type | Operating tool Push-in |
| Connectable conductor materials | Copper |

| | Aluminum |
|---|--|
| Nominal cross section | 2.5 mm ² |
| Solid conductor | 0.25 ... 4 mm ² / 22 ... 12 AWG |
| Solid conductor, push-in termination | 0.75 ... 4 mm ² / 18 ... 12 AWG |
| Fine-stranded conductor | 0.25 ... 4 mm ² / 22 ... 12 AWG |
| Fine-stranded conductor with ferrule, push-in termination, from | 0.75 mm ² / 18 AWG |
| Strip length | 10 ... 12 mm / 0.39 ... 0.47 Inch |
| Total number of connection points | 1 |
| Total number of potentials | 1 |
| Number of levels | 1 |
| Type of wiring | Front-entry wiring |

Geometrical Data

| | |
|---------------------------------------|----------------------|
| Width | 5.2 mm / 0.205 inch |
| Height from upper-edge of DIN-35 rail | 32.5 mm / 1.28 inch |
| Depth | 48.5 mm / 1.909 inch |

Mechanical data

| | |
|------------------|---------------------|
| Design | horizontal |
| Type of mounting | DIN-35 rail |
| Marking level | Center/side marking |

Material Data

| | |
|---------------------|----------------------|
| Color | blue |
| Insulating material | Polyamide 66 (PA 66) |
| Fire load | 0.112 MJ |
| Weight | 5.038 g |

Commercial data

| | |
|--------------------|-------------------|
| Country of origin | CN |
| GTIN | 4050821145073 |
| Customs Tariff No. | 85366990990 |
| Product Group | 18 (X-COM-System) |

Approvals / Certificates

Country specific Approvals


 



 


| Logo | Approval | Certificate name |
|--|---------------------------------|------------------|
|  | CSA DEKRA Certification B.V. | 70107915 |

UL-Approvals


| Logo | Approval | Certificate name |
|--|--------------------------------------|------------------|
|  | UR Underwriters Laboratories Inc. | E45172 |

Compatible products




Carrier rail

















| | | |
|--|--|--|
|  | Item no.: 210-112 Steel carrier rail; 35 x 7.5 mm; 1 mm thick; 2 m long; slotted; according to EN 60715; "Hole width 25 mm | www.wago.com/210-112 |
|  | Item no.: 210-113 Steel carrier rail; 35 x 7.5 mm; 1 mm thick; 2 m long; unslotted; according to EN 60715 | www.wago.com/210-113 |
|  | Item no.: 210-114 Steel carrier rail; 35 x 15 mm; 1.5 mm thick; 2 m long; unslotted; similar to EN 60715 | www.wago.com/210-114 |
|  | Item no.: 210-115 Steel carrier rail; 35 x 7.5 mm; 1 mm thick; 2 m long; slotted; according to EN 60715; "Hole width 18 mm | www.wago.com/210-115 |
|  | Item no.: 210-118 Steel carrier rail; 35 x 15 mm; 2.3 mm thick; 2 m long; unslotted; according to EN 60715 | www.wago.com/210-118 |
|  | Item no.: 210-196 Aluminum carrier rail; 35 x 8.2 mm; 1.6 mm thick; 2 m long; unslotted; similar to EN 60715 | www.wago.com/210-196 |
|  | Item no.: 210-197 Steel carrier rail; 35 x 15 mm; 1.5 mm thick; 2 m long; slotted; similar to EN 60715 | www.wago.com/210-197 |
|  | Item no.: 210-198 Copper carrier rail; 35 x 15 mm; 2.3 mm thick; 2 m long; unslotted; according to EN 60715 | www.wago.com/210-198 |

















Coding














| | | |
|--|---|--|
|  | Item no.: 2022-100 Carrier with 6 coding pins; for coding of female plugs | www.wago.com/2022-100 |
|--|---|--|

Jumper

| | | |
|--|---|--|
|  | Item no.: 2002-400 Adjacent jumper for continuous commoning; insulated; 2-way; Nominal current 25 A | www.wago.com/2002-400 |
|  | Item no.: 2002-402 Push-in type jumper bar; insulated; 2-way; Nominal current 25 A | www.wago.com/2002-402 |
|  | Item no.: 2002-402/000-005 Push-in type jumper bar; insulated; 2-way; Nominal current 25 A | www.wago.com/2002-402/000-005 |

| | | |
|--|--|--|
|  | Item no.: 2002-402/000-006 Push-in type jumper bar; insulated; 2-way; Nominal current 25 A | www.wago.com/2002-402/000-006 |
|  | Item no.: 2002-403 Push-in type jumper bar; insulated; 3-way; Nominal current 25 A | www.wago.com/2002-403 |
|  | Item no.: 2002-403/000-005 Push-in type jumper bar; insulated; 3-way; Nominal current 25 A | www.wago.com/2002-403/000-005 |
|  | Item no.: 2002-403/000-006 Push-in type jumper bar; insulated; 3-way; Nominal current 25 A | www.wago.com/2002-403/000-006 |
|  | Item no.: 2002-404 Push-in type jumper bar; insulated; 4-way; Nominal current 25 A | www.wago.com/2002-404 |
|  | Item no.: 2002-404/000-005 Push-in type jumper bar; insulated; 4-way; Nominal current 25 A | www.wago.com/2002-404/000-005 |
|  | Item no.: 2002-404/000-006 Push-in type jumper bar; insulated; 4-way; Nominal current 25 A | www.wago.com/2002-404/000-006 |
|  | Item no.: 2002-405 Push-in type jumper bar; insulated; 5-way; Nominal current 25 A | www.wago.com/2002-405 |
|  | Item no.: 2002-405/000-005 Push-in type jumper bar; insulated; 5-way; Nominal current 25 A | www.wago.com/2002-405/000-005 |
|  | Item no.: 2002-405/000-006 Push-in type jumper bar; insulated; 5-way; Nominal current 25 A | www.wago.com/2002-405/000-006 |
|  | Item no.: 2002-405/011-000 Star point jumper; insulated; 3-way (1-3-5); IN = IN terminal block | www.wago.com/2002-405/011-000 |
|  | Item no.: 2002-406 Push-in type jumper bar; insulated; 6-way; Nominal current 25 A | www.wago.com/2002-406 |
|  | Item no.: 2002-406/000-005 Push-in type jumper bar; insulated; 6-way; Nominal current 25 A | www.wago.com/2002-406/000-005 |
|  | Item no.: 2002-406/000-006 Push-in type jumper bar; insulated; 6-way; Nominal current 25 A | www.wago.com/2002-406/000-006 |
|  | Item no.: 2002-406/020-000 Delta jumper; insulated; 1-2 3-4 5-6; IN = IN terminal block | www.wago.com/2002-406/020-000 |
|  | Item no.: 2002-407 Push-in type jumper bar; insulated; 7-way; Nominal current 25 A | www.wago.com/2002-407 |

| | | |
|--|---|--|
|  | Item no.: 2002-407/000-005 Push-in type jumper bar; insulated; 7-way; Nominal current 25 A | www.wago.com/2002-407/000-005 |
|  | Item no.: 2002-407/000-006 Push-in type jumper bar; insulated; 7-way; Nominal current 25 A | www.wago.com/2002-407/000-006 |
|  | Item no.: 2002-408 Push-in type jumper bar; insulated; 8-way; Nominal current 25 A | www.wago.com/2002-408 |
|  | Item no.: 2002-408/000-005 Push-in type jumper bar; insulated; 8-way; Nominal current 25 A | www.wago.com/2002-408/000-005 |
|  | Item no.: 2002-408/000-006 Push-in type jumper bar; insulated; 8-way; Nominal current 25 A | www.wago.com/2002-408/000-006 |
|  | Item no.: 2002-409 Push-in type jumper bar; insulated; 9-way; Nominal current 25 A | www.wago.com/2002-409 |
|  | Item no.: 2002-409/000-005 Push-in type jumper bar; insulated; 9-way; Nominal current 25 A | www.wago.com/2002-409/000-005 |
|  | Item no.: 2002-409/000-006 Push-in type jumper bar; insulated; 9-way; Nominal current 25 A | www.wago.com/2002-409/000-006 |
|  | Item no.: 2002-410 Push-in type jumper bar; insulated; 10-way; Nominal current 25 A | www.wago.com/2002-410 |
|  | Item no.: 2002-410/000-005 Push-in type jumper bar; insulated; 10-way; Nominal current 25 A | www.wago.com/2002-410/000-005 |
|  | Item no.: 2002-410/000-006 Push-in type jumper bar; insulated; 10-way; Nominal current 25 A | www.wago.com/2002-410/000-006 |
|  | Item no.: 2002-423 Push-in type jumper bar; insulated; from 1 to 3; Nominal current 25 A | www.wago.com/2002-423 |
|  | Item no.: 2002-423/000-005 Adjacent jumper for continuous commoning; insulated; from 1 to 3; Nominal current 25 A | www.wago.com/2002-423/000-005 |
|  | Item no.: 2002-423/000-006 Adjacent jumper for continuous commoning; insulated; from 1 to 3; Nominal current 25 A | www.wago.com/2002-423/000-006 |
|  | Item no.: 2002-433 Push-in type jumper bar; insulated; from 1 to 3; Nominal current 25 A | www.wago.com/2002-433 |
|  | Item no.: 2002-434 Push-in type jumper bar; insulated; from 1 to 4; Nominal current 25 A | www.wago.com/2002-434 |
| | Item no.: 2002-435 | |

| | | |
|--|---|--|
|  | Push-in type jumper bar; insulated; from 1 to 5; Nominal current 25 A | www.wago.com/2002-435 |
|  | Item no.: 2002-436 Push-in type jumper bar; insulated; from 1 to 6; Nominal current 25 A | www.wago.com/2002-436 |
|  | Item no.: 2002-437 Push-in type jumper bar; insulated; from 1 to 7; Nominal current 25 A | www.wago.com/2002-437 |
|  | Item no.: 2002-438 Push-in type jumper bar; insulated; from 1 to 8; Nominal current 25 A | www.wago.com/2002-438 |
|  | Item no.: 2002-439 Push-in type jumper bar; insulated; from 1 to 9; Nominal current 25 A | www.wago.com/2002-439 |
|  | Item no.: 2002-440 Push-in type jumper bar; insulated; from 1 to 10; Nominal current 25 A | www.wago.com/2002-440 |
|  | Item no.: 2002-472 Staggered jumper; insulated; 2-way; Nominal current 25 A; suitable for 2002 and 2003 Series rail-mounted terminal blocks | www.wago.com/2002-472 |
|  | Item no.: 2002-473 Staggered jumper; insulated; 3-way; Nominal current 25 A; suitable for 2002 and 2003 Series rail-mounted terminal blocks | www.wago.com/2002-473 |
| | Item no.: 2002-473/011-000 Ready-made staggered jumper; insulated; 2-way (1-3); Nominal current 25 A; with contact lugs broken off at the factory and circuit marking | www.wago.com/2002-473/011-000 |
|  | Item no.: 2002-474 Staggered jumper; insulated; 4-way; Nominal current 25 A; suitable for 2002 and 2003 Series rail-mounted terminal blocks | www.wago.com/2002-474 |
|  | Item no.: 2002-475 Staggered jumper; insulated; 5-way; Nominal current 25 A; suitable for 2002 and 2003 Series rail-mounted terminal blocks | www.wago.com/2002-475 |
| | Item no.: 2002-475/011-000 Ready-made staggered jumper; insulated; 3-way (1-3-5); Nominal current 25 A; with contact lugs broken off at the factory and circuit marking | www.wago.com/2002-475/011-000 |
|  | Item no.: 2002-476 Staggered jumper; insulated; 6-way; Nominal current 25 A; suitable for 2002 and 2003 Series rail-mounted terminal blocks | www.wago.com/2002-476 |
|  | Item no.: 2002-477 Staggered jumper; insulated; 7-way; Nominal current 25 A; suitable for 2002 and 2003 Series rail-mounted terminal blocks | www.wago.com/2002-477 |
|  | Item no.: 2002-477/011-000 Ready-made staggered jumper; insulated; 1-3-5-7; Nominal current 25 A; with contact lugs broken off at the factory and circuit marking | www.wago.com/2002-477/011-000 |
|  | Item no.: 2002-478 Staggered jumper; insulated; 8-way; Nominal current 25 A; suitable for 2002 and 2003 Series rail-mounted terminal blocks | www.wago.com/2002-478 |
|  | Item no.: 2002-479 Staggered jumper; insulated; 9-way; Nominal current 25 A; suitable for 2002 and 2003 Series rail-mounted terminal blocks | www.wago.com/2002-479 |
| | Item no.: 2002-479/011-000 | |

Ready-made staggered jumper; insulated; 1-3-5-7-9; Nominal current 25 A; with contact lugs broken off at the factory and circuit marking

www.wago.com/2002-479/011-000



Item no.: 2002-480

Staggered jumper; insulated; 10-way; Nominal current 25 A; suitable for 2002 and 2003 Series rail-mounted terminal blocks

www.wago.com/2002-480



Item no.: 2002-481

Staggered jumper; insulated; 11-way; Nominal current 25 A; suitable for 2002 and 2003 Series rail-mounted terminal blocks

www.wago.com/2002-481

Item no.: 2002-481/011-000

Ready-made staggered jumper; insulated; 1-3-5-7-9-11; Nominal current 25 A; with contact lugs broken off at the factory and circuit marking

www.wago.com/2002-481/011-000



Item no.: 2002-482

Staggered jumper; insulated; 12-way; Nominal current 25 A; suitable for 2002 and 2003 Series rail-mounted terminal blocks

www.wago.com/2002-482



Item no.: 2009-412

Push-in type wire jumper; insulated; wire length 60 mm; Conductor cross section 1.5 mm²; suitable for 2001, 2002, 2003 and 2022 Series rail-mounted terminal blocks

www.wago.com/2009-412



Item no.: 2009-414

Push-in type wire jumper; insulated; wire length 110 mm; Conductor cross section 1.5 mm²; suitable for 2001, 2002, 2003 and 2022 Series rail-mounted terminal blocks

www.wago.com/2009-414



Item no.: 2009-416

Push-in type wire jumper; insulated; wire length 250 mm; Conductor cross section 1.5 mm²; suitable for 2001, 2002, 2003 and 2022 Series rail-mounted terminal blocks

 
www.wago.com/2009-416



Item no.: 210-103

Wire commoning chain; insulated; 50 connections

www.wago.com/210-103



Item no.: 210-123

Wire commoning chain; insulated; 50 connections

www.wago.com/210-123

Insulation stop



Item no.: 2002-171

Insulation stop; 0.25 - 0.5 mm²; 5 pieces/strip

www.wago.com/2002-171



Item no.: 2002-172

Insulation stop; 0.75 - 1 mm²; 5 pieces/strip

www.wago.com/2002-172

End plate



Item no.: 2022-1291

End and intermediate plate; 1 mm thick

www.wago.com/2022-1291



Item no.: 2022-1292

End and intermediate plate; 1 mm thick

www.wago.com/2022-1292

Marking accessories



Item no.: 2002-161

Adaptor
















www.wago.com/2002-161



















Item no.: 2009-110

Marking strips; on reel; not stretchable; plain; snap-on type

www.wago.com/2009-110

| | | |
|---|--|--|
|  | Item no.: 2009-115 WMB-Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type | www.wago.com/2009-115 |
|  | Item no.: 2009-115/000-002 WMB-Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type | www.wago.com/2009-115/000-002 |
|  | Item no.: 2009-115/000-006 WMB-Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type | www.wago.com/2009-115/000-006 |
|  | Item no.: 2009-115/000-007 WMB-Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type | www.wago.com/2009-115/000-007 |
|  | Item no.: 2009-115/000-012 WMB-Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type | www.wago.com/2009-115/000-012 |
|  | Item no.: 2009-115/000-017 WMB-Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type | www.wago.com/2009-115/000-017 |
|  | Item no.: 2009-115/000-023 WMB-Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type | www.wago.com/2009-115/000-023 |
|  | Item no.: 2009-115/000-024 WMB-Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type | www.wago.com/2009-115/000-024 |
|  | Item no.: 2009-145 Mini-WSB Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type | www.wago.com/2009-145 |
|  | Item no.: 2009-145/000-002 Mini-WSB Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type | www.wago.com/2009-145/000-002 |
|  | Item no.: 2009-145/000-005 Mini-WSB Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type | www.wago.com/2009-145/000-005 |
|  | Item no.: 2009-145/000-006 Mini-WSB Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type | www.wago.com/2009-145/000-006 |
|  | Item no.: 2009-145/000-007 Mini-WSB Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type | www.wago.com/2009-145/000-007 |
|  | Item no.: 2009-145/000-012 Mini-WSB Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type | www.wago.com/2009-145/000-012 |
|  | Item no.: 2009-145/000-023 Mini-WSB Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type | www.wago.com/2009-145/000-023 |

| | | |
|--|--|--|
|  | Item no.: 2009-145/000-024 Mini-WSB Inline; on reel; stretchable 5 - 5.2 mm; plain; snap-on type | www.wago.com/2009-145/000-024 |
|  | Item no.: 2009-191 Group marker carrier | www.wago.com/2009-191 |
|  | Item no.: 2009-192 Group marker carrier | www.wago.com/2009-192 |
|  | Item no.: 2009-193 Group marker carrier | www.wago.com/2009-193 |
|  | Item no.: 2009-198 Adaptor | www.wago.com/2009-198 |
|  | Item no.: 248-501 Miniature WSB Quick marking system; plain; Marker width 5 mm; 10 strips with 10 markers per card | www.wago.com/248-501 |
|  | Item no.: 248-501/000-002 Mini-WSB marking card; as card; not stretchable; plain; snap-on type | www.wago.com/248-501/000-002 |
|  | Item no.: 248-501/000-005 Mini-WSB marking card; as card; plain; snap-on type | www.wago.com/248-501/000-005 |
|  | Item no.: 248-501/000-006 Mini-WSB marking card; as card; not stretchable; plain; snap-on type | www.wago.com/248-501/000-006 |
|  | Item no.: 248-501/000-007 Mini-WSB marking card; as card; not stretchable; plain; snap-on type | www.wago.com/248-501/000-007 |
|  | Item no.: 248-501/000-012 Mini-WSB marking card; as card; not stretchable; plain; snap-on type | www.wago.com/248-501/000-012 |
|  | Item no.: 248-501/000-017 Mini-WSB marking card; as card; not stretchable; plain; snap-on type | www.wago.com/248-501/000-017 |
|  | Item no.: 248-501/000-023 Mini-WSB marking card; as card; not stretchable; plain; snap-on type | www.wago.com/248-501/000-023 |
|  | Item no.: 793-501 WMB marking card; as card; not stretchable; plain; snap-on type | www.wago.com/793-501 |
|  | Item no.: 793-501/000-002 WMB marking card; as card; not stretchable; plain; snap-on type | www.wago.com/793-501/000-002 |
|  | Item no.: 793-501/000-005 WMB marking card; as card; not stretchable; plain; snap-on type | www.wago.com/793-501/000-005 |



Item no.: 793-501/000-006
WMB marking card; as card; not stretchable; plain; snap-on type

www.wago.com/793-501/000-006



Item no.: 793-501/000-007
WMB marking card; as card; not stretchable; plain; snap-on type

www.wago.com/793-501/000-007



Item no.: 793-501/000-012
WMB marking card; as card; not stretchable; plain; snap-on type

www.wago.com/793-501/000-012



Item no.: 793-501/000-017
WMB marking card; as card; not stretchable; plain; snap-on type

www.wago.com/793-501/000-017



Item no.: 793-501/000-023
WMB marking card; as card; not stretchable; plain; snap-on type

www.wago.com/793-501/000-023



Item no.: 793-501/000-024
WMB marking card; as card; not stretchable; plain; snap-on type

www.wago.com/793-501/000-024



Item no.: 793-5501
WMB marking card; as card; for terminal block width 5 - 17.5 mm; stretchable 5 - 5.2 mm; plain; snap-on type

www.wago.com/793-5501



Item no.: 793-5501/000-002
WMB marking card; as card; for terminal block width 5 - 17.5 mm; stretchable 5 - 5.2 mm; plain; snap-on type

www.wago.com/793-5501/000-002



Item no.: 793-5501/000-005
WMB marking card; as card; stretchable 5 - 5.2 mm; plain; snap-on type

www.wago.com/793-5501/000-005



Item no.: 793-5501/000-006
WMB marking card; as card; stretchable 5 - 5.2 mm; plain; snap-on type

www.wago.com/793-5501/000-006



Item no.: 793-5501/000-007
WMB marking card; as card; stretchable 5 - 5.2 mm; plain; snap-on type

www.wago.com/793-5501/000-007



Item no.: 793-5501/000-012
WMB marking card; as card; stretchable 5 - 5.2 mm; plain; snap-on type

www.wago.com/793-5501/000-012



Item no.: 793-5501/000-017
WMB marking card; as card; stretchable 5 - 5.2 mm; plain; snap-on type

www.wago.com/793-5501/000-017



Item no.: 793-5501/000-023
WMB marking card; as card; stretchable 5 - 5.2 mm; plain; snap-on type

www.wago.com/793-5501/000-023



Item no.: 793-5501/000-024
WMB marking card; as card; stretchable 5 - 5.2 mm; plain; snap-on type

www.wago.com/793-5501/000-024

tools



Item no.: 210-720
Operating tool with partially insulated shaft; Type 2, blade (3.5 x 0.5) mm

www.wago.com/210-720

check



Item no.: 2002-511
Modular TOPJOB®S connector; modular; for jumper contact slot; 1-pole

www.wago.com/2002-511



Item no.: 2002-549
Spacer module; modular; e.g., for bridging commoned terminal blocks

www.wago.com/2002-549



Item no.: 2002-552
TOPJOB®S connector strip; for jumper contact slot; 2-pole

www.wago.com/2002-552



Item no.: 2002-553
TOPJOB®S connector strip; for jumper contact slot; 3-pole

www.wago.com/2002-553



Item no.: 2002-554
TOPJOB®S connector strip; for jumper contact slot; 4-pole

www.wago.com/2002-554



Item no.: 2002-555
TOPJOB®S connector strip; for jumper contact slot; 5-pole

www.wago.com/2002-555



Item no.: 2002-556
TOPJOB®S connector strip; for jumper contact slot; 6-pole

www.wago.com/2002-556



Item no.: 2002-557
TOPJOB®S connector strip; for jumper contact slot; 7-pole

www.wago.com/2002-557



Item no.: 2002-558
TOPJOB®S connector strip; for jumper contact slot; 8-pole

www.wago.com/2002-558



Item no.: 2002-559
TOPJOB®S connector strip; for jumper contact slot; 9-pole

www.wago.com/2002-559



Item no.: 2002-560
TOPJOB®S connector strip; for jumper contact slot; 10-pole

www.wago.com/2002-560



Item no.: 2009-174
Test plug adapter; for 4 mm Ø test plugs; for testing TOPJOB®S rail-mounted terminal blocks

www.wago.com/2009-174



Item no.: 2009-182
Testing tap; for max. 2.5 mm²; tool-free connection for individual test wires 0.08 - 2.5 mm

www.wago.com/2009-182



Item no.: 859-500
Test pin; 1 mm Ø; with solder connection for test wire

www.wago.com/859-500

General accessories



Item no.: 2022-161
Start module for 1-conductor female connector; with integrated end plate; 2.5 mm²; 1-pole











www.wago.com/2022-161




Item no.: 2022-162
Start module for 1-conductor female connector; with integrated end plate; 2.5 mm²; 1-pole

www.wago.com/2022-162





Item no.: 2022-164





| | | |
|---|---|--|
|  | Start module for 1-conductor female connector; with integrated end plate; 2.5 mm ² ; 1-pole | www.wago.com/2022-164 |
|  | Item no.: 2022-167 Start module for 1-conductor female connector; with integrated end plate; 2.5 mm ² ; 1-pole | www.wago.com/2022-167 |
|  | Item no.: 2022-171 Center module for 1-conductor female connector; 2.5 mm ² ; 1-pole | www.wago.com/2022-171 |
|  | Item no.: 2022-172 Center module for 1-conductor female connector; 2.5 mm ² ; 1-pole | www.wago.com/2022-172 |
|  | Item no.: 2022-174 Center module for 1-conductor female connector; 2.5 mm ² ; 1-pole | www.wago.com/2022-174 |
|  | Item no.: 2022-177 Center module for 1-conductor female connector; 2.5 mm ² ; 1-pole | www.wago.com/2022-177 |
|  | Item no.: 2022-181 End module for 1-conductor female connector; 2.5 mm ² ; 1-pole | www.wago.com/2022-181 |
|  | Item no.: 2022-182 End module for 1-conductor female connector; 2.5 mm ² ; 1-pole | www.wago.com/2022-182 |
|  | Item no.: 2022-184 End module for 1-conductor female connector; 2.5 mm ² ; 1-pole | www.wago.com/2022-184 |
|  | Item no.: 2022-187 End module for 1-conductor female connector; 2.5 mm ² ; 1-pole | www.wago.com/2022-187 |












Protective Warning Marker











| | | |
|--|--|--|
|  | Item no.: 2002-115 Protective warning marker; with high-voltage symbol, black; for 5 terminal blocks | www.wago.com/2002-115 |
|--|--|--|











Female plug




 

| | | |
|--|--|--|
|  | Item no.: 2022-101 1-conductor female plug; 2.5 mm ² ; 1-pole | www.wago.com/2022-101 |
|  | Item no.: 2022-101/000-006 1-conductor female plug; 1-pole | www.wago.com/2022-101/000-006 |
|  | Item no.: 2022-101/000-012 1-conductor female plug; 1-pole | www.wago.com/2022-101/000-012 |
|  | Item no.: 2022-101/000-016 1-conductor female plug; 1-pole | www.wago.com/2022-101/000-016 |
| | Item no.: 2022-101/122-000 1-conductor female plug; 1-pole | www.wago.com/2022-101/122-000 |
| | Item no.: 2022-101/122-006 1-conductor female plug; 1-pole | www.wago.com/2022-101/122-006 |

| | | |
|---|---|--|
| | Item no.: 2022-101/122-016 1-conductor female plug; 1-pole | www.wago.com/2022-101/122-016 |
| | Item no.: 2022-101/132-000 1-conductor female plug; Strain relief plate; 1-pole | www.wago.com/2022-101/132-000 |
| | Item no.: 2022-101/132-006 1-conductor female plug; Strain relief plate; 1-pole | www.wago.com/2022-101/132-006 |
| | Item no.: 2022-101/132-016 1-conductor female plug; Strain relief plate; 1-pole | www.wago.com/2022-101/132-016 |
| | Item no.: 2022-101/142-000 1-conductor female plug; Strain relief plate; 1-pole | www.wago.com/2022-101/142-000 |
| | Item no.: 2022-101/142-006 1-conductor female plug; Strain relief plate; 1-pole | www.wago.com/2022-101/142-006 |
| | Item no.: 2022-101/142-016 1-conductor female plug; Strain relief plate; 1-pole | www.wago.com/2022-101/142-016 |
|  | Item no.: 2022-102 1-conductor female plug; 2.5 mm ² ; 2-pole | www.wago.com/2022-102 |
|  | Item no.: 2022-102/000-006 1-conductor female plug; 2.5 mm ² ; 2-pole | www.wago.com/2022-102/000-006 |
|  | Item no.: 2022-102/000-016 1-conductor female plug; 2.5 mm ² ; 2-pole | www.wago.com/2022-102/000-016 |
| | Item no.: 2022-102/122-000 1-conductor female plug; Locking lever; 2.5 mm ² ; 2-pole | www.wago.com/2022-102/122-000 |
| | Item no.: 2022-102/132-000 1-conductor female plug; Strain relief plate; 2.5 mm ² ; 2-pole | www.wago.com/2022-102/132-000 |
| | Item no.: 2022-102/142-000 1-conductor female plug; Strain relief plate; 2.5 mm ² ; 2-pole | www.wago.com/2022-102/142-000 |
| | Item no.: 2022-103 1-conductor female plug; 2.5 mm ² ; 3-pole | www.wago.com/2022-103 |
|  | Item no.: 2022-103/000-006 1-conductor female plug; 2.5 mm ² ; 3-pole | www.wago.com/2022-103/000-006 |

| | | |
|--|---|--|
|  | Item no.: 2022-103/000-016 1-conductor female plug; 2.5 mm ² ; 3-pole | www.wago.com/2022-103/000-016 |
|  | Item no.: 2022-103/000-036 1-conductor female plug; 2.5 mm ² ; 3-pole | www.wago.com/2022-103/000-036 |
|  | Item no.: 2022-103/000-037 1-conductor female plug; 2.5 mm ² ; 3-pole | www.wago.com/2022-103/000-037 |
|  | Item no.: 2022-103/000-038 1-conductor female plug; 2.5 mm ² ; 3-pole | www.wago.com/2022-103/000-038 |
|  | Item no.: 2022-103/000-039 1-conductor female plug; 2.5 mm ² ; 3-pole | www.wago.com/2022-103/000-039 |
| | Item no.: 2022-103/123-000 1-conductor female plug; Locking lever; 2.5 mm ² ; 3-pole | www.wago.com/2022-103/123-000 |
| | Item no.: 2022-103/133-000 1-conductor female plug; Strain relief plate; 2.5 mm ² ; 3-pole | www.wago.com/2022-103/133-000 |
| | Item no.: 2022-103/143-000 1-conductor female plug; Strain relief plate; 2.5 mm ² ; 3-pole | www.wago.com/2022-103/143-000 |
| | Item no.: 2022-104 1-conductor female plug; 2.5 mm ² ; 4-pole | www.wago.com/2022-104 |
|  | Item no.: 2022-104/000-006 1-conductor female plug; 2.5 mm ² ; 4-pole | www.wago.com/2022-104/000-006 |
|  | Item no.: 2022-104/000-016 1-conductor female plug; 2.5 mm ² ; 4-pole | www.wago.com/2022-104/000-016 |
|  | Item no.: 2022-104/000-036 1-conductor female plug; 2.5 mm ² ; 4-pole | www.wago.com/2022-104/000-036 |
|  | Item no.: 2022-104/000-037 1-conductor female plug; 2.5 mm ² ; 4-pole | www.wago.com/2022-104/000-037 |
|  | Item no.: 2022-104/000-038 1-conductor female plug; 2.5 mm ² ; 4-pole | www.wago.com/2022-104/000-038 |
|  | Item no.: 2022-104/000-039 1-conductor female plug; 2.5 mm ² ; 4-pole | www.wago.com/2022-104/000-039 |

| | | |
|--|---|--|
| | Item no.: 2022-104/123-000 1-conductor female plug; Locking lever; 2.5 mm ² ; 4-pole | www.wago.com/2022-104/123-000 |
| | Item no.: 2022-104/133-000 1-conductor female plug; Strain relief plate; 2.5 mm ² ; 4-pole | www.wago.com/2022-104/133-000 |
| | Item no.: 2022-104/143-000 1-conductor female plug; Strain relief plate; 2.5 mm ² ; 4-pole | www.wago.com/2022-104/143-000 |
|  | Item no.: 2022-105 1-conductor female plug; 2.5 mm ² ; 5-pole | www.wago.com/2022-105 |
|  | Item no.: 2022-105/000-006 1-conductor female plug; 2.5 mm ² ; 5-pole | www.wago.com/2022-105/000-006 |
| | Item no.: 2022-105/000-016 1-conductor female plug; 2.5 mm ² ; 5-pole | www.wago.com/2022-105/000-016 |
|  | Item no.: 2022-105/000-036 1-conductor female plug; 2.5 mm ² ; 5-pole | www.wago.com/2022-105/000-036 |
|  | Item no.: 2022-105/000-037 1-conductor female plug; 2.5 mm ² ; 5-pole | www.wago.com/2022-105/000-037 |
|  | Item no.: 2022-105/000-038 1-conductor female plug; 2.5 mm ² ; 5-pole | www.wago.com/2022-105/000-038 |
|  | Item no.: 2022-105/000-039 1-conductor female plug; 2.5 mm ² ; 5-pole | www.wago.com/2022-105/000-039 |
|  | Item no.: 2022-105/123-000 1-conductor female plug; Locking lever; 2.5 mm ² ; 5-pole | www.wago.com/2022-105/123-000 |
|  | Item no.: 2022-105/134-000 1-conductor female plug; Strain relief plate; 2.5 mm ² ; 5-pole | www.wago.com/2022-105/134-000 |
|  | Item no.: 2022-105/144-000 1-conductor female plug; Strain relief plate; 2.5 mm ² ; 5-pole | www.wago.com/2022-105/144-000 |
| | Item no.: 2022-106 1-conductor female plug; 2.5 mm ² ; 6-pole | www.wago.com/2022-106 |
|  | Item no.: 2022-106/000-006 1-conductor female plug; 2.5 mm ² ; 6-pole | www.wago.com/2022-106/000-006 |

| | | |
|--|---|--|
|  | Item no.: 2022-106/000-016 1-conductor female plug; 2.5 mm ² ; 6-pole | www.wago.com/2022-106/000-016 |
|  | Item no.: 2022-106/000-036 1-conductor female plug; 2.5 mm ² ; 6-pole | www.wago.com/2022-106/000-036 |
|  | Item no.: 2022-106/000-037 1-conductor female plug; 2.5 mm ² ; 6-pole | www.wago.com/2022-106/000-037 |
|  | Item no.: 2022-106/000-038 1-conductor female plug; 2.5 mm ² ; 6-pole | www.wago.com/2022-106/000-038 |
|  | Item no.: 2022-106/000-039 1-conductor female plug; 2.5 mm ² ; 6-pole | www.wago.com/2022-106/000-039 |
| | Item no.: 2022-106/123-000 1-conductor female plug; Locking lever; 2.5 mm ² ; 6-pole | www.wago.com/2022-106/123-000 |
| | Item no.: 2022-106/134-000 1-conductor female plug; Strain relief plate; 2.5 mm ² ; 6-pole | www.wago.com/2022-106/134-000 |
| | Item no.: 2022-106/144-000 1-conductor female plug; Strain relief plate; 2.5 mm ² ; 6-pole | www.wago.com/2022-106/144-000 |
| | Item no.: 2022-107 1-conductor female plug; 2.5 mm ² ; 7-pole | www.wago.com/2022-107 |
|  | Item no.: 2022-107/000-006 1-conductor female plug; 2.5 mm ² ; 7-pole | www.wago.com/2022-107/000-006 |
|  | Item no.: 2022-107/000-016 1-conductor female plug; 2.5 mm ² ; 7-pole | www.wago.com/2022-107/000-016 |
|  | Item no.: 2022-107/000-036 1-conductor female plug; 2.5 mm ² ; 7-pole | www.wago.com/2022-107/000-036 |
|  | Item no.: 2022-107/000-037 1-conductor female plug; 2.5 mm ² ; 7-pole | www.wago.com/2022-107/000-037 |
|  | Item no.: 2022-107/000-038 1-conductor female plug; 2.5 mm ² ; 7-pole | www.wago.com/2022-107/000-038 |
| | Item no.: 2022-107/000-039 1-conductor female plug; 2.5 mm ² ; 7-pole | www.wago.com/2022-107/000-039 |

| | | |
|--|---|--|
| | Item no.: 2022-107/123-000 1-conductor female plug; Locking lever; 2.5 mm ² ; 7-pole | www.wago.com/2022-107/123-000 |
| | Item no.: 2022-107/135-000 1-conductor female plug; Strain relief plate; 2.5 mm ² ; 7-pole | www.wago.com/2022-107/135-000 |
| | Item no.: 2022-107/145-000 1-conductor female plug; Strain relief plate; 2.5 mm ² ; 7-pole | www.wago.com/2022-107/145-000 |
| | Item no.: 2022-108 1-conductor female plug; 2.5 mm ² ; 8-pole | www.wago.com/2022-108 |
|  | Item no.: 2022-108/000-006 1-conductor female plug; 2.5 mm ² ; 8-pole | www.wago.com/2022-108/000-006 |
|  | Item no.: 2022-108/000-016 1-conductor female plug; 2.5 mm ² ; 8-pole | www.wago.com/2022-108/000-016 |
|  | Item no.: 2022-108/000-036 1-conductor female plug; 2.5 mm ² ; 8-pole | www.wago.com/2022-108/000-036 |
| | Item no.: 2022-108/000-037 1-conductor female plug; 2.5 mm ² ; 8-pole | www.wago.com/2022-108/000-037 |
|  | Item no.: 2022-108/000-038 1-conductor female plug; 2.5 mm ² ; 8-pole | www.wago.com/2022-108/000-038 |
| | Item no.: 2022-108/000-039 1-conductor female plug; 2.5 mm ² ; 8-pole | www.wago.com/2022-108/000-039 |
| | Item no.: 2022-108/123-000 1-conductor female plug; Locking lever; 2.5 mm ² ; 8-pole | www.wago.com/2022-108/123-000 |
| | Item no.: 2022-108/135-000 1-conductor female plug; Strain relief plate; 2.5 mm ² ; 8-pole | www.wago.com/2022-108/135-000 |
| | Item no.: 2022-108/145-000 1-conductor female plug; Strain relief plate; 2.5 mm ² ; 8-pole | www.wago.com/2022-108/145-000 |
| | Item no.: 2022-109 1-conductor female plug; 2.5 mm ² ; 9-pole | www.wago.com/2022-109 |
|  | Item no.: 2022-109/000-006 1-conductor female plug; 2.5 mm ² ; 9-pole | www.wago.com/2022-109/000-006 |



Item no.: 2022-109/000-016
1-conductor female plug; 2.5 mm²; 9-pole

www.wago.com/2022-109/000-016



Item no.: 2022-109/000-036
1-conductor female plug; 2.5 mm²; 9-pole

www.wago.com/2022-109/000-036



Item no.: 2022-109/000-037
1-conductor female plug; 2.5 mm²; 9-pole

www.wago.com/2022-109/000-037



Item no.: 2022-109/000-038
1-conductor female plug; 2.5 mm²; 9-pole

www.wago.com/2022-109/000-038



Item no.: 2022-109/000-039
1-conductor female plug; 2.5 mm²; 9-pole

www.wago.com/2022-109/000-039

Item no.: 2022-109/123-000
1-conductor female plug; Locking lever; 2.5 mm²; 9-pole

www.wago.com/2022-109/123-000

Item no.: 2022-109/135-000
1-conductor female plug; Strain relief plate; 2.5 mm²; 9-pole

www.wago.com/2022-109/135-000

Item no.: 2022-109/145-000
1-conductor female plug; Strain relief plate; 2.5 mm²; 9-pole

www.wago.com/2022-109/145-000

Item no.: 2022-110
1-conductor female plug; 2.5 mm²; 10-pole

www.wago.com/2022-110



Item no.: 2022-110/000-006
1-conductor female plug; 2.5 mm²; 10-pole

www.wago.com/2022-110/000-006



Item no.: 2022-110/000-016
1-conductor female plug; 2.5 mm²; 10-pole

www.wago.com/2022-110/000-016



Item no.: 2022-110/000-036
1-conductor female plug; 2.5 mm²; 10-pole

www.wago.com/2022-110/000-036

Item no.: 2022-110/000-037
1-conductor female plug; 2.5 mm²; 10-pole

www.wago.com/2022-110/000-037




 



Item no.: 2022-110/000-038
1-conductor female plug; 2.5 mm²; 10-pole

www.wago.com/2022-110/000-038

Item no.: 2022-110/000-039
1-conductor female plug; 2.5 mm²; 10-pole

www.wago.com/2022-110/000-039

| | | |
|--|--|--|
| | Item no.: 2022-110/123-000 1-conductor female plug; Locking lever; 2.5 mm ² ; 10-pole | www.wago.com/2022-110/123-000 |
| | Item no.: 2022-110/135-000 1-conductor female plug; Strain relief plate; 2.5 mm ² ; 10-pole | www.wago.com/2022-110/135-000 |
| | Item no.: 2022-110/145-000 1-conductor female plug; Strain relief plate; 2.5 mm ² ; 10-pole | www.wago.com/2022-110/145-000 |
| | Item no.: 2022-111 1-conductor female plug; 2.5 mm ² ; 11-pole | www.wago.com/2022-111 |
|  | Item no.: 2022-111/000-006 1-conductor female plug; 2.5 mm ² ; 11-pole | www.wago.com/2022-111/000-006 |
|  | Item no.: 2022-111/000-016 1-conductor female plug; 2.5 mm ² ; 11-pole | www.wago.com/2022-111/000-016 |
|  | Item no.: 2022-111/000-036 1-conductor female plug; 2.5 mm ² ; 11-pole | www.wago.com/2022-111/000-036 |
| | Item no.: 2022-111/000-037 1-conductor female plug; 2.5 mm ² ; 11-pole | www.wago.com/2022-111/000-037 |
|  | Item no.: 2022-111/000-038 1-conductor female plug; 2.5 mm ² ; 11-pole | www.wago.com/2022-111/000-038 |
| | Item no.: 2022-111/000-039 1-conductor female plug; 2.5 mm ² ; 11-pole | www.wago.com/2022-111/000-039 |
| | Item no.: 2022-111/126-000 1-conductor female plug; Locking lever; 2.5 mm ² ; 11-pole | www.wago.com/2022-111/126-000 |
| | Item no.: 2022-111/136-000 1-conductor female plug; Strain relief plate; 2.5 mm ² ; 11-pole | www.wago.com/2022-111/136-000 |
| | Item no.: 2022-111/146-000 1-conductor female plug; Strain relief plate; 2.5 mm ² ; 11-pole | www.wago.com/2022-111/146-000 |
| | Item no.: 2022-112 1-conductor female plug; 2.5 mm ² ; 12-pole | www.wago.com/2022-112 |
|  | Item no.: 2022-112/000-006 1-conductor female plug; 2.5 mm ² ; 12-pole | www.wago.com/2022-112/000-006 |



Item no.: 2022-112/000-016
1-conductor female plug; 2.5 mm²; 12-pole

www.wago.com/2022-112/000-016



Item no.: 2022-112/000-036
1-conductor female plug; 2.5 mm²; 12-pole

www.wago.com/2022-112/000-036



Item no.: 2022-112/000-037
1-conductor female plug; 2.5 mm²; 12-pole

www.wago.com/2022-112/000-037



Item no.: 2022-112/000-038
1-conductor female plug; 2.5 mm²; 12-pole

www.wago.com/2022-112/000-038



Item no.: 2022-112/000-039
1-conductor female plug; 2.5 mm²; 12-pole

www.wago.com/2022-112/000-039

Item no.: 2022-112/126-000
1-conductor female plug; Locking lever; 2.5 mm²; 12-pole

www.wago.com/2022-112/126-000

Item no.: 2022-112/136-000
1-conductor female plug; Strain relief plate; 2.5 mm²; 12-pole

www.wago.com/2022-112/136-000

Item no.: 2022-112/146-000
1-conductor female plug; Strain relief plate; 2.5 mm²; 12-pole

www.wago.com/2022-112/146-000

Item no.: 2022-113
1-conductor female plug; 2.5 mm²; 13-pole

www.wago.com/2022-113



Item no.: 2022-113/000-006
1-conductor female plug; 2.5 mm²; 13-pole

www.wago.com/2022-113/000-006



Item no.: 2022-113/000-016
1-conductor female plug; 2.5 mm²; 13-pole

www.wago.com/2022-113/000-016



Item no.: 2022-113/000-036
1-conductor female plug; 2.5 mm²; 13-pole

www.wago.com/2022-113/000-036

Item no.: 2022-113/000-037
1-conductor female plug; 2.5 mm²; 13-pole

www.wago.com/2022-113/000-037




 





 







Item no.: 2022-113/000-038
1-conductor female plug; 2.5 mm²; 13-pole





www.wago.com/2022-113/000-038

Item no.: 2022-113/000-039
1-conductor female plug; 2.5 mm²; 13-pole

www.wago.com/2022-113/000-039

| | | |
|--|--|--|
| | Item no.: 2022-113/126-000 1-conductor female plug; Locking lever; 2.5 mm ² ; 13-pole | www.wago.com/2022-113/126-000 |
| | Item no.: 2022-113/136-000 1-conductor female plug; Strain relief plate; 2.5 mm ² ; 13-pole | www.wago.com/2022-113/136-000 |
| | Item no.: 2022-113/146-000 1-conductor female plug; Strain relief plate; 2.5 mm ² ; 13-pole | www.wago.com/2022-113/146-000 |
| | Item no.: 2022-114 1-conductor female plug; 2.5 mm ² ; 14-pole | www.wago.com/2022-114 |
|  | Item no.: 2022-114/000-006 1-conductor female plug; 2.5 mm ² ; 14-pole | www.wago.com/2022-114/000-006 |
|  | Item no.: 2022-114/000-016 1-conductor female plug; 2.5 mm ² ; 14-pole | www.wago.com/2022-114/000-016 |
|  | Item no.: 2022-114/000-036 1-conductor female plug; 2.5 mm ² ; 14-pole | www.wago.com/2022-114/000-036 |
| | Item no.: 2022-114/000-037 1-conductor female plug; 2.5 mm ² ; 14-pole | www.wago.com/2022-114/000-037 |
|  | Item no.: 2022-114/000-038 1-conductor female plug; 2.5 mm ² ; 14-pole | www.wago.com/2022-114/000-038 |
| | Item no.: 2022-114/000-039 1-conductor female plug; 2.5 mm ² ; 14-pole | www.wago.com/2022-114/000-039 |
| | Item no.: 2022-114/126-000 1-conductor female plug; Locking lever; 2.5 mm ² ; 14-pole | www.wago.com/2022-114/126-000 |
| | Item no.: 2022-114/136-000 1-conductor female plug; Strain relief plate; 2.5 mm ² ; 14-pole | www.wago.com/2022-114/136-000 |
| | Item no.: 2022-114/146-000 1-conductor female plug; Strain relief plate; 2.5 mm ² ; 14-pole | www.wago.com/2022-114/146-000 |
| | Item no.: 2022-115 1-conductor female plug; 2.5 mm ² ; 15-pole | www.wago.com/2022-115 |
|  | Item no.: 2022-115/000-006 1-conductor female plug; 2.5 mm ² ; 15-pole | www.wago.com/2022-115/000-006 |

| | | |
|--|--|--|
|  | Item no.: 2022-115/000-016 1-conductor female plug; 2.5 mm ² ; 15-pole | www.wago.com/2022-115/000-016 |
|  | Item no.: 2022-115/000-036 1-conductor female plug; 2.5 mm ² ; 15-pole | www.wago.com/2022-115/000-036 |
| | Item no.: 2022-115/000-037 1-conductor female plug; 2.5 mm ² ; 15-pole | www.wago.com/2022-115/000-037 |
|  | Item no.: 2022-115/000-038 1-conductor female plug; 2.5 mm ² ; 15-pole | www.wago.com/2022-115/000-038 |
| | Item no.: 2022-115/000-039 1-conductor female plug; 2.5 mm ² ; 15-pole | www.wago.com/2022-115/000-039 |
| | Item no.: 2022-115/127-000 1-conductor female plug; Locking lever; 2.5 mm ² ; 15-pole | www.wago.com/2022-115/127-000 |
| | Item no.: 2022-115/137-000 1-conductor female plug; Strain relief plate; 2.5 mm ² ; 15-pole | www.wago.com/2022-115/137-000 |
| | Item no.: 2022-115/147-000 1-conductor female plug; Strain relief plate; 2.5 mm ² ; 15-pole | www.wago.com/2022-115/147-000 |
| ferrule | | |
|  | Item no.: 216-241 Ferrule; Sleeve for 0.5 mm ² / AWG 22; insulated; electro-tin plated; electrolytic copper; gastight crimped; acc. to DIN 46228, Part 4/09.90 | www.wago.com/216-241 |
|  | Item no.: 216-242 Ferrule; Sleeve for 0.75 mm ² / AWG 20; insulated; electro-tin plated; electrolytic copper; gastight crimped; acc. to DIN 46228, Part 4/09.90 | www.wago.com/216-242 |
|  | Item no.: 216-243 Ferrule; Sleeve for 1 mm ² / AWG 18; insulated; electro-tin plated; electrolytic copper; gastight crimped; acc. to DIN 46228, Part 4/09.90 | www.wago.com/216-243 |
|  | Item no.: 216-244 Ferrule; Sleeve for 1.5 mm ² / AWG 16; insulated; electro-tin plated; electrolytic copper; gastight crimped; acc. to DIN 46228, Part 4/09.90 | www.wago.com/216-244 |
|  | Item no.: 216-246 Ferrule; Sleeve for 2.5 mm ² / AWG 14; insulated; electro-tin plated; electrolytic copper; gastight crimped; acc. to DIN 46228, Part 4/09.90 | www.wago.com/216-246 |
|  | Item no.: 216-262 Ferrule; Sleeve for 0.75 mm ² / AWG 20; insulated; electro-tin plated; electrolytic copper; gastight crimped; acc. to DIN 46228, Part 4/09.90 | www.wago.com/216-262 |
|  | Item no.: 216-263 Ferrule; Sleeve for 1 mm ² / AWG 18; insulated; electro-tin plated; electrolytic copper; gastight crimped; acc. to DIN 46228, Part 4/09.90 | www.wago.com/216-263 |
| | Item no.: 216-264 | |

| | | |
|--|---|--|
|  | Ferrule; Sleeve for 1.5 mm ² / AWG 16; insulated; electro-tin plated; electrolytic copper; gastight crimped; acc. to DIN 46228, Part 4/09.90 | www.wago.com/216-264 |
|  | Item no.: 216-266 Ferrule; Sleeve for 2.5 mm ² / AWG 14; insulated; electro-tin plated; electrolytic copper; gastight crimped; acc. to DIN 46228, Part 4/09.90 | www.wago.com/216-266 |
|  | Item no.: 216-284 Ferrule; Sleeve for 1.5 mm ² / AWG 16; insulated; electro-tin plated; electrolytic copper; gastight crimped; acc. to DIN 46228, Part 4/09.90 | www.wago.com/216-284 |
|  | Item no.: 216-286 Ferrule; Sleeve for 2.5 mm ² / AWG 14; insulated; electro-tin plated; electrolytic copper; gastight crimped; acc. to DIN 46228, Part 4/09.90 | www.wago.com/216-286 |

Downloads

Documentation

Bid Text

| | | | |
|-----------|--------------|-----------------|----------|
| 2022-1204 | Aug 15, 2018 | DOCX 15.5 kB | Download |
|-----------|--------------|-----------------|----------|

smartDATA

CAD data

| | | |
|-----------------------|-----|----------|
| 3D Download 2022-1204 | URL | Download |
|-----------------------|-----|----------|

Product family

X-COM S

[Show all products from the family](#)

Subject to changes.