


Data sheet | Item number: 2022-2204

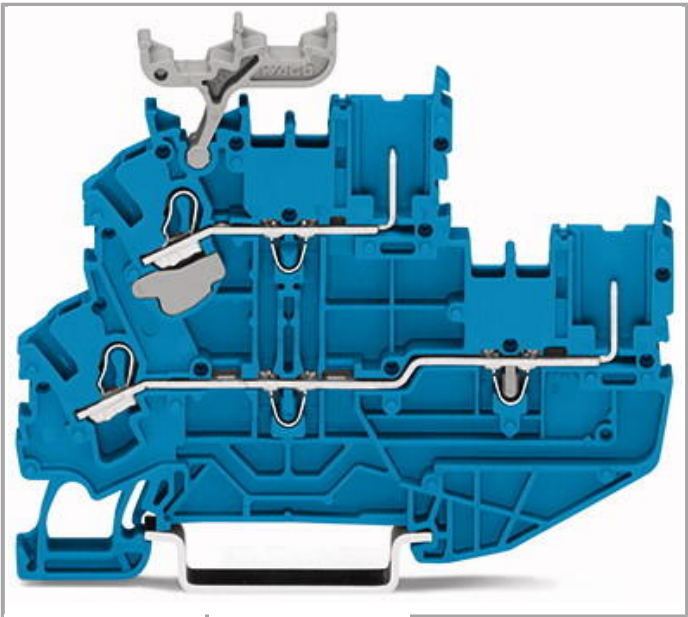

1-conductor/1-pin double deck receptacle terminal block; Through/through terminal block; N/N; without marker carrier; suitable for Ex i applications; for DIN-rail 35 x 15 and 35 x 7.5; 2.5 mm²; Push-in CAGE CLAMP®

www.wago.com/2022-2204



RoHS
Compliant

BOMcheck.net

Color: ■

Data
Electrical data

Ratings per IEC/EN 60664-1

Rated voltage (III / 3)	690 V
Rated impulse voltage (III / 3)	6 kV
Rated current	24 A
Rated current (2)	28 A
Legend (ratings)	(III / 3) ≙ Overvoltage category III / Pollution degree 3

Connection data

Connection technology	Push-in CAGE CLAMP®
Actuation type	Operating tool Push-in
Connectable conductor materials	Copper Aluminum



Nominal cross section	2.5 mm ²
Solid conductor	0.25 ... 4 mm ² / 22 ... 12 AWG
Solid conductor, push-in termination	0.75 ... 4 mm ² / 18 ... 12 AWG
Fine-stranded conductor	0.25 ... 4 mm ² / 22 ... 12 AWG
Fine-stranded conductor with ferrule, push-in termination, from	0.75 mm ² / 18 AWG
Strip length	10 ... 12 mm / 0.39 ... 0.47 Inch
Total number of connection points	2
Total number of potentials	2
Number of levels	2
Type of wiring	Front-entry wiring

Geometrical Data

Width	5.2 mm / 0.205 inch
Height from upper-edge of DIN-35 rail	51.3 mm / 2.02 inch
Depth	80.1 mm / 3.154 inch

Mechanical data

Design	horizontal
Type of mounting	DIN-35 rail
Potential marking	N/N
Marking level	Side marking

Material Data

Color	blue
Insulating material	Polyamide 66 (PA 66)
Fire load	0.245 MJ
Weight	11.49 g

Commercial data

Country of origin	CN
GTIN	4055143265775
Customs Tariff No.	85369010000
Product Group	18 (X-COM-System)

Approvals / Certificates

Country specific Approvals

Logo	Approval	Certificate name
	CSA DEKRA Certification B.V.	70107915

	KEMA/KEUR DEKRA Certification B.V.	71-101201
	KEMA/KEUR DEKRA Certification B.V.	71-101201

Ship Approvals

Logo	Approval	Certificate name
	ABS American Bureau of Shipping	14-HG1293677-PDA
	BV Bureau Veritas S.A.	38586/A0 BV
	LR Lloyds Register	91/20112 (E9)

UL-Approvals

Logo	Approval	Certificate name
	UR Underwriters Laboratories Inc.	E45172

Compatible products

Carrier rail

	Item no.: 210-112 Steel carrier rail; 35 x 7.5 mm; 1 mm thick; 2 m long; slotted; according to EN 60715; "Hole width 25 mm	www.wago.com/210-112
	Item no.: 210-113 Steel carrier rail; 35 x 7.5 mm; 1 mm thick; 2 m long; unslotted; according to EN 60715	www.wago.com/210-113
	Item no.: 210-114 Steel carrier rail; 35 x 15 mm; 1.5 mm thick; 2 m long; unslotted; similar to EN 60715	www.wago.com/210-114
	Item no.: 210-115 Steel carrier rail; 35 x 7.5 mm; 1 mm thick; 2 m long; slotted; according to EN 60715; "Hole width 18 mm	www.wago.com/210-115
	Item no.: 210-118 Steel carrier rail; 35 x 15 mm; 2.3 mm thick; 2 m long; unslotted; according to EN 60715	www.wago.com/210-118

**Item no.: 210-196**

Aluminum carrier rail; 35 x 8.2 mm; 1.6 mm thick; 2 m long; unslotted; similar to EN 60715

www.wago.com/210-196**Item no.: 210-197**

Steel carrier rail; 35 x 15 mm; 1.5 mm thick; 2 m long; slotted; similar to EN 60715

www.wago.com/210-197**Item no.: 210-198**

Copper carrier rail; 35 x 15 mm; 2.3 mm thick; 2 m long; unslotted; according to EN 60715

www.wago.com/210-198**Item no.: 210-504**

Steel carrier rail; 35 x 7.5 mm; 1 mm thick; 2 m long; slotted; galvanized; according to EN 60715

www.wago.com/210-504**Item no.: 210-505**

Steel carrier rail; 35 x 7.5 mm; 1 mm thick; 2 m long; unslotted; galvanized; according to EN 60715

www.wago.com/210-505**Item no.: 210-506**

Steel carrier rail; 35 x 15 mm; 1.5 mm thick; 2 m long; unslotted; galvanized; similar to EN 60715

www.wago.com/210-506**Item no.: 210-508**

Steel carrier rail; 35 x 15 mm; 1.5 mm thick; 2 m long; slotted; galvanized; similar to EN 60715

www.wago.com/210-508**check****Item no.: 2009-174**

Test plug adapter; for 4 mm Ø test plugs; for testing TOPJOB®S rail-mounted terminal blocks

www.wago.com/2009-174**Item no.: 2009-182**Testing tap; for max. 2.5 mm²; tool-free connection for individual test wires 0.08 - 2.5 mmwww.wago.com/2009-182**Jumper****Item no.: 2002-400**

Adjacent jumper for continuous commoning; insulated; 2-way; Nominal current 25 A

www.wago.com/2002-400**Item no.: 2002-402**

Push-in type jumper bar; insulated; 2-way; Nominal current 25 A

www.wago.com/2002-402**Item no.: 2002-402/000-005**

Push-in type jumper bar; insulated; 2-way; Nominal current 25 A

www.wago.com/2002-402/000-005**Item no.: 2002-402/000-006**

Push-in type jumper bar; insulated; 2-way; Nominal current 25 A

www.wago.com/2002-402/000-006**Item no.: 2002-403**

Push-in type jumper bar; insulated; 3-way; Nominal current 25 A

www.wago.com/2002-403**Item no.: 2002-403/000-005**

Push-in type jumper bar; insulated; 3-way; Nominal current 25 A

www.wago.com/2002-403/000-005**Item no.: 2002-403/000-006**

Push-in type jumper bar; insulated; 3-way; Nominal current 25 A

www.wago.com/2002-403/000-006**Item no.: 2002-404**

Push-in type jumper bar; insulated; 4-way; Nominal current 25 A

www.wago.com/2002-404



Item no.: 2002-404/000-005
Push-in type jumper bar; insulated; 4-way; Nominal current 25 A

www.wago.com/2002-404/000-005



Item no.: 2002-404/000-006
Push-in type jumper bar; insulated; 4-way; Nominal current 25 A

www.wago.com/2002-404/000-006



Item no.: 2002-405
Push-in type jumper bar; insulated; 5-way; Nominal current 25 A

www.wago.com/2002-405



Item no.: 2002-405/000-005
Push-in type jumper bar; insulated; 5-way; Nominal current 25 A

www.wago.com/2002-405/000-005



Item no.: 2002-405/000-006
Push-in type jumper bar; insulated; 5-way; Nominal current 25 A

www.wago.com/2002-405/000-006



Item no.: 2002-405/011-000
Star point jumper; insulated; 3-way (1-3-5); IN = IN terminal block

www.wago.com/2002-405/011-000



Item no.: 2002-406
Push-in type jumper bar; insulated; 6-way; Nominal current 25 A

www.wago.com/2002-406



Item no.: 2002-406/000-005
Push-in type jumper bar; insulated; 6-way; Nominal current 25 A

www.wago.com/2002-406/000-005



Item no.: 2002-406/000-006
Push-in type jumper bar; insulated; 6-way; Nominal current 25 A

www.wago.com/2002-406/000-006



Item no.: 2002-406/020-000
Delta jumper; insulated; 1-2 3-4 5-6; IN = IN terminal block

www.wago.com/2002-406/020-000



Item no.: 2002-407
Push-in type jumper bar; insulated; 7-way; Nominal current 25 A

www.wago.com/2002-407



Item no.: 2002-407/000-005
Push-in type jumper bar; insulated; 7-way; Nominal current 25 A

www.wago.com/2002-407/000-005



Item no.: 2002-407/000-006
Push-in type jumper bar; insulated; 7-way; Nominal current 25 A

www.wago.com/2002-407/000-006



Item no.: 2002-408
Push-in type jumper bar; insulated; 8-way; Nominal current 25 A

www.wago.com/2002-408



Item no.: 2002-408/000-005
Push-in type jumper bar; insulated; 8-way; Nominal current 25 A

www.wago.com/2002-408/000-005



Item no.: 2002-408/000-006
Push-in type jumper bar; insulated; 8-way; Nominal current 25 A

www.wago.com/2002-408/000-006

	Item no.: 2002-409 Push-in type jumper bar; insulated; 9-way; Nominal current 25 A	www.wago.com/2002-409
	Item no.: 2002-409/000-005 Push-in type jumper bar; insulated; 9-way; Nominal current 25 A	www.wago.com/2002-409/000-005
	Item no.: 2002-409/000-006 Push-in type jumper bar; insulated; 9-way; Nominal current 25 A	www.wago.com/2002-409/000-006
	Item no.: 2002-410 Push-in type jumper bar; insulated; 10-way; Nominal current 25 A	www.wago.com/2002-410
	Item no.: 2002-410/000-005 Push-in type jumper bar; insulated; 10-way; Nominal current 25 A	www.wago.com/2002-410/000-005
	Item no.: 2002-410/000-006 Push-in type jumper bar; insulated; 10-way; Nominal current 25 A	www.wago.com/2002-410/000-006
	Item no.: 2002-423 Push-in type jumper bar; insulated; from 1 to 3; Nominal current 25 A	www.wago.com/2002-423
	Item no.: 2002-423/000-005 Adjacent jumper for continuous commoning; insulated; from 1 to 3; Nominal current 25 A	www.wago.com/2002-423/000-005
	Item no.: 2002-423/000-006 Adjacent jumper for continuous commoning; insulated; from 1 to 3; Nominal current 25 A	www.wago.com/2002-423/000-006
	Item no.: 2002-433 Push-in type jumper bar; insulated; from 1 to 3; Nominal current 25 A	www.wago.com/2002-433
	Item no.: 2002-434 Push-in type jumper bar; insulated; from 1 to 4; Nominal current 25 A	www.wago.com/2002-434
	Item no.: 2002-435 Push-in type jumper bar; insulated; from 1 to 5; Nominal current 25 A	www.wago.com/2002-435
	Item no.: 2002-436 Push-in type jumper bar; insulated; from 1 to 6; Nominal current 25 A	www.wago.com/2002-436
	Item no.: 2002-437 Push-in type jumper bar; insulated; from 1 to 7; Nominal current 25 A	www.wago.com/2002-437
	Item no.: 2002-438 Push-in type jumper bar; insulated; from 1 to 8; Nominal current 25 A	www.wago.com/2002-438
	Item no.: 2002-439 Push-in type jumper bar; insulated; from 1 to 9; Nominal current 25 A	www.wago.com/2002-439
	Item no.: 2002-440 Push-in type jumper bar; insulated; from 1 to 10; Nominal current 25 A	www.wago.com/2002-440
	Item no.: 2002-472 Staggered jumper; insulated; 2-way; Nominal current 25 A; suitable for 2002 and 2003 Series rail-	www.wago.com/2002-472



mounted terminal blocks

**Item no.: 2002-473**

Staggered jumper; insulated; 3-way; Nominal current 25 A; suitable for 2002 and 2003 Series rail-mounted terminal blocks

www.wago.com/2002-473**Item no.: 2002-473/011-000**

Ready-made staggered jumper; insulated; 2-way (1-3); Nominal current 25 A; with contact lugs broken off at the factory and circuit marking

www.wago.com/2002-473/011-000**Item no.: 2002-474**

Staggered jumper; insulated; 4-way; Nominal current 25 A; suitable for 2002 and 2003 Series rail-mounted terminal blocks

www.wago.com/2002-474**Item no.: 2002-475**

Staggered jumper; insulated; 5-way; Nominal current 25 A; suitable for 2002 and 2003 Series rail-mounted terminal blocks

www.wago.com/2002-475**Item no.: 2002-475/011-000**

Ready-made staggered jumper; insulated; 3-way (1-3-5); Nominal current 25 A; with contact lugs broken off at the factory and circuit marking

www.wago.com/2002-475/011-000**Item no.: 2002-476**

Staggered jumper; insulated; 6-way; Nominal current 25 A; suitable for 2002 and 2003 Series rail-mounted terminal blocks

www.wago.com/2002-476**Item no.: 2002-477**

Staggered jumper; insulated; 7-way; Nominal current 25 A; suitable for 2002 and 2003 Series rail-mounted terminal blocks

www.wago.com/2002-477**Item no.: 2002-477/011-000**

Ready-made staggered jumper; insulated; 1-3-5-7; Nominal current 25 A; with contact lugs broken off at the factory and circuit marking

www.wago.com/2002-477/011-000**Item no.: 2002-478**

Staggered jumper; insulated; 8-way; Nominal current 25 A; suitable for 2002 and 2003 Series rail-mounted terminal blocks

www.wago.com/2002-478**Item no.: 2002-479**

Staggered jumper; insulated; 9-way; Nominal current 25 A; suitable for 2002 and 2003 Series rail-mounted terminal blocks

www.wago.com/2002-479**Item no.: 2002-479/011-000**

Ready-made staggered jumper; insulated; 1-3-5-7-9; Nominal current 25 A; with contact lugs broken off at the factory and circuit marking

www.wago.com/2002-479/011-000**Item no.: 2002-480**

Staggered jumper; insulated; 10-way; Nominal current 25 A; suitable for 2002 and 2003 Series rail-mounted terminal blocks

www.wago.com/2002-480**Item no.: 2002-481**

Staggered jumper; insulated; 11-way; Nominal current 25 A; suitable for 2002 and 2003 Series rail-mounted terminal blocks

 
www.wago.com/2002-481**Item no.: 2002-481/011-000**

Ready-made staggered jumper; insulated; 1-3-5-7-9-11; Nominal current 25 A; with contact lugs broken off at the factory and circuit marking

www.wago.com/2002-481/011-000**Item no.: 2002-482**

Staggered jumper; insulated; 12-way; Nominal current 25 A; suitable for 2002 and 2003 Series rail-mounted terminal blocks

www.wago.com/2002-482

	Item no.: 2002-492 Double-deck vertical jumper; insulated	www.wago.com/2002-492
	Item no.: 2002-492/000-012 Double-deck vertical jumper; insulated	www.wago.com/2002-492/000-012
	Item no.: 2009-412 Push-in type wire jumper; insulated; wire length 60 mm; Conductor cross section 1.5 mm ² ; suitable for 2001, 2002, 2003 and 2022 Series rail-mounted terminal blocks	www.wago.com/2009-412
	Item no.: 2009-414 Push-in type wire jumper; insulated; wire length 110 mm; Conductor cross section 1.5 mm ² ; suitable for 2001, 2002, 2003 and 2022 Series rail-mounted terminal blocks	www.wago.com/2009-414
	Item no.: 2009-416 Push-in type wire jumper; insulated; wire length 250 mm; Conductor cross section 1.5 mm ² ; suitable for 2001, 2002, 2003 and 2022 Series rail-mounted terminal blocks	www.wago.com/2009-416
	Item no.: 210-103 Wire commoning chain; insulated; 50 connections	www.wago.com/210-103
	Item no.: 210-123 Wire commoning chain; insulated; 50 connections	www.wago.com/210-123
ferrule		
	Item no.: 216-241 Ferrule; Sleeve for 0.5 mm ² / AWG 22; insulated; electro-tin plated; electrolytic copper; gastight crimped; acc. to DIN 46228, Part 4/09.90	www.wago.com/216-241
	Item no.: 216-242 Ferrule; Sleeve for 0.75 mm ² / AWG 20; insulated; electro-tin plated; electrolytic copper; gastight crimped; acc. to DIN 46228, Part 4/09.90	www.wago.com/216-242
	Item no.: 216-243 Ferrule; Sleeve for 1 mm ² / AWG 18; insulated; electro-tin plated; electrolytic copper; gastight crimped; acc. to DIN 46228, Part 4/09.90	www.wago.com/216-243
	Item no.: 216-244 Ferrule; Sleeve for 1.5 mm ² / AWG 16; insulated; electro-tin plated; electrolytic copper; gastight crimped; acc. to DIN 46228, Part 4/09.90	www.wago.com/216-244
	Item no.: 216-246 Ferrule; Sleeve for 2.5 mm ² / AWG 14; insulated; electro-tin plated; electrolytic copper; gastight crimped; acc. to DIN 46228, Part 4/09.90	www.wago.com/216-246
	Item no.: 216-262 Ferrule; Sleeve for 0.75 mm ² / AWG 20; insulated; electro-tin plated; electrolytic copper; gastight crimped; acc. to DIN 46228, Part 4/09.90	www.wago.com/216-262
	Item no.: 216-263 Ferrule; Sleeve for 1 mm ² / AWG 18; insulated; electro-tin plated; electrolytic copper; gastight crimped; acc. to DIN 46228, Part 4/09.90	www.wago.com/216-263
	Item no.: 216-264 Ferrule; Sleeve for 1.5 mm ² / AWG 16; insulated; electro-tin plated; electrolytic copper; gastight crimped; acc. to DIN 46228, Part 4/09.90	www.wago.com/216-264
	Item no.: 216-266 Ferrule; Sleeve for 2.5 mm ² / AWG 14; insulated; electro-tin plated; electrolytic copper; gastight crimped; acc. to DIN 46228, Part 4/09.90	www.wago.com/216-266
	Item no.: 216-284 Ferrule; Sleeve for 1.5 mm ² / AWG 16; insulated; electro-tin plated; electrolytic copper; gastight crimped; acc. to DIN 46228, Part 4/09.90	www.wago.com/216-284

**Item no.: 216-286**

Ferrule; Sleeve for 2.5 mm² / AWG 14; insulated; electro-tin plated; electrolytic copper; gastight crimped; acc. to DIN 46228, Part 4/09.90

www.wago.com/216-286
Female plug**Item no.: 2022-101**

1-conductor female plug; 2.5 mm²; 1-pole

www.wago.com/2022-101
**Item no.: 2022-101/000-006**

1-conductor female plug; 1-pole

www.wago.com/2022-101/000-006
**Item no.: 2022-101/000-012**

1-conductor female plug; 1-pole

www.wago.com/2022-101/000-012
**Item no.: 2022-101/000-016**

1-conductor female plug; 1-pole

www.wago.com/2022-101/000-016
Item no.: 2022-101/122-000

1-conductor female plug; 1-pole

www.wago.com/2022-101/122-000
Item no.: 2022-101/122-006

1-conductor female plug; 1-pole

www.wago.com/2022-101/122-006
Item no.: 2022-101/122-016

1-conductor female plug; 1-pole

www.wago.com/2022-101/122-016
Item no.: 2022-101/132-000

1-conductor female plug; Strain relief plate; 1-pole

www.wago.com/2022-101/132-000
Item no.: 2022-101/132-006

1-conductor female plug; Strain relief plate; 1-pole

www.wago.com/2022-101/132-006
Item no.: 2022-101/132-016

1-conductor female plug; Strain relief plate; 1-pole

www.wago.com/2022-101/132-016
Item no.: 2022-101/142-000

1-conductor female plug; Strain relief plate; 1-pole

www.wago.com/2022-101/142-000
Item no.: 2022-101/142-006

1-conductor female plug; Strain relief plate; 1-pole

www.wago.com/2022-101/142-006
Item no.: 2022-101/142-016

1-conductor female plug; Strain relief plate; 1-pole

www.wago.com/2022-101/142-016

**Item no.: 2022-102**1-conductor female plug; 2.5 mm²; 2-polewww.wago.com/2022-102**Item no.: 2022-102/000-006**1-conductor female plug; 2.5 mm²; 2-polewww.wago.com/2022-102/000-006**Item no.: 2022-102/000-016**1-conductor female plug; 2.5 mm²; 2-polewww.wago.com/2022-102/000-016**Item no.: 2022-102/122-000**1-conductor female plug; Locking lever; 2.5 mm²; 2-polewww.wago.com/2022-102/122-000**Item no.: 2022-102/132-000**1-conductor female plug; Strain relief plate; 2.5 mm²; 2-polewww.wago.com/2022-102/132-000**Item no.: 2022-102/142-000**1-conductor female plug; Strain relief plate; 2.5 mm²; 2-polewww.wago.com/2022-102/142-000**Item no.: 2022-103**1-conductor female plug; 2.5 mm²; 3-polewww.wago.com/2022-103**Item no.: 2022-103/000-006**1-conductor female plug; 2.5 mm²; 3-polewww.wago.com/2022-103/000-006**Item no.: 2022-103/000-016**1-conductor female plug; 2.5 mm²; 3-polewww.wago.com/2022-103/000-016**Item no.: 2022-103/000-036**1-conductor female plug; 2.5 mm²; 3-polewww.wago.com/2022-103/000-036**Item no.: 2022-103/000-037**1-conductor female plug; 2.5 mm²; 3-polewww.wago.com/2022-103/000-037**Item no.: 2022-103/000-038**1-conductor female plug; 2.5 mm²; 3-polewww.wago.com/2022-103/000-038**Item no.: 2022-103/000-039**1-conductor female plug; 2.5 mm²; 3-polewww.wago.com/2022-103/000-039**Item no.: 2022-103/123-000**1-conductor female plug; Locking lever; 2.5 mm²; 3-polewww.wago.com/2022-103/123-000**Item no.: 2022-103/133-000**1-conductor female plug; Strain relief plate; 2.5 mm²; 3-polewww.wago.com/2022-103/133-000

	Item no.: 2022-103/143-000 1-conductor female plug; Strain relief plate; 2.5 mm ² ; 3-pole	www.wago.com/2022-103/143-000
	Item no.: 2022-104 1-conductor female plug; 2.5 mm ² ; 4-pole	www.wago.com/2022-104
	Item no.: 2022-104/000-006 1-conductor female plug; 2.5 mm ² ; 4-pole	www.wago.com/2022-104/000-006
	Item no.: 2022-104/000-016 1-conductor female plug; 2.5 mm ² ; 4-pole	www.wago.com/2022-104/000-016
	Item no.: 2022-104/000-036 1-conductor female plug; 2.5 mm ² ; 4-pole	www.wago.com/2022-104/000-036
	Item no.: 2022-104/000-037 1-conductor female plug; 2.5 mm ² ; 4-pole	www.wago.com/2022-104/000-037
	Item no.: 2022-104/000-038 1-conductor female plug; 2.5 mm ² ; 4-pole	www.wago.com/2022-104/000-038
	Item no.: 2022-104/000-039 1-conductor female plug; 2.5 mm ² ; 4-pole	www.wago.com/2022-104/000-039
	Item no.: 2022-104/123-000 1-conductor female plug; Locking lever; 2.5 mm ² ; 4-pole	www.wago.com/2022-104/123-000
	Item no.: 2022-104/133-000 1-conductor female plug; Strain relief plate; 2.5 mm ² ; 4-pole	www.wago.com/2022-104/133-000
	Item no.: 2022-104/143-000 1-conductor female plug; Strain relief plate; 2.5 mm ² ; 4-pole	www.wago.com/2022-104/143-000
	Item no.: 2022-105 1-conductor female plug; 2.5 mm ² ; 5-pole	www.wago.com/2022-105
	Item no.: 2022-105/000-006 1-conductor female plug; 2.5 mm ² ; 5-pole	www.wago.com/2022-105/000-006
	Item no.: 2022-105/000-016 1-conductor female plug; 2.5 mm ² ; 5-pole	www.wago.com/2022-105/000-016
	Item no.: 2022-105/000-036 1-conductor female plug; 2.5 mm ² ; 5-pole	www.wago.com/2022-105/000-036



Item no.: 2022-105/000-037
1-conductor female plug; 2.5 mm²; 5-pole

www.wago.com/2022-105/000-037



Item no.: 2022-105/000-038
1-conductor female plug; 2.5 mm²; 5-pole

www.wago.com/2022-105/000-038



Item no.: 2022-105/000-039
1-conductor female plug; 2.5 mm²; 5-pole

www.wago.com/2022-105/000-039



Item no.: 2022-105/123-000
1-conductor female plug; Locking lever; 2.5 mm²; 5-pole

www.wago.com/2022-105/123-000



Item no.: 2022-105/134-000
1-conductor female plug; Strain relief plate; 2.5 mm²; 5-pole

www.wago.com/2022-105/134-000



Item no.: 2022-105/144-000
1-conductor female plug; Strain relief plate; 2.5 mm²; 5-pole

www.wago.com/2022-105/144-000

Item no.: 2022-106
1-conductor female plug; 2.5 mm²; 6-pole

www.wago.com/2022-106



Item no.: 2022-106/000-006
1-conductor female plug; 2.5 mm²; 6-pole

www.wago.com/2022-106/000-006



Item no.: 2022-106/000-016
1-conductor female plug; 2.5 mm²; 6-pole

www.wago.com/2022-106/000-016



Item no.: 2022-106/000-036
1-conductor female plug; 2.5 mm²; 6-pole

www.wago.com/2022-106/000-036



Item no.: 2022-106/000-037
1-conductor female plug; 2.5 mm²; 6-pole

www.wago.com/2022-106/000-037



Item no.: 2022-106/000-038
1-conductor female plug; 2.5 mm²; 6-pole

www.wago.com/2022-106/000-038



Item no.: 2022-106/000-039
1-conductor female plug; 2.5 mm²; 6-pole

www.wago.com/2022-106/000-039

Item no.: 2022-106/123-000
1-conductor female plug; Locking lever; 2.5 mm²; 6-pole

www.wago.com/2022-106/123-000

Item no.: 2022-106/134-000
1-conductor female plug; Strain relief plate; 2.5 mm²; 6-pole

www.wago.com/2022-106/134-000

	Item no.: 2022-106/144-000 1-conductor female plug; Strain relief plate; 2.5 mm ² ; 6-pole	www.wago.com/2022-106/144-000
	Item no.: 2022-107 1-conductor female plug; 2.5 mm ² ; 7-pole	www.wago.com/2022-107
	Item no.: 2022-107/000-006 1-conductor female plug; 2.5 mm ² ; 7-pole	www.wago.com/2022-107/000-006
	Item no.: 2022-107/000-016 1-conductor female plug; 2.5 mm ² ; 7-pole	www.wago.com/2022-107/000-016
	Item no.: 2022-107/000-036 1-conductor female plug; 2.5 mm ² ; 7-pole	www.wago.com/2022-107/000-036
	Item no.: 2022-107/000-037 1-conductor female plug; 2.5 mm ² ; 7-pole	www.wago.com/2022-107/000-037
	Item no.: 2022-107/000-038 1-conductor female plug; 2.5 mm ² ; 7-pole	www.wago.com/2022-107/000-038
	Item no.: 2022-107/000-039 1-conductor female plug; 2.5 mm ² ; 7-pole	www.wago.com/2022-107/000-039
	Item no.: 2022-107/123-000 1-conductor female plug; Locking lever; 2.5 mm ² ; 7-pole	www.wago.com/2022-107/123-000
	Item no.: 2022-107/135-000 1-conductor female plug; Strain relief plate; 2.5 mm ² ; 7-pole	www.wago.com/2022-107/135-000
	Item no.: 2022-107/145-000 1-conductor female plug; Strain relief plate; 2.5 mm ² ; 7-pole	www.wago.com/2022-107/145-000
	Item no.: 2022-108 1-conductor female plug; 2.5 mm ² ; 8-pole	www.wago.com/2022-108
	Item no.: 2022-108/000-006 1-conductor female plug; 2.5 mm ² ; 8-pole	www.wago.com/2022-108/000-006
	Item no.: 2022-108/000-016 1-conductor female plug; 2.5 mm ² ; 8-pole	www.wago.com/2022-108/000-016
	Item no.: 2022-108/000-036 1-conductor female plug; 2.5 mm ² ; 8-pole	www.wago.com/2022-108/000-036

	Item no.: 2022-108/000-037 1-conductor female plug; 2.5 mm ² ; 8-pole	www.wago.com/2022-108/000-037
	Item no.: 2022-108/000-038 1-conductor female plug; 2.5 mm ² ; 8-pole	www.wago.com/2022-108/000-038
	Item no.: 2022-108/000-039 1-conductor female plug; 2.5 mm ² ; 8-pole	www.wago.com/2022-108/000-039
	Item no.: 2022-108/123-000 1-conductor female plug; Locking lever; 2.5 mm ² ; 8-pole	www.wago.com/2022-108/123-000
	Item no.: 2022-108/135-000 1-conductor female plug; Strain relief plate; 2.5 mm ² ; 8-pole	www.wago.com/2022-108/135-000
	Item no.: 2022-108/145-000 1-conductor female plug; Strain relief plate; 2.5 mm ² ; 8-pole	www.wago.com/2022-108/145-000
	Item no.: 2022-109 1-conductor female plug; 2.5 mm ² ; 9-pole	www.wago.com/2022-109
	Item no.: 2022-109/000-006 1-conductor female plug; 2.5 mm ² ; 9-pole	www.wago.com/2022-109/000-006
	Item no.: 2022-109/000-016 1-conductor female plug; 2.5 mm ² ; 9-pole	www.wago.com/2022-109/000-016
	Item no.: 2022-109/000-036 1-conductor female plug; 2.5 mm ² ; 9-pole	www.wago.com/2022-109/000-036
	Item no.: 2022-109/000-037 1-conductor female plug; 2.5 mm ² ; 9-pole	www.wago.com/2022-109/000-037
	Item no.: 2022-109/000-038 1-conductor female plug; 2.5 mm ² ; 9-pole	www.wago.com/2022-109/000-038
	Item no.: 2022-109/000-039 1-conductor female plug; 2.5 mm ² ; 9-pole	www.wago.com/2022-109/000-039
	Item no.: 2022-109/123-000 1-conductor female plug; Locking lever; 2.5 mm ² ; 9-pole	www.wago.com/2022-109/123-000
	Item no.: 2022-109/135-000 1-conductor female plug; Strain relief plate; 2.5 mm ² ; 9-pole	www.wago.com/2022-109/135-000

	Item no.: 2022-109/145-000 1-conductor female plug; Strain relief plate; 2.5 mm ² ; 9-pole	www.wago.com/2022-109/145-000
	Item no.: 2022-110 1-conductor female plug; 2.5 mm ² ; 10-pole	www.wago.com/2022-110
	Item no.: 2022-110/000-006 1-conductor female plug; 2.5 mm ² ; 10-pole	www.wago.com/2022-110/000-006
	Item no.: 2022-110/000-016 1-conductor female plug; 2.5 mm ² ; 10-pole	www.wago.com/2022-110/000-016
	Item no.: 2022-110/000-036 1-conductor female plug; 2.5 mm ² ; 10-pole	www.wago.com/2022-110/000-036
	Item no.: 2022-110/000-037 1-conductor female plug; 2.5 mm ² ; 10-pole	www.wago.com/2022-110/000-037
	Item no.: 2022-110/000-038 1-conductor female plug; 2.5 mm ² ; 10-pole	www.wago.com/2022-110/000-038
	Item no.: 2022-110/000-039 1-conductor female plug; 2.5 mm ² ; 10-pole	www.wago.com/2022-110/000-039
	Item no.: 2022-110/123-000 1-conductor female plug; Locking lever; 2.5 mm ² ; 10-pole	www.wago.com/2022-110/123-000
	Item no.: 2022-110/135-000 1-conductor female plug; Strain relief plate; 2.5 mm ² ; 10-pole	www.wago.com/2022-110/135-000
	Item no.: 2022-110/145-000 1-conductor female plug; Strain relief plate; 2.5 mm ² ; 10-pole	www.wago.com/2022-110/145-000
	Item no.: 2022-111 1-conductor female plug; 2.5 mm ² ; 11-pole	www.wago.com/2022-111
	Item no.: 2022-111/000-006 1-conductor female plug; 2.5 mm ² ; 11-pole	www.wago.com/2022-111/000-006
	Item no.: 2022-111/000-016 1-conductor female plug; 2.5 mm ² ; 11-pole	www.wago.com/2022-111/000-016
	Item no.: 2022-111/000-036 1-conductor female plug; 2.5 mm ² ; 11-pole	www.wago.com/2022-111/000-036

	Item no.: 2022-111/000-037 1-conductor female plug; 2.5 mm ² ; 11-pole	www.wago.com/2022-111/000-037
	Item no.: 2022-111/000-038 1-conductor female plug; 2.5 mm ² ; 11-pole	www.wago.com/2022-111/000-038
	Item no.: 2022-111/000-039 1-conductor female plug; 2.5 mm ² ; 11-pole	www.wago.com/2022-111/000-039
	Item no.: 2022-111/126-000 1-conductor female plug; Locking lever; 2.5 mm ² ; 11-pole	www.wago.com/2022-111/126-000
	Item no.: 2022-111/136-000 1-conductor female plug; Strain relief plate; 2.5 mm ² ; 11-pole	www.wago.com/2022-111/136-000
	Item no.: 2022-111/146-000 1-conductor female plug; Strain relief plate; 2.5 mm ² ; 11-pole	www.wago.com/2022-111/146-000
	Item no.: 2022-112 1-conductor female plug; 2.5 mm ² ; 12-pole	www.wago.com/2022-112
	Item no.: 2022-112/000-006 1-conductor female plug; 2.5 mm ² ; 12-pole	www.wago.com/2022-112/000-006
	Item no.: 2022-112/000-016 1-conductor female plug; 2.5 mm ² ; 12-pole	www.wago.com/2022-112/000-016
	Item no.: 2022-112/000-036 1-conductor female plug; 2.5 mm ² ; 12-pole	www.wago.com/2022-112/000-036
	Item no.: 2022-112/000-037 1-conductor female plug; 2.5 mm ² ; 12-pole	www.wago.com/2022-112/000-037
	Item no.: 2022-112/000-038 1-conductor female plug; 2.5 mm ² ; 12-pole	www.wago.com/2022-112/000-038
	Item no.: 2022-112/000-039 1-conductor female plug; 2.5 mm ² ; 12-pole	www.wago.com/2022-112/000-039
	Item no.: 2022-112/126-000 1-conductor female plug; Locking lever; 2.5 mm ² ; 12-pole	www.wago.com/2022-112/126-000
	Item no.: 2022-112/136-000 1-conductor female plug; Strain relief plate; 2.5 mm ² ; 12-pole	www.wago.com/2022-112/136-000

	Item no.: 2022-112/146-000 1-conductor female plug; Strain relief plate; 2.5 mm ² ; 12-pole	www.wago.com/2022-112/146-000
	Item no.: 2022-113 1-conductor female plug; 2.5 mm ² ; 13-pole	www.wago.com/2022-113
	Item no.: 2022-113/000-006 1-conductor female plug; 2.5 mm ² ; 13-pole	www.wago.com/2022-113/000-006
	Item no.: 2022-113/000-016 1-conductor female plug; 2.5 mm ² ; 13-pole	www.wago.com/2022-113/000-016
	Item no.: 2022-113/000-036 1-conductor female plug; 2.5 mm ² ; 13-pole	www.wago.com/2022-113/000-036
	Item no.: 2022-113/000-037 1-conductor female plug; 2.5 mm ² ; 13-pole	www.wago.com/2022-113/000-037
	Item no.: 2022-113/000-038 1-conductor female plug; 2.5 mm ² ; 13-pole	www.wago.com/2022-113/000-038
	Item no.: 2022-113/000-039 1-conductor female plug; 2.5 mm ² ; 13-pole	www.wago.com/2022-113/000-039
	Item no.: 2022-113/126-000 1-conductor female plug; Locking lever; 2.5 mm ² ; 13-pole	www.wago.com/2022-113/126-000
	Item no.: 2022-113/136-000 1-conductor female plug; Strain relief plate; 2.5 mm ² ; 13-pole	www.wago.com/2022-113/136-000
	Item no.: 2022-113/146-000 1-conductor female plug; Strain relief plate; 2.5 mm ² ; 13-pole	www.wago.com/2022-113/146-000
	Item no.: 2022-114 1-conductor female plug; 2.5 mm ² ; 14-pole	www.wago.com/2022-114
	Item no.: 2022-114/000-006 1-conductor female plug; 2.5 mm ² ; 14-pole	www.wago.com/2022-114/000-006
	Item no.: 2022-114/000-016 1-conductor female plug; 2.5 mm ² ; 14-pole	www.wago.com/2022-114/000-016
	Item no.: 2022-114/000-036 1-conductor female plug; 2.5 mm ² ; 14-pole	www.wago.com/2022-114/000-036

	Item no.: 2022-114/000-037 1-conductor female plug; 2.5 mm ² ; 14-pole	www.wago.com/2022-114/000-037
	Item no.: 2022-114/000-038 1-conductor female plug; 2.5 mm ² ; 14-pole	www.wago.com/2022-114/000-038
	Item no.: 2022-114/000-039 1-conductor female plug; 2.5 mm ² ; 14-pole	www.wago.com/2022-114/000-039
	Item no.: 2022-114/126-000 1-conductor female plug; Locking lever; 2.5 mm ² ; 14-pole	www.wago.com/2022-114/126-000
	Item no.: 2022-114/136-000 1-conductor female plug; Strain relief plate; 2.5 mm ² ; 14-pole	www.wago.com/2022-114/136-000
	Item no.: 2022-114/146-000 1-conductor female plug; Strain relief plate; 2.5 mm ² ; 14-pole	www.wago.com/2022-114/146-000
	Item no.: 2022-115 1-conductor female plug; 2.5 mm ² ; 15-pole	www.wago.com/2022-115
	Item no.: 2022-115/000-006 1-conductor female plug; 2.5 mm ² ; 15-pole	www.wago.com/2022-115/000-006
	Item no.: 2022-115/000-016 1-conductor female plug; 2.5 mm ² ; 15-pole	www.wago.com/2022-115/000-016
	Item no.: 2022-115/000-036 1-conductor female plug; 2.5 mm ² ; 15-pole	www.wago.com/2022-115/000-036
	Item no.: 2022-115/000-037 1-conductor female plug; 2.5 mm ² ; 15-pole	www.wago.com/2022-115/000-037
	Item no.: 2022-115/000-038 1-conductor female plug; 2.5 mm ² ; 15-pole	www.wago.com/2022-115/000-038
	Item no.: 2022-115/000-039 1-conductor female plug; 2.5 mm ² ; 15-pole	www.wago.com/2022-115/000-039
	Item no.: 2022-115/127-000 1-conductor female plug; Locking lever; 2.5 mm ² ; 15-pole	www.wago.com/2022-115/127-000
	Item no.: 2022-115/137-000 1-conductor female plug; Strain relief plate; 2.5 mm ² ; 15-pole	www.wago.com/2022-115/137-000

Item no.: 2022-115/147-000
1-conductor female plug; Strain relief plate; 2.5 mm²; 15-pole

www.wago.com/2022-115/147-000

Coding



Item no.: 2022-100
Carrier with 6 coding pins; for coding of female plugs

www.wago.com/2022-100

Protective Warning Marker



Item no.: 2002-115
Protective warning marker; with high-voltage symbol, black; for 5 terminal blocks

www.wago.com/2002-115

End plate



Item no.: 2022-2291
End and intermediate plate; 1 mm thick

www.wago.com/2022-2291



Item no.: 2022-2292
End and intermediate plate; 1 mm thick

www.wago.com/2022-2292

Insulation stop



Item no.: 2002-171
Insulation stop; 0.25 - 0.5 mm²; 5 pieces/strip

www.wago.com/2002-171



Item no.: 2002-172
Insulation stop; 0.75 - 1 mm²; 5 pieces/strip

www.wago.com/2002-172

Marking accessories



Item no.: 2002-161
Adaptor

www.wago.com/2002-161



Item no.: 2009-110
Marking strips; on reel; not stretchable; plain; snap-on type

www.wago.com/2009-110



Item no.: 2009-115
WMB-Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type

www.wago.com/2009-115



Item no.: 2009-115/000-002
WMB-Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type

www.wago.com/2009-115/000-002



Item no.: 2009-115/000-006
WMB-Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type

www.wago.com/2009-115/000-006



Item no.: 2009-115/000-007
WMB-Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type

www.wago.com/2009-115/000-007



Item no.: 2009-115/000-012
WMB-Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type

www.wago.com/2009-115/000-012

	Item no.: 2009-115/000-017 WMB-Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type	www.wago.com/2009-115/000-017
	Item no.: 2009-115/000-023 WMB-Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type	www.wago.com/2009-115/000-023
	Item no.: 2009-115/000-024 WMB-Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type	www.wago.com/2009-115/000-024
	Item no.: 2009-145 Mini-WSB Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type	www.wago.com/2009-145
	Item no.: 2009-145/000-002 Mini-WSB Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type	www.wago.com/2009-145/000-002
	Item no.: 2009-145/000-005 Mini-WSB Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type	www.wago.com/2009-145/000-005
	Item no.: 2009-145/000-006 Mini-WSB Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type	www.wago.com/2009-145/000-006
	Item no.: 2009-145/000-007 Mini-WSB Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type	www.wago.com/2009-145/000-007
	Item no.: 2009-145/000-012 Mini-WSB Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type	www.wago.com/2009-145/000-012
	Item no.: 2009-145/000-023 Mini-WSB Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type	www.wago.com/2009-145/000-023
	Item no.: 2009-145/000-024 Mini-WSB Inline; on reel; stretchable 5 - 5.2 mm; plain; snap-on type	www.wago.com/2009-145/000-024
	Item no.: 2009-191 Group marker carrier	www.wago.com/2009-191
	Item no.: 2009-192 Group marker carrier	www.wago.com/2009-192
	Item no.: 2009-193 Group marker carrier	www.wago.com/2009-193
	Item no.: 2009-198 Adaptor	www.wago.com/2009-198
	Item no.: 248-501 Miniature WSB Quick marking system; plain; Marker width 5 mm; 10 strips with 10 markers per card	www.wago.com/248-501

**Item no.: 248-501/000-002**

Mini-WSB marking card; as card; not stretchable; plain; snap-on type

www.wago.com/248-501/000-002**Item no.: 248-501/000-005**

Mini-WSB marking card; as card; plain; snap-on type

www.wago.com/248-501/000-005**Item no.: 248-501/000-006**

Mini-WSB marking card; as card; not stretchable; plain; snap-on type

www.wago.com/248-501/000-006**Item no.: 248-501/000-007**

Mini-WSB marking card; as card; not stretchable; plain; snap-on type

www.wago.com/248-501/000-007**Item no.: 248-501/000-012**

Mini-WSB marking card; as card; not stretchable; plain; snap-on type

www.wago.com/248-501/000-012**Item no.: 248-501/000-017**

Mini-WSB marking card; as card; not stretchable; plain; snap-on type

www.wago.com/248-501/000-017**Item no.: 248-501/000-023**

Mini-WSB marking card; as card; not stretchable; plain; snap-on type

www.wago.com/248-501/000-023**Item no.: 248-501/000-024**

Mini-WSB marking card; as card; not stretchable; plain; snap-on type

www.wago.com/248-501/000-024**Item no.: 793-501**

WMB marking card; as card; not stretchable; plain; snap-on type

www.wago.com/793-501**Item no.: 793-501/000-002**

WMB marking card; as card; not stretchable; plain; snap-on type

www.wago.com/793-501/000-002**Item no.: 793-501/000-005**

WMB marking card; as card; not stretchable; plain; snap-on type

www.wago.com/793-501/000-005**Item no.: 793-501/000-006**

WMB marking card; as card; not stretchable; plain; snap-on type

www.wago.com/793-501/000-006**Item no.: 793-501/000-007**

WMB marking card; as card; not stretchable; plain; snap-on type

www.wago.com/793-501/000-007**Item no.: 793-501/000-012**

WMB marking card; as card; not stretchable; plain; snap-on type

www.wago.com/793-501/000-012**Item no.: 793-501/000-017**

WMB marking card; as card; not stretchable; plain; snap-on type

www.wago.com/793-501/000-017



Item no.: 793-501/000-023
WMB marking card; as card; not stretchable; plain; snap-on type

www.wago.com/793-501/000-023



Item no.: 793-501/000-024
WMB marking card; as card; not stretchable; plain; snap-on type

www.wago.com/793-501/000-024



Item no.: 793-5501
WMB marking card; as card; for terminal block width 5 - 17.5 mm; stretchable 5 - 5.2 mm; plain; snap-on type

www.wago.com/793-5501



Item no.: 793-5501/000-002
WMB marking card; as card; for terminal block width 5 - 17.5 mm; stretchable 5 - 5.2 mm; plain; snap-on type

www.wago.com/793-5501/000-002



Item no.: 793-5501/000-005
WMB marking card; as card; stretchable 5 - 5.2 mm; plain; snap-on type

www.wago.com/793-5501/000-005



Item no.: 793-5501/000-006
WMB marking card; as card; stretchable 5 - 5.2 mm; plain; snap-on type

www.wago.com/793-5501/000-006



Item no.: 793-5501/000-007
WMB marking card; as card; stretchable 5 - 5.2 mm; plain; snap-on type

www.wago.com/793-5501/000-007



Item no.: 793-5501/000-012
WMB marking card; as card; stretchable 5 - 5.2 mm; plain; snap-on type

www.wago.com/793-5501/000-012



Item no.: 793-5501/000-017
WMB marking card; as card; stretchable 5 - 5.2 mm; plain; snap-on type

www.wago.com/793-5501/000-017



Item no.: 793-5501/000-023
WMB marking card; as card; stretchable 5 - 5.2 mm; plain; snap-on type

www.wago.com/793-5501/000-023



Item no.: 793-5501/000-024
WMB marking card; as card; stretchable 5 - 5.2 mm; plain; snap-on type

www.wago.com/793-5501/000-024

General accessories



Item no.: 2002-121
Adaptor

www.wago.com/2002-121



Item no.: 2022-161
Start module for 1-conductor female connector; with integrated end plate; 2.5 mm²; 1-pole

www.wago.com/2022-161



Item no.: 2022-162
Start module for 1-conductor female connector; with integrated end plate; 2.5 mm²; 1-pole

www.wago.com/2022-162



Item no.: 2022-164
Start module for 1-conductor female connector; with integrated end plate; 2.5 mm²; 1-pole

www.wago.com/2022-164

**Item no.: 2022-167**Start module for 1-conductor female connector; with integrated end plate; 2.5 mm²; 1-polewww.wago.com/2022-167**Item no.: 2022-171**Center module for 1-conductor female connector; 2.5 mm²; 1-polewww.wago.com/2022-171**Item no.: 2022-172**Center module for 1-conductor female connector; 2.5 mm²; 1-polewww.wago.com/2022-172**Item no.: 2022-174**Center module for 1-conductor female connector; 2.5 mm²; 1-polewww.wago.com/2022-174**Item no.: 2022-177**Center module for 1-conductor female connector; 2.5 mm²; 1-polewww.wago.com/2022-177**Item no.: 2022-181**End module for 1-conductor female connector; 2.5 mm²; 1-polewww.wago.com/2022-181**Item no.: 2022-182**End module for 1-conductor female connector; 2.5 mm²; 1-polewww.wago.com/2022-182**Item no.: 2022-184**End module for 1-conductor female connector; 2.5 mm²; 1-polewww.wago.com/2022-184**Item no.: 2022-187**End module for 1-conductor female connector; 2.5 mm²; 1-polewww.wago.com/2022-187**tools****Item no.: 210-720**

Operating tool with partially insulated shaft; Type 2, blade (3.5 x 0.5) mm

www.wago.com/210-720**Downloads****Documentation****Bid Text**

2022-2204

Aug 15, 2018

DOCX
15.7 kB[Download](#)**smartDATA****CAD data**

3D Download 2022-2204

[URL](#)[Download](#)**Product family****X-COM S**[Show all products from the family](#)



Subject to changes.

WAGO Kontakttechnik GmbH & Co. KG
Hansastr. 27
32423 Minden
Phone: +49571 887-0 | Fax: +49571 887-169
Email: info.de@wago.com | Web: www.wago.com

Do you have any questions about our products?
We are always happy to take your call at +49 (571) 887-44222.