

Data sheet | Item number: 267-114

Female connector; with snap-in mounting feet and ground conductor termination; 4-pole; with molded pole marking; adjustable




www.wago.com/267-114



RoHS Compliant

[BOMcheck.net](https://www.bomcheck.net)

Color:

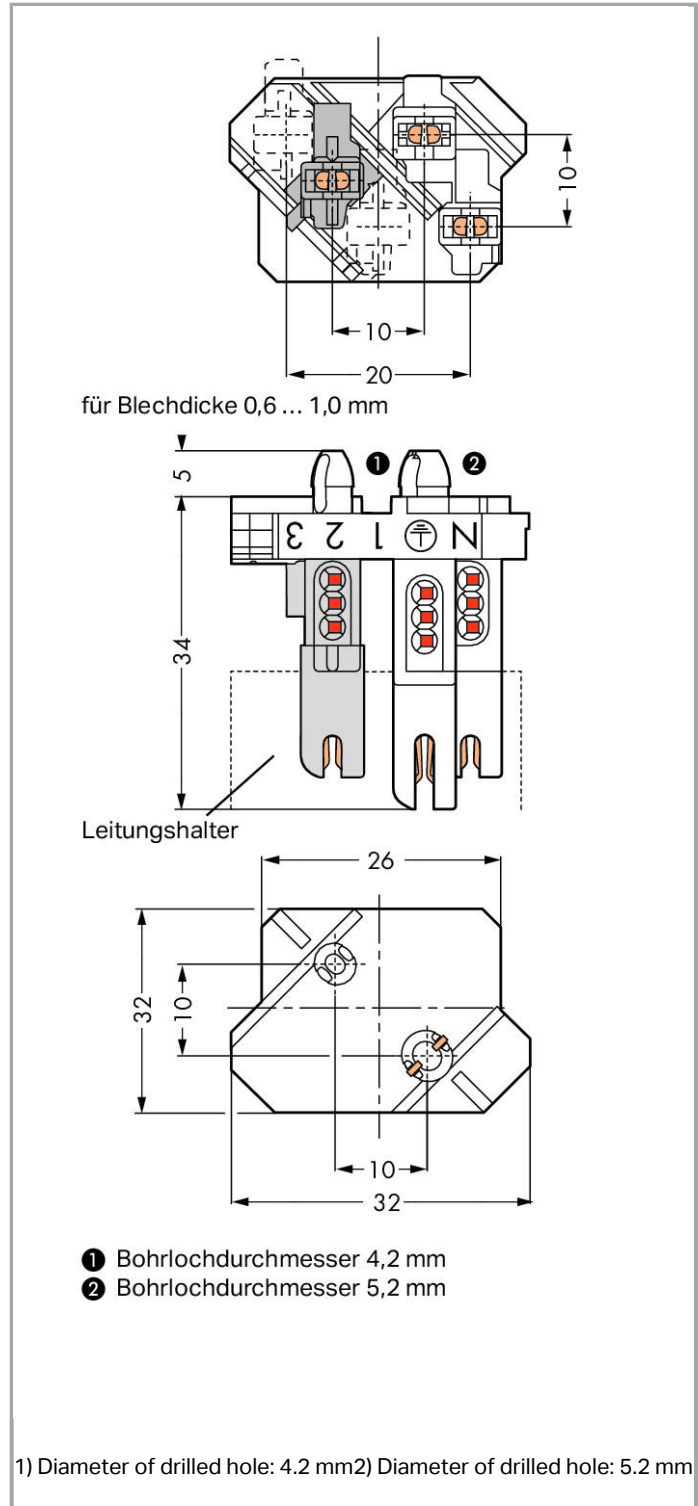



Item description

- Flexible, modular 5- to 11-pole connector system
- Future system expansions possible
- Compact design

Data

Electrical data

Ratings per IEC/EN 60664-1

Rated voltage (III / 2)	500 V
Rated impulse voltage (III / 2)	4 kV
Rated current	6 A
Legend (ratings)	(III / 2) ≙ Overvoltage category III / Pollution degree 2

Connection data

Strip length	8 mm / 0.31 inch
No. of poles	4
Number of connection types	1

Geometrical Data

Width	32 mm / 1.26 inch
Height from the surface	34 mm / 1.339 inch
Depth	32 mm / 1.26 inch

Material Data

Color	white
Material group	I
Insulating material	Polyamide 66 (PA 66)
Flammability class per UL94	V0
Clamping spring material	Chrome nickel spring steel (CrNi)
Contact material	Electrolytic copper (Ecu)
Contact plating	tin-plated
Fire load	0.14 MJ
Weight	7.33 g

Environmental Requirements

Temperature stability	105 °C
-----------------------	--------

Commercial data

Packaging type	bag
Country of origin	PL
GTIN	4044918499507
Customs Tariff No.	85366990990
Product Group	8 (Misc. Chassis Mount Blocks)

Approvals / Certificates

Country specific Approvals

Logo	Approval	Certificate name
	CCA DEKRA Certification B.V.	NL-47718
	KEMA/KEUR DEKRA Certification B.V.	71-100641
	VDE VDE Prüf- und Zertifizierungsinstitut	40032309
UL-Approvals		
Logo	Approval	Certificate name
	UL UL International Germany GmbH	E45171 vol. 2 sec. 14

Downloads

smartDATA

CAD data

3D Download 267-114	URL	Download

Subject to changes.