


Data sheet | Item number: 267-163

Female connector; with snap-in mounting feet and ground conductor termination; 3-pole; with molded pole marking; adjustable

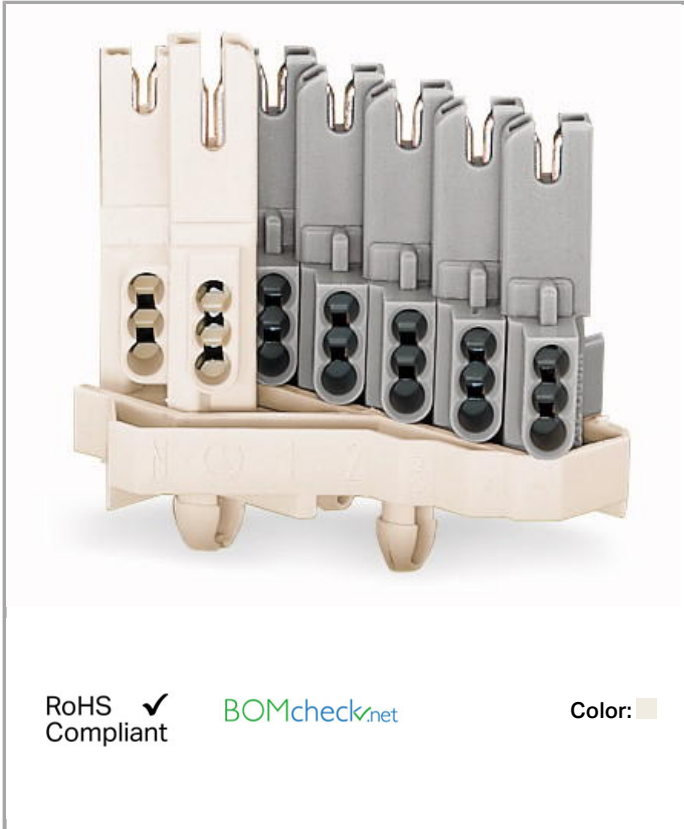


[www.wago.com/267-163](http://www.wago.com/267-163)



RoHS  
Compliant ✓

[BOMcheck.net](http://BOMcheck.net)

Color:

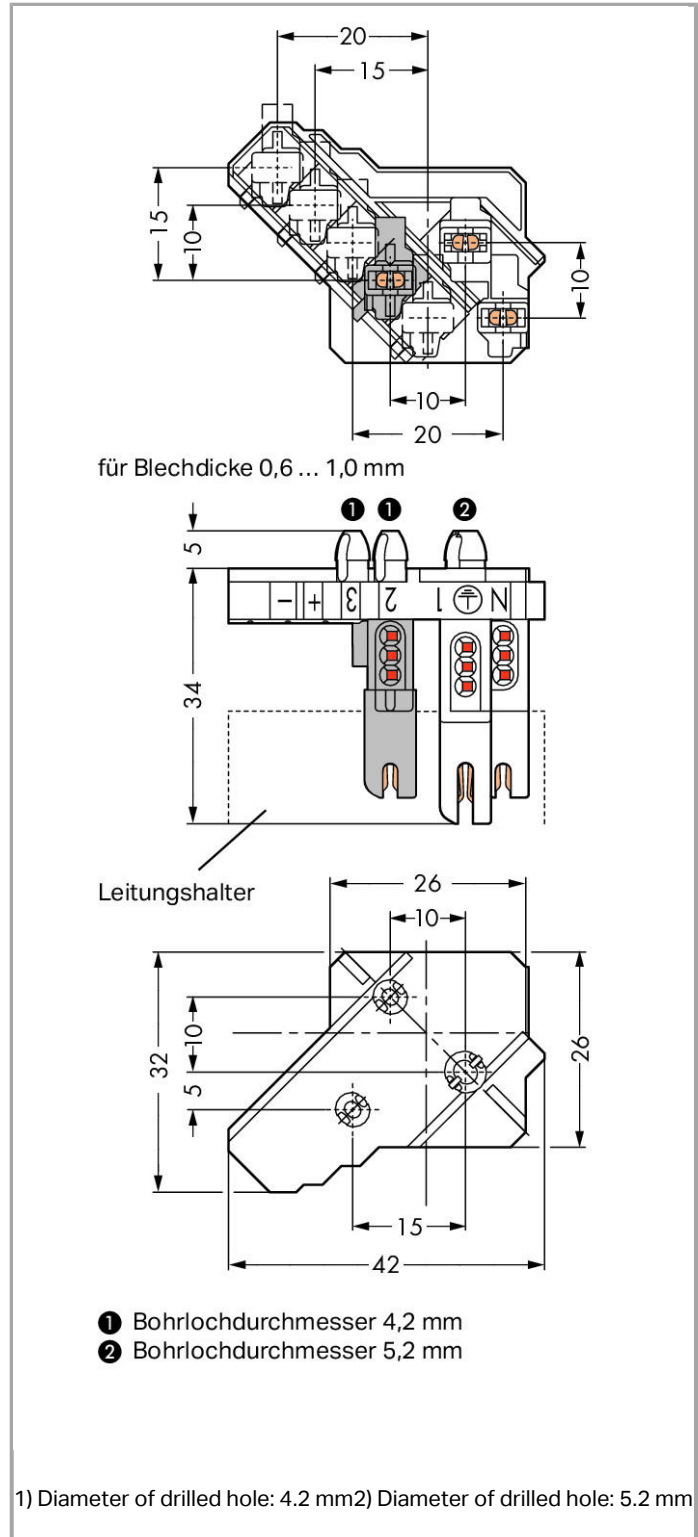



## Item description

- Flexible, modular 5- to 11-pole connector system
- Future system expansions possible
- Compact design

## Data

### Electrical data

#### Ratings per IEC/EN 60664-1

Rated voltage (III / 2)	500 V
Rated impulse voltage (III / 2)	4 kV
Rated current	6 A
Legend (ratings)	(III / 2) $\triangleq$ Overvoltage category III / Pollution degree 2

### Connection data

Connection technology	PUSH WIRE <sup>®</sup>
Strip length	8 mm / 0.31 Inch
No. of poles	3
Number of connection types	1

### Geometrical Data

Width	26 mm / 1.024 inch
Height from the surface	34 mm / 1.339 inch
Depth	42 mm / 1.654 inch

### Material Data

Color	white
Material group	I
Insulating material	Polyamide 66 (PA 66)
Flammability class per UL94	V0
Clamping spring material	Chrome nickel spring steel (CrNi)
Contact material	Electrolytic copper (Ecu)
Contact plating	tin-plated
Fire load	0.145 MJ
Weight	7 g

### Environmental Requirements



Temperature stability	105 °C
-----------------------	--------

## Commercial data

Packaging type	bag
Country of origin	PL
GTIN	4044918499651
Customs Tariff No.	85369010000
Product Group	8 (Misc. Chassis Mount Blocks)

## Approvals / Certificates

### Country specific Approvals

Logo	Approval	Certificate name
	<b>CCA</b> DEKRA Certification B.V.	NL-47718
	<b>KEMA/KEUR</b> DEKRA Certification B.V.	71-100641
	<b>VDE</b> VDE Prüf- und Zertifizierungsinstitut	40032309

## Downloads smartDATA

### CAD data

	URL	Download
3D Download 267-163		

Subject to changes.