



Data sheet | Item number: 267-501
Female connector; N PE 1 2 3 + -; 7-pole

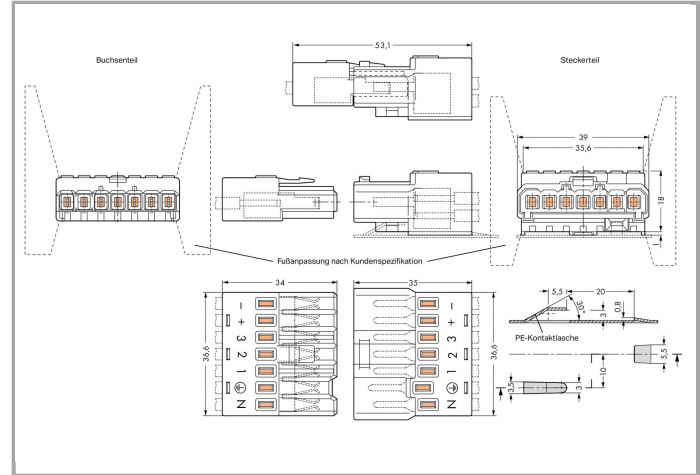

www.wago.com/267-501

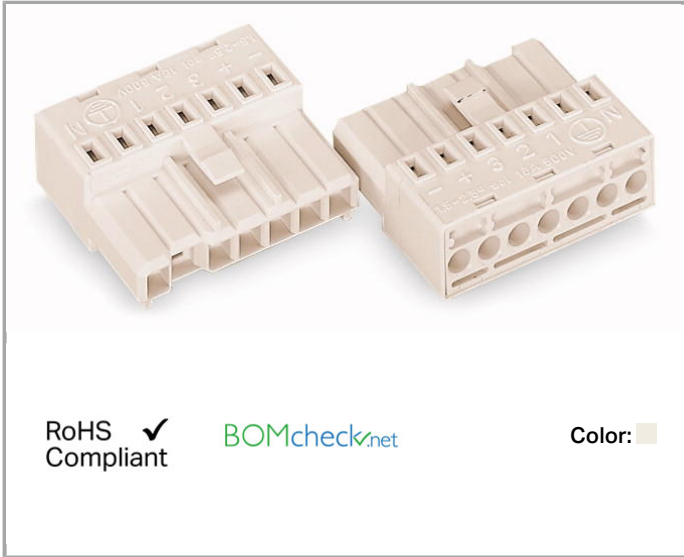

Data

Electrical data

Ratings per IEC/EN 60664-1

Rated voltage (III / 2)	500 V
Rated impulse voltage (III / 2)	4 kV
Rated current	16 A
Legend (ratings)	(III / 2) ≙ Overvoltage category III / Pollution degree 2

Connection data

Connection technology	PUSH WIRE®
Solid conductor	1.5 ... 2.5 mm ² / ...
Strip length	11 ... 12 mm / 0.43 ... 0.47 Inch
No. of poles	7
Total number of connection points	7
Number of connection types	1
Number of levels	1

Geometrical Data

Width	34 mm / 1.339 inch
Height	18 mm / 0.709 inch
Depth	39 mm / 1.535 inch

Material Data

Color	white
Material group	I
Insulating material	Polyamide 66 (PA 66)
Flammability class per UL94	V0
Clamping spring material	Chrome nickel spring steel (CrNi)
Contact material	Electrolytic copper (Ecu)
Contact plating	tin-plated
Fire load	0.181 MJ
Weight	13.928 g

Environmental Requirements



Temperature stability	105 °C
-----------------------	--------

Commercial data

Country of origin	PL
GTIN	4044918546492
Customs Tariff No.	85369010000
Product Group	8 (Misc. Chassis Mount Blocks)

Approvals / Certificates

Country specific Approvals

Logo	Approval	Certificate name
	CCA DEKRA Certification B.V.	2156138.01
	CCA DEKRA Certification B.V.	NL-47713
	VDE VDE Prüf- und Zertifizierungsinstitut	40032309

Downloads smartDATA

CAD data

3D Download 267-501	URL	Download
---------------------	-----	----------



Subject to changes.

WAGO Kontakttechnik GmbH & Co. KG
Hansastr. 27
32423 Minden
Phone: +49571 887-0 | Fax: +49571 887-169
Email: info.de@wago.com | Web: www.wago.com

Do you have any questions about our products?
We are always happy to take your call at +49 (571) 887-44222.