


Data sheet | Item number: 279-907

2-conductor ground terminal block; 1.5 mm<sup>2</sup>; center marking; for DIN-rail 35 x 15 and 35 x 7.5; CAGE CLAMP®

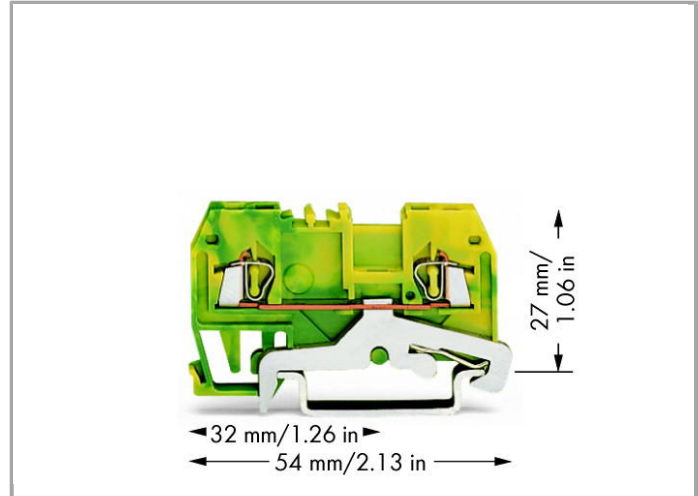


[www.wago.com/279-907](http://www.wago.com/279-907)



RoHS  Compliant

[BOMcheck.net](https://www.bomcheck.net)

Color: ■

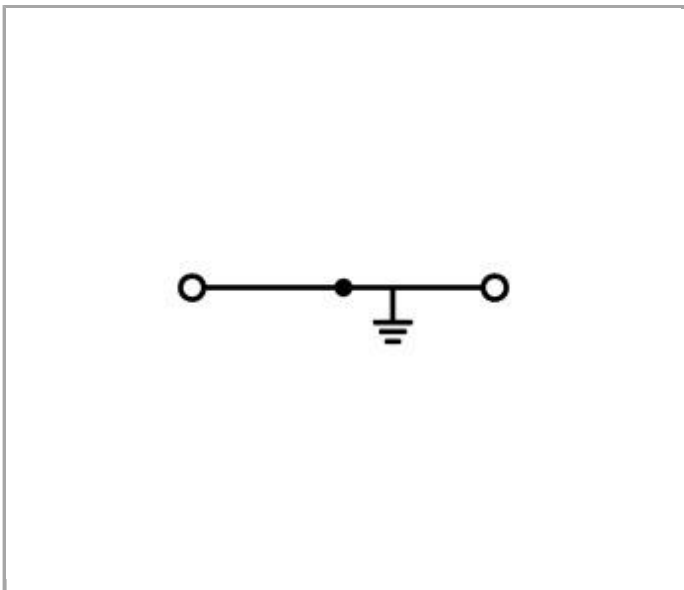

Data

Connection data

Connection technology

CAGE CLAMP®

Actuation type

Operating tool

|                                   |  |
|-----------------------------------|--|
| Connectable conductor materials   | Copper<br>Aluminum                           |
| Solid conductor                   | 0.08 ... 1.5 mm <sup>2</sup> / 28 ... 16 AWG |
| Fine-stranded conductor           | 0.08 ... 1.5 mm <sup>2</sup> / 28 ... 16 AWG |
| Strip length                      | 8 ... 9 mm / 0.31 ... 0.35 Inch              |
| Total number of connection points | 2  |
| Total number of potentials        | 1  |
| Number of levels                  | 1  |
| Type of wiring                    | Front-entry wiring                           |

### Geometrical Data

|                                       |                    |
|---------------------------------------|--------------------|
| Width                                 | 4 mm / 0.157 inch  |
| Height from upper-edge of DIN-35 rail | 27 mm / 1.063 inch |
| Depth                                 | 54 mm / 2.126 inch |

### Mechanical data

|                  |                |
|------------------|----------------|
| Design           | horizontal     |
| Type of mounting | DIN-35 rail    |
| Marking level    | Center marking |

### Material Data


|                     |                      |
|---------------------|----------------------|
| Color               | green-yellow         |
| Insulating material | Polyamide 66 (PA 66) |
| Fire load           | 0.076 MJ             |
| Weight              | 7.922 g              |

### Commercial data




|                    |               |
|--------------------|---------------|
| Country of origin  | DE            |
| GTIN               | 4045454084479 |
| Customs Tariff No. | 85369010000   |

### Approvals / Certificates


#### Country specific Approvals

| Logo   | Approval                              | Certificate name |
|--|---------------------------------------|------------------|
|  | CCA<br>DEKRA Certification B.V.       | NTR NL-7081      |
|  | KEMA/KEUR<br>DEKRA Certification B.V. | 2160584.04       |

## Ship Approvals

| Logo   | Approval                                  | Certificate name |
|--|---|------------------|
|  | <b>ABS</b><br>American Bureau of Shipping | 14-HG1293677-PDA |
|  | <b>BV</b><br>Bureau Veritas S.A.          | 07436/E0 BV      |
|  | <b>LR</b><br>Lloyds Register              | 91/20112 (E9)    |

## UL-Approvals

| Logo   | Approval                                    | Certificate name |
|--|---|------------------|
|  | <b>UR</b><br>Underwriters Laboratories Inc. | E45172           |

## Compatible products


## End plate

|  |  |  |
|--|--|--|
|  | <b>Item no.: 279-325</b><br>End and intermediate plate; 2 mm thick | <a href="http://www.wago.com/279-325">www.wago.com/279-325</a> |
|  | <b>Item no.: 279-326</b><br>Separator plate; 2 mm thick; oversized | <a href="http://www.wago.com/279-326">www.wago.com/279-326</a> |
|  | <b>Item no.: 279-328</b><br>End and intermediate plate; 2 mm thick | <a href="http://www.wago.com/279-328">www.wago.com/279-328</a> |
|  | <b>Item no.: 279-329</b><br>Separator plate; 2 mm thick; oversized | <a href="http://www.wago.com/279-329">www.wago.com/279-329</a> |


## Insulation stop

|  |   |  |
|--|---|--|
|  | <b>Item no.: 279-470</b><br>Insulation stop; 0.08 - 0.2 mm <sup>2</sup> "s" (0.14 mm <sup>2</sup> "f-st"); 5 pieces/strip | <a href="http://www.wago.com/279-470">www.wago.com/279-470</a> |
|  | <b>Item no.: 279-471</b><br>Insulation stop; 0.25 mm <sup>2</sup> ; 5 pieces/strip  | <a href="http://www.wago.com/279-471">www.wago.com/279-471</a> |

## Protective Warning Marker


|  |   |  |
|--|---|--|
|  | <b>Item no.: 279-415</b><br>Protective warning marker; with high-voltage symbol, black; for 5 terminal blocks | <a href="http://www.wago.com/279-415">www.wago.com/279-415</a> |
|--|---|--|

## check


|   |  |  |
|---|--|--|
|  | <b>Item no.: 209-170</b><br>Test plug adapter; 8.3 mm wide; for 4 mm Ø test plugs; suitable for 1.5 mm <sup>2</sup> - 10 mm <sup>2</sup> tbs | <a href="http://www.wago.com/209-170">www.wago.com/209-170</a> |
|---|--|--|


## General accessories


|  |  |  |
|--|--|--|
|  | <b>Item no.: 249-105</b><br>Group marker carrier | <a href="http://www.wago.com/249-105">www.wago.com/249-105</a> |
|--|--|--|


|   |  |  |
|---|--|--|
|  | <b>Item no.: 280-404</b><br>Test plug adapter; 5 mm wide; for test plug 210-137 (2.3 mm Ø); suitable for 1.5 mm <sup>2</sup> - 4 mm <sup>2</sup> tbs | <a href="http://www.wago.com/280-404">www.wago.com/280-404</a> |
|---|--|--|


## Marking accessories


|  |   |  |
|--|---|--|
|  | <b>Item no.: 2009-114</b><br>WMB-Inline; for smartPRINTER; on reel; stretchable 4 - 4.2 mm; plain; snap-on type | <a href="http://www.wago.com/2009-114">www.wago.com/2009-114</a> |
|--|---|--|


|  |   |  |
|--|---|--|
|  | <b>Item no.: 2009-114/000-002</b><br>WMB-Inline; for smartPRINTER; on reel; stretchable 4 - 4.2 mm; plain; snap-on type | <a href="http://www.wago.com/2009-114/000-002">www.wago.com/2009-114/000-002</a> |
|--|---|--|


|  |   |  |
|--|---|--|
|  | <b>Item no.: 2009-114/000-005</b><br>WMB-Inline; for smartPRINTER; on reel; stretchable 4 - 4.2 mm; plain; snap-on type | <a href="http://www.wago.com/2009-114/000-005">www.wago.com/2009-114/000-005</a> |
|--|---|--|

|  |   |  |
|--|---|--|
|  | <b>Item no.: 2009-114/000-006</b><br>WMB-Inline; for smartPRINTER; on reel; stretchable 4 - 4.2 mm; plain; snap-on type | <a href="http://www.wago.com/2009-114/000-006">www.wago.com/2009-114/000-006</a> |
|--|---|--|

|  |   |  |
|--|---|--|
|  | <b>Item no.: 2009-114/000-007</b><br>WMB-Inline; for smartPRINTER; on reel; stretchable 4 - 4.2 mm; plain; snap-on type | <a href="http://www.wago.com/2009-114/000-007">www.wago.com/2009-114/000-007</a> |
|--|---|--|

|  |   |  |
|--|---|--|
|  | <b>Item no.: 2009-114/000-012</b><br>WMB-Inline; for smartPRINTER; on reel; stretchable 4 - 4.2 mm; plain; snap-on type | <a href="http://www.wago.com/2009-114/000-012">www.wago.com/2009-114/000-012</a> |
|--|---|--|

|  |   |  |
|--|---|--|
|  | <b>Item no.: 2009-114/000-023</b><br>WMB-Inline; for smartPRINTER; on reel; stretchable 4 - 4.2 mm; plain; snap-on type | <a href="http://www.wago.com/2009-114/000-023">www.wago.com/2009-114/000-023</a> |
|--|---|--|

|  |   |  |
|--|---|--|
|  | <b>Item no.: 2009-114/000-024</b><br>WMB-Inline; for smartPRINTER; on reel; stretchable 4 - 4.2 mm; plain; snap-on type | <a href="http://www.wago.com/2009-114/000-024">www.wago.com/2009-114/000-024</a> |
|--|---|--|

|  |                                     |  |
|--|-------------------------------------|--|
|  | <b>Item no.: 209-128</b><br>Adaptor | <a href="http://www.wago.com/209-128">www.wago.com/209-128</a> |
|--|-------------------------------------|--|

|  |  |  |
|--|--|--|
|  | <b>Item no.: 209-140</b><br>Group marker carrier | <a href="http://www.wago.com/209-140">www.wago.com/209-140</a> |
|--|--|--|

|  |  |  |
|--|--|--|
|  | <b>Item no.: 209-141</b><br>Group marker carrier | <a href="http://www.wago.com/209-141">www.wago.com/209-141</a> |
|--|--|--|

|  |  |  |
|--|--|--|
|  | <b>Item no.: 209-142</b><br>Group marker carrier | <a href="http://www.wago.com/209-142">www.wago.com/209-142</a> |
|--|--|--|



**Item no.: 209-185**  
Adaptor

[www.wago.com/209-185](http://www.wago.com/209-185)



**Item no.: 793-4501**  
WMB marking card; as card; stretchable 4 - 4.2 mm; plain; snap-on type

[www.wago.com/793-4501](http://www.wago.com/793-4501)



**Item no.: 793-4501/000-002**  
WMB marking card; as card; stretchable 4 - 4.2 mm; plain; snap-on type

[www.wago.com/793-4501/000-002](http://www.wago.com/793-4501/000-002)



**Item no.: 793-4501/000-005**  
WMB marking card; as card; stretchable 4 - 4.2 mm; plain; snap-on type

[www.wago.com/793-4501/000-005](http://www.wago.com/793-4501/000-005)



**Item no.: 793-4501/000-006**  
WMB marking card; as card; stretchable 4 - 4.2 mm; plain; snap-on type

[www.wago.com/793-4501/000-006](http://www.wago.com/793-4501/000-006)



**Item no.: 793-4501/000-007**  
WMB marking card; as card; stretchable 4 - 4.2 mm; plain; snap-on type

[www.wago.com/793-4501/000-007](http://www.wago.com/793-4501/000-007)



**Item no.: 793-4501/000-012**  
WMB marking card; as card; stretchable 4 - 4.2 mm; plain; snap-on type

[www.wago.com/793-4501/000-012](http://www.wago.com/793-4501/000-012)



**Item no.: 793-4501/000-017**  
WMB marking card; as card; stretchable 4 - 4.2 mm; plain; snap-on type

[www.wago.com/793-4501/000-017](http://www.wago.com/793-4501/000-017)



**Item no.: 793-4501/000-023**  
WMB marking card; as card; stretchable 4 - 4.2 mm; plain; snap-on type

[www.wago.com/793-4501/000-023](http://www.wago.com/793-4501/000-023)



**Item no.: 793-4501/000-024**  
WMB marking card; as card; stretchable 4 - 4.2 mm; plain; snap-on type

[www.wago.com/793-4501/000-024](http://www.wago.com/793-4501/000-024)

## ferrule



**Item no.: 216-101**  
Ferrule; Sleeve for 0.5 mm<sup>2</sup> / AWG 22; uninsulated; electro-tin plated

[www.wago.com/216-101](http://www.wago.com/216-101)



**Item no.: 216-102**  
Ferrule; Sleeve for 0.75 mm<sup>2</sup> / AWG 20; uninsulated; electro-tin plated

[www.wago.com/216-102](http://www.wago.com/216-102)



**Item no.: 216-103**  
Ferrule; Sleeve for 1 mm<sup>2</sup> / AWG 18; uninsulated; electro-tin plated

[www.wago.com/216-103](http://www.wago.com/216-103)



**Item no.: 216-201**  
Ferrule; Sleeve for 0.5 mm<sup>2</sup> / AWG 22; insulated; electro-tin plated

[www.wago.com/216-201](http://www.wago.com/216-201)






 



 



 






**Item no.: 216-202**  
Ferrule; Sleeve for 0.75 mm<sup>2</sup> / AWG 20; insulated; electro-tin plated








[www.wago.com/216-202](http://www.wago.com/216-202)





**Item no.: 216-203**  
Ferrule; Sleeve for 1 mm<sup>2</sup> / AWG 18; insulated; electro-tin plated

[www.wago.com/216-203](http://www.wago.com/216-203)




|  |  |  |
|--|--|--|
|    | <b>Item no.: 216-301</b><br>Ferrule; Sleeve for 0.25 mm <sup>2</sup> / AWG 24; insulated; electro-tin plated                         | <a href="http://www.wago.com/216-301">www.wago.com/216-301</a> |
|    | <b>Item no.: 216-302</b><br>Ferrule; Sleeve for 0.34 mm <sup>2</sup> / AWG 24; insulated; electro-tin plated                         | <a href="http://www.wago.com/216-302">www.wago.com/216-302</a> |
| <b>Carrier rail</b>  |  |  |
|    | <b>Item no.: 210-112</b><br>Steel carrier rail; 35 x 7.5 mm; 1 mm thick; 2 m long; slotted; according to EN 60715; "Hole width 25 mm | <a href="http://www.wago.com/210-112">www.wago.com/210-112</a> |
|    | <b>Item no.: 210-113</b><br>Steel carrier rail; 35 x 7.5 mm; 1 mm thick; 2 m long; unslotted; according to EN 60715                  | <a href="http://www.wago.com/210-113">www.wago.com/210-113</a> |
|    | <b>Item no.: 210-114</b><br>Steel carrier rail; 35 x 15 mm; 1.5 mm thick; 2 m long; unslotted; similar to EN 60715                   | <a href="http://www.wago.com/210-114">www.wago.com/210-114</a> |
|    | <b>Item no.: 210-115</b><br>Steel carrier rail; 35 x 7.5 mm; 1 mm thick; 2 m long; slotted; according to EN 60715; "Hole width 18 mm | <a href="http://www.wago.com/210-115">www.wago.com/210-115</a> |
|    | <b>Item no.: 210-118</b><br>Steel carrier rail; 35 x 15 mm; 2.3 mm thick; 2 m long; unslotted; according to EN 60715                 | <a href="http://www.wago.com/210-118">www.wago.com/210-118</a> |
|    | <b>Item no.: 210-196</b><br>Aluminum carrier rail; 35 x 8.2 mm; 1.6 mm thick; 2 m long; unslotted; similar to EN 60715               | <a href="http://www.wago.com/210-196">www.wago.com/210-196</a> |
|   | <b>Item no.: 210-197</b><br>Steel carrier rail; 35 x 15 mm; 1.5 mm thick; 2 m long; slotted; similar to EN 60715                     | <a href="http://www.wago.com/210-197">www.wago.com/210-197</a> |
|  | <b>Item no.: 210-198</b><br>Copper carrier rail; 35 x 15 mm; 2.3 mm thick; 2 m long; unslotted; according to EN 60715                | <a href="http://www.wago.com/210-198">www.wago.com/210-198</a> |
|  | <b>Item no.: 210-504</b><br>Steel carrier rail; 35 x 7.5 mm; 1 mm thick; 2 m long; slotted; galvanized; according to EN 60715        | <a href="http://www.wago.com/210-504">www.wago.com/210-504</a> |
|  | <b>Item no.: 210-505</b><br>Steel carrier rail; 35 x 7.5 mm; 1 mm thick; 2 m long; unslotted; galvanized; according to EN 60715      | <a href="http://www.wago.com/210-505">www.wago.com/210-505</a> |
|  | <b>Item no.: 210-506</b><br>Steel carrier rail; 35 x 15 mm; 1.5 mm thick; 2 m long; unslotted; galvanized; similar to EN 60715       | <a href="http://www.wago.com/210-506">www.wago.com/210-506</a> |
|  | <b>Item no.: 210-508</b><br>Steel carrier rail; 35 x 15 mm; 1.5 mm thick; 2 m long; slotted; galvanized; similar to EN 60715         | <a href="http://www.wago.com/210-508">www.wago.com/210-508</a> |
| <b>Jumper</b>  |  |  |
|  | <b>Item no.: 249-123</b><br>Push-in type wire jumper; insulated; wire length 180 mm; Conductor cross section 0.75 mm <sup>2</sup>    | <a href="http://www.wago.com/249-123">www.wago.com/249-123</a> |
|  | <b>Item no.: 249-125</b><br>Push-in type wire jumper; insulated; wire length 60 mm; Conductor cross section 0.75 mm <sup>2</sup>     | <a href="http://www.wago.com/249-125">www.wago.com/249-125</a> |
|  | <b>Item no.: 249-126</b><br>Push-in type wire jumper; insulated; wire length 110 mm; Conductor cross section 0.75 mm <sup>2</sup>    | <a href="http://www.wago.com/249-126">www.wago.com/249-126</a> |
|  | <b>Item no.: 249-127</b><br>Push-in type wire jumper; insulated; wire length 250 mm; Conductor cross section 0.75 mm <sup>2</sup>    | <a href="http://www.wago.com/249-127">www.wago.com/249-127</a> |
|  | <b>Item no.: 279-402</b>   |  |

|  |   |  |
|--|---|--|
|  | Adjacent jumper; insulated; Nominal current 15 A  | <a href="http://www.wago.com/279-402">www.wago.com/279-402</a> |
|  | <b>Item no.: 279-409</b><br>Alternate jumper; insulated; Nominal current 15 A                         | <a href="http://www.wago.com/279-409">www.wago.com/279-409</a> |
|  | <b>Item no.: 279-422</b><br>Adjacent jumper; insulated; Nominal current 15 A                          | <a href="http://www.wago.com/279-422">www.wago.com/279-422</a> |
|  | <b>Item no.: 279-482</b><br>Comb-style jumper bar; insulated; 2-way; IN = IN terminal block           | <a href="http://www.wago.com/279-482">www.wago.com/279-482</a> |
|  | <b>Item no.: 279-483</b><br>Comb-style jumper bar; insulated; 3-way; IN = IN terminal block           | <a href="http://www.wago.com/279-483">www.wago.com/279-483</a> |
|  | <b>Item no.: 279-490</b><br>Comb-style jumper bar; insulated; 10-way; IN = IN terminal block          | <a href="http://www.wago.com/279-490">www.wago.com/279-490</a> |
|  | <b>Item no.: 279-492</b><br>Alternate comb-style jumper bar; insulated; 2-way; IN = IN terminal block | <a href="http://www.wago.com/279-492">www.wago.com/279-492</a> |

assembling

|   |   |  |
|---|---|--|
|   | <b>Item no.: 209-106</b><br>Mounting carrier; for isolated mounting on DIN 35 rails     | <a href="http://www.wago.com/209-106">www.wago.com/209-106</a> |
|  | <b>Item no.: 709-153</b><br>Cover; Type 1; suitable for cover carrier, type 1; 1 m long | <a href="http://www.wago.com/709-153">www.wago.com/709-153</a> |

tools

|  |  |  |
|--|--|--|
|  | <b>Item no.: 210-647</b><br>Operating tool with partially insulated shaft; Blade (2.5 x 0.4) mm; short         | <a href="http://www.wago.com/210-647">www.wago.com/210-647</a> |
|  | <b>Item no.: 210-648</b><br>Operating tool with partially insulated shaft; Blade (2.5 x 0.4) mm; short; angled | <a href="http://www.wago.com/210-648">www.wago.com/210-648</a> |
|  | <b>Item no.: 210-719</b><br>Operating tool with partially insulated shaft; Type 1, blade (2.5 x 0.4) mm        | <a href="http://www.wago.com/210-719">www.wago.com/210-719</a> |

Downloads

Documentation

Bid Text

|         |              |                |          |
|---------|--------------|----------------|----------|
| 279-907 | Oct 12, 2017 | DOC<br>24.1 kB | Download |
|---------|--------------|----------------|----------|

smartDATA

CAD data

|                     |     |          |
|---------------------|-----|----------|
| 3D Download 279-907 | URL | Download |
|---------------------|-----|----------|



Subject to changes.

---

WAGO Kontakttechnik GmbH & Co. KG  
Hansastr. 27  
32423 Minden  
Phone: +49571 887-0 | Fax: +49571 887-169  
Email: [info.de@wago.com](mailto:info.de@wago.com) | Web: [www.wago.com](http://www.wago.com)

Do you have any questions about our products?  
We are always happy to take your call at +49 (571) 887-44222.