


Data sheet | Item number: 726-241

Matrix patchboard; Marking 1-32; Color of modules: blue; Numbering of modules on sides 1 and 2 arranged vertically and horizontally; suitable for Ex i applications; 32-pole

www.wago.com/726-241

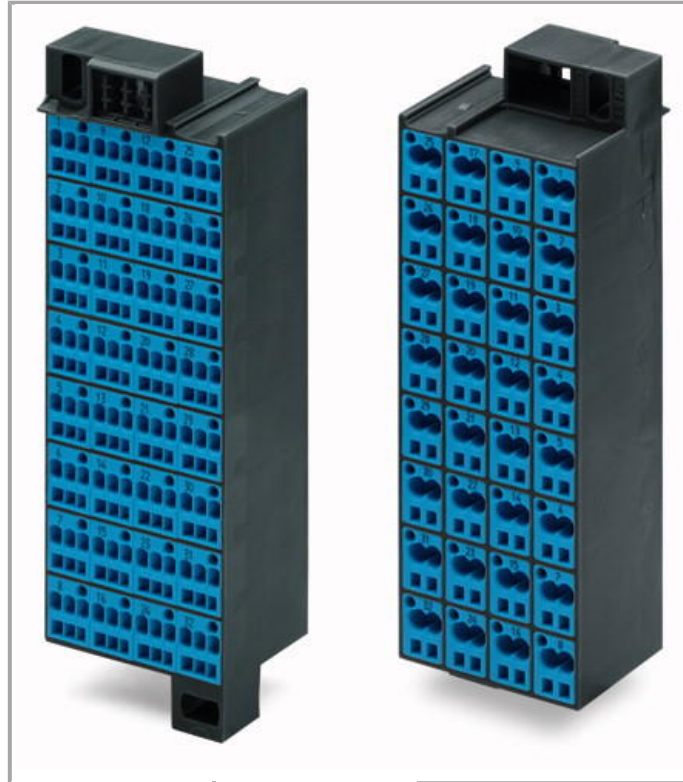

RoHS Compliant

BOMcheck.net

Color: ■

Data

Electrical data

Ratings per IEC/EN 60664-1

| | |
|---------------------------------|---|
| Rated voltage (III / 3) | 500 V |
| Rated impulse voltage (III / 3) | 6 kV |
| Rated current | 10 A |
| Legend (ratings) | (III / 3) ≙ Overvoltage category III / Pollution degree 3 |

Connection data

| | |
|-----------------------|-------------|
| Connection type (1) | Side 1 |
| Connection technology | CAGE CLAMP® |

| | |
|---|--|
| Number of connection points (connection type) | 3 |
| Actuation type | Operating tool |
| Connectable conductor materials | Copper Aluminum |
| Solid conductor | 0.08 ... 1.5 mm ² / 28 ... 16 AWG |
| Fine-stranded conductor | 0.08 ... 1.5 mm ² / 28 ... 16 AWG |
| Strip length | 8 ... 10 mm / 0.31 ... 0.39 Inch |
| Connection type (2) | Side 2 |
| Number of connection points | 2 |
| No. of poles | 32 |
| Type of wiring | Front-entry wiring |

Geometrical Data

| | |
|--------|----------------------|
| Width | 44 mm / 1.732 inch |
| Height | 132 mm / 5.197 inch |
| Depth | 36.5 mm / 1.437 inch |

Mechanical data

| | |
|---------|--------------|
| Marking | Marking 1-32 |
|---------|--------------|

Material Data

| | |
|-----------|-----------|
| Color | dark gray |
| Fire load | 2.941 MJ |
| Weight | 181.28 g |

Commercial data


| | |
|--------------------|---------------|
| Country of origin | DE |
| GTIN | 4044918979948 |
| Customs Tariff No. | 85369010000 |

Approvals / Certificates

Country specific Approvals




| Logo | Approval | Certificate name |
|--|---------------------------------------|------------------|
|  | CSA DEKRA Certification B.V. | 1101143 |
|  | KEMA/KEUR DEKRA Certification B.V. | 71-100850 |

UL-Approvals

| Logo | Approval | Certificate name |
|--|-------------------------------------|------------------|
|  | UL UL International Germany GmbH | E45172 |

Compatible products





General accessories

| | | |
|--|---|--|
|  | Item no.: 726-902 Adaptor | www.wago.com/726-902 |
|  | Item no.: 726-903 Additional module for matrix patchboards; for snap-on fixing to the lower fixing element; Additional module with contact to mounting frame | www.wago.com/726-903 |
|  | Item no.: 726-904 Additional module for matrix patchboards; for snap-on fixing to the lower fixing element; insulated; Additional module | www.wago.com/726-904 |


 


check

| | | |
|--|---|--|
|  | Item no.: 210-137 Test plug; 2.3 mm Ø; with 500 mm cable | www.wago.com/210-137 |
|--|---|--|

ferrule

| | | |
|--|--|--|
|  | Item no.: 216-104 Ferrule; Sleeve for 1.5 mm ² / AWG 16; uninsulated; electro-tin plated | www.wago.com/216-104 |
|  | Item no.: 216-123 Ferrule; Sleeve for 1 mm ² / AWG 18; uninsulated; electro-tin plated | www.wago.com/216-123 |
|  | Item no.: 216-202 Ferrule; Sleeve for 0.75 mm ² / AWG 20; insulated; electro-tin plated | www.wago.com/216-202 |
|  | Item no.: 216-204 Ferrule; Sleeve for 1.5 mm ² / AWG 16; insulated; electro-tin plated | www.wago.com/216-204 |

Marking accessories

| | | |
|--|---|--|
|  | Item no.: 209-185 Adaptor | www.wago.com/209-185 |
|  | Item no.: 209-500/209-035 WSB marking card; as card; MARKED; X (100x); not stretchable; Horizontal marking; snap-on type | www.wago.com/209-500/209-035 |
|  | Item no.: 209-501 WSB marking card; as card; not stretchable; plain; snap-on type | www.wago.com/209-501 |
|  | Item no.: 209-501/000-002 WSB marking card; as card; not stretchable; plain; snap-on type | www.wago.com/209-501/000-002 |



Item no.: 209-501/000-005
WSB marking card; as card; not stretchable; plain; snap-on type

www.wago.com/209-501/000-005



Item no.: 209-501/000-006
WSB marking card; as card; not stretchable; plain; snap-on type

www.wago.com/209-501/000-006



Item no.: 209-501/000-007
WSB marking card; as card; not stretchable; plain; snap-on type

www.wago.com/209-501/000-007



Item no.: 209-501/000-012
WSB marking card; as card; not stretchable; plain; snap-on type

www.wago.com/209-501/000-012



Item no.: 209-501/000-017
WSB marking card; as card; not stretchable; plain; snap-on type

www.wago.com/209-501/000-017



Item no.: 209-501/000-023
WSB marking card; as card; not stretchable; plain; snap-on type

www.wago.com/209-501/000-023



Item no.: 209-501/000-024
WSB marking card; as card; not stretchable; plain; snap-on type

www.wago.com/209-501/000-024



Item no.: 209-502
WSB marking card; as card; MARKED; 1 ... 10 (10x); not stretchable; Horizontal marking; snap-on type

www.wago.com/209-502



Item no.: 209-566
WSB marking card; as card; MARKED; 1 ... 50 (2x); not stretchable; Horizontal marking; snap-on type

www.wago.com/209-566



Item no.: 210-612
Marking strips; for self-marking; plain; Self-adhesive

www.wago.com/210-612



Item no.: 726-905
Adaptor

www.wago.com/726-905

Jumper



Item no.: 709-107
Wire commoning chain; insulated; 32 connections

www.wago.com/709-107

tools



Item no.: 210-719
Operating tool with partially insulated shaft; Type 1, blade (2.5 x 0.4) mm

www.wago.com/210-719

Insulation stop



Item no.: 726-901
Insulation stop; 0.08 - 0.2 mm² "s" (0.14 mm² "f-st"); 4 x 3 pieces/strip

www.wago.com/726-901



Item no.: 726-906
Insulation stop; 0.25 mm² "s"; 0.14 - 0.25 mm² "f-st"; 4 x 3 pieces/strip

www.wago.com/726-906



Item no.: 726-907

Insulation stop; 0.25 - 0.5 mm² "s+f-st"; 4 x 3 pieces/strip

www.wago.com/726-907

Downloads

Documentation

Bid Text

| | | | |
|---------|--------------|----------------|----------|
| 726-241 | Oct 18, 2017 | DOC 25.6 kB | Download |
|---------|--------------|----------------|----------|

Subject to changes.