



Data sheet | Item number: 756-5516/040-010

Sensor/actuator distribution cable; fitted on both ends; 4-pole; 2 x M12 socket, straight; M12 plug, straight; 1 m

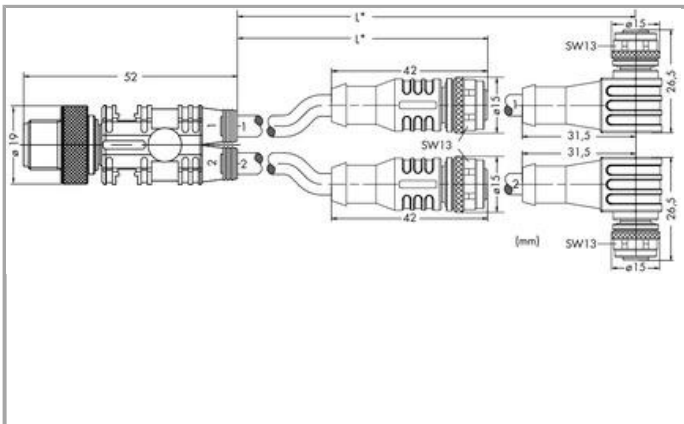

[www.wago.com/756-5516/040-010](http://www.wago.com/756-5516/040-010)

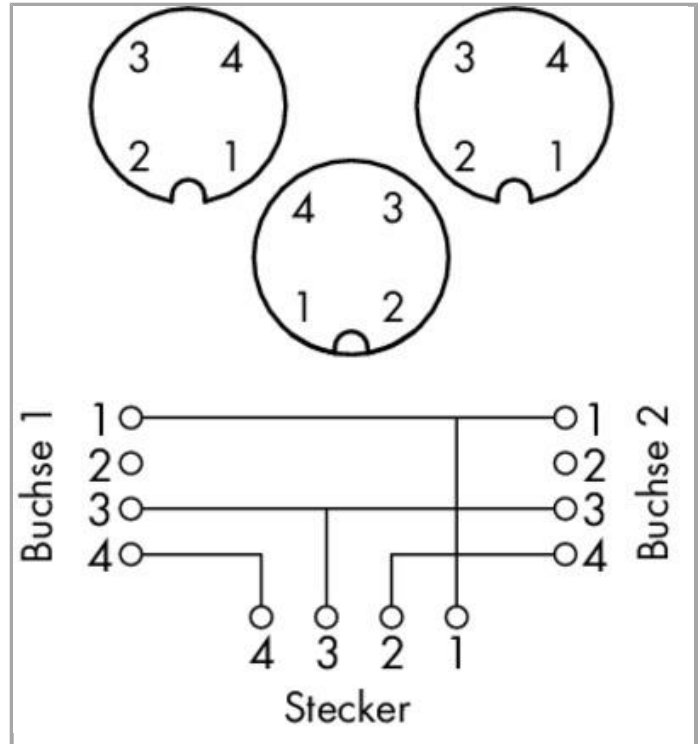

Pin 1 - 4: 0,34 mm<sup>2</sup>

## Item description

### Short description:

- PUR, halogen-free
- Suitable for drag chains
- Good resistance to microbes, hydrolysis, oil, chemicals and UV radiation.
- Good chemical resistance.
- Cable used: UL listed

## Data

### Technical Data

Connection type	M12 socket; M12 socket
No. of poles	4
Leitungsanschlussrichtung zur Steckrichtung	0°
Leitungsanschlussrichtung zur Steckrichtung (2)	0°
Steckgesichtskodierung Leitung/Adapter 1 1	A coded
Steckgesichtskodierung Leitung/Adapter 2 1	A coded
Steckgesichtskodierung Leitung/Adapter 1 2	A coded
Cable length	1 m
Operating voltage	AC/DC 250 V
Operating current	4 A
Rated surge voltage	2,5 kV

### Mechanical data

Bending cycles	2
Schleppkettentauglichkeit	yes
Color of sheathed cable	black
Durchmesser der Mantelleitung	4.5 ... 4.9 mm
Sheath material	Polyurethane (OPUR), halogen-free per DIN VDE 0472 Part 815, flame resistant per IEC 332-2, self-extinguishing
Halogen-free	Yes
Housing material	Polyurethan (PUR)
Contact material	CuSn
Contact plating	CuNi/Au
Tightening torque	1 Nm
Weight	91 g

### Environmental Requirements

Umgebungstemperatur (Betrieb) bewegt	-25 ... +90 °C
Umgebungstemperatur (Betrieb) ruhend	-50 ... +90 °C
Degree of protection	IP67



Degree of pollution (5)

3 acc. to VDE 0110

---

### Commercial data

Country of origin

DE

GTIN

4044918994859

Customs Tariff No.

85444290900

---

### Downloads

#### Documentation

#### System Description

IP67 Cables and Pluggable Connectors

Jun 6, 2017

434.4 kB

[Download](#)

---

Subject to changes.

---

WAGO Kontakttechnik GmbH & Co. KG

Hansastr. 27

32423 Minden

Phone: +49571 887-0 | Fax: +49571 887-169

Email: [info.de@wago.com](mailto:info.de@wago.com) | Web: [www.wago.com](http://www.wago.com)

Do you have any questions about our products?

We are always happy to take your call at +49 (571) 887-44222.