



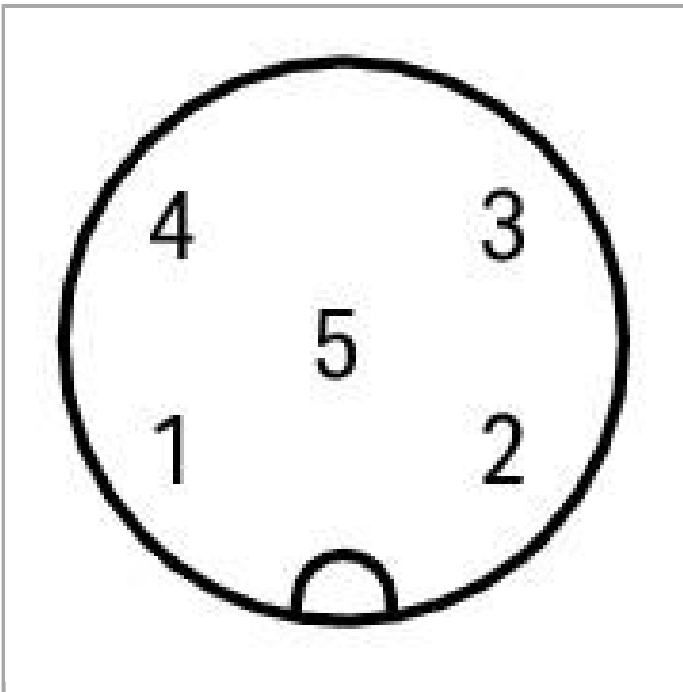

RoHS Compliant

[BOMcheck.net](https://www.bomcheck.net)

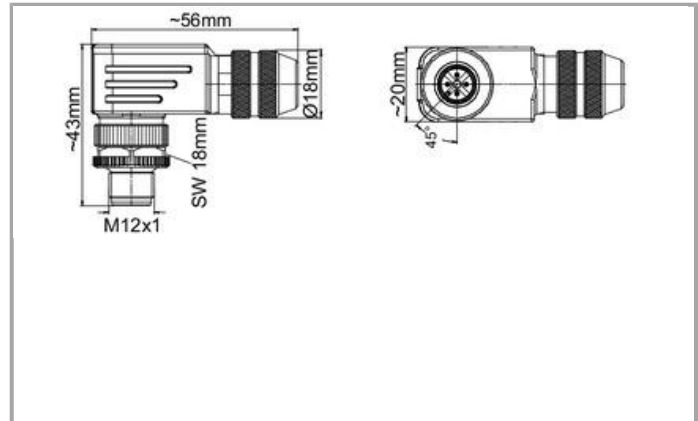

Anschließbare Leitung
Ø 6 ... 8 mm / 0,14 - 0,5 mm²

Data



Technical Data

Connection type	M12 plug
No. of poles	5
Anschlusspunkt geschirmt	yes
Leitungsanschlussrichtung zur Steckrichtung	90°
Steckgesichtskodierung Leitung/Adapter 1 1	A coded

Connection data

Connection type (1)	Federtechnik
Solid conductor	0.14 ... 0.5 mm ² / ...

Mechanical data

Connectable sheathed cable diameter	6 ... 8 mm
Weight	66.8 g

Environmental Requirements

Degree of protection	IP67
----------------------	------

Commercial data

Country of origin	DE
GTIN	4045454686413
Customs Tariff No.	85369010000

Downloads

Documentation

System Description

IP67 Cables and Pluggable Connectors	Jun 6, 2017	434.4 kB	Download
767 Series, SPEEDWAY accessories, data sheet	May 16, 2018	1.0 MB	Download

Subject to changes.