
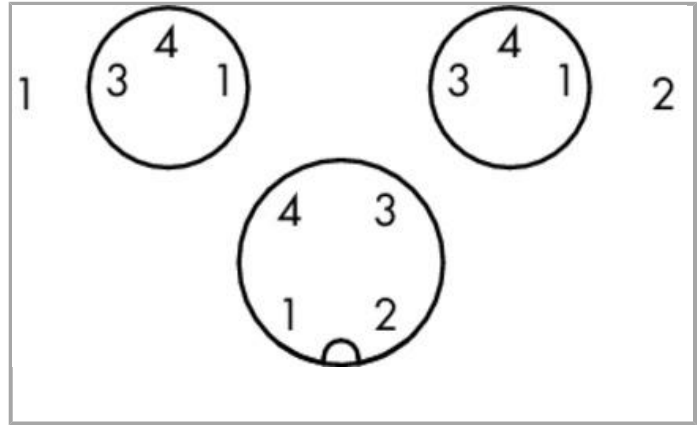


RoHS  Compliant

[BOMcheck.net](https://www.bomcheck.net)

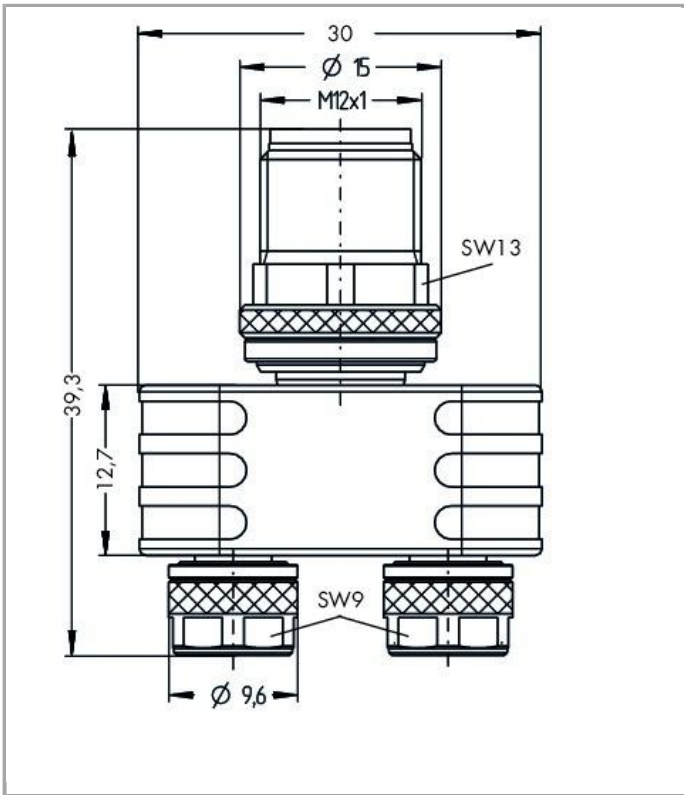

## Data

### Technical Data

Connection type	M8 socket; M8 socket
No. of poles	4
Steckgesichtskodierung Leitung/Adapter 2 1	A coded
Isolationswiderstand	1000 MΩ

### Mechanical data

Weight	20 g
--------	------

### Environmental Requirements

Degree of protection	IP67
Degree of pollution (5)	3/2

### Commercial data

Country of origin	DE
GTIN	4045454835644
Customs Tariff No.	85366990990



Downloads

Documentation

System Description

IP67 Cables and Pluggable Connectors

Jun 6, 2017

Download

434.4 kB

---

Subject to changes.

---

WAGO Kontakttechnik GmbH & Co. KG

Hansastr. 27

32423 Minden

Phone: +49571 887-0 | Fax: +49571 887-169

Email: [info.de@wago.com](mailto:info.de@wago.com) | Web: [www.wago.com](http://www.wago.com)

Do you have any questions about our products?

We are always happy to take your call at +49 (571) 887-44222.