


RoHS Compliant

[BOMcheck.net](https://www.bomcheck.net)

Color: ■

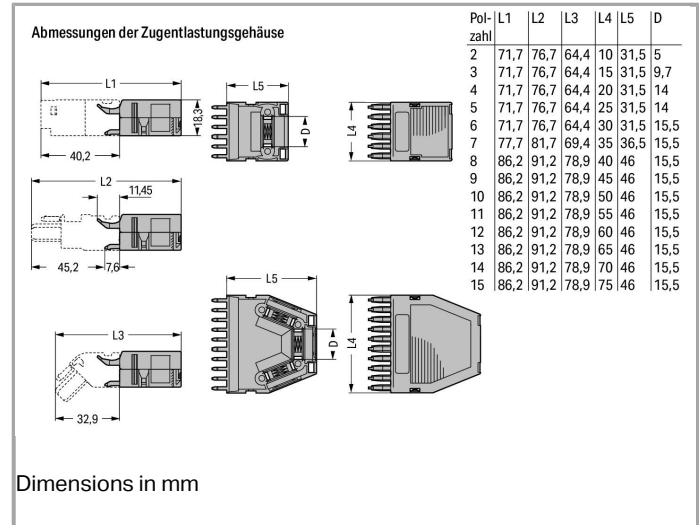

Data

Connection data

No. of poles 14

Geometrical Data

Width 70 mm / 2.756 inch

Height 18.3 mm / 0.72 inch

Depth 46 mm / 1.811 inch

Material Data

Color gray

Fire load 0.501 MJ

Weight 16.71 g

Commercial data

Country of origin DE

GTIN 4017332736503










Customs Tariff No. 85389099990

Product Group

18 (X-COM-System)

Compatible products

Marking accessories

	Item no.: 209-501 WSB marking card; as card; not stretchable; plain; snap-on type	www.wago.com/209-501
	Item no.: 209-501/000-002 WSB marking card; as card; not stretchable; plain; snap-on type	www.wago.com/209-501/000-002
	Item no.: 209-501/000-005 WSB marking card; as card; not stretchable; plain; snap-on type	www.wago.com/209-501/000-005
	Item no.: 209-501/000-006 WSB marking card; as card; not stretchable; plain; snap-on type	www.wago.com/209-501/000-006
	Item no.: 209-501/000-007 WSB marking card; as card; not stretchable; plain; snap-on type	www.wago.com/209-501/000-007
	Item no.: 209-501/000-012 WSB marking card; as card; not stretchable; plain; snap-on type	www.wago.com/209-501/000-012
	Item no.: 209-501/000-017 WSB marking card; as card; not stretchable; plain; snap-on type	www.wago.com/209-501/000-017
	Item no.: 209-501/000-023 WSB marking card; as card; not stretchable; plain; snap-on type	www.wago.com/209-501/000-023
	Item no.: 209-501/000-024 WSB marking card; as card; not stretchable; plain; snap-on type	www.wago.com/209-501/000-024

General accessories

	Item no.: 209-173 Fixing screw; for cable clamp; 7 or more poles	www.wago.com/209-173
	Item no.: 209-174 Cable clamp; for strain relief; 7 or more poles	www.wago.com/209-174

Downloads

Documentation

Bid Text

769-1614

Oct 19, 2017

DOC

Download



23.6 kB

smartDATA

CAD data

3D Download 769-1614

URL

Download

Subject to changes.