
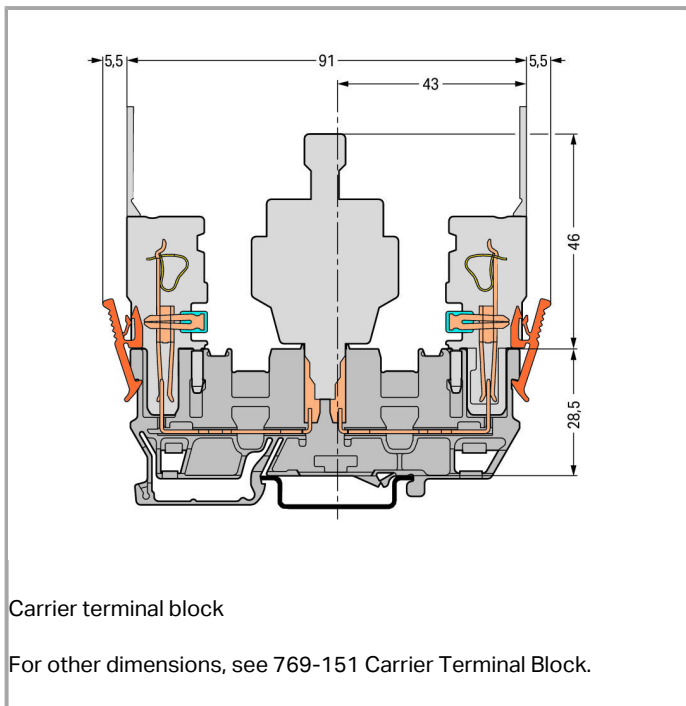
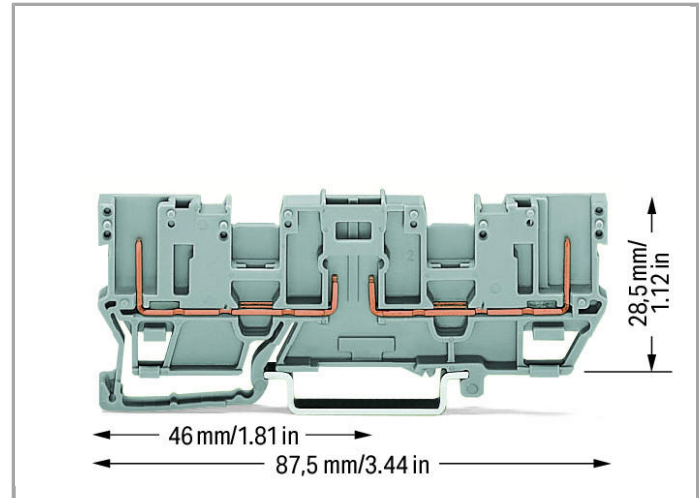


## Data sheet | Item number: 769-161

2-pin carrier terminal block; with 2 jumper positions; for DIN-rail 35 x 15 and 35 x 7.5

[www.wago.com/769-161](http://www.wago.com/769-161)

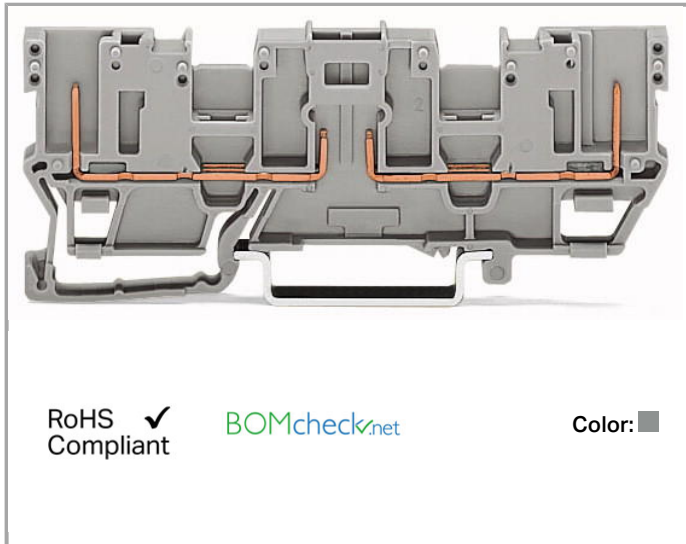

### Data

#### Electrical data

#### Ratings per IEC/EN 60664-1

Rated voltage (III / 3)

400 V



Rated impulse voltage (III / 3)	6 kV
Rated current	16 A
Legend (ratings)	(III / 3) $\triangleq$ Overvoltage category III / Pollution degree 3

### Connection data

Actuation type	Operating tool
Connectable conductor materials	Copper Aluminum
No. of poles	2
Total number of potentials	2
Number of levels	1
Type of wiring	Front-entry wiring

### Geometrical Data

Width	5 mm / 0.197 inch
Height from upper-edge of DIN-35 rail	28.5 mm / 1.122 inch
Depth	87.5 mm / 3.445 inch

### Mechanical data

Design	horizontal
Type of mounting	DIN-35 rail
Marking level	Center marking

### Material Data

Color	gray
Insulating material	Polyamide 66 (PA 66)
Fire load	0.167 MJ
Weight	7.714 g

### Commercial data

Country of origin	DE
GTIN	4044918630092
Customs Tariff No.	85369010000
Product Group	18 (X-COM-System)

### Approvals / Certificates

#### Country specific Approvals

Logo	Approval	Certificate name
	CCA DEKRA Certification B.V.	NTR NL-7626

CCA



CSA  
DEKRA Certification B.V.



1101144





KEMA/KEUR  
DEKRA Certification B.V.

2190419.01

## Ship Approvals




Logo	Approval	Certificate name
	<b>ABS</b> American Bureau of Shipping	14-HG1293677-PDA
	<b>LR</b> Lloyds Register	91/20112 (E9)















## UL-Approvals

Logo	Approval	Certificate name
	<b>UR</b> Underwriters Laboratories Inc.	E45171
	<b>UR</b> Underwriters Laboratories Inc.	E45172

## Compatible products

## Marking accessories

	Item no.: 2009-145 Mini-WSB Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type	<a href="http://www.wago.com/2009-145">www.wago.com/2009-145</a>
	Item no.: 2009-145/000-002 Mini-WSB Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type	<a href="http://www.wago.com/2009-145/000-002">www.wago.com/2009-145/000-002</a>
	Item no.: 2009-145/000-005 Mini-WSB Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type	<a href="http://www.wago.com/2009-145/000-005">www.wago.com/2009-145/000-005</a>

	<b>Item no.: 2009-145/000-006</b> Mini-WSB Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type	<a href="http://www.wago.com/2009-145/000-006">www.wago.com/2009-145/000-006</a>
	<b>Item no.: 2009-145/000-007</b> Mini-WSB Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type	<a href="http://www.wago.com/2009-145/000-007">www.wago.com/2009-145/000-007</a>
	<b>Item no.: 2009-145/000-012</b> Mini-WSB Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type	<a href="http://www.wago.com/2009-145/000-012">www.wago.com/2009-145/000-012</a>
	<b>Item no.: 2009-145/000-023</b> Mini-WSB Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type	<a href="http://www.wago.com/2009-145/000-023">www.wago.com/2009-145/000-023</a>
	<b>Item no.: 2009-145/000-024</b> Mini-WSB Inline; on reel; stretchable 5 - 5.2 mm; plain; snap-on type	<a href="http://www.wago.com/2009-145/000-024">www.wago.com/2009-145/000-024</a>
	<b>Item no.: 248-501</b> Miniature WSB Quick marking system; plain; Marker width 5 mm; 10 strips with 10 markers per card	<a href="http://www.wago.com/248-501">www.wago.com/248-501</a>
	<b>Item no.: 248-501/000-002</b> Mini-WSB marking card; as card; not stretchable; plain; snap-on type	<a href="http://www.wago.com/248-501/000-002">www.wago.com/248-501/000-002</a>
	<b>Item no.: 248-501/000-005</b> Mini-WSB marking card; as card; plain; snap-on type	<a href="http://www.wago.com/248-501/000-005">www.wago.com/248-501/000-005</a>
	<b>Item no.: 248-501/000-006</b> Mini-WSB marking card; as card; not stretchable; plain; snap-on type	<a href="http://www.wago.com/248-501/000-006">www.wago.com/248-501/000-006</a>
	<b>Item no.: 248-501/000-007</b> Mini-WSB marking card; as card; not stretchable; plain; snap-on type	<a href="http://www.wago.com/248-501/000-007">www.wago.com/248-501/000-007</a>
	<b>Item no.: 248-501/000-012</b> Mini-WSB marking card; as card; not stretchable; plain; snap-on type	<a href="http://www.wago.com/248-501/000-012">www.wago.com/248-501/000-012</a>
	<b>Item no.: 248-501/000-017</b> Mini-WSB marking card; as card; not stretchable; plain; snap-on type	<a href="http://www.wago.com/248-501/000-017">www.wago.com/248-501/000-017</a>
	<b>Item no.: 248-501/000-023</b> Mini-WSB marking card; as card; not stretchable; plain; snap-on type	<a href="http://www.wago.com/248-501/000-023">www.wago.com/248-501/000-023</a>
	<b>Item no.: 248-501/000-024</b> Mini-WSB marking card; as card; not stretchable; plain; snap-on type	<a href="http://www.wago.com/248-501/000-024">www.wago.com/248-501/000-024</a>
















## check



**Item no.: 210-137**  
 Test plug; 2.3 mm Ø; with 500 mm cable

[www.wago.com/210-137](http://www.wago.com/210-137)

## plug

	<b>Item no.: 280-850</b> Fuse plug; 5 mm wide; with soldered miniature fuse; 250 mA FF	<a href="http://www.wago.com/280-850">www.wago.com/280-850</a>
	<b>Item no.: 280-850/281-413</b> Fuse plug; 5 mm wide; with soldered miniature fuse; with additional indicator lamp; red LED; DC 15 - 30 V; 250 mA FF	<a href="http://www.wago.com/280-850/281-413">www.wago.com/280-850/281-413</a>
	<b>Item no.: 280-850/281-414</b> Fuse plug; 5 mm wide; with soldered miniature fuse; with additional indicator lamp; red LED; DC 30 - 65 V; 250 mA FF	<a href="http://www.wago.com/280-850/281-414">www.wago.com/280-850/281-414</a>
	<b>Item no.: 280-850/281-415</b> Fuse plug; 5 mm wide; with soldered miniature fuse; with additional indicator lamp; red LED; AC 15 - 30 V; 250 mA FF	<a href="http://www.wago.com/280-850/281-415">www.wago.com/280-850/281-415</a>
	<b>Item no.: 280-852</b> Fuse plug; 5 mm wide; with soldered miniature fuse; 500 mA FF	<a href="http://www.wago.com/280-852">www.wago.com/280-852</a>
	<b>Item no.: 280-852/281-413</b> Fuse plug; 5 mm wide; with soldered miniature fuse; with additional indicator lamp; red LED; DC 15 - 30 V; 500 mA FF	<a href="http://www.wago.com/280-852/281-413">www.wago.com/280-852/281-413</a>
	<b>Item no.: 280-852/281-414</b> Fuse plug; 5 mm wide; with soldered miniature fuse; with additional indicator lamp; red LED; DC 30 - 65 V; 500 mA FF	<a href="http://www.wago.com/280-852/281-414">www.wago.com/280-852/281-414</a>
	<b>Item no.: 280-852/281-415</b> Fuse plug; 5 mm wide; with soldered miniature fuse; with additional indicator lamp; red LED; AC 15 - 30 V; 500 mA FF	<a href="http://www.wago.com/280-852/281-415">www.wago.com/280-852/281-415</a>
	<b>Item no.: 280-854</b> Fuse plug; 5 mm wide; with soldered miniature fuse; 1 A FF	<a href="http://www.wago.com/280-854">www.wago.com/280-854</a>
	<b>Item no.: 280-854/281-413</b> Fuse plug; 5 mm wide; with soldered miniature fuse; with additional indicator lamp; red LED; DC 15 - 30 V; 1 A FF	<a href="http://www.wago.com/280-854/281-413">www.wago.com/280-854/281-413</a>
	<b>Item no.: 280-854/281-414</b> Fuse plug; 5 mm wide; with soldered miniature fuse; with additional indicator lamp; red LED; DC 30 - 65 V; 1 A FF	<a href="http://www.wago.com/280-854/281-414">www.wago.com/280-854/281-414</a>
	<b>Item no.: 280-854/281-415</b> Fuse plug; 5 mm wide; with soldered miniature fuse; with additional indicator lamp; red LED; AC 15 - 30 V; 1 A FF	<a href="http://www.wago.com/280-854/281-415">www.wago.com/280-854/281-415</a>
	<b>Item no.: 280-856</b> Fuse plug; 5 mm wide; with soldered miniature fuse; 2 A FF	<a href="http://www.wago.com/280-856">www.wago.com/280-856</a>
	<b>Item no.: 280-856/281-413</b> Fuse plug; 5 mm wide; with soldered miniature fuse; with additional indicator lamp; red LED; DC 15 - 30 V; 2 A FF	<a href="http://www.wago.com/280-856/281-413">www.wago.com/280-856/281-413</a>
	<b>Item no.: 280-856/281-414</b> Fuse plug; 5 mm wide; with soldered miniature fuse; with additional indicator lamp; red LED; DC 30 - 65 V; 2 A FF	<a href="http://www.wago.com/280-856/281-414">www.wago.com/280-856/281-414</a>

**Item no.: 280-856/281-415**

Fuse plug; 5 mm wide; with soldered miniature fuse; with additional indicator lamp; red LED; AC 15 - 30 V; 2 A FF

[www.wago.com/280-856/281-415](http://www.wago.com/280-856/281-415)

**Carrier rail****Item no.: 210-112**

Steel carrier rail; 35 x 7.5 mm; 1 mm thick; 2 m long; slotted; according to EN 60715; "Hole width 25 mm

[www.wago.com/210-112](http://www.wago.com/210-112)

**Item no.: 210-113**

Steel carrier rail; 35 x 7.5 mm; 1 mm thick; 2 m long; unslotted; according to EN 60715

[www.wago.com/210-113](http://www.wago.com/210-113)

**Item no.: 210-114**

Steel carrier rail; 35 x 15 mm; 1.5 mm thick; 2 m long; unslotted; similar to EN 60715

[www.wago.com/210-114](http://www.wago.com/210-114)

**Item no.: 210-115**

Steel carrier rail; 35 x 7.5 mm; 1 mm thick; 2 m long; slotted; according to EN 60715; "Hole width 18 mm

[www.wago.com/210-115](http://www.wago.com/210-115)

**Item no.: 210-118**

Steel carrier rail; 35 x 15 mm; 2.3 mm thick; 2 m long; unslotted; according to EN 60715

[www.wago.com/210-118](http://www.wago.com/210-118)

**Item no.: 210-196**

Aluminum carrier rail; 35 x 8.2 mm; 1.6 mm thick; 2 m long; unslotted; similar to EN 60715

[www.wago.com/210-196](http://www.wago.com/210-196)

**Item no.: 210-197**

Steel carrier rail; 35 x 15 mm; 1.5 mm thick; 2 m long; slotted; similar to EN 60715

[www.wago.com/210-197](http://www.wago.com/210-197)

**Item no.: 210-198**

Copper carrier rail; 35 x 15 mm; 2.3 mm thick; 2 m long; unslotted; according to EN 60715

[www.wago.com/210-198](http://www.wago.com/210-198)

**Item no.: 210-504**

Steel carrier rail; 35 x 7.5 mm; 1 mm thick; 2 m long; slotted; galvanized; according to EN 60715

[www.wago.com/210-504](http://www.wago.com/210-504)

**Item no.: 210-505**

Steel carrier rail; 35 x 7.5 mm; 1 mm thick; 2 m long; unslotted; galvanized; according to EN 60715

[www.wago.com/210-505](http://www.wago.com/210-505)

**Item no.: 210-506**

Steel carrier rail; 35 x 15 mm; 1.5 mm thick; 2 m long; unslotted; galvanized; similar to EN 60715

[www.wago.com/210-506](http://www.wago.com/210-506)

**Item no.: 210-508**

Steel carrier rail; 35 x 15 mm; 1.5 mm thick; 2 m long; slotted; galvanized; similar to EN 60715

[www.wago.com/210-508](http://www.wago.com/210-508)

**Female plug****Item no.: 769-101**

1-conductor female plug; 4 mm<sup>2</sup>; 1-pole

[www.wago.com/769-101](http://www.wago.com/769-101)

**Item no.: 769-101/000-006**

1-conductor female plug; 4 mm<sup>2</sup>; 1-pole

[www.wago.com/769-101/000-006](http://www.wago.com/769-101/000-006)

**Item no.: 769-101/000-016**

1-conductor female plug; 4 mm<sup>2</sup>; 1-pole

[www.wago.com/769-101/000-016](http://www.wago.com/769-101/000-016)

**Item no.: 769-101/022-000**

1-conductor female plug; angled; 4 mm<sup>2</sup>; 1-pole

[www.wago.com/769-101/022-000](http://www.wago.com/769-101/022-000)



**Item no.: 769-101/022-016**  
1-conductor female plug; angled; 4 mm²; 1-pole

[www.wago.com/769-101/022-016](http://www.wago.com/769-101/022-016)



**Item no.: 769-102**  
1-conductor female plug; 4 mm²; 2-pole

[www.wago.com/769-102](http://www.wago.com/769-102)

**Item no.: 769-102/000-006**  
1-conductor female plug; 4 mm²; 2-pole

[www.wago.com/769-102/000-006](http://www.wago.com/769-102/000-006)

**Item no.: 769-102/000-036**  
1-conductor female plug; 4 mm²; 2-pole

[www.wago.com/769-102/000-036](http://www.wago.com/769-102/000-036)

**Item no.: 769-102/000-037**  
1-conductor female plug; 4 mm²; 2-pole

[www.wago.com/769-102/000-037](http://www.wago.com/769-102/000-037)



**Item no.: 769-102/022-000**  
1-conductor female plug; angled; 4 mm²; 2-pole

[www.wago.com/769-102/022-000](http://www.wago.com/769-102/022-000)

**Item no.: 769-103**  
1-conductor female plug; 4 mm²; 3-pole

[www.wago.com/769-103](http://www.wago.com/769-103)

**Item no.: 769-103/000-006**  
1-conductor female plug; 4 mm²; 3-pole

[www.wago.com/769-103/000-006](http://www.wago.com/769-103/000-006)



**Item no.: 769-103/000-036**  
1-conductor female plug; 4 mm²; 3-pole

[www.wago.com/769-103/000-036](http://www.wago.com/769-103/000-036)



**Item no.: 769-103/000-037**  
1-conductor female plug; 4 mm²; 3-pole

[www.wago.com/769-103/000-037](http://www.wago.com/769-103/000-037)



**Item no.: 769-103/000-038**  
1-conductor female plug; 4 mm²; 3-pole

[www.wago.com/769-103/000-038](http://www.wago.com/769-103/000-038)



**Item no.: 769-103/000-039**  
1-conductor female plug; 4 mm²; 3-pole

[www.wago.com/769-103/000-039](http://www.wago.com/769-103/000-039)



**Item no.: 769-103/022-000**  
1-conductor female plug; angled; 4 mm²; 3-pole

[www.wago.com/769-103/022-000](http://www.wago.com/769-103/022-000)

**Item no.: 769-104**  
1-conductor female plug; 4 mm²; 4-pole

[www.wago.com/769-104](http://www.wago.com/769-104)

**Item no.: 769-104/000-006**  
1-conductor female plug; 4 mm²; 4-pole

[www.wago.com/769-104/000-006](http://www.wago.com/769-104/000-006)



**Item no.: 769-104/000-036**  
1-conductor female plug; 4 mm²; 4-pole

[www.wago.com/769-104/000-036](http://www.wago.com/769-104/000-036)



**Item no.: 769-104/000-037**  
1-conductor female plug; 4 mm²; 4-pole

[www.wago.com/769-104/000-037](http://www.wago.com/769-104/000-037)



**Item no.: 769-104/000-038**  
1-conductor female plug; 4 mm²; 4-pole

[www.wago.com/769-104/000-038](http://www.wago.com/769-104/000-038)



**Item no.: 769-104/000-039**  
1-conductor female plug; 4 mm²; 4-pole

[www.wago.com/769-104/000-039](http://www.wago.com/769-104/000-039)



**Item no.: 769-104/022-000**  
1-conductor female plug; angled; 4 mm²; 4-pole

[www.wago.com/769-104/022-000](http://www.wago.com/769-104/022-000)



**Item no.: 769-105**  
1-conductor female plug; 4 mm²; 5-pole

[www.wago.com/769-105](http://www.wago.com/769-105)



**Item no.: 769-105/000-006**  
1-conductor female plug; 4 mm²; 5-pole

[www.wago.com/769-105/000-006](http://www.wago.com/769-105/000-006)



**Item no.: 769-105/000-036**  
1-conductor female plug; 4 mm²; 5-pole

[www.wago.com/769-105/000-036](http://www.wago.com/769-105/000-036)



**Item no.: 769-105/000-037**  
1-conductor female plug; 4 mm²; 5-pole

[www.wago.com/769-105/000-037](http://www.wago.com/769-105/000-037)



**Item no.: 769-105/000-038**  
1-conductor female plug; 4 mm²; 5-pole

[www.wago.com/769-105/000-038](http://www.wago.com/769-105/000-038)



**Item no.: 769-105/000-039**  
1-conductor female plug; 4 mm²; 5-pole

[www.wago.com/769-105/000-039](http://www.wago.com/769-105/000-039)



**Item no.: 769-105/022-000**  
1-conductor female plug; angled; 4 mm²; 5-pole

[www.wago.com/769-105/022-000](http://www.wago.com/769-105/022-000)

**Item no.: 769-106**  
1-conductor female plug; 4 mm²; 6-pole

[www.wago.com/769-106](http://www.wago.com/769-106)

**Item no.: 769-106/000-006**  
1-conductor female plug; 4 mm²; 6-pole

[www.wago.com/769-106/000-006](http://www.wago.com/769-106/000-006)



**Item no.: 769-106/000-036**  
1-conductor female plug; 4 mm²; 6-pole

[www.wago.com/769-106/000-036](http://www.wago.com/769-106/000-036)





**Item no.: 769-106/000-037**  
1-conductor female plug; 4 mm²; 6-pole

[www.wago.com/769-106/000-037](http://www.wago.com/769-106/000-037)



**Item no.: 769-106/000-038**  
1-conductor female plug; 4 mm²; 6-pole

[www.wago.com/769-106/000-038](http://www.wago.com/769-106/000-038)



**Item no.: 769-106/000-039**  
1-conductor female plug; 4 mm²; 6-pole

[www.wago.com/769-106/000-039](http://www.wago.com/769-106/000-039)

**Item no.: 769-106/022-000**  
1-conductor female plug; angled; 4 mm²; 6-pole

[www.wago.com/769-106/022-000](http://www.wago.com/769-106/022-000)

**Item no.: 769-107**  
1-conductor female plug; 4 mm²; 7-pole

[www.wago.com/769-107](http://www.wago.com/769-107)

**Item no.: 769-107/000-006**  
1-conductor female plug; 4 mm²; 7-pole

[www.wago.com/769-107/000-006](http://www.wago.com/769-107/000-006)



**Item no.: 769-107/000-036**  
1-conductor female plug; 4 mm²; 7-pole

[www.wago.com/769-107/000-036](http://www.wago.com/769-107/000-036)



**Item no.: 769-107/000-037**  
1-conductor female plug; 4 mm²; 7-pole

[www.wago.com/769-107/000-037](http://www.wago.com/769-107/000-037)



**Item no.: 769-107/000-038**  
1-conductor female plug; 4 mm²; 7-pole

[www.wago.com/769-107/000-038](http://www.wago.com/769-107/000-038)



**Item no.: 769-107/000-039**  
1-conductor female plug; 4 mm²; 7-pole

[www.wago.com/769-107/000-039](http://www.wago.com/769-107/000-039)

**Item no.: 769-107/022-000**  
1-conductor female plug; angled; 4 mm²; 7-pole

[www.wago.com/769-107/022-000](http://www.wago.com/769-107/022-000)

**Item no.: 769-108**  
1-conductor female plug; 4 mm²; 8-pole

[www.wago.com/769-108](http://www.wago.com/769-108)

**Item no.: 769-108/000-006**  
1-conductor female plug; 4 mm²; 8-pole





[www.wago.com/769-108/000-006](http://www.wago.com/769-108/000-006)





**Item no.: 769-108/000-036**  
1-conductor female plug; 4 mm²; 8-pole

[www.wago.com/769-108/000-036](http://www.wago.com/769-108/000-036)

**Item no.: 769-108/000-037**  
1-conductor female plug; 4 mm²; 8-pole

[www.wago.com/769-108/000-037](http://www.wago.com/769-108/000-037)

	<b>Item no.: 769-108/000-038</b> 1-conductor female plug; 4 mm <sup>2</sup> ; 8-pole	<a href="http://www.wago.com/769-108/000-038">www.wago.com/769-108/000-038</a>
	<b>Item no.: 769-108/000-039</b> 1-conductor female plug; 4 mm <sup>2</sup> ; 8-pole	<a href="http://www.wago.com/769-108/000-039">www.wago.com/769-108/000-039</a>
	<b>Item no.: 769-108/022-000</b> 1-conductor female plug; angled; 4 mm <sup>2</sup> ; 8-pole	<a href="http://www.wago.com/769-108/022-000">www.wago.com/769-108/022-000</a>
	<b>Item no.: 769-109</b> 1-conductor female plug; 4 mm <sup>2</sup> ; 9-pole	<a href="http://www.wago.com/769-109">www.wago.com/769-109</a>
	<b>Item no.: 769-109/000-006</b> 1-conductor female plug; 4 mm <sup>2</sup> ; 9-pole	<a href="http://www.wago.com/769-109/000-006">www.wago.com/769-109/000-006</a>
	<b>Item no.: 769-109/000-036</b> 1-conductor female plug; 4 mm <sup>2</sup> ; 9-pole	<a href="http://www.wago.com/769-109/000-036">www.wago.com/769-109/000-036</a>
	<b>Item no.: 769-109/000-037</b> 1-conductor female plug; 4 mm <sup>2</sup> ; 9-pole	<a href="http://www.wago.com/769-109/000-037">www.wago.com/769-109/000-037</a>
	<b>Item no.: 769-109/000-038</b> 1-conductor female plug; 4 mm <sup>2</sup> ; 9-pole	<a href="http://www.wago.com/769-109/000-038">www.wago.com/769-109/000-038</a>
	<b>Item no.: 769-109/000-039</b> 1-conductor female plug; 4 mm <sup>2</sup> ; 9-pole	<a href="http://www.wago.com/769-109/000-039">www.wago.com/769-109/000-039</a>
	<b>Item no.: 769-109/022-000</b> 1-conductor female plug; angled; 4 mm <sup>2</sup> ; 9-pole	<a href="http://www.wago.com/769-109/022-000">www.wago.com/769-109/022-000</a>
	<b>Item no.: 769-110</b> 1-conductor female plug; 4 mm <sup>2</sup> ; 10-pole	<a href="http://www.wago.com/769-110">www.wago.com/769-110</a>
	<b>Item no.: 769-110/000-006</b> 1-conductor female plug; 4 mm <sup>2</sup> ; 10-pole	<a href="http://www.wago.com/769-110/000-006">www.wago.com/769-110/000-006</a>
	<b>Item no.: 769-110/000-036</b> 1-conductor female plug; 4 mm <sup>2</sup> ; 10-pole	<a href="http://www.wago.com/769-110/000-036">www.wago.com/769-110/000-036</a>
	<b>Item no.: 769-110/000-037</b> 1-conductor female plug; 4 mm <sup>2</sup> ; 10-pole	<a href="http://www.wago.com/769-110/000-037">www.wago.com/769-110/000-037</a>
	<b>Item no.: 769-110/000-038</b> 1-conductor female plug; 4 mm <sup>2</sup> ; 10-pole	<a href="http://www.wago.com/769-110/000-038">www.wago.com/769-110/000-038</a>

	<b>Item no.: 769-110/000-039</b> 1-conductor female plug; 4 mm <sup>2</sup> ; 10-pole	<a href="http://www.wago.com/769-110/000-039">www.wago.com/769-110/000-039</a>
	<b>Item no.: 769-110/022-000</b> 1-conductor female plug; angled; 4 mm <sup>2</sup> ; 10-pole	<a href="http://www.wago.com/769-110/022-000">www.wago.com/769-110/022-000</a>
	<b>Item no.: 769-111</b> 1-conductor female plug; 4 mm <sup>2</sup> ; 11-pole	<a href="http://www.wago.com/769-111">www.wago.com/769-111</a>
	<b>Item no.: 769-111/000-006</b> 1-conductor female plug; 4 mm <sup>2</sup> ; 11-pole	<a href="http://www.wago.com/769-111/000-006">www.wago.com/769-111/000-006</a>
	<b>Item no.: 769-111/000-036</b> 1-conductor female plug; 4 mm <sup>2</sup> ; 11-pole	<a href="http://www.wago.com/769-111/000-036">www.wago.com/769-111/000-036</a>
	<b>Item no.: 769-111/000-037</b> 1-conductor female plug; 4 mm <sup>2</sup> ; 11-pole	<a href="http://www.wago.com/769-111/000-037">www.wago.com/769-111/000-037</a>
	<b>Item no.: 769-111/000-038</b> 1-conductor female plug; 4 mm <sup>2</sup> ; 11-pole	<a href="http://www.wago.com/769-111/000-038">www.wago.com/769-111/000-038</a>
	<b>Item no.: 769-111/000-039</b> 1-conductor female plug; 4 mm <sup>2</sup> ; 11-pole	<a href="http://www.wago.com/769-111/000-039">www.wago.com/769-111/000-039</a>
	<b>Item no.: 769-111/022-000</b> 1-conductor female plug; angled; 4 mm <sup>2</sup> ; 11-pole	<a href="http://www.wago.com/769-111/022-000">www.wago.com/769-111/022-000</a>
	<b>Item no.: 769-112</b> 1-conductor female plug; 4 mm <sup>2</sup> ; 12-pole	<a href="http://www.wago.com/769-112">www.wago.com/769-112</a>
	<b>Item no.: 769-112/000-006</b> 1-conductor female plug; 4 mm <sup>2</sup> ; 12-pole	<a href="http://www.wago.com/769-112/000-006">www.wago.com/769-112/000-006</a>
	<b>Item no.: 769-112/000-036</b> 1-conductor female plug; 4 mm <sup>2</sup> ; 12-pole	<a href="http://www.wago.com/769-112/000-036">www.wago.com/769-112/000-036</a>
	<b>Item no.: 769-112/000-037</b> 1-conductor female plug; 4 mm <sup>2</sup> ; 12-pole	<a href="http://www.wago.com/769-112/000-037">www.wago.com/769-112/000-037</a>
	<b>Item no.: 769-112/000-038</b> 1-conductor female plug; 4 mm <sup>2</sup> ; 12-pole	<a href="http://www.wago.com/769-112/000-038">www.wago.com/769-112/000-038</a>
	<b>Item no.: 769-112/000-039</b> 1-conductor female plug; 4 mm <sup>2</sup> ; 12-pole	<a href="http://www.wago.com/769-112/000-039">www.wago.com/769-112/000-039</a>

**Item no.: 769-112/022-000**1-conductor female plug; angled; 4 mm<sup>2</sup>; 12-pole[www.wago.com/769-112/022-000](http://www.wago.com/769-112/022-000)**Item no.: 769-113**1-conductor female plug; 4 mm<sup>2</sup>; 13-pole[www.wago.com/769-113](http://www.wago.com/769-113)**Item no.: 769-113/000-036**1-conductor female plug; 4 mm<sup>2</sup>; 13-pole[www.wago.com/769-113/000-036](http://www.wago.com/769-113/000-036)**Item no.: 769-113/000-037**1-conductor female plug; 4 mm<sup>2</sup>; 13-pole[www.wago.com/769-113/000-037](http://www.wago.com/769-113/000-037)**Item no.: 769-113/000-038**1-conductor female plug; 4 mm<sup>2</sup>; 13-pole[www.wago.com/769-113/000-038](http://www.wago.com/769-113/000-038)**Item no.: 769-113/000-039**1-conductor female plug; 4 mm<sup>2</sup>; 13-pole[www.wago.com/769-113/000-039](http://www.wago.com/769-113/000-039)**Item no.: 769-113/022-000**1-conductor female plug; angled; 4 mm<sup>2</sup>; 13-pole[www.wago.com/769-113/022-000](http://www.wago.com/769-113/022-000)**Item no.: 769-114**1-conductor female plug; 4 mm<sup>2</sup>; 14-pole[www.wago.com/769-114](http://www.wago.com/769-114)**Item no.: 769-114/000-006**1-conductor female plug; 4 mm<sup>2</sup>; 14-pole[www.wago.com/769-114/000-006](http://www.wago.com/769-114/000-006)**Item no.: 769-114/000-036**1-conductor female plug; 4 mm<sup>2</sup>; 14-pole[www.wago.com/769-114/000-036](http://www.wago.com/769-114/000-036)**Item no.: 769-114/000-037**1-conductor female plug; 4 mm<sup>2</sup>; 14-pole[www.wago.com/769-114/000-037](http://www.wago.com/769-114/000-037)**Item no.: 769-114/000-038**1-conductor female plug; 4 mm<sup>2</sup>; 14-pole[www.wago.com/769-114/000-038](http://www.wago.com/769-114/000-038)**Item no.: 769-114/000-039**1-conductor female plug; 4 mm<sup>2</sup>; 14-pole[www.wago.com/769-114/000-039](http://www.wago.com/769-114/000-039)**Item no.: 769-114/022-000**1-conductor female plug; angled; 4 mm<sup>2</sup>; 14-pole[www.wago.com/769-114/022-000](http://www.wago.com/769-114/022-000)**Item no.: 769-115**1-conductor female plug; 4 mm<sup>2</sup>; 15-pole[www.wago.com/769-115](http://www.wago.com/769-115)

**Item no.: 769-115/000-036**1-conductor female plug; 4 mm<sup>2</sup>; 15-pole[www.wago.com/769-115/000-036](http://www.wago.com/769-115/000-036)**Item no.: 769-115/000-037**1-conductor female plug; 4 mm<sup>2</sup>; 15-pole[www.wago.com/769-115/000-037](http://www.wago.com/769-115/000-037)**Item no.: 769-115/000-038**1-conductor female plug; 4 mm<sup>2</sup>; 15-pole[www.wago.com/769-115/000-038](http://www.wago.com/769-115/000-038)**Item no.: 769-115/000-039**1-conductor female plug; 4 mm<sup>2</sup>; 15-pole[www.wago.com/769-115/000-039](http://www.wago.com/769-115/000-039)**Item no.: 769-115/022-000**1-conductor female plug; angled; 4 mm<sup>2</sup>; 15-pole[www.wago.com/769-115/022-000](http://www.wago.com/769-115/022-000)**End plate****Item no.: 769-309**

End and intermediate plate; 1.1 mm thick

[www.wago.com/769-309](http://www.wago.com/769-309)**Item no.: 769-310**

End and intermediate plate; 1.1 mm thick

[www.wago.com/769-310](http://www.wago.com/769-310)**Item no.: 769-313**

Separator plate; 1.1 mm thick; oversized

[www.wago.com/769-313](http://www.wago.com/769-313)**Jumper****Item no.: 249-123**Push-in type wire jumper; insulated; wire length 180 mm; Conductor cross section 0.75 mm<sup>2</sup>[www.wago.com/249-123](http://www.wago.com/249-123)**Item no.: 249-125**Push-in type wire jumper; insulated; wire length 60 mm; Conductor cross section 0.75 mm<sup>2</sup>[www.wago.com/249-125](http://www.wago.com/249-125)**Item no.: 249-126**Push-in type wire jumper; insulated; wire length 110 mm; Conductor cross section 0.75 mm<sup>2</sup>[www.wago.com/249-126](http://www.wago.com/249-126)**Item no.: 249-127**Push-in type wire jumper; insulated; wire length 250 mm; Conductor cross section 0.75 mm<sup>2</sup>[www.wago.com/249-127](http://www.wago.com/249-127)**Item no.: 280-402**

Adjacent jumper; insulated; IN = IN terminal block

[www.wago.com/280-402](http://www.wago.com/280-402)**Item no.: 280-409**

Alternate jumper; insulated; IN = IN terminal block

[www.wago.com/280-409](http://www.wago.com/280-409)**Item no.: 780-452**

Staggered jumper; insulated; from 1 to 2; Spacing: 5 mm; suitable for 2-conductor female plugs

[www.wago.com/780-452](http://www.wago.com/780-452)**Item no.: 780-453**

Staggered jumper; insulated; from 1 to 3; Spacing: 5 mm; suitable for 2-conductor female plugs

[www.wago.com/780-453](http://www.wago.com/780-453)**Item no.: 780-454**



Staggered jumper; insulated; from 1 to 4; Spacing: 5 mm; suitable for 2-conductor female plugs

[www.wago.com/780-454](http://www.wago.com/780-454)**Item no.: 780-455**

Staggered jumper; insulated; from 1 to 5; Spacing: 5 mm; suitable for 2-conductor female plugs

[www.wago.com/780-455](http://www.wago.com/780-455)**Item no.: 780-456**

Staggered jumper; insulated; from 1 to 6; Spacing: 5 mm; suitable for 2-conductor female plugs

[www.wago.com/780-456](http://www.wago.com/780-456)**Item no.: 780-457**

Staggered jumper; insulated; from 1 to 7; Spacing: 5 mm; suitable for 2-conductor female plugs

[www.wago.com/780-457](http://www.wago.com/780-457)**Item no.: 780-458**

Staggered jumper; insulated; from 1 to 8; Spacing: 5 mm; suitable for 2-conductor female plugs

[www.wago.com/780-458](http://www.wago.com/780-458)

## General accessories

**Item no.: 280-404**

Test plug adapter; 5 mm wide; for test plug 210-137 (2.3 mm Ø); suitable for 1.5 mm² - 4 mm² tbs

[www.wago.com/280-404](http://www.wago.com/280-404)**Item no.: 280-418**

Test plug module; modular; suitable for all WAGO 280 and 780 Series rail-mounted terminal blocks with jumper slots in the current bar

[www.wago.com/280-418](http://www.wago.com/280-418)**Item no.: 280-419**

Spacer module; modular; bridging commoned terminal blocks

[www.wago.com/280-419](http://www.wago.com/280-419)**Item no.: 280-801**

Empty component plug housing; 5 mm wide; 2-pole; Type 1

[www.wago.com/280-801](http://www.wago.com/280-801)**Item no.: 280-801/281-411**

Diode module; with diode 1N4007; 5 mm wide

[www.wago.com/280-801/281-411](http://www.wago.com/280-801/281-411)**Item no.: 280-801/281-413**

LED module; with red LED; 5 mm wide; 24 VDC

[www.wago.com/280-801/281-413](http://www.wago.com/280-801/281-413)**Item no.: 280-801/281-414**

LED module; with red LED; 5 mm wide; 48 VDC

[www.wago.com/280-801/281-414](http://www.wago.com/280-801/281-414)**Item no.: 280-801/281-415**

LED module; with red LED; 5 mm wide; 24 V AC/DC

[www.wago.com/280-801/281-415](http://www.wago.com/280-801/281-415)**Item no.: 280-801/281-416**

LED module; with red LED; 5 mm wide; AC/DC 48 V

[www.wago.com/280-801/281-416](http://www.wago.com/280-801/281-416)**Item no.: 280-801/281-417**

Neon indicator module; 5 mm wide; 230 VAC/VDC

[www.wago.com/280-801/281-417](http://www.wago.com/280-801/281-417)**Item no.: 280-801/281-418**

Neon indicator module; 5 mm wide; AC/DC 120 V

[www.wago.com/280-801/281-418](http://www.wago.com/280-801/281-418)

**Item no.: 280-801/281-420**

Diode module; with 1N4007 recovery diode; red LED; 5 mm wide; 24 VDC

[www.wago.com/280-801/281-420](http://www.wago.com/280-801/281-420)**Item no.: 280-801/281-421**

Diode module; with 1N4007 recovery diode; red LED; 5 mm wide; 48 VDC

[www.wago.com/280-801/281-421](http://www.wago.com/280-801/281-421)**Item no.: 280-802**

Empty component plug housing; 10 mm wide; 2-pole; Type 2

[www.wago.com/280-802](http://www.wago.com/280-802)**Item no.: 280-804**

Empty component plug housing; 10 mm wide; Type 3; 4-pole

[www.wago.com/280-804](http://www.wago.com/280-804)**Item no.: 281-511**

Fuse plug with pull-tab; for miniature metric fuses 5 x 20 mm and 5 x 25 mm; 6 mm wide

[www.wago.com/281-511](http://www.wago.com/281-511)**Item no.: 281-512**

Fuse plug with pull-tab; for miniature metric fuses 5 x 20 mm and 5 x 25 mm; with hole for one led (for self-assembly); 6 mm wide

[www.wago.com/281-512](http://www.wago.com/281-512)**Item no.: 281-512/281-417**

Fuse plug with pull-tab; for miniature metric fuses 5 x 20 mm and 5 x 25 mm; with neon lamp, 230 V AC/DC; 6 mm wide

[www.wago.com/281-512/281-417](http://www.wago.com/281-512/281-417)**Item no.: 281-512/281-418**

Fuse plug with pull-tab; for miniature metric fuses 5 x 20 mm and 5 x 25 mm; with neon lamp, 120 V AC/DC; 6 mm wide

[www.wago.com/281-512/281-418](http://www.wago.com/281-512/281-418)**Item no.: 281-512/281-501**

Fuse plug with pull-tab; for miniature metric fuses 5 x 20 mm and 5 x 25 mm; with LED indicator; 24 V AC/DC; 6 mm wide

[www.wago.com/281-512/281-501](http://www.wago.com/281-512/281-501)**Item no.: 286-110**

Empty component plug housing; Type 9; 10 mm wide; 4-pole

[www.wago.com/286-110](http://www.wago.com/286-110)**Item no.: 286-111**

Empty component plug housing; Type 10; 15 mm wide; 6-pole

[www.wago.com/286-111](http://www.wago.com/286-111)**Item no.: 286-112**

Empty component plug housing; Type 11; 20 mm wide; 8-pole

[www.wago.com/286-112](http://www.wago.com/286-112)**Item no.: 286-113**

Empty component plug housing; Type 12; 25 mm wide; 10-pole

[www.wago.com/286-113](http://www.wago.com/286-113)**Item no.: 286-304**

Relay module; Nominal input voltage: 24 VDC; 1 changeover contact; Limiting continuous current: 7 A; Red status indicator; Module width: 15 mm

[www.wago.com/286-304](http://www.wago.com/286-304)**Item no.: 286-304/004-000**

Relay module; Relay with 1 changeover contact (1u); with extended input voltage and temperature range; with miniature switching relay

[www.wago.com/286-304/004-000](http://www.wago.com/286-304/004-000)**Item no.: 286-307/004-000**

Relay module; Nominal input voltage: 110 VDC; 1 changeover contact; Limiting continuous current: 7 A; Path; Red status indicator; Module width: 15 mm

[www.wago.com/286-307/004-000](http://www.wago.com/286-307/004-000)**Item no.: 286-312**

Relay module; Relay with 2 changeover contacts (2u)

[www.wago.com/286-312](http://www.wago.com/286-312)

**Item no.: 286-312/004-000**

Relay module; Nominal input voltage: 24 VDC; 2 changeover contacts; Limiting continuous current: 7 A; Path; Red status indicator; Module width: 20 mm

[www.wago.com/286-312/004-000](http://www.wago.com/286-312/004-000)

**Item no.: 286-316**

Relay module; Nominal input voltage: 220 VDC; 2 changeover contacts; Limiting continuous current: 7 A; Red status indicator; Module width: 20 mm

[www.wago.com/286-316](http://www.wago.com/286-316)

**Item no.: 286-320**

Relay module; Nominal input voltage: 24 VDC; 1 break and 1 make contact; Limiting continuous current: 6 A; Red status indicator; Module width: 20 mm

[www.wago.com/286-320](http://www.wago.com/286-320)

**Item no.: 286-320/004-000**

Relay module; Nominal input voltage: 24 VDC; 1 break and 1 make contact; Path; Red status indicator; Module width: 20 mm

[www.wago.com/286-320/004-000](http://www.wago.com/286-320/004-000)

**Item no.: 286-328**

Relay module; Nominal input voltage: 24 VDC; 2 make contact; Limiting continuous current: 6 A; Red status indicator; Module width: 20 mm

[www.wago.com/286-328](http://www.wago.com/286-328)

**Item no.: 286-328/004-000**

Relay module; Nominal input voltage: 24 VDC; 2 make contact; Limiting continuous current: 6 A; Path; Red status indicator; Module width: 20 mm

[www.wago.com/286-328/004-000](http://www.wago.com/286-328/004-000)

**Item no.: 286-336/001-000**

Relay module; Nominal input voltage: 24 VDC; 2 break and 2 make contacts; Red status indicator; Module width: 25 mm

[www.wago.com/286-336/001-000](http://www.wago.com/286-336/001-000)

**Item no.: 286-344/004-000**

Relay module; Nominal input voltage: 24 VDC; 3 break contacts and 1 make contact; Path; Red status indicator; Module width: 25 mm

[www.wago.com/286-344/004-000](http://www.wago.com/286-344/004-000)

**Item no.: 286-352/004-000**

Relay module; Nominal input voltage: 24 VDC; 4 make contacts; Limiting continuous current: 5 A; Path; Red status indicator; Module width: 25 mm

[www.wago.com/286-352/004-000](http://www.wago.com/286-352/004-000)

**Item no.: 286-364**

Relay module; Nominal input voltage: 24 VDC; 1 make contact; Limiting continuous current: 5 A; Red status indicator; Module width: 10 mm

[www.wago.com/286-364](http://www.wago.com/286-364)

**Item no.: 286-364/004-000**

Relay module; Relay with 1 make contact (1a); with miniature switching relay; with extended input voltage and temperature range

[www.wago.com/286-364/004-000](http://www.wago.com/286-364/004-000)

**Item no.: 286-368**

Relay module; Nominal input voltage: 24 VDC; 1 break contact; Limiting continuous current: 5 A; Red status indicator; Module width: 10 mm

[www.wago.com/286-368](http://www.wago.com/286-368)

**Item no.: 286-368/004-000**

Relay module; Nominal input voltage: 24 VDC; 1 break contact; Limiting continuous current: 5 A; Path; Red status indicator; 10 mm wide

[www.wago.com/286-368/004-000](http://www.wago.com/286-368/004-000)

**Item no.: 286-376**

Relay module; Nominal input voltage: 24 VDC; 1 make contact; Limiting continuous current: 5 A; for switching higher DC loads; Red status indicator; Module width: 15 mm

[www.wago.com/286-376](http://www.wago.com/286-376)

**Item no.: 286-380**

Bistable relay module; Nominal input voltage: 24 VDC; 1 changeover contact; Limiting continuous current: 6 A; Red status indicator; Module width: 15 mm

[www.wago.com/286-380](http://www.wago.com/286-380)

**Item no.: 286-381**

Bistable relay module; Nominal input voltage: 24 VDC; 1 changeover contact; Limiting continuous current: 6 A; Red status indicator; Module width: 15 mm

[www.wago.com/286-381](http://www.wago.com/286-381)



**Item no.: 286-394/004-000**

Relay module; Relay with 1 changeover contact (1u); with extended input voltage and temperature range; with miniature switching relay

[www.wago.com/286-394/004-000](http://www.wago.com/286-394/004-000)

**Item no.: 286-427**

Relay module; Pulse lengthening with trigger voltage; with trigger voltage; Relay with 1 changeover contact (1u)

[www.wago.com/286-427](http://www.wago.com/286-427)

**Item no.: 286-507**

Relay module; Nominal input voltage: 115 VAC; 1 changeover contact; Limiting continuous current: 7 A; Red status indicator; Module width: 15 mm

[www.wago.com/286-507](http://www.wago.com/286-507)

**Item no.: 286-508**

Relay module; Nominal input voltage: 230 VAC; 1 changeover contact; Limiting continuous current: 7 A; Red status indicator; Module width: 15 mm

[www.wago.com/286-508](http://www.wago.com/286-508)

**Item no.: 286-516**

Relay module; Nominal input voltage: 230 VAC; 2 changeover contacts; Limiting continuous current: 7 A; Red status indicator; Module width: 15 mm

[www.wago.com/286-516](http://www.wago.com/286-516)

**Item no.: 286-573**

Latching relay module; Nominal input voltage: 24 VDC; 1 changeover contact; Limiting continuous current: 6 A; Red status indicator; Module width: 17 mm

[www.wago.com/286-573](http://www.wago.com/286-573)

**Item no.: 286-575**

Latching relay module; Nominal input voltage: 24 VDC; 1 changeover contact; Limiting continuous current: 3 A; Path; Red status indicator; Module width: 22 mm

[www.wago.com/286-575](http://www.wago.com/286-575)

**Item no.: 286-604/004-000**

Timer relay module; Nominal input voltage: 24 VDC; Limiting continuous current: 6 A; On-delay: 10 ... 100 s; Red status indicator; Module width: 20 mm

[www.wago.com/286-604/004-000](http://www.wago.com/286-604/004-000)

**Item no.: 286-640**

Timer relay module; Nominal input voltage: 24 VDC; Limiting continuous current: 6 A; Path; Multifunction/Multitime; Yellow status indicator; Module width: 6 mm

[www.wago.com/286-640](http://www.wago.com/286-640)

**Item no.: 286-640/004-000**

Multifunction timing relay module; Relay with 1 changeover contact (1u); 4 time ranges; for railway operations; 4 functions

[www.wago.com/286-640/004-000](http://www.wago.com/286-640/004-000)

**Item no.: 286-661**

Current flow monitoring module; AC current flow monitoring module; 80 mA ... 6 A

[www.wago.com/286-661](http://www.wago.com/286-661)

**Item no.: 286-662**

Current flow monitoring module; DC current flow monitoring module; 0.4 A ... 3.5 A; Relay with 1 make contact (1a)

[www.wago.com/286-662](http://www.wago.com/286-662)

**Item no.: 286-664**

Current flow monitoring module; AC current flow monitoring module; 1 A ... 10 A; adjustable; Relay with 1 changeover contact (1u)

[www.wago.com/286-664](http://www.wago.com/286-664)

**Item no.: 286-665**

Current flow monitoring module; Relay with 1 changeover contact (1u); adjustable

[www.wago.com/286-665](http://www.wago.com/286-665)

**Item no.: 286-721**



















Optocoupler module; Nominal input voltage: 24 VDC; Output voltage range: 15 ... 30 VDC; Limiting continuous current: 5 A; 3-wire connection/low-side switching; Red status indicator; Module width: 15 mm



















[www.wago.com/286-721](http://www.wago.com/286-721)

















**Item no.: 286-723**

Optocoupler module; Nominal input voltage: 24 VDC; Output voltage range: 15 ... 30 VDC; Limiting continuous current: 4 A; 3-wire connection/high-side switching; Red status indicator; Module width: 15 mm

[www.wago.com/286-723](http://www.wago.com/286-723)

	<b>Item no.: 286-725</b> Optocoupler module; Input AC/DC 10 V ... 30 V; Output DC 24 V/ 1 mA ... 0.5 A; negative switching	<a href="http://www.wago.com/286-725">www.wago.com/286-725</a>
	<b>Item no.: 286-742</b> S0 interface power supply; Input voltage: 230 VAC; S0 interface	<a href="http://www.wago.com/286-742">www.wago.com/286-742</a>
	<b>Item no.: 286-752</b> Optocoupler module; Nominal input voltage: 24 VDC; Output voltage range: 20 ... 30 VDC; Limiting continuous current: 0.5 A; 3-wire connection/high-side switching; Frequency: 25 kHz; Red status indicator; Module width: 15 mm	<a href="http://www.wago.com/286-752">www.wago.com/286-752</a>
	<b>Item no.: 286-752/002-000</b> Optocoupler module; Red status indicator	<a href="http://www.wago.com/286-752/002-000">www.wago.com/286-752/002-000</a>
	<b>Item no.: 286-790</b> Optocoupler module	<a href="http://www.wago.com/286-790">www.wago.com/286-790</a>
	<b>Item no.: 286-791</b> Optocoupler module; Nominal input voltage: 24 VDC; Output voltage range: 20 ... 60 VDC; Limiting continuous current: 0.1 A; 2-wire connection; Frequency: 3 kHz; Red status indicator; Module width: 10 mm	<a href="http://www.wago.com/286-791">www.wago.com/286-791</a>
	<b>Item no.: 286-792</b> Optocoupler module; Red status indicator	<a href="http://www.wago.com/286-792">www.wago.com/286-792</a>
	<b>Item no.: 286-794</b> Optocoupler module; Nominal input voltage: 24 VDC; Output voltage range: 20 ... 60 VDC; Limiting continuous current: 0.1 A; 2-wire connection; Red status indicator; Module width: 10 mm	<a href="http://www.wago.com/286-794">www.wago.com/286-794</a>
	<b>Item no.: 286-797</b> Optocoupler module; Red status indicator	<a href="http://www.wago.com/286-797">www.wago.com/286-797</a>
	<b>Item no.: 286-803</b> Component module with diode	<a href="http://www.wago.com/286-803">www.wago.com/286-803</a>
	<b>Item no.: 286-805</b> Component module with diode	<a href="http://www.wago.com/286-805">www.wago.com/286-805</a>
	<b>Item no.: 286-807</b> Component module with diode; with 7 pcs; Diode 1N4007; with common anode	<a href="http://www.wago.com/286-807">www.wago.com/286-807</a>
	<b>Item no.: 286-809</b> Component module with diode	<a href="http://www.wago.com/286-809">www.wago.com/286-809</a>
	<b>Item no.: 286-822</b> Component module with LED; Red LED; with common cathode	<a href="http://www.wago.com/286-822">www.wago.com/286-822</a>
	<b>Item no.: 286-826</b> AND gate module with 6 inputs	<a href="http://www.wago.com/286-826">www.wago.com/286-826</a>
	<b>Item no.: 286-830</b> Bridge rectifier module; Input voltage: 24 VAC; with varistor protective circuit	<a href="http://www.wago.com/286-830">www.wago.com/286-830</a>
	<b>Item no.: 286-831</b> Surge suppression module for signal technology; Nominal voltage: 24 VAC/DC; for 2 signal paths with common surge arrester; plugged on rail-mount terminal block, 15 mm wide	<a href="http://www.wago.com/286-831">www.wago.com/286-831</a>
	<b>Item no.: 286-832</b> Surge suppression module for signal technology; Nominal voltage: 24 VAC/DC; for 2 signal paths with common surge arrester; pluggable on rail-mount terminal block, 20 mm wide	<a href="http://www.wago.com/286-832">www.wago.com/286-832</a>

	<b>Item no.: 286-833</b> Surge suppression module for signal technology; Nominal voltage: 24 VDC; for 1 signal path; plugged on rail-mount terminal block, 15 mm wide	<a href="http://www.wago.com/286-833">www.wago.com/286-833</a>
	<b>Item no.: 286-834</b> Surge suppression module for signal technology; Nominal voltage: 12 VDC; for 2 signal paths with common surge arrester; pluggable on rail-mount terminal block, 20 mm wide	<a href="http://www.wago.com/286-834">www.wago.com/286-834</a>
	<b>Item no.: 286-834/024-000</b> Surge suppression module for signal technology; Nominal voltage: 24 VDC; for 2 signal paths with common surge arrester; pluggable on rail-mount terminal block, 15 mm wide	<a href="http://www.wago.com/286-834/024-000">www.wago.com/286-834/024-000</a>
	<b>Item no.: 286-840</b> Bridge rectifier module; Input voltage: 250 VAC; with varistor protective circuit	<a href="http://www.wago.com/286-840">www.wago.com/286-840</a>
	<b>Item no.: 286-841</b> Surge suppression module for signal technology; Nominal voltage: 220 VDC; for 2 signal paths with common surge arrester; pluggable on rail-mount terminal block, 25 mm wide	<a href="http://www.wago.com/286-841">www.wago.com/286-841</a>
	<b>Item no.: 286-842</b> Surge suppression module for signal technology; Nominal voltage: 230 VAC; for 2 signal paths with common surge arrester; pluggable on rail-mount terminal block, 25 mm wide	<a href="http://www.wago.com/286-842">www.wago.com/286-842</a>
	<b>Item no.: 286-843</b> Surge suppression module for signal technology; Nominal voltage: 115 VAC; for 2 signal paths with common surge arrester; pluggable on rail-mount terminal block, 25 mm wide	<a href="http://www.wago.com/286-843">www.wago.com/286-843</a>
	<b>Item no.: 286-844</b> Surge suppression module for signal technology; for 2 signal paths with common surge arrester; pluggable on rail-mount terminal block, 25 mm wide	<a href="http://www.wago.com/286-844">www.wago.com/286-844</a>
	<b>Item no.: 286-890</b> Component module with fuse; for (5 x 20) mm microfuse; Nominal voltage: 24 VAC/DC	<a href="http://www.wago.com/286-890">www.wago.com/286-890</a>
	<b>Item no.: 286-891</b> Component module with fuse; for (5 x 20) mm microfuse; Nominal voltage: 230 VAC/DC	<a href="http://www.wago.com/286-891">www.wago.com/286-891</a>
	<b>Item no.: 286-895</b> Switching module; with changeover rocker switch; Switching voltage: 250 VAC; Switching current: 6 A	<a href="http://www.wago.com/286-895">www.wago.com/286-895</a>
	<b>Item no.: 286-896</b> Switching module; Changeover; 1-pole; with momentary switch	<a href="http://www.wago.com/286-896">www.wago.com/286-896</a>
	<b>Item no.: 769-438</b> Pin cover; with marker slot for miniature WSB	<a href="http://www.wago.com/769-438">www.wago.com/769-438</a>
	<b>Item no.: 769-439</b> Pin cover; with marker slot for miniature WSB	<a href="http://www.wago.com/769-439">www.wago.com/769-439</a>
	<b>Item no.: 769-501</b> Start module for 1-conductor female connector; with integrated end plate; 4 mm <sup>2</sup> ; 1-pole	<a href="http://www.wago.com/769-501">www.wago.com/769-501</a>
	<b>Item no.: 769-501/000-006</b> Start module for 1-conductor female connector; 4 mm <sup>2</sup> ; 1-pole	<a href="http://www.wago.com/769-501/000-006">www.wago.com/769-501/000-006</a>
	<b>Item no.: 769-501/000-016</b> Start module for 1-conductor female connector; with integrated end plate; 4 mm <sup>2</sup> ; 1-pole	<a href="http://www.wago.com/769-501/000-016">www.wago.com/769-501/000-016</a>
	<b>Item no.: 769-502</b> Center module for 1-conductor female connector; 4 mm <sup>2</sup> ; 1-pole	<a href="http://www.wago.com/769-502">www.wago.com/769-502</a>

	<b>Item no.: 769-502/000-006</b> Center module for 1-conductor female connector; 4 mm <sup>2</sup> ; 1-pole	<a href="http://www.wago.com/769-502/000-006">www.wago.com/769-502/000-006</a>
	<b>Item no.: 769-502/000-016</b> 1-conductor center module; codable; can be commoned with miniature adjacent jumpers; 1-pole	<a href="http://www.wago.com/769-502/000-016">www.wago.com/769-502/000-016</a>
	<b>Item no.: 769-503</b> End module for 1-conductor female connector; 4 mm <sup>2</sup> ; 1-pole	<a href="http://www.wago.com/769-503">www.wago.com/769-503</a>
	<b>Item no.: 769-503/000-006</b> End module for 1-conductor female connector; 4 mm <sup>2</sup> ; 1-pole	<a href="http://www.wago.com/769-503/000-006">www.wago.com/769-503/000-006</a>
	<b>Item no.: 769-503/000-016</b> End module for 1-conductor female connector; 4 mm <sup>2</sup> ; 1-pole	<a href="http://www.wago.com/769-503/000-016">www.wago.com/769-503/000-016</a>
	<b>Item no.: 769-512</b> Start module for 1-conductor female connector; angled; 4 mm <sup>2</sup> ; 1-pole	<a href="http://www.wago.com/769-512">www.wago.com/769-512</a>
	<b>Item no.: 769-512/000-006</b> Start module for 1-conductor female connector; angled; 4 mm <sup>2</sup> ; 1-pole	<a href="http://www.wago.com/769-512/000-006">www.wago.com/769-512/000-006</a>
	<b>Item no.: 769-512/000-016</b> Start module for 1-conductor female connector; angled; 4 mm <sup>2</sup> ; 1-pole	<a href="http://www.wago.com/769-512/000-016">www.wago.com/769-512/000-016</a>
	<b>Item no.: 769-513</b> Center module for 1-conductor female connector; angled; 4 mm <sup>2</sup> ; 1-pole	<a href="http://www.wago.com/769-513">www.wago.com/769-513</a>
	<b>Item no.: 769-513/000-006</b> 1-conductor center module; angled; codable; 1-pole	<a href="http://www.wago.com/769-513/000-006">www.wago.com/769-513/000-006</a>
	<b>Item no.: 769-513/000-016</b> 1-conductor center module; angled; codable; 1-pole	<a href="http://www.wago.com/769-513/000-016">www.wago.com/769-513/000-016</a>
	<b>Item no.: 769-515</b> 1-conductor end module; angled; codable; 1-pole	<a href="http://www.wago.com/769-515">www.wago.com/769-515</a>
	<b>Item no.: 769-515/000-006</b> 1-conductor end module; angled; codable; 1-pole	<a href="http://www.wago.com/769-515/000-006">www.wago.com/769-515/000-006</a>
	<b>Item no.: 769-515/000-016</b> 1-conductor end module; angled; codable; 1-pole	<a href="http://www.wago.com/769-515/000-016">www.wago.com/769-515/000-016</a>
	<b>Item no.: 786-101</b> Empty component plug housing; Type 14; 15 mm wide; 6-pole	<a href="http://www.wago.com/786-101">www.wago.com/786-101</a>
	<b>Item no.: 786-102</b> Empty component plug housing; Type 15; 20 mm wide; 8-pole	<a href="http://www.wago.com/786-102">www.wago.com/786-102</a>



Item no.: 786-103

Empty component plug housing; Type 16; 25 mm wide; 10-pole

[www.wago.com/786-103](http://www.wago.com/786-103)

## Coding



Item no.: 769-435

Coding pin; for coding of female plugs; for carrier terminal blocks / male connectors

[www.wago.com/769-435](http://www.wago.com/769-435)

## assembling



Item no.: 209-106

Mounting carrier; for isolated mounting on DIN 35 rails

[www.wago.com/209-106](http://www.wago.com/209-106)

## tools



Item no.: 210-720

Operating tool with partially insulated shaft; Type 2, blade (3.5 x 0.5) mm

[www.wago.com/210-720](http://www.wago.com/210-720)

## Downloads

### Documentation

#### Bid Text

769-161	Oct 18, 2017	DOC 25.1 kB	Download
---------	--------------	----------------	----------

## smartDATA

### CAD data

3D Download 769-161	URL	Download
---------------------	-----	----------

## Product family

### X-COM

[Learn more about the product family.](#)

[Show all products from the family](#)

Subject to changes.

WAGO Kontakttechnik GmbH & Co. KG

Hansastr. 27

32423 Minden

Phone: +49571 887-0 | Fax: +49571 887-169

Email: [info.de@wago.com](mailto:info.de@wago.com) | Web: [www.wago.com](http://www.wago.com)

Do you have any questions about our products?

We are always happy to take your call at +49 (571) 887-44222.