



Data sheet | Item number: 769-162/769-313

2-pin terminal block for pluggable modules; 4-pole; with 2 jumper positions;
with orange separator plate; for DIN-rail 35 x 15 and 35 x 7.5

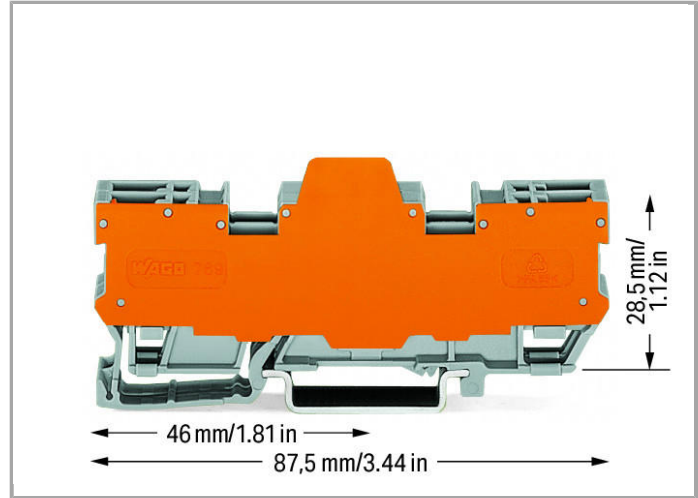

www.wago.com/769-162/769-313

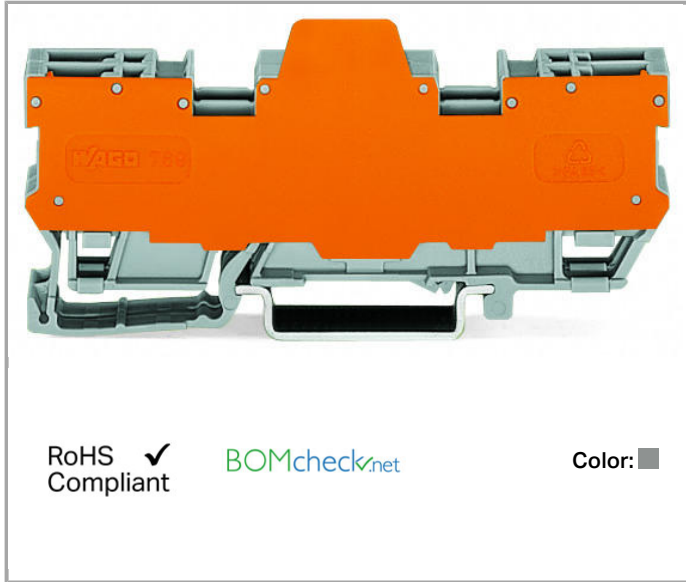

Data

Electrical data

Ratings per IEC/EN 60664-1

Rated voltage (III / 3)	400 V
Rated impulse voltage (III / 3)	6 kV
Rated current	16 A
Legend (ratings)	(III / 3) $\hat{=}$ Overvoltage category III / Pollution degree 3

Connection data

Actuation type	Operating tool
Connectable conductor materials	Copper Aluminum
No. of poles	4
Total number of potentials	4
Number of levels	1
Type of wiring	Front-entry wiring

Geometrical Data

Width	11.1 mm / 0.437 inch
Height from upper-edge of DIN-35 rail	28.5 mm / 1.122 inch
Depth	87.5 mm / 3.445 inch

Mechanical data

Design	horizontal
Type of mounting	DIN-35 rail
Marking level	Center marking

Material Data




Color	gray
Insulating material	Polyamide 66 (PA 66)
Fire load	0.402 MJ
Weight	17.69 g

Commercial data

Country of origin	DE
GTIN	4044918630146
Customs Tariff No.	85369010000
Product Group	18 (X-COM-System)

Approvals / Certificates

Country specific Approvals

Logo	Approval	Certificate name
	CCA DEKRA Certification B.V.	NTR NL-7626
	CSA DEKRA Certification B.V.	1101144
	KEMA/KEUR DEKRA Certification B.V.	2190419.01

Ship Approvals

Logo	Approval	Certificate name
	ABS American Bureau of Shipping	14-HG1293677-PDA

UL-Approvals

Logo	Approval	Certificate name
------	----------	------------------



UR
Underwriters Laboratories Inc.

E45171



UR
Underwriters Laboratories Inc.

E45172

Compatible products

tools



Item no.: 210-720

Operating tool with partially insulated shaft; Type 2, blade (3.5 x 0.5) mm

www.wago.com/210-720

Carrier rail



Item no.: 210-112

Steel carrier rail; 35 x 7.5 mm; 1 mm thick; 2 m long; slotted; according to EN 60715; "Hole width 25 mm

www.wago.com/210-112



Item no.: 210-113

Steel carrier rail; 35 x 7.5 mm; 1 mm thick; 2 m long; unslotted; according to EN 60715

www.wago.com/210-113



Item no.: 210-114

Steel carrier rail; 35 x 15 mm; 1.5 mm thick; 2 m long; unslotted; similar to EN 60715

www.wago.com/210-114



Item no.: 210-115

Steel carrier rail; 35 x 7.5 mm; 1 mm thick; 2 m long; slotted; according to EN 60715; "Hole width 18 mm

www.wago.com/210-115



Item no.: 210-118

Steel carrier rail; 35 x 15 mm; 2.3 mm thick; 2 m long; unslotted; according to EN 60715

www.wago.com/210-118



Item no.: 210-196

Aluminum carrier rail; 35 x 8.2 mm; 1.6 mm thick; 2 m long; unslotted; similar to EN 60715

www.wago.com/210-196



Item no.: 210-197

Steel carrier rail; 35 x 15 mm; 1.5 mm thick; 2 m long; slotted; similar to EN 60715

www.wago.com/210-197



Item no.: 210-198

Copper carrier rail; 35 x 15 mm; 2.3 mm thick; 2 m long; unslotted; according to EN 60715

www.wago.com/210-198



Item no.: 210-504

Steel carrier rail; 35 x 7.5 mm; 1 mm thick; 2 m long; slotted; galvanized; according to EN 60715

www.wago.com/210-504



Item no.: 210-505

Steel carrier rail; 35 x 7.5 mm; 1 mm thick; 2 m long; unslotted; galvanized; according to EN 60715

www.wago.com/210-505



Item no.: 210-506

Steel carrier rail; 35 x 15 mm; 1.5 mm thick; 2 m long; unslotted; galvanized; similar to EN 60715

www.wago.com/210-506



Item no.: 210-508

Steel carrier rail; 35 x 15 mm; 1.5 mm thick; 2 m long; slotted; galvanized; similar to EN 60715

www.wago.com/210-508















check



Item no.: 210-137
Test plug; 2.3 mm Ø; with 500 mm cable

www.wago.com/210-137

Marking accessories

	Item no.: 2009-145 Mini-WSB Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type	www.wago.com/2009-145
	Item no.: 2009-145/000-002 Mini-WSB Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type	www.wago.com/2009-145/000-002
	Item no.: 2009-145/000-005 Mini-WSB Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type	www.wago.com/2009-145/000-005
	Item no.: 2009-145/000-006 Mini-WSB Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type	www.wago.com/2009-145/000-006
	Item no.: 2009-145/000-007 Mini-WSB Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type	www.wago.com/2009-145/000-007
	Item no.: 2009-145/000-012 Mini-WSB Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type	www.wago.com/2009-145/000-012
	Item no.: 2009-145/000-023 Mini-WSB Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type	www.wago.com/2009-145/000-023
	Item no.: 2009-145/000-024 Mini-WSB Inline; on reel; stretchable 5 - 5.2 mm; plain; snap-on type	www.wago.com/2009-145/000-024
	Item no.: 248-501 Miniature WSB Quick marking system; plain; Marker width 5 mm; 10 strips with 10 markers per card	www.wago.com/248-501
	Item no.: 248-501/000-002 Mini-WSB marking card; as card; not stretchable; plain; snap-on type	www.wago.com/248-501/000-002
	Item no.: 248-501/000-005 Mini-WSB marking card; as card; plain; snap-on type	www.wago.com/248-501/000-005
	Item no.: 248-501/000-006 Mini-WSB marking card; as card; not stretchable; plain; snap-on type	www.wago.com/248-501/000-006
	Item no.: 248-501/000-007 Mini-WSB marking card; as card; not stretchable; plain; snap-on type	www.wago.com/248-501/000-007
	Item no.: 248-501/000-012 Mini-WSB marking card; as card; not stretchable; plain; snap-on type	www.wago.com/248-501/000-012



Item no.: 248-501/000-017
Mini-WSB marking card; as card; not stretchable; plain; snap-on type

www.wago.com/248-501/000-017



Item no.: 248-501/000-023
Mini-WSB marking card; as card; not stretchable; plain; snap-on type

www.wago.com/248-501/000-023



Item no.: 248-501/000-024
Mini-WSB marking card; as card; not stretchable; plain; snap-on type

www.wago.com/248-501/000-024

Female plug



Item no.: 769-101
1-conductor female plug; 4 mm²; 1-pole

www.wago.com/769-101



Item no.: 769-101/000-006
1-conductor female plug; 4 mm²; 1-pole

www.wago.com/769-101/000-006



Item no.: 769-101/000-016
1-conductor female plug; 4 mm²; 1-pole

www.wago.com/769-101/000-016



Item no.: 769-101/022-000
1-conductor female plug; angled; 4 mm²; 1-pole

www.wago.com/769-101/022-000



Item no.: 769-101/022-016
1-conductor female plug; angled; 4 mm²; 1-pole

www.wago.com/769-101/022-016



Item no.: 769-102
1-conductor female plug; 4 mm²; 2-pole

www.wago.com/769-102

Item no.: 769-102/000-006
1-conductor female plug; 4 mm²; 2-pole

www.wago.com/769-102/000-006

Item no.: 769-102/000-036
1-conductor female plug; 4 mm²; 2-pole

www.wago.com/769-102/000-036

Item no.: 769-102/000-037
1-conductor female plug; 4 mm²; 2-pole

www.wago.com/769-102/000-037



Item no.: 769-102/022-000
1-conductor female plug; angled; 4 mm²; 2-pole














www.wago.com/769-102/022-000

Item no.: 769-103
1-conductor female plug; 4 mm²; 3-pole

www.wago.com/769-103

Item no.: 769-103/000-006
1-conductor female plug; 4 mm²; 3-pole

www.wago.com/769-103/000-006

	<p>Item no.: 769-103/000-036 1-conductor female plug; 4 mm²; 3-pole</p>	www.wago.com/769-103/000-036
	<p>Item no.: 769-103/000-037 1-conductor female plug; 4 mm²; 3-pole</p>	www.wago.com/769-103/000-037
	<p>Item no.: 769-103/000-038 1-conductor female plug; 4 mm²; 3-pole</p>	www.wago.com/769-103/000-038
	<p>Item no.: 769-103/000-039 1-conductor female plug; 4 mm²; 3-pole</p>	www.wago.com/769-103/000-039
	<p>Item no.: 769-103/022-000 1-conductor female plug; angled; 4 mm²; 3-pole</p>	www.wago.com/769-103/022-000
	<p>Item no.: 769-104 1-conductor female plug; 4 mm²; 4-pole</p>	www.wago.com/769-104
	<p>Item no.: 769-104/000-006 1-conductor female plug; 4 mm²; 4-pole</p>	www.wago.com/769-104/000-006
	<p>Item no.: 769-104/000-036 1-conductor female plug; 4 mm²; 4-pole</p>	www.wago.com/769-104/000-036
	<p>Item no.: 769-104/000-037 1-conductor female plug; 4 mm²; 4-pole</p>	www.wago.com/769-104/000-037
	<p>Item no.: 769-104/000-038 1-conductor female plug; 4 mm²; 4-pole</p>	www.wago.com/769-104/000-038
	<p>Item no.: 769-104/000-039 1-conductor female plug; 4 mm²; 4-pole</p>	www.wago.com/769-104/000-039
	<p>Item no.: 769-104/022-000 1-conductor female plug; angled; 4 mm²; 4-pole</p>	www.wago.com/769-104/022-000
	<p>Item no.: 769-105 1-conductor female plug; 4 mm²; 5-pole</p>	www.wago.com/769-105
	<p>Item no.: 769-105/000-006 1-conductor female plug; 4 mm²; 5-pole</p>	www.wago.com/769-105/000-006
	<p>Item no.: 769-105/000-036 1-conductor female plug; 4 mm²; 5-pole</p>	www.wago.com/769-105/000-036



Item no.: 769-105/000-037
1-conductor female plug; 4 mm²; 5-pole

www.wago.com/769-105/000-037



Item no.: 769-105/000-038
1-conductor female plug; 4 mm²; 5-pole

www.wago.com/769-105/000-038



Item no.: 769-105/000-039
1-conductor female plug; 4 mm²; 5-pole

www.wago.com/769-105/000-039



Item no.: 769-105/022-000
1-conductor female plug; angled; 4 mm²; 5-pole

www.wago.com/769-105/022-000

Item no.: 769-106
1-conductor female plug; 4 mm²; 6-pole

www.wago.com/769-106

Item no.: 769-106/000-006
1-conductor female plug; 4 mm²; 6-pole

www.wago.com/769-106/000-006



Item no.: 769-106/000-036
1-conductor female plug; 4 mm²; 6-pole

www.wago.com/769-106/000-036



Item no.: 769-106/000-037
1-conductor female plug; 4 mm²; 6-pole

www.wago.com/769-106/000-037



Item no.: 769-106/000-038
1-conductor female plug; 4 mm²; 6-pole

www.wago.com/769-106/000-038



Item no.: 769-106/000-039
1-conductor female plug; 4 mm²; 6-pole

www.wago.com/769-106/000-039

Item no.: 769-106/022-000
1-conductor female plug; angled; 4 mm²; 6-pole

www.wago.com/769-106/022-000

Item no.: 769-107
1-conductor female plug; 4 mm²; 7-pole

www.wago.com/769-107

Item no.: 769-107/000-006
1-conductor female plug; 4 mm²; 7-pole

www.wago.com/769-107/000-006



Item no.: 769-107/000-036
1-conductor female plug; 4 mm²; 7-pole

www.wago.com/769-107/000-036



Item no.: 769-107/000-037
1-conductor female plug; 4 mm²; 7-pole

www.wago.com/769-107/000-037



Item no.: 769-107/000-038
1-conductor female plug; 4 mm²; 7-pole

www.wago.com/769-107/000-038



Item no.: 769-107/000-039
1-conductor female plug; 4 mm²; 7-pole

www.wago.com/769-107/000-039

Item no.: 769-107/022-000
1-conductor female plug; angled; 4 mm²; 7-pole

www.wago.com/769-107/022-000

Item no.: 769-108
1-conductor female plug; 4 mm²; 8-pole

www.wago.com/769-108

Item no.: 769-108/000-006
1-conductor female plug; 4 mm²; 8-pole

www.wago.com/769-108/000-006

Item no.: 769-108/000-036
1-conductor female plug; 4 mm²; 8-pole

www.wago.com/769-108/000-036

Item no.: 769-108/000-037
1-conductor female plug; 4 mm²; 8-pole

www.wago.com/769-108/000-037

Item no.: 769-108/000-038
1-conductor female plug; 4 mm²; 8-pole

www.wago.com/769-108/000-038

Item no.: 769-108/000-039
1-conductor female plug; 4 mm²; 8-pole

www.wago.com/769-108/000-039

Item no.: 769-108/022-000
1-conductor female plug; angled; 4 mm²; 8-pole

www.wago.com/769-108/022-000

Item no.: 769-109
1-conductor female plug; 4 mm²; 9-pole

www.wago.com/769-109

Item no.: 769-109/000-006
1-conductor female plug; 4 mm²; 9-pole

www.wago.com/769-109/000-006



Item no.: 769-109/000-036
1-conductor female plug; 4 mm²; 9-pole

www.wago.com/769-109/000-036



Item no.: 769-109/000-037
1-conductor female plug; 4 mm²; 9-pole

www.wago.com/769-109/000-037



Item no.: 769-109/000-038
1-conductor female plug; 4 mm²; 9-pole

www.wago.com/769-109/000-038



Item no.: 769-109/000-039
1-conductor female plug; 4 mm²; 9-pole

www.wago.com/769-109/000-039

Item no.: 769-109/022-000
1-conductor female plug; angled; 4 mm²; 9-pole

www.wago.com/769-109/022-000

Item no.: 769-110
1-conductor female plug; 4 mm²; 10-pole

www.wago.com/769-110

Item no.: 769-110/000-006
1-conductor female plug; 4 mm²; 10-pole

www.wago.com/769-110/000-006

Item no.: 769-110/000-036
1-conductor female plug; 4 mm²; 10-pole

www.wago.com/769-110/000-036

Item no.: 769-110/000-037
1-conductor female plug; 4 mm²; 10-pole

www.wago.com/769-110/000-037

Item no.: 769-110/000-038
1-conductor female plug; 4 mm²; 10-pole

www.wago.com/769-110/000-038

Item no.: 769-110/000-039
1-conductor female plug; 4 mm²; 10-pole

www.wago.com/769-110/000-039

Item no.: 769-110/022-000
1-conductor female plug; angled; 4 mm²; 10-pole

www.wago.com/769-110/022-000

Item no.: 769-111
1-conductor female plug; 4 mm²; 11-pole

www.wago.com/769-111

Item no.: 769-111/000-006
1-conductor female plug; 4 mm²; 11-pole

www.wago.com/769-111/000-006

Item no.: 769-111/000-036
1-conductor female plug; 4 mm²; 11-pole

www.wago.com/769-111/000-036

Item no.: 769-111/000-037
1-conductor female plug; 4 mm²; 11-pole





www.wago.com/769-111/000-037

Item no.: 769-111/000-038
1-conductor female plug; 4 mm²; 11-pole

www.wago.com/769-111/000-038

Item no.: 769-111/000-039
1-conductor female plug; 4 mm²; 11-pole

www.wago.com/769-111/000-039

	<p>Item no.: 769-111/022-000 1-conductor female plug; angled; 4 mm²; 11-pole</p>	<p>www.wago.com/769-111/022-000</p>
	<p>Item no.: 769-112 1-conductor female plug; 4 mm²; 12-pole</p>	<p>www.wago.com/769-112</p>
	<p>Item no.: 769-112/000-006 1-conductor female plug; 4 mm²; 12-pole</p>	<p>www.wago.com/769-112/000-006</p>
	<p>Item no.: 769-112/000-036 1-conductor female plug; 4 mm²; 12-pole</p>	<p>www.wago.com/769-112/000-036</p>
	<p>Item no.: 769-112/000-037 1-conductor female plug; 4 mm²; 12-pole</p>	<p>www.wago.com/769-112/000-037</p>
	<p>Item no.: 769-112/000-038 1-conductor female plug; 4 mm²; 12-pole</p>	<p>www.wago.com/769-112/000-038</p>
	<p>Item no.: 769-112/000-039 1-conductor female plug; 4 mm²; 12-pole</p>	<p>www.wago.com/769-112/000-039</p>
	<p>Item no.: 769-112/022-000 1-conductor female plug; angled; 4 mm²; 12-pole</p>	<p>www.wago.com/769-112/022-000</p>
	<p>Item no.: 769-113 1-conductor female plug; 4 mm²; 13-pole</p>	<p>www.wago.com/769-113</p>
	<p>Item no.: 769-113/000-036 1-conductor female plug; 4 mm²; 13-pole</p>	<p>www.wago.com/769-113/000-036</p>
	<p>Item no.: 769-113/000-037 1-conductor female plug; 4 mm²; 13-pole</p>	<p>www.wago.com/769-113/000-037</p>
	<p>Item no.: 769-113/000-038 1-conductor female plug; 4 mm²; 13-pole</p>	<p>www.wago.com/769-113/000-038</p>
	<p>Item no.: 769-113/000-039 1-conductor female plug; 4 mm²; 13-pole</p>	<p>www.wago.com/769-113/000-039</p>
	<p>Item no.: 769-113/022-000 1-conductor female plug; angled; 4 mm²; 13-pole</p>	<p>www.wago.com/769-113/022-000</p>
	<p>Item no.: 769-114 1-conductor female plug; 4 mm²; 14-pole</p>	<p>www.wago.com/769-114</p>

Item no.: 769-114/000-006 1-conductor female plug; 4 mm ² ; 14-pole	www.wago.com/769-114/000-006
Item no.: 769-114/000-036 1-conductor female plug; 4 mm ² ; 14-pole	www.wago.com/769-114/000-036
Item no.: 769-114/000-037 1-conductor female plug; 4 mm ² ; 14-pole	www.wago.com/769-114/000-037
Item no.: 769-114/000-038 1-conductor female plug; 4 mm ² ; 14-pole	www.wago.com/769-114/000-038
Item no.: 769-114/000-039 1-conductor female plug; 4 mm ² ; 14-pole	www.wago.com/769-114/000-039
Item no.: 769-114/022-000 1-conductor female plug; angled; 4 mm ² ; 14-pole	www.wago.com/769-114/022-000
Item no.: 769-115 1-conductor female plug; 4 mm ² ; 15-pole	www.wago.com/769-115
Item no.: 769-115/000-036 1-conductor female plug; 4 mm ² ; 15-pole	www.wago.com/769-115/000-036
Item no.: 769-115/000-037 1-conductor female plug; 4 mm ² ; 15-pole	www.wago.com/769-115/000-037
Item no.: 769-115/000-038 1-conductor female plug; 4 mm ² ; 15-pole	www.wago.com/769-115/000-038
Item no.: 769-115/000-039 1-conductor female plug; 4 mm ² ; 15-pole	www.wago.com/769-115/000-039
Item no.: 769-115/022-000 1-conductor female plug; angled; 4 mm ² ; 15-pole	www.wago.com/769-115/022-000

assembling















Item no.: 209-106 Mounting carrier; for isolated mounting on DIN 35 rails	www.wago.com/209-106
---	--



Jumper



 


Item no.: 249-123 Push-in type wire jumper; insulated; wire length 180 mm; Conductor cross section 0.75 mm ²	www.wago.com/249-123
---	--

	Item no.: 249-125 Push-in type wire jumper; insulated; wire length 60 mm; Conductor cross section 0.75 mm ²	www.wago.com/249-125
	Item no.: 249-126 Push-in type wire jumper; insulated; wire length 110 mm; Conductor cross section 0.75 mm ²	www.wago.com/249-126
	Item no.: 249-127 Push-in type wire jumper; insulated; wire length 250 mm; Conductor cross section 0.75 mm ²	www.wago.com/249-127
	Item no.: 280-402 Adjacent jumper; insulated; IN = IN terminal block	www.wago.com/280-402
	Item no.: 280-409 Alternate jumper; insulated; IN = IN terminal block	www.wago.com/280-409
	Item no.: 780-452 Staggered jumper; insulated; from 1 to 2; Spacing: 5 mm; suitable for 2-conductor female plugs	www.wago.com/780-452
	Item no.: 780-453 Staggered jumper; insulated; from 1 to 3; Spacing: 5 mm; suitable for 2-conductor female plugs	www.wago.com/780-453
	Item no.: 780-454 Staggered jumper; insulated; from 1 to 4; Spacing: 5 mm; suitable for 2-conductor female plugs	www.wago.com/780-454
	Item no.: 780-455 Staggered jumper; insulated; from 1 to 5; Spacing: 5 mm; suitable for 2-conductor female plugs	www.wago.com/780-455
	Item no.: 780-456 Staggered jumper; insulated; from 1 to 6; Spacing: 5 mm; suitable for 2-conductor female plugs	www.wago.com/780-456
	Item no.: 780-457 Staggered jumper; insulated; from 1 to 7; Spacing: 5 mm; suitable for 2-conductor female plugs	www.wago.com/780-457
	Item no.: 780-458 Staggered jumper; insulated; from 1 to 8; Spacing: 5 mm; suitable for 2-conductor female plugs	www.wago.com/780-458



















End plate













	Item no.: 769-309 End and intermediate plate; 1.1 mm thick	www.wago.com/769-309
	Item no.: 769-310 End and intermediate plate; 1.1 mm thick	www.wago.com/769-310
	Item no.: 769-313 Separator plate; 1.1 mm thick; oversized	www.wago.com/769-313

General accessories

	Item no.: 280-404 Test plug adapter; 5 mm wide; for test plug 210-137 (2.3 mm Ø); suitable for 1.5 mm ² - 4 mm ² tbs	www.wago.com/280-404
	Item no.: 280-418 Test plug module; modular; suitable for all WAGO 280 and 780 Series rail-mounted terminal blocks with jumper slots in the current bar	www.wago.com/280-418
	Item no.: 280-419 Spacer module; modular; bridging commoned terminal blocks	www.wago.com/280-419

	Item no.: 280-804 Empty component plug housing; 10 mm wide; Type 3; 4-pole	www.wago.com/280-804
	Item no.: 286-110 Empty component plug housing; Type 9; 10 mm wide; 4-pole	www.wago.com/286-110
	Item no.: 286-113 Empty component plug housing; Type 12; 25 mm wide; 10-pole	www.wago.com/286-113
	Item no.: 286-336/001-000 Relay module; Nominal input voltage: 24 VDC; 2 break and 2 make contacts; Red status indicator; Module width: 25 mm	www.wago.com/286-336/001-000
	Item no.: 286-344/004-000 Relay module; Nominal input voltage: 24 VDC; 3 break contacts and 1 make contact; Path; Red status indicator; Module width: 25 mm	www.wago.com/286-344/004-000
	Item no.: 286-352/004-000 Relay module; Nominal input voltage: 24 VDC; 4 make contacts; Limiting continuous current: 5 A; Path; Red status indicator; Module width: 25 mm	www.wago.com/286-352/004-000
	Item no.: 286-364 Relay module; Nominal input voltage: 24 VDC; 1 make contact; Limiting continuous current: 5 A; Red status indicator; Module width: 10 mm	www.wago.com/286-364
	Item no.: 286-364/004-000 Relay module; Relay with 1 make contact (1a); with miniature switching relay; with extended input voltage and temperature range	www.wago.com/286-364/004-000
	Item no.: 286-368 Relay module; Nominal input voltage: 24 VDC; 1 break contact; Limiting continuous current: 5 A; Red status indicator; Module width: 10 mm	www.wago.com/286-368
	Item no.: 286-368/004-000 Relay module; Nominal input voltage: 24 VDC; 1 break contact; Limiting continuous current: 5 A; Path; Red status indicator; 10 mm wide	www.wago.com/286-368/004-000
	Item no.: 286-664 Current flow monitoring module; AC current flow monitoring module; 1 A ... 10 A; adjustable; Relay with 1 changeover contact (1u)	www.wago.com/286-664
	Item no.: 286-665 Current flow monitoring module; Relay with 1 changeover contact (1u); adjustable	www.wago.com/286-665
	Item no.: 286-742 S0 interface power supply; Input voltage: 230 VAC; S0 interface	www.wago.com/286-742
	Item no.: 286-791 Optocoupler module; Nominal input voltage: 24 VDC; Output voltage range: 20 ... 60 VDC; Limiting continuous current: 0.1 A; 2-wire connection; Frequency: 3 kHz; Red status indicator; Module width: 10 mm	www.wago.com/286-791
	Item no.: 286-794 Optocoupler module; Nominal input voltage: 24 VDC; Output voltage range: 20 ... 60 VDC; Limiting continuous current: 0.1 A; 2-wire connection; Red status indicator; Module width: 10 mm	www.wago.com/286-794
	Item no.: 286-803 Component module with diode	www.wago.com/286-803
	Item no.: 286-809 Component module with diode	www.wago.com/286-809

	Item no.: 286-822 Component module with LED; Red LED; with common cathode	www.wago.com/286-822
	Item no.: 286-826 AND gate module with 6 inputs	www.wago.com/286-826
	Item no.: 286-841 Surge suppression module for signal technology; Nominal voltage: 220 VDC; for 2 signal paths with common surge arrester; pluggable on rail-mount terminal block, 25 mm wide	www.wago.com/286-841
	Item no.: 286-842 Surge suppression module for signal technology; Nominal voltage: 230 VAC; for 2 signal paths with common surge arrester; pluggable on rail-mount terminal block, 25 mm wide	www.wago.com/286-842
	Item no.: 286-843 Surge suppression module for signal technology; Nominal voltage: 115 VAC; for 2 signal paths with common surge arrester; pluggable on rail-mount terminal block, 25 mm wide	www.wago.com/286-843
	Item no.: 286-844 Surge suppression module for signal technology; for 2 signal paths with common surge arrester; pluggable on rail-mount terminal block, 25 mm wide	www.wago.com/286-844
	Item no.: 286-890 Component module with fuse; for (5 x 20) mm microfuse; Nominal voltage: 24 VAC/DC	www.wago.com/286-890
	Item no.: 286-891 Component module with fuse; for (5 x 20) mm microfuse; Nominal voltage: 230 VAC/DC	www.wago.com/286-891
	Item no.: 769-438 Pin cover; with marker slot for miniature WSB	www.wago.com/769-438
	Item no.: 769-439 Pin cover; with marker slot for miniature WSB	www.wago.com/769-439
	Item no.: 769-501 Start module for 1-conductor female connector; with integrated end plate; 4 mm ² ; 1-pole	www.wago.com/769-501
	Item no.: 769-501/000-006 Start module for 1-conductor female connector; 4 mm ² ; 1-pole	www.wago.com/769-501/000-006
	Item no.: 769-501/000-016 Start module for 1-conductor female connector; with integrated end plate; 4 mm ² ; 1-pole	www.wago.com/769-501/000-016
	Item no.: 769-502 Center module for 1-conductor female connector; 4 mm ² ; 1-pole	www.wago.com/769-502
	Item no.: 769-502/000-006 Center module for 1-conductor female connector; 4 mm ² ; 1-pole	www.wago.com/769-502/000-006
	Item no.: 769-502/000-016 1-conductor center module; codable; can be commoned with miniature adjacent jumpers; 1-pole	www.wago.com/769-502/000-016
	Item no.: 769-503 End module for 1-conductor female connector; 4 mm ² ; 1-pole	www.wago.com/769-503
	Item no.: 769-503/000-006 End module for 1-conductor female connector; 4 mm ² ; 1-pole	www.wago.com/769-503/000-006

	Item no.: 769-503/000-016 End module for 1-conductor female connector; 4 mm ² ; 1-pole	www.wago.com/769-503/000-016
	Item no.: 769-512 Start module for 1-conductor female connector; angled; 4 mm ² ; 1-pole	www.wago.com/769-512
	Item no.: 769-512/000-006 Start module for 1-conductor female connector; angled; 4 mm ² ; 1-pole	www.wago.com/769-512/000-006
	Item no.: 769-512/000-016 Start module for 1-conductor female connector; angled; 4 mm ² ; 1-pole	www.wago.com/769-512/000-016
	Item no.: 769-513 Center module for 1-conductor female connector; angled; 4 mm ² ; 1-pole	www.wago.com/769-513
	Item no.: 769-513/000-006 1-conductor center module; angled; codable; 1-pole	www.wago.com/769-513/000-006
	Item no.: 769-513/000-016 1-conductor center module; angled; codable; 1-pole	www.wago.com/769-513/000-016
	Item no.: 769-515 1-conductor end module; angled; codable; 1-pole	www.wago.com/769-515
	Item no.: 769-515/000-006 1-conductor end module; angled; codable; 1-pole	www.wago.com/769-515/000-006
	Item no.: 769-515/000-016 1-conductor end module; angled; codable; 1-pole	www.wago.com/769-515/000-016
	Item no.: 786-103 Empty component plug housing; Type 16; 25 mm wide; 10-pole	www.wago.com/786-103
Coding		
	Item no.: 769-435 Coding pin; for coding of female plugs; for carrier terminal blocks / male connectors	www.wago.com/769-435

Downloads Documentation

Bid Text

769-162/769-313

Oct 18, 2017

DOC
25.6 kB

Download



smartDATA

CAD data

3D Download 769-162/769-313

URL

Download

Product family

X-COM

[Learn more about the product family.](#)

[Show all products from the family](#)

Subject to changes.

WAGO Kontakttechnik GmbH & Co. KG

Hansastr. 27

32423 Minden

Phone: +49571 887-0 | Fax: +49571 887-169

Email: info.de@wago.com | Web: www.wago.com

Do you have any questions about our products?

We are always happy to take your call at +49 (571) 887-44222.