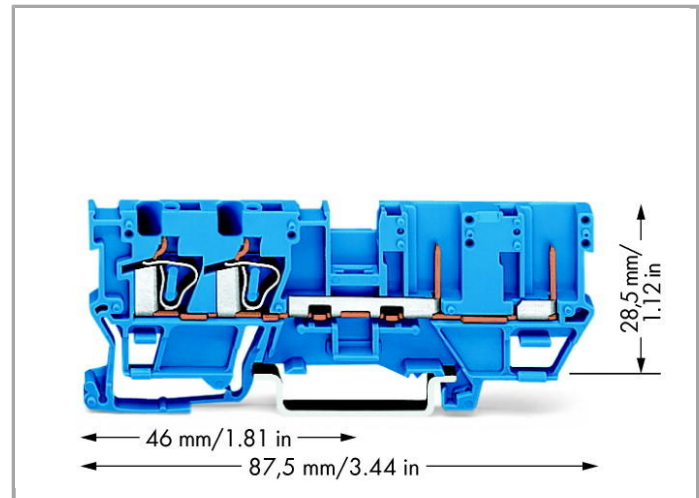
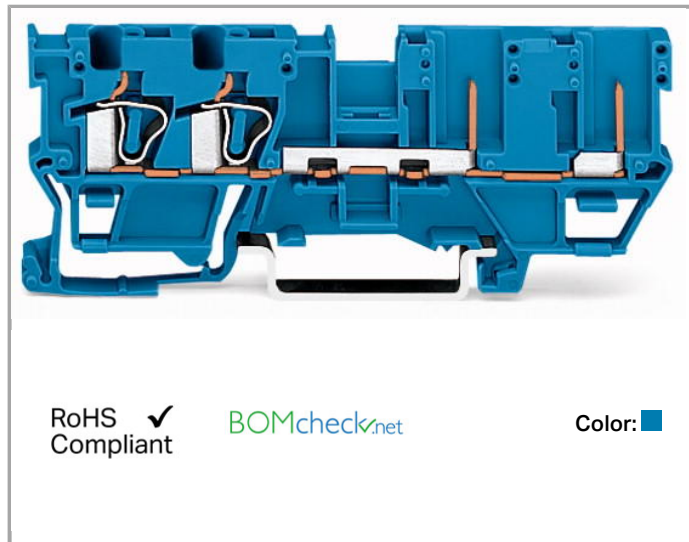


Data sheet | Item number: 769-171/000-006

2-conductor/2-pin carrier terminal block; for DIN-rail 35 x 15 and 35 x 7.5; 4 mm²; CAGE CLAMP®



www.wago.com/769-171/000-006



Data

Electrical data

Ratings per IEC/EN 60664-1

| | |
|---------------------------------|---|
| Rated voltage (III / 3) | 500 V |
| Rated impulse voltage (III / 3) | 6 kV |
| Rated current | 32 A |
| Legend (ratings) | (III / 3) ≙ Overvoltage category III / Pollution degree 3 |

Connection data

| | |
|-----------------------------------|--|
| Connection technology | CAGE CLAMP® |
| Actuation type | Operating tool |
| Connectable conductor materials | Copper Aluminum |
| Nominal cross section | 4 mm ² |
| Solid conductor | 0.08 ... 4 mm ² / 28 ... 12 AWG |
| Fine-stranded conductor | 0.08 ... 4 mm ² / 28 ... 12 AWG |
| Strip length | 8 ... 9 mm / 0.31 ... 0.35 Inch |
| Total number of connection points | 2 |
| Total number of potentials | 1 |
| Number of levels | 1 |
| Type of wiring | Front-entry wiring |

Geometrical Data

| | |
|---------------------------------------|----------------------|
| Width | 5 mm / 0.197 inch |
| Height from upper-edge of DIN-35 rail | 28.5 mm / 1.122 inch |
| Depth | 87.5 mm / 3.445 inch |

Mechanical data

| | |
|------------------|----------------|
| Design | horizontal |
| Type of mounting | DIN-35 rail |
| Marking level | Center marking |

Material Data




| | |
|---------------------|----------------------|
| Color | blue |
| Insulating material | Polyamide 66 (PA 66) |
| Fire load | 0.168 MJ |
| Weight | 10.323 g |

Commercial data

| | |
|--------------------|-------------------|
| Country of origin | CN |
| GTIN | 4045454871680 |
| Customs Tariff No. | 85369010000 |
| Product Group | 18 (X-COM-System) |

Approvals / Certificates

Country specific Approvals

| Logo | Approval | Certificate name |
|--|---------------------------------------|------------------|
|  | CCA DEKRA Certification B.V. | NTR NL-7626 |
|  | CSA DEKRA Certification B.V. | 1101144 |
|  | KEMA/KEUR DEKRA Certification B.V. | 2190419.01 |

UL-Approvals

| Logo | Approval | Certificate name |
|------|--------------------------------------|------------------|
| | UR Underwriters Laboratories Inc. | E45171 |



UR

Underwriters Laboratories Inc.

E45172

Compatible products

Coding



Item no.: 769-435

Coding pin; for coding of female plugs; for carrier terminal blocks / male connectors

www.wago.com/769-435

tools



Item no.: 210-720

Operating tool with partially insulated shaft; Type 2, blade (3.5 x 0.5) mm

www.wago.com/210-720

End plate



Item no.: 769-303

End and intermediate plate; 1.1 mm thick

www.wago.com/769-303

Item no.: 769-304

End and intermediate plate; 1.1 mm thick

www.wago.com/769-304

Insulation stop



Item no.: 769-470

Insulation stop; 0.08 - 0.2 mm² "s" (0.14 mm² "f-st"); 5 pieces/stripwww.wago.com/769-470

Item no.: 769-471

Insulation stop; 0.25 - 0.5 mm²; 5 pieces/stripwww.wago.com/769-471

Item no.: 769-472

Insulation stop; 0.75 - 1 mm²; 5 pieces/stripwww.wago.com/769-472

ferrule



Item no.: 216-101

Ferrule; Sleeve for 0.5 mm² / AWG 22; uninsulated; electro-tin platedwww.wago.com/216-101

Item no.: 216-102




















Ferrule; Sleeve for 0.75 mm² / AWG 20; uninsulated; electro-tin platedwww.wago.com/216-102

Item no.: 216-103









Ferrule; Sleeve for 1 mm² / AWG 18; uninsulated; electro-tin platedwww.wago.com/216-103

Item no.: 216-104

Ferrule; Sleeve for 1.5 mm² / AWG 16; uninsulated; electro-tin platedwww.wago.com/216-104

| | | |
|--|--|--|
|  | Item no.: 216-201 Ferrule; Sleeve for 0.5 mm ² / AWG 22; insulated; electro-tin plated | www.wago.com/216-201 |
|  | Item no.: 216-202 Ferrule; Sleeve for 0.75 mm ² / AWG 20; insulated; electro-tin plated | www.wago.com/216-202 |
|  | Item no.: 216-203 Ferrule; Sleeve for 1 mm ² / AWG 18; insulated; electro-tin plated | www.wago.com/216-203 |
|  | Item no.: 216-204 Ferrule; Sleeve for 1.5 mm ² / AWG 16; insulated; electro-tin plated | www.wago.com/216-204 |
|  | Item no.: 216-206 Ferrule; Sleeve for 2.5 mm ² / AWG 14; insulated; electro-tin plated | www.wago.com/216-206 |
|  | Item no.: 216-301 Ferrule; Sleeve for 0.25 mm ² / AWG 24; insulated; electro-tin plated | www.wago.com/216-301 |
|  | Item no.: 216-302 Ferrule; Sleeve for 0.34 mm ² / AWG 24; insulated; electro-tin plated | www.wago.com/216-302 |
| Carrier rail | | |
|  | Item no.: 210-112 Steel carrier rail; 35 x 7.5 mm; 1 mm thick; 2 m long; slotted; according to EN 60715; "Hole width 25 mm | www.wago.com/210-112 |
|  | Item no.: 210-113 Steel carrier rail; 35 x 7.5 mm; 1 mm thick; 2 m long; unslotted; according to EN 60715 | www.wago.com/210-113 |
|  | Item no.: 210-114 Steel carrier rail; 35 x 15 mm; 1.5 mm thick; 2 m long; unslotted; similar to EN 60715 | www.wago.com/210-114 |
|  | Item no.: 210-115 Steel carrier rail; 35 x 7.5 mm; 1 mm thick; 2 m long; slotted; according to EN 60715; "Hole width 18 mm | www.wago.com/210-115 |
|  | Item no.: 210-118 Steel carrier rail; 35 x 15 mm; 2.3 mm thick; 2 m long; unslotted; according to EN 60715 | www.wago.com/210-118 |
|  | Item no.: 210-196 Aluminum carrier rail; 35 x 8.2 mm; 1.6 mm thick; 2 m long; unslotted; similar to EN 60715 | www.wago.com/210-196 |
|  | Item no.: 210-197 Steel carrier rail; 35 x 15 mm; 1.5 mm thick; 2 m long; slotted; similar to EN 60715 | www.wago.com/210-197 |
|  | Item no.: 210-198 Copper carrier rail; 35 x 15 mm; 2.3 mm thick; 2 m long; unslotted; according to EN 60715 | www.wago.com/210-198 |
|  | Item no.: 210-504 Steel carrier rail; 35 x 7.5 mm; 1 mm thick; 2 m long; slotted; galvanized; according to EN 60715 | www.wago.com/210-504 |
|  | Item no.: 210-505 Steel carrier rail; 35 x 7.5 mm; 1 mm thick; 2 m long; unslotted; galvanized; according to EN 60715 | www.wago.com/210-505 |
|  | Item no.: 210-506 Steel carrier rail; 35 x 15 mm; 1.5 mm thick; 2 m long; unslotted; galvanized; similar to EN 60715 | www.wago.com/210-506 |
|  | Item no.: 210-508 Steel carrier rail; 35 x 15 mm; 1.5 mm thick; 2 m long; slotted; galvanized; similar to EN 60715 | www.wago.com/210-508 |

Female plug

| | | |
|---|---|--|
|  | Item no.: 769-101 1-conductor female plug; 4 mm ² ; 1-pole | www.wago.com/769-101 |
|  | Item no.: 769-101/000-006 1-conductor female plug; 4 mm ² ; 1-pole | www.wago.com/769-101/000-006 |
|  | Item no.: 769-101/000-016 1-conductor female plug; 4 mm ² ; 1-pole | www.wago.com/769-101/000-016 |
|  | Item no.: 769-102 1-conductor female plug; 4 mm ² ; 2-pole | www.wago.com/769-102 |
| | Item no.: 769-102/000-006 1-conductor female plug; 4 mm ² ; 2-pole | www.wago.com/769-102/000-006 |
| | Item no.: 769-102/000-036 1-conductor female plug; 4 mm ² ; 2-pole | www.wago.com/769-102/000-036 |
| | Item no.: 769-102/000-037 1-conductor female plug; 4 mm ² ; 2-pole | www.wago.com/769-102/000-037 |
| | Item no.: 769-103 1-conductor female plug; 4 mm ² ; 3-pole | www.wago.com/769-103 |
| | Item no.: 769-103/000-006 1-conductor female plug; 4 mm ² ; 3-pole | www.wago.com/769-103/000-006 |
|  | Item no.: 769-103/000-036 1-conductor female plug; 4 mm ² ; 3-pole | www.wago.com/769-103/000-036 |
|  | Item no.: 769-103/000-037 1-conductor female plug; 4 mm ² ; 3-pole | www.wago.com/769-103/000-037 |
|  | Item no.: 769-103/000-038 1-conductor female plug; 4 mm ² ; 3-pole | www.wago.com/769-103/000-038 |
|  | Item no.: 769-103/000-039 1-conductor female plug; 4 mm ² ; 3-pole | www.wago.com/769-103/000-039 |
| | Item no.: 769-104 1-conductor female plug; 4 mm ² ; 4-pole | www.wago.com/769-104 |
| | Item no.: 769-104/000-006 1-conductor female plug; 4 mm ² ; 4-pole | www.wago.com/769-104/000-006 |



Item no.: 769-104/000-036
1-conductor female plug; 4 mm²; 4-pole

www.wago.com/769-104/000-036



Item no.: 769-104/000-037
1-conductor female plug; 4 mm²; 4-pole

www.wago.com/769-104/000-037



Item no.: 769-104/000-038
1-conductor female plug; 4 mm²; 4-pole

www.wago.com/769-104/000-038



Item no.: 769-104/000-039
1-conductor female plug; 4 mm²; 4-pole

www.wago.com/769-104/000-039



Item no.: 769-105
1-conductor female plug; 4 mm²; 5-pole

www.wago.com/769-105



Item no.: 769-105/000-006
1-conductor female plug; 4 mm²; 5-pole

www.wago.com/769-105/000-006



Item no.: 769-105/000-036
1-conductor female plug; 4 mm²; 5-pole

www.wago.com/769-105/000-036



Item no.: 769-105/000-037
1-conductor female plug; 4 mm²; 5-pole

www.wago.com/769-105/000-037



Item no.: 769-105/000-038
1-conductor female plug; 4 mm²; 5-pole

www.wago.com/769-105/000-038



Item no.: 769-105/000-039
1-conductor female plug; 4 mm²; 5-pole

www.wago.com/769-105/000-039

Item no.: 769-106
1-conductor female plug; 4 mm²; 6-pole

www.wago.com/769-106

Item no.: 769-106/000-006
1-conductor female plug; 4 mm²; 6-pole

www.wago.com/769-106/000-006



Item no.: 769-106/000-036
1-conductor female plug; 4 mm²; 6-pole

www.wago.com/769-106/000-036



Item no.: 769-106/000-037
1-conductor female plug; 4 mm²; 6-pole

www.wago.com/769-106/000-037



Item no.: 769-106/000-038
1-conductor female plug; 4 mm²; 6-pole

www.wago.com/769-106/000-038



Item no.: 769-106/000-039
1-conductor female plug; 4 mm²; 6-pole

www.wago.com/769-106/000-039

Item no.: 769-107
1-conductor female plug; 4 mm²; 7-pole

www.wago.com/769-107

Item no.: 769-107/000-006
1-conductor female plug; 4 mm²; 7-pole

www.wago.com/769-107/000-006



Item no.: 769-107/000-036
1-conductor female plug; 4 mm²; 7-pole

www.wago.com/769-107/000-036



Item no.: 769-107/000-037
1-conductor female plug; 4 mm²; 7-pole

www.wago.com/769-107/000-037



Item no.: 769-107/000-038
1-conductor female plug; 4 mm²; 7-pole

www.wago.com/769-107/000-038



Item no.: 769-107/000-039
1-conductor female plug; 4 mm²; 7-pole

www.wago.com/769-107/000-039

Item no.: 769-108
1-conductor female plug; 4 mm²; 8-pole

www.wago.com/769-108

Item no.: 769-108/000-006
1-conductor female plug; 4 mm²; 8-pole

www.wago.com/769-108/000-006

Item no.: 769-108/000-036
1-conductor female plug; 4 mm²; 8-pole

www.wago.com/769-108/000-036

Item no.: 769-108/000-037
1-conductor female plug; 4 mm²; 8-pole

www.wago.com/769-108/000-037

Item no.: 769-108/000-038
1-conductor female plug; 4 mm²; 8-pole

www.wago.com/769-108/000-038

Item no.: 769-108/000-039
1-conductor female plug; 4 mm²; 8-pole

www.wago.com/769-108/000-039

Item no.: 769-109
1-conductor female plug; 4 mm²; 9-pole

www.wago.com/769-109

Item no.: 769-109/000-006
1-conductor female plug; 4 mm²; 9-pole

www.wago.com/769-109/000-006



Item no.: 769-109/000-036
1-conductor female plug; 4 mm²; 9-pole

www.wago.com/769-109/000-036



Item no.: 769-109/000-037
1-conductor female plug; 4 mm²; 9-pole

www.wago.com/769-109/000-037



Item no.: 769-109/000-038
1-conductor female plug; 4 mm²; 9-pole

www.wago.com/769-109/000-038



Item no.: 769-109/000-039
1-conductor female plug; 4 mm²; 9-pole

www.wago.com/769-109/000-039

Item no.: 769-110
1-conductor female plug; 4 mm²; 10-pole

www.wago.com/769-110

Item no.: 769-110/000-006
1-conductor female plug; 4 mm²; 10-pole

www.wago.com/769-110/000-006

Item no.: 769-110/000-036
1-conductor female plug; 4 mm²; 10-pole

www.wago.com/769-110/000-036

Item no.: 769-110/000-037
1-conductor female plug; 4 mm²; 10-pole

www.wago.com/769-110/000-037

Item no.: 769-110/000-038
1-conductor female plug; 4 mm²; 10-pole

www.wago.com/769-110/000-038

Item no.: 769-110/000-039
1-conductor female plug; 4 mm²; 10-pole

www.wago.com/769-110/000-039

Item no.: 769-111
1-conductor female plug; 4 mm²; 11-pole

www.wago.com/769-111

Item no.: 769-111/000-006
1-conductor female plug; 4 mm²; 11-pole

www.wago.com/769-111/000-006

Item no.: 769-111/000-036
1-conductor female plug; 4 mm²; 11-pole





www.wago.com/769-111/000-036





Item no.: 769-111/000-037
1-conductor female plug; 4 mm²; 11-pole

 
 
 
 
 
 
www.wago.com/769-111/000-037

Item no.: 769-111/000-038
1-conductor female plug; 4 mm²; 11-pole

www.wago.com/769-111/000-038

| | | |
|--|--|---|
| | <p>Item no.: 769-111/000-039 1-conductor female plug; 4 mm²; 11-pole</p> | <p>www.wago.com/769-111/000-039</p> |
| | <p>Item no.: 769-112 1-conductor female plug; 4 mm²; 12-pole</p> | <p>www.wago.com/769-112</p> |
| | <p>Item no.: 769-112/000-006 1-conductor female plug; 4 mm²; 12-pole</p> | <p>www.wago.com/769-112/000-006</p> |
|  | <p>Item no.: 769-112/000-036 1-conductor female plug; 4 mm²; 12-pole</p> | <p>www.wago.com/769-112/000-036</p> |
|  | <p>Item no.: 769-112/000-037 1-conductor female plug; 4 mm²; 12-pole</p> | <p>www.wago.com/769-112/000-037</p> |
|  | <p>Item no.: 769-112/000-038 1-conductor female plug; 4 mm²; 12-pole</p> | <p>www.wago.com/769-112/000-038</p> |
|  | <p>Item no.: 769-112/000-039 1-conductor female plug; 4 mm²; 12-pole</p> | <p>www.wago.com/769-112/000-039</p> |
| | <p>Item no.: 769-113 1-conductor female plug; 4 mm²; 13-pole</p> | <p>www.wago.com/769-113</p> |
| | <p>Item no.: 769-113/000-036 1-conductor female plug; 4 mm²; 13-pole</p> | <p>www.wago.com/769-113/000-036</p> |
| | <p>Item no.: 769-113/000-037 1-conductor female plug; 4 mm²; 13-pole</p> | <p>www.wago.com/769-113/000-037</p> |
| | <p>Item no.: 769-113/000-038 1-conductor female plug; 4 mm²; 13-pole</p> | <p>www.wago.com/769-113/000-038</p> |
| | <p>Item no.: 769-113/000-039 1-conductor female plug; 4 mm²; 13-pole</p> | <p>www.wago.com/769-113/000-039</p> |
| | <p>Item no.: 769-114 1-conductor female plug; 4 mm²; 14-pole</p> | <p>www.wago.com/769-114</p> |
| | <p>Item no.: 769-114/000-006 1-conductor female plug; 4 mm²; 14-pole</p> | <p>www.wago.com/769-114/000-006</p> |
| | <p>Item no.: 769-114/000-036 1-conductor female plug; 4 mm²; 14-pole</p> | <p>www.wago.com/769-114/000-036</p> |
| | <p>Item no.: 769-114/000-037 1-conductor female plug; 4 mm²; 14-pole</p> | <p>www.wago.com/769-114/000-037</p> |

| | | |
|--|--|--|
| | Item no.: 769-114/000-038 1-conductor female plug; 4 mm ² ; 14-pole | www.wago.com/769-114/000-038 |
| | Item no.: 769-114/000-039 1-conductor female plug; 4 mm ² ; 14-pole | www.wago.com/769-114/000-039 |
| | Item no.: 769-115 1-conductor female plug; 4 mm ² ; 15-pole | www.wago.com/769-115 |
| | Item no.: 769-115/000-036 1-conductor female plug; 4 mm ² ; 15-pole | www.wago.com/769-115/000-036 |
| | Item no.: 769-115/000-037 1-conductor female plug; 4 mm ² ; 15-pole | www.wago.com/769-115/000-037 |
| | Item no.: 769-115/000-038 1-conductor female plug; 4 mm ² ; 15-pole | www.wago.com/769-115/000-038 |
| | Item no.: 769-115/000-039 1-conductor female plug; 4 mm ² ; 15-pole | www.wago.com/769-115/000-039 |
|  | Item no.: 769-121 2-conductor female connector; 4 mm ² ; 1-pole | www.wago.com/769-121 |
|  | Item no.: 769-121/000-016 2-conductor female connector; 4 mm ² ; 1-pole | www.wago.com/769-121/000-016 |
|  | Item no.: 769-122 2-conductor female connector; 4 mm ² ; 2-pole | www.wago.com/769-122 |
| | Item no.: 769-123 2-conductor female connector; 4 mm ² ; 3-pole | www.wago.com/769-123 |
| | Item no.: 769-124 2-conductor female connector; 4 mm ² ; 4-pole | www.wago.com/769-124 |
|  | Item no.: 769-125 2-conductor female connector; 4 mm ² ; 5-pole | www.wago.com/769-125 |
| | Item no.: 769-126 2-conductor female connector; 4 mm ² ; 6-pole | www.wago.com/769-126 |
| | Item no.: 769-127 2-conductor female connector; 4 mm ² ; 7-pole | www.wago.com/769-127 |
| | Item no.: 769-128 2-conductor female connector; 4 mm ² ; 8-pole | www.wago.com/769-128 |
| | Item no.: 769-129 2-conductor female connector; 4 mm ² ; 9-pole | www.wago.com/769-129 |

| | | |
|---|---|--|
|  | Item no.: 769-130 2-conductor female connector; 4 mm ² ; 10-pole | www.wago.com/769-130 |
|  | Item no.: 769-131 2-conductor female connector; 4 mm ² ; 11-pole | www.wago.com/769-131 |
|  | Item no.: 769-132 2-conductor female connector; 4 mm ² ; 12-pole | www.wago.com/769-132 |
|  | Item no.: 769-133 2-conductor female connector; 4 mm ² ; 13-pole | www.wago.com/769-133 |
|  | Item no.: 769-134 2-conductor female connector; 4 mm ² ; 14-pole | www.wago.com/769-134 |
|  | Item no.: 769-135 2-conductor female connector; 4 mm ² ; 15-pole | www.wago.com/769-135 |

Protective Warning Marker



| | |
|---|--|
| Item no.: 280-415 Protective warning marker; with high-voltage symbol, black; for 5 terminal blocks | www.wago.com/280-415 |
|---|--|

assembling



| | |
|---|--|
| Item no.: 209-106 Mounting carrier; for isolated mounting on DIN 35 rails | www.wago.com/209-106 |
|---|--|

check



| | |
|--|--|
| Item no.: 210-136 Test plug; 2 mm Ø; with 500 mm cable | www.wago.com/210-136 |
|--|--|



| | |
|--|--|
| Item no.: 210-137 Test plug; 2.3 mm Ø; with 500 mm cable | www.wago.com/210-137 |
|--|--|

General accessories



| | |
|--|--|
| Item no.: 280-404 Test plug adapter; 5 mm wide; for test plug 210-137 (2.3 mm Ø); suitable for 1.5 mm ² - 4 mm ² tbs | www.wago.com/280-404 |
|--|--|



| | |
|---|--|
| Item no.: 280-418 Test plug module; modular; suitable for all WAGO 280 and 780 Series rail-mounted terminal blocks with jumper slots in the current bar | www.wago.com/280-418 |
|---|--|



| | |
|---|--|
| Item no.: 280-419 Spacer module; modular; bridging commoned terminal blocks | www.wago.com/280-419 |
|---|--|



















| | |
|---|--|
| Item no.: 769-438 Pin cover; with marker slot for miniature WSB | www.wago.com/769-438 |
|---|--|













| | |
|---|--|
| Item no.: 769-439 Pin cover; with marker slot for miniature WSB | www.wago.com/769-439 |
|---|--|























| | |
|--|--|
| Item no.: 769-501 Start module for 1-conductor female connector; with integrated end plate; 4 mm ² ; 1-pole | www.wago.com/769-501 |
|--|--|

| | | |
|--|--|--|
|  | Item no.: 769-501/000-006 Start module for 1-conductor female connector; 4 mm ² ; 1-pole | www.wago.com/769-501/000-006 |
|  | Item no.: 769-501/000-016 Start module for 1-conductor female connector; with integrated end plate; 4 mm ² ; 1-pole | www.wago.com/769-501/000-016 |
|  | Item no.: 769-502 Center module for 1-conductor female connector; 4 mm ² ; 1-pole | www.wago.com/769-502 |
|  | Item no.: 769-502/000-006 Center module for 1-conductor female connector; 4 mm ² ; 1-pole | www.wago.com/769-502/000-006 |
|  | Item no.: 769-502/000-016 1-conductor center module; codable; can be commoned with miniature adjacent jumpers; 1-pole | www.wago.com/769-502/000-016 |
|  | Item no.: 769-503 End module for 1-conductor female connector; 4 mm ² ; 1-pole | www.wago.com/769-503 |
|  | Item no.: 769-503/000-006 End module for 1-conductor female connector; 4 mm ² ; 1-pole | www.wago.com/769-503/000-006 |
|  | Item no.: 769-503/000-016 End module for 1-conductor female connector; 4 mm ² ; 1-pole | www.wago.com/769-503/000-016 |
|  | Item no.: 769-504 2-conductor base module; with integrated end plate; codable; can be commoned with adjacent jumpers and staggered jumpers; 1-pole | www.wago.com/769-504 |
|  | Item no.: 769-504/000-006 Start module for 2-conductor female connector; with integrated end plate; 4 mm ² ; 1-pole | www.wago.com/769-504/000-006 |
|  | Item no.: 769-504/000-016 Start module for 2-conductor female connector; 4 mm ² ; 1-pole | www.wago.com/769-504/000-016 |
|  | Item no.: 769-505 Center module for 2-conductor female connector; 4 mm ² ; 1-pole | www.wago.com/769-505 |
|  | Item no.: 769-505/000-006 Center module for 2-conductor female connector; 4 mm ² ; 1-pole | www.wago.com/769-505/000-006 |
|  | Item no.: 769-505/000-016 Center module for 2-conductor female connector; 4 mm ² ; 1-pole | www.wago.com/769-505/000-016 |
|  | Item no.: 769-506 2-conductor end module; codable; can be commoned with adjacent jumpers and staggered jumpers; 1-pole | www.wago.com/769-506 |
|  | Item no.: 769-506/000-006 End module for 2-conductor female connector; 4 mm ² ; 1-pole | www.wago.com/769-506/000-006 |











| | | |
|--|---|--|
|  | Item no.: 769-506/000-016 End module for 2-conductor female connector; 4 mm ² ; 1-pole | www.wago.com/769-506/000-016 |
|  | Item no.: 769-512 Start module for 1-conductor female connector; angled; 4 mm ² ; 1-pole | www.wago.com/769-512 |
|  | Item no.: 769-512/000-006 Start module for 1-conductor female connector; angled; 4 mm ² ; 1-pole | www.wago.com/769-512/000-006 |
|  | Item no.: 769-512/000-016 Start module for 1-conductor female connector; angled; 4 mm ² ; 1-pole | www.wago.com/769-512/000-016 |
|  | Item no.: 769-513 Center module for 1-conductor female connector; angled; 4 mm ² ; 1-pole | www.wago.com/769-513 |
|  | Item no.: 769-513/000-006 1-conductor center module; angled; codable; 1-pole | www.wago.com/769-513/000-006 |
|  | Item no.: 769-513/000-016 1-conductor center module; angled; codable; 1-pole | www.wago.com/769-513/000-016 |
|  | Item no.: 769-515 1-conductor end module; angled; codable; 1-pole | www.wago.com/769-515 |
|  | Item no.: 769-515/000-006 1-conductor end module; angled; codable; 1-pole | www.wago.com/769-515/000-006 |
|  | Item no.: 769-515/000-016 1-conductor end module; angled; codable; 1-pole | www.wago.com/769-515/000-016 |

Marking accessories

| | | |
|--|--|--|
|  | Item no.: 2009-145 Mini-WSB Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type | www.wago.com/2009-145 |
|  | Item no.: 2009-145/000-002 Mini-WSB Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type | www.wago.com/2009-145/000-002 |
|  | Item no.: 2009-145/000-005 Mini-WSB Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type | www.wago.com/2009-145/000-005 |
|  | Item no.: 2009-145/000-006 Mini-WSB Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type | www.wago.com/2009-145/000-006 |
|  | Item no.: 2009-145/000-007 Mini-WSB Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type | www.wago.com/2009-145/000-007 |

| | | |
|--|--|--|
|  | <p>Item no.: 2009-145/000-012 Mini-WSB Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type</p> | www.wago.com/2009-145/000-012 |
|  | <p>Item no.: 2009-145/000-023 Mini-WSB Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type</p> | www.wago.com/2009-145/000-023 |
|  | <p>Item no.: 2009-145/000-024 Mini-WSB Inline; on reel; stretchable 5 - 5.2 mm; plain; snap-on type</p> | www.wago.com/2009-145/000-024 |
|  | <p>Item no.: 248-501 Miniature WSB Quick marking system; plain; Marker width 5 mm; 10 strips with 10 markers per card</p> | www.wago.com/248-501 |
|  | <p>Item no.: 248-501/000-002 Mini-WSB marking card; as card; not stretchable; plain; snap-on type</p> | www.wago.com/248-501/000-002 |
|  | <p>Item no.: 248-501/000-005 Mini-WSB marking card; as card; plain; snap-on type</p> | www.wago.com/248-501/000-005 |
|  | <p>Item no.: 248-501/000-006 Mini-WSB marking card; as card; not stretchable; plain; snap-on type</p> | www.wago.com/248-501/000-006 |
|  | <p>Item no.: 248-501/000-007 Mini-WSB marking card; as card; not stretchable; plain; snap-on type</p> | www.wago.com/248-501/000-007 |
|  | <p>Item no.: 248-501/000-012 Mini-WSB marking card; as card; not stretchable; plain; snap-on type</p> | www.wago.com/248-501/000-012 |
|  | <p>Item no.: 248-501/000-017 Mini-WSB marking card; as card; not stretchable; plain; snap-on type</p> | www.wago.com/248-501/000-017 |
|  | <p>Item no.: 248-501/000-023 Mini-WSB marking card; as card; not stretchable; plain; snap-on type</p> | www.wago.com/248-501/000-023 |
|  | <p>Item no.: 248-501/000-024 Mini-WSB marking card; as card; not stretchable; plain; snap-on type</p> | www.wago.com/248-501/000-024 |
| Jumper | | |
|  | <p>Item no.: 249-123 Push-in type wire jumper; insulated; wire length 180 mm; Conductor cross section 0.75 mm²</p> | www.wago.com/249-123 |
|  | <p>Item no.: 249-125 Push-in type wire jumper; insulated; wire length 60 mm; Conductor cross section 0.75 mm²</p> | www.wago.com/249-125 |
|  | <p>Item no.: 249-126 Push-in type wire jumper; insulated; wire length 110 mm; Conductor cross section 0.75 mm²</p> | www.wago.com/249-126 |



| | | |
|---|---|--|
|  | <p>Item no.: 249-127 Push-in type wire jumper; insulated; wire length 250 mm; Conductor cross section 0.75 mm²</p> | www.wago.com/249-127 |
|  | <p>Item no.: 280-402 Adjacent jumper; insulated; IN = IN terminal block</p> | www.wago.com/280-402 |
|  | <p>Item no.: 280-409 Alternate jumper; insulated; IN = IN terminal block</p> | www.wago.com/280-409 |
|  | <p>Item no.: 780-452 Staggered jumper; insulated; from 1 to 2; Spacing: 5 mm; suitable for 2-conductor female plugs</p> | www.wago.com/780-452 |
|  | <p>Item no.: 780-453 Staggered jumper; insulated; from 1 to 3; Spacing: 5 mm; suitable for 2-conductor female plugs</p> | www.wago.com/780-453 |
|  | <p>Item no.: 780-454 Staggered jumper; insulated; from 1 to 4; Spacing: 5 mm; suitable for 2-conductor female plugs</p> | www.wago.com/780-454 |
|  | <p>Item no.: 780-455 Staggered jumper; insulated; from 1 to 5; Spacing: 5 mm; suitable for 2-conductor female plugs</p> | www.wago.com/780-455 |
|  | <p>Item no.: 780-456 Staggered jumper; insulated; from 1 to 6; Spacing: 5 mm; suitable for 2-conductor female plugs</p> | www.wago.com/780-456 |
|  | <p>Item no.: 780-457 Staggered jumper; insulated; from 1 to 7; Spacing: 5 mm; suitable for 2-conductor female plugs</p> | www.wago.com/780-457 |
|  | <p>Item no.: 780-458 Staggered jumper; insulated; from 1 to 8; Spacing: 5 mm; suitable for 2-conductor female plugs</p> | www.wago.com/780-458 |

Downloads

Documentation

Bid Text

| | | | |
|-----------------|--------------|----------------|----------|
| 769-171/000-006 | Oct 18, 2017 | DOC 25.6 kB | Download |
|-----------------|--------------|----------------|----------|

smartDATA

CAD data

| | | |
|-----------------------------|-----|----------|
| 3D Download 769-171/000-006 | URL | Download |
|-----------------------------|-----|----------|

Product family

X-COM

[Learn more about the product family.](#)

[Show all products from the family](#)



Subject to changes.

WAGO Kontakttechnik GmbH & Co. KG

Hansastr. 27

32423 Minden

Phone: +49571 887-0 | Fax: +49571 887-169

Email: info.de@wago.com | Web: www.wago.com

Do you have any questions about our products?

We are always happy to take your call at +49 (571) 887-44222.