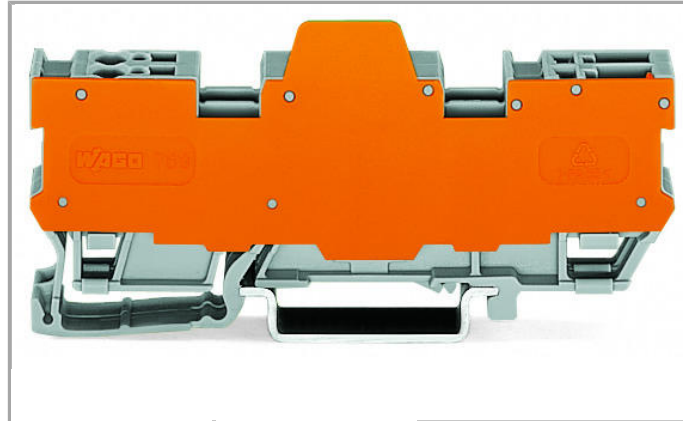


Data sheet | Item number: 769-185/769-314

1-conductor/1-pin terminal block for pluggable modules; 10-pole; with 2 jumper positions; with orange separator plate; for DIN-rail 35 x 15 and 35 x 7.5; 4 mm²

www.wago.com/769-185/769-314



RoHS
Compliant ✓

BOMcheck.net

Color: ■

Data

Electrical data

Ratings per IEC/EN 60664-1

| | |
|---------------------------------|---|
| Rated voltage (III / 3) | 400 V |
| Rated impulse voltage (III / 3) | 6 kV |
| Rated current | 16 A |
| Legend (ratings) | (III / 3) ≙ Overvoltage category III / Pollution degree 3 |

Connection data

| | |
|-----------------------------------|--|
| Connection technology | CAGE CLAMP® |
| Actuation type | Operating tool |
| Connectable conductor materials | Copper Aluminum |
| Nominal cross section | 4 mm ² |
| Solid conductor | 0.08 ... 4 mm ² / 28 ... 12 AWG |
| Fine-stranded conductor | 0.08 ... 4 mm ² / 28 ... 12 AWG |
| Strip length | 8 ... 9 mm / 0.31 ... 0.35 Inch |
| No. of poles | 10 |
| Total number of connection points | 5 |
| Total number of potentials | 10 |
| Number of levels | 1 |

| | |
|----------------|--------------------|
| Type of wiring | Front-entry wiring |
|----------------|--------------------|

Geometrical Data

| | |
|---------------------------------------|----------------------|
| Width | 26.1 mm / 1.028 inch |
| Height from upper-edge of DIN-35 rail | 28.5 mm / 1.122 inch |
| Depth | 87.5 mm / 3.445 inch |

Mechanical data

| | |
|------------------|----------------|
| Design | horizontal |
| Type of mounting | DIN-35 rail |
| Marking level | Center marking |

Material Data




| | |
|---------------------|----------------------|
| Color | gray |
| Insulating material | Polyamide 66 (PA 66) |
| Fire load | 0.908 MJ |
| Weight | 43.754 g |

Commercial data

| | |
|--------------------|-------------------|
| Country of origin | DE |
| GTIN | 4044918934909 |
| Customs Tariff No. | 85369010000 |
| Product Group | 18 (X-COM-System) |

Approvals / Certificates

Country specific Approvals

| Logo | Approval | Certificate name |
|--|---------------------------------------|------------------|
|  | CCA DEKRA Certification B.V. | NTR NL-7626 |
|  | CSA DEKRA Certification B.V. | 1101144 |
|  | KEMA/KEUR DEKRA Certification B.V. | 2190419.01 |

Ship Approvals



| Logo | Approval | Certificate name |
|------|----------|------------------|
| | | |

ABS

ABS
American Bureau of Shipping


14-HG1293677-PDA

UL-Approvals










| Logo | Approval | Certificate name |
|--|--------------------------------------|------------------|
|  | UR Underwriters Laboratories Inc. | E45171 |
|  | UR Underwriters Laboratories Inc. | E45172 |


















Compatible products













tools

| | | |
|--|--|--|
|  | Item no.: 210-720 Operating tool with partially insulated shaft; Type 2, blade (3.5 x 0.5) mm | www.wago.com/210-720 |
|--|--|--|




General accessories















| | | |
|--|--|--|
|  | Item no.: 280-404 Test plug adapter; 5 mm wide; for test plug 210-137 (2.3 mm Ø); suitable for 1.5 mm ² - 4 mm ² tbs | www.wago.com/280-404 |
|  | Item no.: 280-418 Test plug module; modular; suitable for all WAGO 280 and 780 Series rail-mounted terminal blocks with jumper slots in the current bar | www.wago.com/280-418 |
|  | Item no.: 280-419 Spacer module; modular; bridging commoned terminal blocks | www.wago.com/280-419 |
|  | Item no.: 286-113 Empty component plug housing; Type 12; 25 mm wide; 10-pole | www.wago.com/286-113 |
|  | Item no.: 286-336/001-000 Relay module; Nominal input voltage: 24 VDC; 2 break and 2 make contacts; Red status indicator; Module width: 25 mm | www.wago.com/286-336/001-000 |
|  | Item no.: 286-344/004-000 Relay module; Nominal input voltage: 24 VDC; 3 break contacts and 1 make contact; Path; Red status indicator; Module width: 25 mm | www.wago.com/286-344/004-000 |
|  | Item no.: 286-352/004-000 Relay module; Nominal input voltage: 24 VDC; 4 make contacts; Limiting continuous current: 5 A; Path; Red status indicator; Module width: 25 mm | www.wago.com/286-352/004-000 |
|  | Item no.: 286-664 Current flow monitoring module; AC current flow monitoring module; 1 A ... 10 A; adjustable; Relay with 1 changeover contact (1u) | www.wago.com/286-664 |
|  | Item no.: 286-665 Current flow monitoring module; Relay with 1 changeover contact (1u); adjustable | www.wago.com/286-665 |

| | | |
|--|---|--|
|  | Item no.: 286-742 S0 interface power supply; Input voltage: 230 VAC; S0 interface | www.wago.com/286-742 |
|  | Item no.: 286-809 Component module with diode | www.wago.com/286-809 |
|  | Item no.: 286-822 Component module with LED; Red LED; with common cathode | www.wago.com/286-822 |
|  | Item no.: 286-826 AND gate module with 6 inputs | www.wago.com/286-826 |
|  | Item no.: 286-841 Surge suppression module for signal technology; Nominal voltage: 220 VDC; for 2 signal paths with common surge arrester; pluggable on rail-mount terminal block, 25 mm wide | www.wago.com/286-841 |
|  | Item no.: 286-842 Surge suppression module for signal technology; Nominal voltage: 230 VAC; for 2 signal paths with common surge arrester; pluggable on rail-mount terminal block, 25 mm wide | www.wago.com/286-842 |
|  | Item no.: 286-843 Surge suppression module for signal technology; Nominal voltage: 115 VAC; for 2 signal paths with common surge arrester; pluggable on rail-mount terminal block, 25 mm wide | www.wago.com/286-843 |
|  | Item no.: 286-844 Surge suppression module for signal technology; for 2 signal paths with common surge arrester; pluggable on rail-mount terminal block, 25 mm wide | www.wago.com/286-844 |
|  | Item no.: 769-438 Pin cover; with marker slot for miniature WSB | www.wago.com/769-438 |
|  | Item no.: 769-439 Pin cover; with marker slot for miniature WSB | www.wago.com/769-439 |
|  | Item no.: 769-501 Start module for 1-conductor female connector; with integrated end plate; 4 mm ² ; 1-pole | www.wago.com/769-501 |
|  | Item no.: 769-501/000-006 Start module for 1-conductor female connector; 4 mm ² ; 1-pole | www.wago.com/769-501/000-006 |
|  | Item no.: 769-501/000-016 Start module for 1-conductor female connector; with integrated end plate; 4 mm ² ; 1-pole | www.wago.com/769-501/000-016 |
|  | Item no.: 769-502 Center module for 1-conductor female connector; 4 mm ² ; 1-pole | www.wago.com/769-502 |
|  | Item no.: 769-502/000-006 Center module for 1-conductor female connector; 4 mm ² ; 1-pole | www.wago.com/769-502/000-006 |
|  | Item no.: 769-502/000-016 1-conductor center module; codable; can be commoned with miniature adjacent jumpers; 1-pole | www.wago.com/769-502/000-016 |
|  | Item no.: 769-503 End module for 1-conductor female connector; 4 mm ² ; 1-pole | www.wago.com/769-503 |

| | | |
|--|---|--|
|  | <p>Item no.: 769-503/000-006 End module for 1-conductor female connector; 4 mm²; 1-pole</p> | www.wago.com/769-503/000-006 |
|  | <p>Item no.: 769-503/000-016 End module for 1-conductor female connector; 4 mm²; 1-pole</p> | www.wago.com/769-503/000-016 |
|  | <p>Item no.: 769-512 Start module for 1-conductor female connector; angled; 4 mm²; 1-pole</p> | www.wago.com/769-512 |
|  | <p>Item no.: 769-512/000-006 Start module for 1-conductor female connector; angled; 4 mm²; 1-pole</p> | www.wago.com/769-512/000-006 |
|  | <p>Item no.: 769-512/000-016 Start module for 1-conductor female connector; angled; 4 mm²; 1-pole</p> | www.wago.com/769-512/000-016 |
|  | <p>Item no.: 769-513 Center module for 1-conductor female connector; angled; 4 mm²; 1-pole</p> | www.wago.com/769-513 |
|  | <p>Item no.: 769-513/000-006 1-conductor center module; angled; codable; 1-pole</p> | www.wago.com/769-513/000-006 |
|  | <p>Item no.: 769-513/000-016 1-conductor center module; angled; codable; 1-pole</p> | www.wago.com/769-513/000-016 |
|  | <p>Item no.: 769-515 1-conductor end module; angled; codable; 1-pole</p> | www.wago.com/769-515 |
|  | <p>Item no.: 769-515/000-006 1-conductor end module; angled; codable; 1-pole</p> | www.wago.com/769-515/000-006 |
|  | <p>Item no.: 769-515/000-016 1-conductor end module; angled; codable; 1-pole</p> | www.wago.com/769-515/000-016 |
|  | <p>Item no.: 786-103 Empty component plug housing; Type 16; 25 mm wide; 10-pole</p> | www.wago.com/786-103 |

Marking accessories

| | | |
|--|--|--|
|  | <p>Item no.: 2009-145 Mini-WSB Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type</p> | www.wago.com/2009-145 |
|  | <p>Item no.: 2009-145/000-002 Mini-WSB Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type</p> | www.wago.com/2009-145/000-002 |
|  | <p>Item no.: 2009-145/000-005 Mini-WSB Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type</p> | www.wago.com/2009-145/000-005 |

| | | |
|--|---|--|
|  | <p>Item no.: 2009-145/000-006 Mini-WSB Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type</p> | www.wago.com/2009-145/000-006 |
|  | <p>Item no.: 2009-145/000-007 Mini-WSB Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type</p> | www.wago.com/2009-145/000-007 |
|  | <p>Item no.: 2009-145/000-012 Mini-WSB Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type</p> | www.wago.com/2009-145/000-012 |
|  | <p>Item no.: 2009-145/000-023 Mini-WSB Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type</p> | www.wago.com/2009-145/000-023 |
|  | <p>Item no.: 2009-145/000-024 Mini-WSB Inline; on reel; stretchable 5 - 5.2 mm; plain; snap-on type</p> | www.wago.com/2009-145/000-024 |
|  | <p>Item no.: 248-501 Miniature WSB Quick marking system; plain; Marker width 5 mm; 10 strips with 10 markers per card</p> | www.wago.com/248-501 |
|  | <p>Item no.: 248-501/000-002 Mini-WSB marking card; as card; not stretchable; plain; snap-on type</p> | www.wago.com/248-501/000-002 |
|  | <p>Item no.: 248-501/000-005 Mini-WSB marking card; as card; plain; snap-on type</p> | www.wago.com/248-501/000-005 |
|  | <p>Item no.: 248-501/000-006 Mini-WSB marking card; as card; not stretchable; plain; snap-on type</p> | www.wago.com/248-501/000-006 |
|  | <p>Item no.: 248-501/000-007 Mini-WSB marking card; as card; not stretchable; plain; snap-on type</p> | www.wago.com/248-501/000-007 |
|  | <p>Item no.: 248-501/000-012 Mini-WSB marking card; as card; not stretchable; plain; snap-on type</p> | www.wago.com/248-501/000-012 |
|  | <p>Item no.: 248-501/000-017 Mini-WSB marking card; as card; not stretchable; plain; snap-on type</p> | www.wago.com/248-501/000-017 |
|  | <p>Item no.: 248-501/000-023 Mini-WSB marking card; as card; not stretchable; plain; snap-on type</p> | www.wago.com/248-501/000-023 |
|  | <p>Item no.: 248-501/000-024 Mini-WSB marking card; as card; not stretchable; plain; snap-on type</p> | www.wago.com/248-501/000-024 |

Coding


 









Item no.: 769-435



Coding pin; for coding of female plugs; for carrier terminal blocks / male connectors

www.wago.com/769-435



Carrier rail

| | | |
|--|--|--|
|  | Item no.: 210-112 Steel carrier rail; 35 x 7.5 mm; 1 mm thick; 2 m long; slotted; according to EN 60715; "Hole width 25 mm | www.wago.com/210-112 |
|  | Item no.: 210-113 Steel carrier rail; 35 x 7.5 mm; 1 mm thick; 2 m long; unslotted; according to EN 60715 | www.wago.com/210-113 |
|  | Item no.: 210-114 Steel carrier rail; 35 x 15 mm; 1.5 mm thick; 2 m long; unslotted; similar to EN 60715 | www.wago.com/210-114 |
|  | Item no.: 210-115 Steel carrier rail; 35 x 7.5 mm; 1 mm thick; 2 m long; slotted; according to EN 60715; "Hole width 18 mm | www.wago.com/210-115 |
|  | Item no.: 210-118 Steel carrier rail; 35 x 15 mm; 2.3 mm thick; 2 m long; unslotted; according to EN 60715 | www.wago.com/210-118 |
|  | Item no.: 210-196 Aluminum carrier rail; 35 x 8.2 mm; 1.6 mm thick; 2 m long; unslotted; similar to EN 60715 | www.wago.com/210-196 |
|  | Item no.: 210-197 Steel carrier rail; 35 x 15 mm; 1.5 mm thick; 2 m long; slotted; similar to EN 60715 | www.wago.com/210-197 |
|  | Item no.: 210-198 Copper carrier rail; 35 x 15 mm; 2.3 mm thick; 2 m long; unslotted; according to EN 60715 | www.wago.com/210-198 |
|  | Item no.: 210-504 Steel carrier rail; 35 x 7.5 mm; 1 mm thick; 2 m long; slotted; galvanized; according to EN 60715 | www.wago.com/210-504 |
|  | Item no.: 210-505 Steel carrier rail; 35 x 7.5 mm; 1 mm thick; 2 m long; unslotted; galvanized; according to EN 60715 | www.wago.com/210-505 |
|  | Item no.: 210-506 Steel carrier rail; 35 x 15 mm; 1.5 mm thick; 2 m long; unslotted; galvanized; similar to EN 60715 | www.wago.com/210-506 |
|  | Item no.: 210-508 Steel carrier rail; 35 x 15 mm; 1.5 mm thick; 2 m long; slotted; galvanized; similar to EN 60715 | www.wago.com/210-508 |

check

| | | |
|--|--|--|
|  | Item no.: 210-136 Test plug; 2 mm Ø; with 500 mm cable | www.wago.com/210-136 |
|  | Item no.: 210-137 Test plug; 2.3 mm Ø; with 500 mm cable | www.wago.com/210-137 |

Jumper

| | | |
|--|---|--|
|  | Item no.: 249-123 Push-in type wire jumper; insulated; wire length 180 mm; Conductor cross section 0.75 mm ² | www.wago.com/249-123 |
|  | Item no.: 249-125 Push-in type wire jumper; insulated; wire length 60 mm; Conductor cross section 0.75 mm ² | www.wago.com/249-125 |

**Item no.: 249-126**Push-in type wire jumper; insulated; wire length 110 mm; Conductor cross section 0.75 mm²www.wago.com/249-126**Item no.: 249-127**Push-in type wire jumper; insulated; wire length 250 mm; Conductor cross section 0.75 mm²www.wago.com/249-127**Item no.: 280-402**

Adjacent jumper; insulated; IN = IN terminal block

www.wago.com/280-402**Item no.: 280-409**

Alternate jumper; insulated; IN = IN terminal block

www.wago.com/280-409**Item no.: 780-452**

Staggered jumper; insulated; from 1 to 2; Spacing: 5 mm; suitable for 2-conductor female plugs

www.wago.com/780-452**Item no.: 780-453**

Staggered jumper; insulated; from 1 to 3; Spacing: 5 mm; suitable for 2-conductor female plugs

www.wago.com/780-453**Item no.: 780-454**

Staggered jumper; insulated; from 1 to 4; Spacing: 5 mm; suitable for 2-conductor female plugs

www.wago.com/780-454**Item no.: 780-455**

Staggered jumper; insulated; from 1 to 5; Spacing: 5 mm; suitable for 2-conductor female plugs

www.wago.com/780-455**Item no.: 780-456**

Staggered jumper; insulated; from 1 to 6; Spacing: 5 mm; suitable for 2-conductor female plugs

www.wago.com/780-456**Item no.: 780-457**

Staggered jumper; insulated; from 1 to 7; Spacing: 5 mm; suitable for 2-conductor female plugs

www.wago.com/780-457**Item no.: 780-458**

Staggered jumper; insulated; from 1 to 8; Spacing: 5 mm; suitable for 2-conductor female plugs

www.wago.com/780-458

Insulation stop

**Item no.: 769-470**Insulation stop; 0.08 - 0.2 mm² "s" (0.14 mm² "f-st"); 5 pieces/stripwww.wago.com/769-470**Item no.: 769-471**Insulation stop; 0.25 - 0.5 mm²; 5 pieces/stripwww.wago.com/769-471**Item no.: 769-472**Insulation stop; 0.75 - 1 mm²; 5 pieces/stripwww.wago.com/769-472

assembling

**Item no.: 209-106**

Mounting carrier; for isolated mounting on DIN 35 rails

www.wago.com/209-106

Protective Warning Marker

**Item no.: 280-415**

Protective warning marker; with high-voltage symbol, black; for 5 terminal blocks






www.wago.com/280-415

End plate












**Item no.: 769-309**

End and intermediate plate; 1.1 mm thick



www.wago.com/769-309











| | | |
|--|--|--|
|  | Item no.: 769-310 End and intermediate plate; 1.1 mm thick | www.wago.com/769-310 |
|  | Item no.: 769-311 End and intermediate plate; 1.1 mm thick | www.wago.com/769-311 |
|  | Item no.: 769-312 End and intermediate plate; 1.1 mm thick | www.wago.com/769-312 |
|  | Item no.: 769-313 Separator plate; 1.1 mm thick; oversized | www.wago.com/769-313 |
|  | Item no.: 769-314 Separator plate; 1.1 mm thick; oversized | www.wago.com/769-314 |











 

ferrule

| | | |
|--|--|--|
|  | Item no.: 216-101 Ferrule; Sleeve for 0.5 mm ² / AWG 22; uninsulated; electro-tin plated | www.wago.com/216-101 |
|  | Item no.: 216-102 Ferrule; Sleeve for 0.75 mm ² / AWG 20; uninsulated; electro-tin plated | www.wago.com/216-102 |
|  | Item no.: 216-103 Ferrule; Sleeve for 1 mm ² / AWG 18; uninsulated; electro-tin plated | www.wago.com/216-103 |
|  | Item no.: 216-104 Ferrule; Sleeve for 1.5 mm ² / AWG 16; uninsulated; electro-tin plated | www.wago.com/216-104 |
|  | Item no.: 216-201 Ferrule; Sleeve for 0.5 mm ² / AWG 22; insulated; electro-tin plated | www.wago.com/216-201 |
|  | Item no.: 216-202 Ferrule; Sleeve for 0.75 mm ² / AWG 20; insulated; electro-tin plated | www.wago.com/216-202 |
|  | Item no.: 216-203 Ferrule; Sleeve for 1 mm ² / AWG 18; insulated; electro-tin plated | www.wago.com/216-203 |
|  | Item no.: 216-204 Ferrule; Sleeve for 1.5 mm ² / AWG 16; insulated; electro-tin plated | www.wago.com/216-204 |
|  | Item no.: 216-206 Ferrule; Sleeve for 2.5 mm ² / AWG 14; insulated; electro-tin plated | www.wago.com/216-206 |
|  | Item no.: 216-301 Ferrule; Sleeve for 0.25 mm ² / AWG 24; insulated; electro-tin plated | www.wago.com/216-301 |
|  | Item no.: 216-302 Ferrule; Sleeve for 0.34 mm ² / AWG 24; insulated; electro-tin plated | www.wago.com/216-302 |

Female plug

| | | |
|--|---|--|
|  | Item no.: 769-101 1-conductor female plug; 4 mm ² ; 1-pole | www.wago.com/769-101 |
|  | Item no.: 769-101/000-006 1-conductor female plug; 4 mm ² ; 1-pole | www.wago.com/769-101/000-006 |

| | | |
|--|---|--|
|  | Item no.: 769-101/000-016 1-conductor female plug; 4 mm ² ; 1-pole | www.wago.com/769-101/000-016 |
|  | Item no.: 769-101/022-000 1-conductor female plug; angled; 4 mm ² ; 1-pole | www.wago.com/769-101/022-000 |
|  | Item no.: 769-101/022-016 1-conductor female plug; angled; 4 mm ² ; 1-pole | www.wago.com/769-101/022-016 |
|  | Item no.: 769-102 1-conductor female plug; 4 mm ² ; 2-pole | www.wago.com/769-102 |
| | Item no.: 769-102/000-006 1-conductor female plug; 4 mm ² ; 2-pole | www.wago.com/769-102/000-006 |
| | Item no.: 769-102/000-036 1-conductor female plug; 4 mm ² ; 2-pole | www.wago.com/769-102/000-036 |
| | Item no.: 769-102/000-037 1-conductor female plug; 4 mm ² ; 2-pole | www.wago.com/769-102/000-037 |
|  | Item no.: 769-102/022-000 1-conductor female plug; angled; 4 mm ² ; 2-pole | www.wago.com/769-102/022-000 |
| | Item no.: 769-103 1-conductor female plug; 4 mm ² ; 3-pole | www.wago.com/769-103 |
| | Item no.: 769-103/000-006 1-conductor female plug; 4 mm ² ; 3-pole | www.wago.com/769-103/000-006 |
|  | Item no.: 769-103/000-036 1-conductor female plug; 4 mm ² ; 3-pole | www.wago.com/769-103/000-036 |
|  | Item no.: 769-103/000-037 1-conductor female plug; 4 mm ² ; 3-pole | www.wago.com/769-103/000-037 |
|  | Item no.: 769-103/000-038 1-conductor female plug; 4 mm ² ; 3-pole | www.wago.com/769-103/000-038 |
|  | Item no.: 769-103/000-039 1-conductor female plug; 4 mm ² ; 3-pole | www.wago.com/769-103/000-039 |
|  | Item no.: 769-103/022-000 1-conductor female plug; angled; 4 mm ² ; 3-pole | www.wago.com/769-103/022-000 |
| | Item no.: 769-104 | |

| | | |
|--|---|--|
| | 1-conductor female plug; 4 mm ² ; 4-pole | www.wago.com/769-104 |
| | Item no.: 769-104/000-006 1-conductor female plug; 4 mm ² ; 4-pole | www.wago.com/769-104/000-006 |
|  | Item no.: 769-104/000-036 1-conductor female plug; 4 mm ² ; 4-pole | www.wago.com/769-104/000-036 |
|  | Item no.: 769-104/000-037 1-conductor female plug; 4 mm ² ; 4-pole | www.wago.com/769-104/000-037 |
|  | Item no.: 769-104/000-038 1-conductor female plug; 4 mm ² ; 4-pole | www.wago.com/769-104/000-038 |
|  | Item no.: 769-104/000-039 1-conductor female plug; 4 mm ² ; 4-pole | www.wago.com/769-104/000-039 |
|  | Item no.: 769-104/022-000 1-conductor female plug; angled; 4 mm ² ; 4-pole | www.wago.com/769-104/022-000 |
|  | Item no.: 769-105 1-conductor female plug; 4 mm ² ; 5-pole | www.wago.com/769-105 |
|  | Item no.: 769-105/000-006 1-conductor female plug; 4 mm ² ; 5-pole | www.wago.com/769-105/000-006 |
|  | Item no.: 769-105/000-036 1-conductor female plug; 4 mm ² ; 5-pole | www.wago.com/769-105/000-036 |
|  | Item no.: 769-105/000-037 1-conductor female plug; 4 mm ² ; 5-pole | www.wago.com/769-105/000-037 |
|  | Item no.: 769-105/000-038 1-conductor female plug; 4 mm ² ; 5-pole | www.wago.com/769-105/000-038 |
|  | Item no.: 769-105/000-039 1-conductor female plug; 4 mm ² ; 5-pole | www.wago.com/769-105/000-039 |
|  | Item no.: 769-105/022-000 1-conductor female plug; angled; 4 mm ² ; 5-pole | www.wago.com/769-105/022-000 |
| | Item no.: 769-106 1-conductor female plug; 4 mm ² ; 6-pole | www.wago.com/769-106 |
| | Item no.: 769-106/000-006 1-conductor female plug; 4 mm ² ; 6-pole | www.wago.com/769-106/000-006 |



Item no.: 769-106/000-036
1-conductor female plug; 4 mm²; 6-pole

www.wago.com/769-106/000-036



Item no.: 769-106/000-037
1-conductor female plug; 4 mm²; 6-pole

www.wago.com/769-106/000-037



Item no.: 769-106/000-038
1-conductor female plug; 4 mm²; 6-pole

www.wago.com/769-106/000-038



Item no.: 769-106/000-039
1-conductor female plug; 4 mm²; 6-pole

www.wago.com/769-106/000-039

Item no.: 769-106/022-000
1-conductor female plug; angled; 4 mm²; 6-pole

www.wago.com/769-106/022-000

Item no.: 769-107
1-conductor female plug; 4 mm²; 7-pole

www.wago.com/769-107

Item no.: 769-107/000-006
1-conductor female plug; 4 mm²; 7-pole

www.wago.com/769-107/000-006



Item no.: 769-107/000-036
1-conductor female plug; 4 mm²; 7-pole

www.wago.com/769-107/000-036



Item no.: 769-107/000-037
1-conductor female plug; 4 mm²; 7-pole

www.wago.com/769-107/000-037



Item no.: 769-107/000-038
1-conductor female plug; 4 mm²; 7-pole

www.wago.com/769-107/000-038



Item no.: 769-107/000-039
1-conductor female plug; 4 mm²; 7-pole

www.wago.com/769-107/000-039

Item no.: 769-107/022-000
1-conductor female plug; angled; 4 mm²; 7-pole

www.wago.com/769-107/022-000

Item no.: 769-108
1-conductor female plug; 4 mm²; 8-pole





www.wago.com/769-108




Item no.: 769-108/000-006
1-conductor female plug; 4 mm²; 8-pole

www.wago.com/769-108/000-006

Item no.: 769-108/000-036
1-conductor female plug; 4 mm²; 8-pole

www.wago.com/769-108/000-036

| | | |
|--|---|---|
| | <p>Item no.: 769-108/000-037 1-conductor female plug; 4 mm²; 8-pole</p> | <p>www.wago.com/769-108/000-037</p> |
| | <p>Item no.: 769-108/000-038 1-conductor female plug; 4 mm²; 8-pole</p> | <p>www.wago.com/769-108/000-038</p> |
| | <p>Item no.: 769-108/000-039 1-conductor female plug; 4 mm²; 8-pole</p> | <p>www.wago.com/769-108/000-039</p> |
| | <p>Item no.: 769-108/022-000 1-conductor female plug; angled; 4 mm²; 8-pole</p> | <p>www.wago.com/769-108/022-000</p> |
| | <p>Item no.: 769-109 1-conductor female plug; 4 mm²; 9-pole</p> | <p>www.wago.com/769-109</p> |
| | <p>Item no.: 769-109/000-006 1-conductor female plug; 4 mm²; 9-pole</p> | <p>www.wago.com/769-109/000-006</p> |
|  | <p>Item no.: 769-109/000-036 1-conductor female plug; 4 mm²; 9-pole</p> | <p>www.wago.com/769-109/000-036</p> |
|  | <p>Item no.: 769-109/000-037 1-conductor female plug; 4 mm²; 9-pole</p> | <p>www.wago.com/769-109/000-037</p> |
|  | <p>Item no.: 769-109/000-038 1-conductor female plug; 4 mm²; 9-pole</p> | <p>www.wago.com/769-109/000-038</p> |
|  | <p>Item no.: 769-109/000-039 1-conductor female plug; 4 mm²; 9-pole</p> | <p>www.wago.com/769-109/000-039</p> |
| | <p>Item no.: 769-109/022-000 1-conductor female plug; angled; 4 mm²; 9-pole</p> | <p>www.wago.com/769-109/022-000</p> |
| | <p>Item no.: 769-110 1-conductor female plug; 4 mm²; 10-pole</p> | <p>www.wago.com/769-110</p> |
| | <p>Item no.: 769-110/000-006 1-conductor female plug; 4 mm²; 10-pole</p> | <p>www.wago.com/769-110/000-006</p> |
| | <p>Item no.: 769-110/000-036 1-conductor female plug; 4 mm²; 10-pole</p> | <p>www.wago.com/769-110/000-036</p> |
| | <p>Item no.: 769-110/000-037 1-conductor female plug; 4 mm²; 10-pole</p> | <p>www.wago.com/769-110/000-037</p> |

| | | |
|--|--|---|
| <p>Item no.: 769-110/000-038 1-conductor female plug; 4 mm²; 10-pole</p> | <p>www.wago.com/769-110/000-038</p> | |
| <p>Item no.: 769-110/000-039 1-conductor female plug; 4 mm²; 10-pole</p> | <p>www.wago.com/769-110/000-039</p> | |
| <p>Item no.: 769-110/022-000 1-conductor female plug; angled; 4 mm²; 10-pole</p> | <p>www.wago.com/769-110/022-000</p> | |
| <p>Item no.: 769-111 1-conductor female plug; 4 mm²; 11-pole</p> | <p>www.wago.com/769-111</p> | |
| <p>Item no.: 769-111/000-006 1-conductor female plug; 4 mm²; 11-pole</p> | <p>www.wago.com/769-111/000-006</p> | |
| <p>Item no.: 769-111/000-036 1-conductor female plug; 4 mm²; 11-pole</p> | <p>www.wago.com/769-111/000-036</p> | |
| <p>Item no.: 769-111/000-037 1-conductor female plug; 4 mm²; 11-pole</p> | <p>www.wago.com/769-111/000-037</p> | |
| <p>Item no.: 769-111/000-038 1-conductor female plug; 4 mm²; 11-pole</p> | <p>www.wago.com/769-111/000-038</p> | |
| <p>Item no.: 769-111/000-039 1-conductor female plug; 4 mm²; 11-pole</p> | <p>www.wago.com/769-111/000-039</p> | |
| <p>Item no.: 769-111/022-000 1-conductor female plug; angled; 4 mm²; 11-pole</p> | <p>www.wago.com/769-111/022-000</p> | |
| <p>Item no.: 769-112 1-conductor female plug; 4 mm²; 12-pole</p> | <p>www.wago.com/769-112</p> | |
| <p>Item no.: 769-112/000-006 1-conductor female plug; 4 mm²; 12-pole</p> | <p>www.wago.com/769-112/000-006</p> | |
|  | <p>Item no.: 769-112/000-036 1-conductor female plug; 4 mm²; 12-pole</p> | <p>www.wago.com/769-112/000-036</p> |
|  | <p>Item no.: 769-112/000-037 1-conductor female plug; 4 mm²; 12-pole</p> | <p>www.wago.com/769-112/000-037</p> |
|  | <p>Item no.: 769-112/000-038 1-conductor female plug; 4 mm²; 12-pole</p> | <p>www.wago.com/769-112/000-038</p> |



| | |
|--|--|
| Item no.: 769-112/000-039 1-conductor female plug; 4 mm ² ; 12-pole | www.wago.com/769-112/000-039 |
| Item no.: 769-112/022-000 1-conductor female plug; angled; 4 mm ² ; 12-pole | www.wago.com/769-112/022-000 |
| Item no.: 769-113 1-conductor female plug; 4 mm ² ; 13-pole | www.wago.com/769-113 |
| Item no.: 769-113/000-036 1-conductor female plug; 4 mm ² ; 13-pole | www.wago.com/769-113/000-036 |
| Item no.: 769-113/000-037 1-conductor female plug; 4 mm ² ; 13-pole | www.wago.com/769-113/000-037 |
| Item no.: 769-113/000-038 1-conductor female plug; 4 mm ² ; 13-pole | www.wago.com/769-113/000-038 |
| Item no.: 769-113/000-039 1-conductor female plug; 4 mm ² ; 13-pole | www.wago.com/769-113/000-039 |
| Item no.: 769-113/022-000 1-conductor female plug; angled; 4 mm ² ; 13-pole | www.wago.com/769-113/022-000 |
| Item no.: 769-114 1-conductor female plug; 4 mm ² ; 14-pole | www.wago.com/769-114 |
| Item no.: 769-114/000-006 1-conductor female plug; 4 mm ² ; 14-pole | www.wago.com/769-114/000-006 |
| Item no.: 769-114/000-036 1-conductor female plug; 4 mm ² ; 14-pole | www.wago.com/769-114/000-036 |
| Item no.: 769-114/000-037 1-conductor female plug; 4 mm ² ; 14-pole | www.wago.com/769-114/000-037 |
| Item no.: 769-114/000-038 1-conductor female plug; 4 mm ² ; 14-pole | www.wago.com/769-114/000-038 |
| Item no.: 769-114/000-039 1-conductor female plug; 4 mm ² ; 14-pole | www.wago.com/769-114/000-039 |
| Item no.: 769-114/022-000 1-conductor female plug; angled; 4 mm ² ; 14-pole | www.wago.com/769-114/022-000 |



Item no.: 769-115
1-conductor female plug; 4 mm²; 15-pole

www.wago.com/769-115

Item no.: 769-115/000-036
1-conductor female plug; 4 mm²; 15-pole

www.wago.com/769-115/000-036

Item no.: 769-115/000-037
1-conductor female plug; 4 mm²; 15-pole

www.wago.com/769-115/000-037

Item no.: 769-115/000-038
1-conductor female plug; 4 mm²; 15-pole

www.wago.com/769-115/000-038

Item no.: 769-115/000-039
1-conductor female plug; 4 mm²; 15-pole

www.wago.com/769-115/000-039

Item no.: 769-115/022-000
1-conductor female plug; angled; 4 mm²; 15-pole

www.wago.com/769-115/022-000

Downloads

Documentation

Bid Text

| | | | |
|-----------------|--------------|----------------|----------|
| 769-185/769-314 | Oct 18, 2017 | DOC 26.1 kB | Download |
|-----------------|--------------|----------------|----------|

smartDATA

CAD data

| | | |
|-----------------------------|-----|----------|
| 3D Download 769-185/769-314 | URL | Download |
|-----------------------------|-----|----------|

Product family

X-COM

[Learn more about the product family.](#)

[Show all products from the family](#)



Subject to changes.

WAGO Kontakttechnik GmbH & Co. KG
Hansastr. 27
32423 Minden
Phone: +49571 887-0 | Fax: +49571 887-169
Email: info.de@wago.com | Web: www.wago.com

Do you have any questions about our products?
We are always happy to take your call at +49 (571) 887-44222.