



Data sheet | Item number: 769-201

4-pin carrier terminal block; with shield contact; for DIN-rail 35 x 15 and 35 x 7.5; 4 mm²

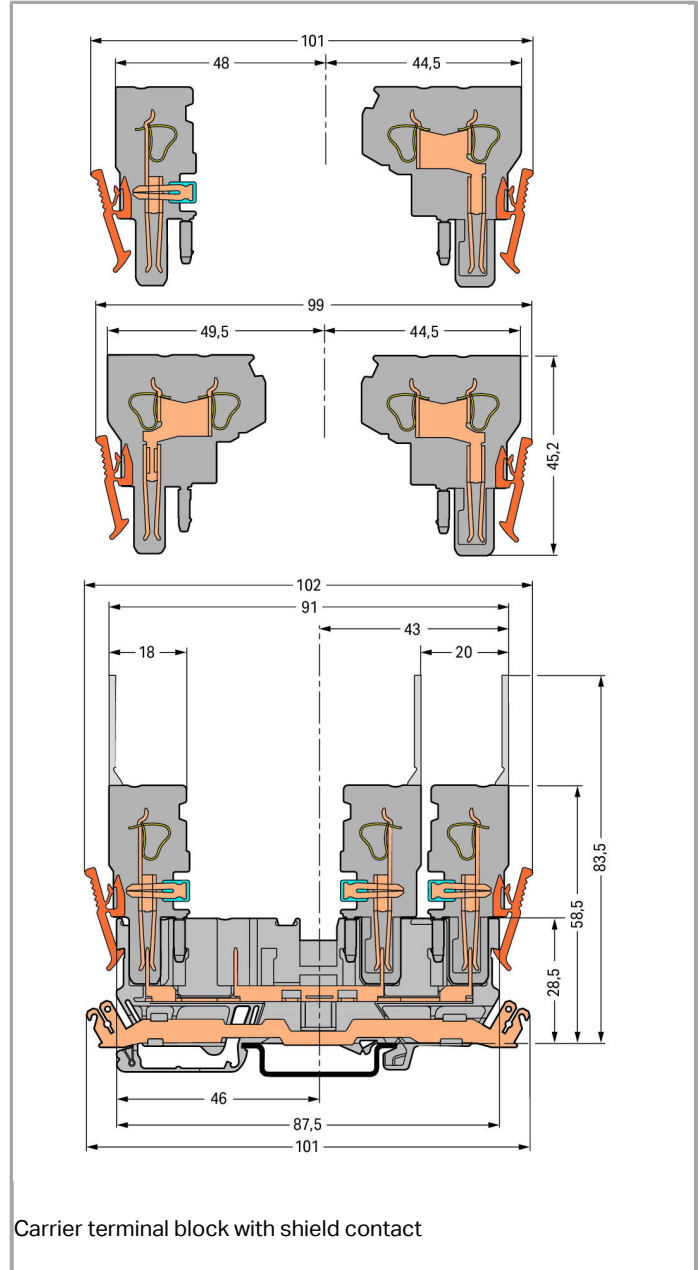

www.wago.com/769-201

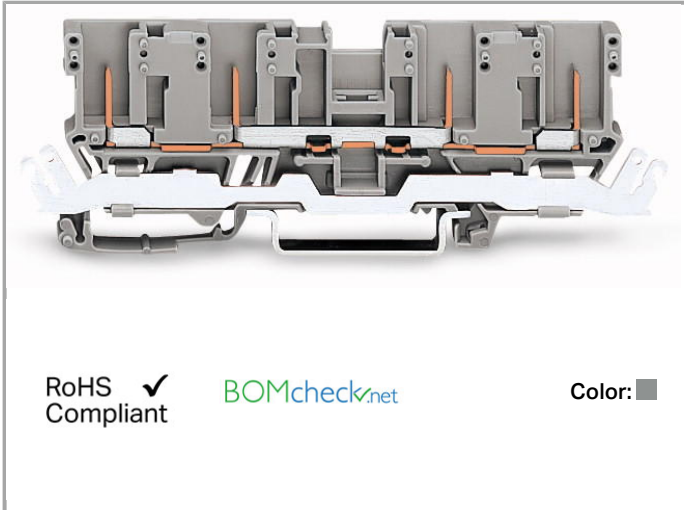

Data

Electrical data

Ratings per IEC/EN 60664-1

Rated voltage (III / 3)

250 V



Rated impulse voltage (III / 3)	4 kV
Rated current	32 A
Legend (ratings)	(III / 3) $\hat{=}$ Overvoltage category III / Pollution degree 3

Connection data

Actuation type	Operating tool
Connectable conductor materials	Copper Aluminum
Total number of potentials	1
Number of levels	1
Type of wiring	Front-entry wiring

Geometrical Data

Width	5 mm / 0.197 inch
Height from upper-edge of DIN-35 rail	28.5 mm / 1.122 inch
Depth	101 mm / 3.976 inch

Mechanical data

Design	horizontal
Type of mounting	DIN-35 rail
Marking level	Center marking

Material Data

Color	gray
Insulating material	Polyamide 66 (PA 66)
Fire load	0.161 MJ
Weight	11.9 g



Commercial data

Country of origin	DE
GTIN	4044918556057
Customs Tariff No.	85369010000
Product Group	18 (X-COM-System)


Approvals / Certificates

Country specific Approvals



Logo	Approval	Certificate name
	CCA DEKRA Certification B.V.	NTR NL-7626

	CSA DEKRA Certification B.V.	1101144
	KEMA/KEUR DEKRA Certification B.V.	2190419.01

Ship Approvals




Logo	Approval	Certificate name
	ABS American Bureau of Shipping	14-HG1293677-PDA
	BV Bureau Veritas S.A.	07436/E0 BV
	LR Lloyds Register	91/20112 (E9)















UL-Approvals

Logo	Approval	Certificate name
	UR Underwriters Laboratories Inc.	E45172
	UR Underwriters Laboratories Inc.	E45171

Compatible products

Marking accessories

	Item no.: 2009-145 Mini-WSB Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type	www.wago.com/2009-145
	Item no.: 2009-145/000-002 Mini-WSB Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type	www.wago.com/2009-145/000-002
	Item no.: 2009-145/000-005 Mini-WSB Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type	www.wago.com/2009-145/000-005

	<p>Item no.: 2009-145/000-006 Mini-WSB Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type</p>	www.wago.com/2009-145/000-006
	<p>Item no.: 2009-145/000-007 Mini-WSB Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type</p>	www.wago.com/2009-145/000-007
	<p>Item no.: 2009-145/000-012 Mini-WSB Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type</p>	www.wago.com/2009-145/000-012
	<p>Item no.: 2009-145/000-023 Mini-WSB Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type</p>	www.wago.com/2009-145/000-023
	<p>Item no.: 2009-145/000-024 Mini-WSB Inline; on reel; stretchable 5 - 5.2 mm; plain; snap-on type</p>	www.wago.com/2009-145/000-024
	<p>Item no.: 248-501 Miniature WSB Quick marking system; plain; Marker width 5 mm; 10 strips with 10 markers per card</p>	www.wago.com/248-501
	<p>Item no.: 248-501/000-002 Mini-WSB marking card; as card; not stretchable; plain; snap-on type</p>	www.wago.com/248-501/000-002
	<p>Item no.: 248-501/000-005 Mini-WSB marking card; as card; plain; snap-on type</p>	www.wago.com/248-501/000-005
	<p>Item no.: 248-501/000-006 Mini-WSB marking card; as card; not stretchable; plain; snap-on type</p>	www.wago.com/248-501/000-006
	<p>Item no.: 248-501/000-007 Mini-WSB marking card; as card; not stretchable; plain; snap-on type</p>	www.wago.com/248-501/000-007
	<p>Item no.: 248-501/000-012 Mini-WSB marking card; as card; not stretchable; plain; snap-on type</p>	www.wago.com/248-501/000-012
	<p>Item no.: 248-501/000-017 Mini-WSB marking card; as card; not stretchable; plain; snap-on type</p>	www.wago.com/248-501/000-017
	<p>Item no.: 248-501/000-023 Mini-WSB marking card; as card; not stretchable; plain; snap-on type</p>	www.wago.com/248-501/000-023
	<p>Item no.: 248-501/000-024 Mini-WSB marking card; as card; not stretchable; plain; snap-on type</p>	www.wago.com/248-501/000-024
















assembling



















Item no.: 209-106
Mounting carrier; for isolated mounting on DIN 35 rails

www.wago.com/209-106

General accessories

	Item no.: 280-404 Test plug adapter; 5 mm wide; for test plug 210-137 (2.3 mm Ø); suitable for 1.5 mm ² - 4 mm ² tbs	www.wago.com/280-404
	Item no.: 280-418 Test plug module; modular; suitable for all WAGO 280 and 780 Series rail-mounted terminal blocks with jumper slots in the current bar	www.wago.com/280-418
	Item no.: 280-419 Spacer module; modular; bridging commoned terminal blocks	www.wago.com/280-419
	Item no.: 769-438 Pin cover; with marker slot for miniature WSB	www.wago.com/769-438
	Item no.: 769-439 Pin cover; with marker slot for miniature WSB	www.wago.com/769-439
	Item no.: 769-501 Start module for 1-conductor female connector; with integrated end plate; 4 mm ² ; 1-pole	www.wago.com/769-501
	Item no.: 769-501/000-006 Start module for 1-conductor female connector; 4 mm ² ; 1-pole	www.wago.com/769-501/000-006
	Item no.: 769-501/000-016 Start module for 1-conductor female connector; with integrated end plate; 4 mm ² ; 1-pole	www.wago.com/769-501/000-016
	Item no.: 769-502 Center module for 1-conductor female connector; 4 mm ² ; 1-pole	www.wago.com/769-502
	Item no.: 769-502/000-006 Center module for 1-conductor female connector; 4 mm ² ; 1-pole	www.wago.com/769-502/000-006
	Item no.: 769-502/000-016 1-conductor center module; codable; can be commoned with miniature adjacent jumpers; 1-pole	www.wago.com/769-502/000-016
	Item no.: 769-503 End module for 1-conductor female connector; 4 mm ² ; 1-pole	www.wago.com/769-503
	Item no.: 769-503/000-006 End module for 1-conductor female connector; 4 mm ² ; 1-pole	www.wago.com/769-503/000-006
	Item no.: 769-503/000-016 End module for 1-conductor female connector; 4 mm ² ; 1-pole	www.wago.com/769-503/000-016
	Item no.: 769-504 2-conductor base module; with integrated end plate; codable; can be commoned with adjacent jumpers and staggered jumpers; 1-pole	www.wago.com/769-504

	Item no.: 769-504/000-006 Start module for 2-conductor female connector; with integrated end plate; 4 mm ² ; 1-pole	www.wago.com/769-504/000-006
	Item no.: 769-504/000-016 Start module for 2-conductor female connector; 4 mm ² ; 1-pole	www.wago.com/769-504/000-016
	Item no.: 769-505 Center module for 2-conductor female connector; 4 mm ² ; 1-pole	www.wago.com/769-505
	Item no.: 769-505/000-006 Center module for 2-conductor female connector; 4 mm ² ; 1-pole	www.wago.com/769-505/000-006
	Item no.: 769-505/000-016 Center module for 2-conductor female connector; 4 mm ² ; 1-pole	www.wago.com/769-505/000-016
	Item no.: 769-506 2-conductor end module; codable; can be commoned with adjacent jumpers and staggered jumpers; 1-pole	www.wago.com/769-506
	Item no.: 769-506/000-006 End module for 2-conductor female connector; 4 mm ² ; 1-pole	www.wago.com/769-506/000-006
	Item no.: 769-506/000-016 End module for 2-conductor female connector; 4 mm ² ; 1-pole	www.wago.com/769-506/000-016
	Item no.: 769-512 Start module for 1-conductor female connector; angled; 4 mm ² ; 1-pole	www.wago.com/769-512
	Item no.: 769-512/000-006 Start module for 1-conductor female connector; angled; 4 mm ² ; 1-pole	www.wago.com/769-512/000-006
	Item no.: 769-512/000-016 Start module for 1-conductor female connector; angled; 4 mm ² ; 1-pole	www.wago.com/769-512/000-016
	Item no.: 769-513 Center module for 1-conductor female connector; angled; 4 mm ² ; 1-pole	www.wago.com/769-513
	Item no.: 769-513/000-006 1-conductor center module; angled; codable; 1-pole	www.wago.com/769-513/000-006
	Item no.: 769-513/000-016 1-conductor center module; angled; codable; 1-pole	www.wago.com/769-513/000-016
	Item no.: 769-515 1-conductor end module; angled; codable; 1-pole	www.wago.com/769-515
	Item no.: 769-515/000-006 1-conductor end module; angled; codable; 1-pole	www.wago.com/769-515/000-006



Item no.: 769-515/000-016
1-conductor end module; angled; codable; 1-pole

www.wago.com/769-515/000-016

Jumper



Item no.: 249-123
Push-in type wire jumper; insulated; wire length 180 mm; Conductor cross section 0.75 mm²

www.wago.com/249-123



Item no.: 249-125
Push-in type wire jumper; insulated; wire length 60 mm; Conductor cross section 0.75 mm²

www.wago.com/249-125



Item no.: 249-126
Push-in type wire jumper; insulated; wire length 110 mm; Conductor cross section 0.75 mm²

www.wago.com/249-126



Item no.: 249-127
Push-in type wire jumper; insulated; wire length 250 mm; Conductor cross section 0.75 mm²

www.wago.com/249-127



Item no.: 280-402
Adjacent jumper; insulated; IN = IN terminal block

www.wago.com/280-402



Item no.: 280-409
Alternate jumper; insulated; IN = IN terminal block

www.wago.com/280-409



Item no.: 780-452
Staggered jumper; insulated; from 1 to 2; Spacing: 5 mm; suitable for 2-conductor female plugs

www.wago.com/780-452



Item no.: 780-453
Staggered jumper; insulated; from 1 to 3; Spacing: 5 mm; suitable for 2-conductor female plugs

www.wago.com/780-453



Item no.: 780-454
Staggered jumper; insulated; from 1 to 4; Spacing: 5 mm; suitable for 2-conductor female plugs

www.wago.com/780-454



Item no.: 780-455
Staggered jumper; insulated; from 1 to 5; Spacing: 5 mm; suitable for 2-conductor female plugs

www.wago.com/780-455



Item no.: 780-456
Staggered jumper; insulated; from 1 to 6; Spacing: 5 mm; suitable for 2-conductor female plugs

www.wago.com/780-456



Item no.: 780-457
Staggered jumper; insulated; from 1 to 7; Spacing: 5 mm; suitable for 2-conductor female plugs

www.wago.com/780-457



Item no.: 780-458
Staggered jumper; insulated; from 1 to 8; Spacing: 5 mm; suitable for 2-conductor female plugs

www.wago.com/780-458

Carrier rail



Item no.: 210-112
Steel carrier rail; 35 x 7.5 mm; 1 mm thick; 2 m long; slotted; according to EN 60715; "Hole width 25 mm

www.wago.com/210-112



Item no.: 210-113
Steel carrier rail; 35 x 7.5 mm; 1 mm thick; 2 m long; unslotted; according to EN 60715

www.wago.com/210-113



 



 




















Item no.: 210-114
Steel carrier rail; 35 x 15 mm; 1.5 mm thick; 2 m long; unslotted; similar to EN 60715

www.wago.com/210-114

Item no.: 210-115
Steel carrier rail; 35 x 7.5 mm; 1 mm thick; 2 m long; slotted; according to EN 60715; "Hole width 18 mm

www.wago.com/210-115

	mm	
	Item no.: 210-118 Steel carrier rail; 35 x 15 mm; 2.3 mm thick; 2 m long; unslotted; according to EN 60715	www.wago.com/210-118
	Item no.: 210-196 Aluminum carrier rail; 35 x 8.2 mm; 1.6 mm thick; 2 m long; unslotted; similar to EN 60715	www.wago.com/210-196
	Item no.: 210-197 Steel carrier rail; 35 x 15 mm; 1.5 mm thick; 2 m long; slotted; similar to EN 60715	www.wago.com/210-197
	Item no.: 210-198 Copper carrier rail; 35 x 15 mm; 2.3 mm thick; 2 m long; unslotted; according to EN 60715	www.wago.com/210-198
	Item no.: 210-504 Steel carrier rail; 35 x 7.5 mm; 1 mm thick; 2 m long; slotted; galvanized; according to EN 60715	www.wago.com/210-504
	Item no.: 210-505 Steel carrier rail; 35 x 7.5 mm; 1 mm thick; 2 m long; unslotted; galvanized; according to EN 60715	www.wago.com/210-505
	Item no.: 210-506 Steel carrier rail; 35 x 15 mm; 1.5 mm thick; 2 m long; unslotted; galvanized; similar to EN 60715	www.wago.com/210-506
	Item no.: 210-508 Steel carrier rail; 35 x 15 mm; 1.5 mm thick; 2 m long; slotted; galvanized; similar to EN 60715	www.wago.com/210-508
End plate		
	Item no.: 769-301 End and intermediate plate; 1.1 mm thick	www.wago.com/769-301
	Item no.: 769-302 End and intermediate plate; 1.1 mm thick	www.wago.com/769-302
Female plug		
	Item no.: 769-101 1-conductor female plug; 4 mm ² ; 1-pole	www.wago.com/769-101
	Item no.: 769-101/000-006 1-conductor female plug; 4 mm ² ; 1-pole	www.wago.com/769-101/000-006
	Item no.: 769-101/000-016 1-conductor female plug; 4 mm ² ; 1-pole	www.wago.com/769-101/000-016
	Item no.: 769-102 1-conductor female plug; 4 mm ² ; 2-pole	www.wago.com/769-102
	Item no.: 769-102/000-006 1-conductor female plug; 4 mm ² ; 2-pole	www.wago.com/769-102/000-006
	Item no.: 769-102/000-036 1-conductor female plug; 4 mm ² ; 2-pole	www.wago.com/769-102/000-036

	Item no.: 769-102/000-037 1-conductor female plug; 4 mm ² ; 2-pole	www.wago.com/769-102/000-037
	Item no.: 769-103 1-conductor female plug; 4 mm ² ; 3-pole	www.wago.com/769-103
	Item no.: 769-103/000-006 1-conductor female plug; 4 mm ² ; 3-pole	www.wago.com/769-103/000-006
	Item no.: 769-103/000-036 1-conductor female plug; 4 mm ² ; 3-pole	www.wago.com/769-103/000-036
	Item no.: 769-103/000-037 1-conductor female plug; 4 mm ² ; 3-pole	www.wago.com/769-103/000-037
	Item no.: 769-103/000-038 1-conductor female plug; 4 mm ² ; 3-pole	www.wago.com/769-103/000-038
	Item no.: 769-103/000-039 1-conductor female plug; 4 mm ² ; 3-pole	www.wago.com/769-103/000-039
	Item no.: 769-104 1-conductor female plug; 4 mm ² ; 4-pole	www.wago.com/769-104
	Item no.: 769-104/000-006 1-conductor female plug; 4 mm ² ; 4-pole	www.wago.com/769-104/000-006
	Item no.: 769-104/000-036 1-conductor female plug; 4 mm ² ; 4-pole	www.wago.com/769-104/000-036
	Item no.: 769-104/000-037 1-conductor female plug; 4 mm ² ; 4-pole	www.wago.com/769-104/000-037
	Item no.: 769-104/000-038 1-conductor female plug; 4 mm ² ; 4-pole	www.wago.com/769-104/000-038
	Item no.: 769-104/000-039 1-conductor female plug; 4 mm ² ; 4-pole	www.wago.com/769-104/000-039
	Item no.: 769-105 1-conductor female plug; 4 mm ² ; 5-pole	www.wago.com/769-105
	Item no.: 769-105/000-006 1-conductor female plug; 4 mm ² ; 5-pole	www.wago.com/769-105/000-006



Item no.: 769-105/000-036
1-conductor female plug; 4 mm²; 5-pole

www.wago.com/769-105/000-036



Item no.: 769-105/000-037
1-conductor female plug; 4 mm²; 5-pole

www.wago.com/769-105/000-037



Item no.: 769-105/000-038
1-conductor female plug; 4 mm²; 5-pole

www.wago.com/769-105/000-038



Item no.: 769-105/000-039
1-conductor female plug; 4 mm²; 5-pole

www.wago.com/769-105/000-039

Item no.: 769-106
1-conductor female plug; 4 mm²; 6-pole

www.wago.com/769-106

Item no.: 769-106/000-006
1-conductor female plug; 4 mm²; 6-pole

www.wago.com/769-106/000-006



Item no.: 769-106/000-036
1-conductor female plug; 4 mm²; 6-pole

www.wago.com/769-106/000-036



Item no.: 769-106/000-037
1-conductor female plug; 4 mm²; 6-pole

www.wago.com/769-106/000-037



Item no.: 769-106/000-038
1-conductor female plug; 4 mm²; 6-pole

www.wago.com/769-106/000-038



Item no.: 769-106/000-039
1-conductor female plug; 4 mm²; 6-pole

www.wago.com/769-106/000-039

Item no.: 769-107
1-conductor female plug; 4 mm²; 7-pole

www.wago.com/769-107

Item no.: 769-107/000-006
1-conductor female plug; 4 mm²; 7-pole

www.wago.com/769-107/000-006



Item no.: 769-107/000-036
1-conductor female plug; 4 mm²; 7-pole

www.wago.com/769-107/000-036



Item no.: 769-107/000-037
1-conductor female plug; 4 mm²; 7-pole

www.wago.com/769-107/000-037



Item no.: 769-107/000-038
1-conductor female plug; 4 mm²; 7-pole

www.wago.com/769-107/000-038



Item no.: 769-107/000-039
1-conductor female plug; 4 mm²; 7-pole

www.wago.com/769-107/000-039

Item no.: 769-108
1-conductor female plug; 4 mm²; 8-pole

www.wago.com/769-108

Item no.: 769-108/000-006
1-conductor female plug; 4 mm²; 8-pole

www.wago.com/769-108/000-006

Item no.: 769-108/000-036
1-conductor female plug; 4 mm²; 8-pole

www.wago.com/769-108/000-036

Item no.: 769-108/000-037
1-conductor female plug; 4 mm²; 8-pole

www.wago.com/769-108/000-037

Item no.: 769-108/000-038
1-conductor female plug; 4 mm²; 8-pole

www.wago.com/769-108/000-038

Item no.: 769-108/000-039
1-conductor female plug; 4 mm²; 8-pole

www.wago.com/769-108/000-039

Item no.: 769-109
1-conductor female plug; 4 mm²; 9-pole

www.wago.com/769-109

Item no.: 769-109/000-006
1-conductor female plug; 4 mm²; 9-pole

www.wago.com/769-109/000-006



Item no.: 769-109/000-036
1-conductor female plug; 4 mm²; 9-pole

www.wago.com/769-109/000-036



Item no.: 769-109/000-037
1-conductor female plug; 4 mm²; 9-pole

www.wago.com/769-109/000-037



Item no.: 769-109/000-038
1-conductor female plug; 4 mm²; 9-pole

www.wago.com/769-109/000-038



Item no.: 769-109/000-039
1-conductor female plug; 4 mm²; 9-pole

www.wago.com/769-109/000-039

Item no.: 769-110
1-conductor female plug; 4 mm²; 10-pole





www.wago.com/769-110

Item no.: 769-110/000-006
1-conductor female plug; 4 mm²; 10-pole

www.wago.com/769-110/000-006

Item no.: 769-110/000-036
1-conductor female plug; 4 mm²; 10-pole

www.wago.com/769-110/000-036

	Item no.: 769-110/000-037 1-conductor female plug; 4 mm ² ; 10-pole	www.wago.com/769-110/000-037
	Item no.: 769-110/000-038 1-conductor female plug; 4 mm ² ; 10-pole	www.wago.com/769-110/000-038
	Item no.: 769-110/000-039 1-conductor female plug; 4 mm ² ; 10-pole	www.wago.com/769-110/000-039
	Item no.: 769-111 1-conductor female plug; 4 mm ² ; 11-pole	www.wago.com/769-111
	Item no.: 769-111/000-006 1-conductor female plug; 4 mm ² ; 11-pole	www.wago.com/769-111/000-006
	Item no.: 769-111/000-036 1-conductor female plug; 4 mm ² ; 11-pole	www.wago.com/769-111/000-036
	Item no.: 769-111/000-037 1-conductor female plug; 4 mm ² ; 11-pole	www.wago.com/769-111/000-037
	Item no.: 769-111/000-038 1-conductor female plug; 4 mm ² ; 11-pole	www.wago.com/769-111/000-038
	Item no.: 769-111/000-039 1-conductor female plug; 4 mm ² ; 11-pole	www.wago.com/769-111/000-039
	Item no.: 769-112 1-conductor female plug; 4 mm ² ; 12-pole	www.wago.com/769-112
	Item no.: 769-112/000-006 1-conductor female plug; 4 mm ² ; 12-pole	www.wago.com/769-112/000-006
	Item no.: 769-112/000-036 1-conductor female plug; 4 mm ² ; 12-pole	www.wago.com/769-112/000-036
	Item no.: 769-112/000-037 1-conductor female plug; 4 mm ² ; 12-pole	www.wago.com/769-112/000-037
	Item no.: 769-112/000-038 1-conductor female plug; 4 mm ² ; 12-pole	www.wago.com/769-112/000-038
	Item no.: 769-112/000-039 1-conductor female plug; 4 mm ² ; 12-pole	www.wago.com/769-112/000-039

**Item no.: 769-113**1-conductor female plug; 4 mm²; 13-polewww.wago.com/769-113**Item no.: 769-113/000-036**1-conductor female plug; 4 mm²; 13-polewww.wago.com/769-113/000-036**Item no.: 769-113/000-037**1-conductor female plug; 4 mm²; 13-polewww.wago.com/769-113/000-037**Item no.: 769-113/000-038**1-conductor female plug; 4 mm²; 13-polewww.wago.com/769-113/000-038**Item no.: 769-113/000-039**1-conductor female plug; 4 mm²; 13-polewww.wago.com/769-113/000-039**Item no.: 769-114**1-conductor female plug; 4 mm²; 14-polewww.wago.com/769-114**Item no.: 769-114/000-006**1-conductor female plug; 4 mm²; 14-polewww.wago.com/769-114/000-006**Item no.: 769-114/000-036**1-conductor female plug; 4 mm²; 14-polewww.wago.com/769-114/000-036**Item no.: 769-114/000-037**1-conductor female plug; 4 mm²; 14-polewww.wago.com/769-114/000-037**Item no.: 769-114/000-038**1-conductor female plug; 4 mm²; 14-polewww.wago.com/769-114/000-038**Item no.: 769-114/000-039**1-conductor female plug; 4 mm²; 14-polewww.wago.com/769-114/000-039**Item no.: 769-115**1-conductor female plug; 4 mm²; 15-polewww.wago.com/769-115**Item no.: 769-115/000-036**1-conductor female plug; 4 mm²; 15-polewww.wago.com/769-115/000-036**Item no.: 769-115/000-037**1-conductor female plug; 4 mm²; 15-polewww.wago.com/769-115/000-037**Item no.: 769-115/000-038**1-conductor female plug; 4 mm²; 15-polewww.wago.com/769-115/000-038

Item no.: 769-115/000-0391-conductor female plug; 4 mm²; 15-polewww.wago.com/769-115/000-039**Item no.: 769-121**2-conductor female connector; 4 mm²; 1-polewww.wago.com/769-121**Item no.: 769-121/000-016**2-conductor female connector; 4 mm²; 1-polewww.wago.com/769-121/000-016**Item no.: 769-122**2-conductor female connector; 4 mm²; 2-polewww.wago.com/769-122**Item no.: 769-123**2-conductor female connector; 4 mm²; 3-polewww.wago.com/769-123**Item no.: 769-124**2-conductor female connector; 4 mm²; 4-polewww.wago.com/769-124**Item no.: 769-125**2-conductor female connector; 4 mm²; 5-polewww.wago.com/769-125**Item no.: 769-126**2-conductor female connector; 4 mm²; 6-polewww.wago.com/769-126**Item no.: 769-127**2-conductor female connector; 4 mm²; 7-polewww.wago.com/769-127**Item no.: 769-128**2-conductor female connector; 4 mm²; 8-polewww.wago.com/769-128**Item no.: 769-129**2-conductor female connector; 4 mm²; 9-polewww.wago.com/769-129**Item no.: 769-130**2-conductor female connector; 4 mm²; 10-polewww.wago.com/769-130**Item no.: 769-131**2-conductor female connector; 4 mm²; 11-polewww.wago.com/769-131**Item no.: 769-132**2-conductor female connector; 4 mm²; 12-polewww.wago.com/769-132**Item no.: 769-133**2-conductor female connector; 4 mm²; 13-polewww.wago.com/769-133**Item no.: 769-134**2-conductor female connector; 4 mm²; 14-polewww.wago.com/769-134**Item no.: 769-135**2-conductor female connector; 4 mm²; 15-polewww.wago.com/769-135**Coding****Item no.: 769-435**

Coding pin; for coding of female plugs; for carrier terminal blocks / male connectors

www.wago.com/769-435

check



Item no.: 210-137
Test plug; 2.3 mm Ø; with 500 mm cable

www.wago.com/210-137

tools



Item no.: 210-720
Operating tool with partially insulated shaft; Type 2, blade (3.5 x 0.5) mm

www.wago.com/210-720

Downloads

Documentation

Bid Text

769-201	Oct 18, 2017	DOC 24.6 kB	Download
---------	--------------	----------------	----------

smartDATA

CAD data

3D Download 769-201	URL	Download
---------------------	-----	----------

Product family

X-COM

[Learn more about the product family.](#)

[Show all products from the family](#)

Subject to changes.