



## Data sheet | Item number: 769-213

1-conductor/1-pin disconnect carrier terminal block; with shield contact; with 2 jumper positions; for DIN-rail 35 x 15 and 35 x 7.5; 4 mm<sup>2</sup>; CAGE CLAMP®

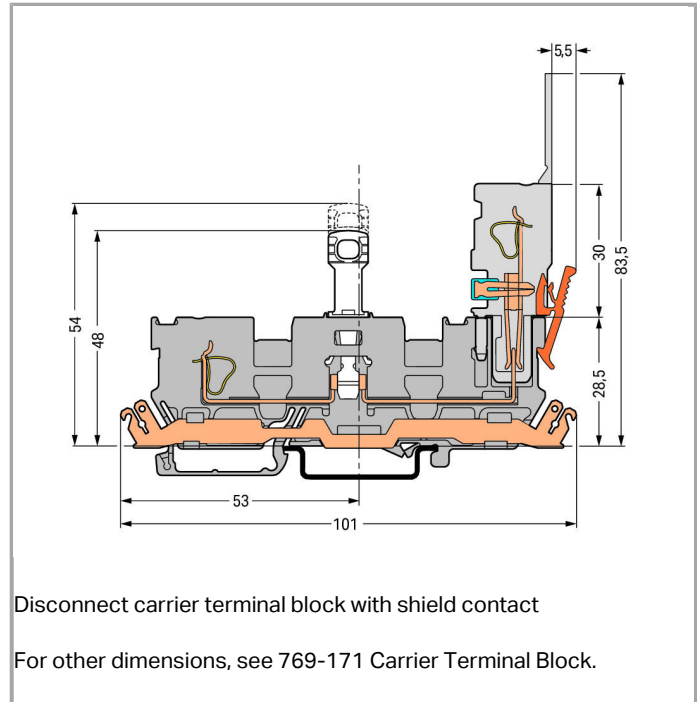

[www.wago.com/769-213](http://www.wago.com/769-213)

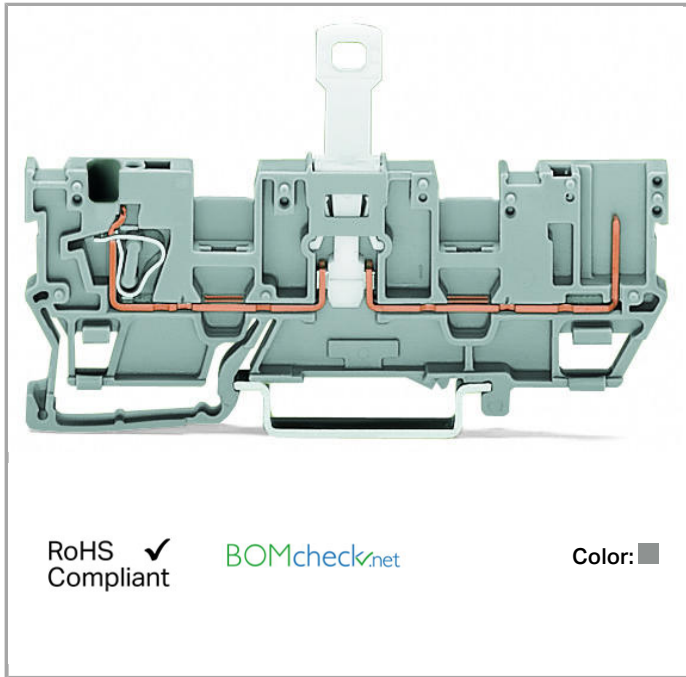

### Data

#### Electrical data

#### Ratings per IEC/EN 60664-1

Rated voltage (III / 3)	250 V
Rated impulse voltage (III / 3)	4 kV
Rated current	16 A
Legend (ratings)	(III / 3) ≙ Overvoltage category III / Pollution degree 3

#### Connection data

Connection technology	CAGE CLAMP®
Actuation type	Operating tool
Connectable conductor materials	Copper Aluminum
Nominal cross section	4 mm <sup>2</sup>
Solid conductor	0.08 ... 4 mm <sup>2</sup> / 28 ... 12 AWG
Fine-stranded conductor	0.08 ... 4 mm <sup>2</sup> / 28 ... 12 AWG
Strip length	8 ... 9 mm / 0.31 ... 0.35 Inch
Total number of connection points	1

Total number of potentials	1
Number of levels	1
Type of wiring	Front-entry wiring

### Geometrical Data

Width	5 mm / 0.197 inch
Height from upper-edge of DIN-35 rail	28.5 mm / 1.122 inch
Depth	101 mm / 3.976 inch

### Mechanical data

Design	horizontal
Type of mounting	DIN-35 rail
Marking level	Center marking

### Material Data




Color	gray
Insulating material	Polyamide 66 (PA 66)
Fire load	0.181 MJ
Weight	11.9 g

### Commercial data



Country of origin	DE
GTIN	4044918934787
Customs Tariff No.	85365080990
Product Group	18 (X-COM-System)

### Approvals / Certificates



#### Country specific Approvals

Logo	Approval	Certificate name
	CCA DEKRA Certification B.V.	NTR NL-7626
	CSA DEKRA Certification B.V.	1101144
	KEMA/KEUR DEKRA Certification B.V.	2190419.01

## Ship Approvals


 


 
 


Logo	Approval	Certificate name
	<b>ABS</b> American Bureau of Shipping	14-HG1293677-PDA
	<b>LR</b> Lloyds Register	91/20112 (E9)


 

 














## UL-Approvals

Logo	Approval	Certificate name
	<b>UR</b> Underwriters Laboratories Inc.	E45171
	<b>UR</b> Underwriters Laboratories Inc.	E45172



## Compatible products

## Carrier rail


	<b>Item no.: 210-112</b> Steel carrier rail; 35 x 7.5 mm; 1 mm thick; 2 m long; slotted; according to EN 60715; "Hole width 25 mm	<a href="http://www.wago.com/210-112">www.wago.com/210-112</a>
	<b>Item no.: 210-113</b> Steel carrier rail; 35 x 7.5 mm; 1 mm thick; 2 m long; unslotted; according to EN 60715	<a href="http://www.wago.com/210-113">www.wago.com/210-113</a>
	<b>Item no.: 210-114</b> Steel carrier rail; 35 x 15 mm; 1.5 mm thick; 2 m long; unslotted; similar to EN 60715	<a href="http://www.wago.com/210-114">www.wago.com/210-114</a>
	<b>Item no.: 210-115</b> Steel carrier rail; 35 x 7.5 mm; 1 mm thick; 2 m long; slotted; according to EN 60715; "Hole width 18 mm	<a href="http://www.wago.com/210-115">www.wago.com/210-115</a>
	<b>Item no.: 210-118</b> Steel carrier rail; 35 x 15 mm; 2.3 mm thick; 2 m long; unslotted; according to EN 60715	<a href="http://www.wago.com/210-118">www.wago.com/210-118</a>
	<b>Item no.: 210-196</b> Aluminum carrier rail; 35 x 8.2 mm; 1.6 mm thick; 2 m long; unslotted; similar to EN 60715	<a href="http://www.wago.com/210-196">www.wago.com/210-196</a>
	<b>Item no.: 210-197</b> Steel carrier rail; 35 x 15 mm; 1.5 mm thick; 2 m long; slotted; similar to EN 60715	<a href="http://www.wago.com/210-197">www.wago.com/210-197</a>
	<b>Item no.: 210-198</b> Copper carrier rail; 35 x 15 mm; 2.3 mm thick; 2 m long; unslotted; according to EN 60715	<a href="http://www.wago.com/210-198">www.wago.com/210-198</a>
	<b>Item no.: 210-504</b>	

	Steel carrier rail; 35 x 7.5 mm; 1 mm thick; 2 m long; slotted; galvanized; according to EN 60715	<a href="http://www.wago.com/210-504">www.wago.com/210-504</a>
	<b>Item no.: 210-505</b> Steel carrier rail; 35 x 7.5 mm; 1 mm thick; 2 m long; unslotted; galvanized; according to EN 60715	<a href="http://www.wago.com/210-505">www.wago.com/210-505</a>
	<b>Item no.: 210-506</b> Steel carrier rail; 35 x 15 mm; 1.5 mm thick; 2 m long; unslotted; galvanized; similar to EN 60715	<a href="http://www.wago.com/210-506">www.wago.com/210-506</a>
	<b>Item no.: 210-508</b> Steel carrier rail; 35 x 15 mm; 1.5 mm thick; 2 m long; slotted; galvanized; similar to EN 60715	<a href="http://www.wago.com/210-508">www.wago.com/210-508</a>
<b>Jumper</b>		
	<b>Item no.: 249-123</b> Push-in type wire jumper; insulated; wire length 180 mm; Conductor cross section 0.75 mm <sup>2</sup>	<a href="http://www.wago.com/249-123">www.wago.com/249-123</a>
	<b>Item no.: 249-125</b> Push-in type wire jumper; insulated; wire length 60 mm; Conductor cross section 0.75 mm <sup>2</sup>	<a href="http://www.wago.com/249-125">www.wago.com/249-125</a>
	<b>Item no.: 249-126</b> Push-in type wire jumper; insulated; wire length 110 mm; Conductor cross section 0.75 mm <sup>2</sup>	<a href="http://www.wago.com/249-126">www.wago.com/249-126</a>
	<b>Item no.: 249-127</b> Push-in type wire jumper; insulated; wire length 250 mm; Conductor cross section 0.75 mm <sup>2</sup>	<a href="http://www.wago.com/249-127">www.wago.com/249-127</a>
	<b>Item no.: 280-402</b> Adjacent jumper; insulated; IN = IN terminal block	<a href="http://www.wago.com/280-402">www.wago.com/280-402</a>
	<b>Item no.: 280-409</b> Alternate jumper; insulated; IN = IN terminal block	<a href="http://www.wago.com/280-409">www.wago.com/280-409</a>
	<b>Item no.: 780-452</b> Staggered jumper; insulated; from 1 to 2; Spacing: 5 mm; suitable for 2-conductor female plugs	<a href="http://www.wago.com/780-452">www.wago.com/780-452</a>
	<b>Item no.: 780-453</b> Staggered jumper; insulated; from 1 to 3; Spacing: 5 mm; suitable for 2-conductor female plugs	<a href="http://www.wago.com/780-453">www.wago.com/780-453</a>
	<b>Item no.: 780-454</b> Staggered jumper; insulated; from 1 to 4; Spacing: 5 mm; suitable for 2-conductor female plugs	<a href="http://www.wago.com/780-454">www.wago.com/780-454</a>
	<b>Item no.: 780-455</b> Staggered jumper; insulated; from 1 to 5; Spacing: 5 mm; suitable for 2-conductor female plugs	<a href="http://www.wago.com/780-455">www.wago.com/780-455</a>
	<b>Item no.: 780-456</b> Staggered jumper; insulated; from 1 to 6; Spacing: 5 mm; suitable for 2-conductor female plugs	<a href="http://www.wago.com/780-456">www.wago.com/780-456</a>
	<b>Item no.: 780-457</b> Staggered jumper; insulated; from 1 to 7; Spacing: 5 mm; suitable for 2-conductor female plugs	<a href="http://www.wago.com/780-457">www.wago.com/780-457</a>
	<b>Item no.: 780-458</b> Staggered jumper; insulated; from 1 to 8; Spacing: 5 mm; suitable for 2-conductor female plugs	<a href="http://www.wago.com/780-458">www.wago.com/780-458</a>
<b>Protective Warning Marker</b>		
	<b>Item no.: 280-415</b> Protective warning marker; with high-voltage symbol, black; for 5 terminal blocks	<a href="http://www.wago.com/280-415">www.wago.com/280-415</a>

## End plate

















	<b>Item no.: 769-311</b> End and intermediate plate; 1.1 mm thick	<a href="http://www.wago.com/769-311">www.wago.com/769-311</a>
	<b>Item no.: 769-312</b> End and intermediate plate; 1.1 mm thick	<a href="http://www.wago.com/769-312">www.wago.com/769-312</a>
	<b>Item no.: 769-314</b> Separator plate; 1.1 mm thick; oversized	<a href="http://www.wago.com/769-314">www.wago.com/769-314</a>

## assembling

	<b>Item no.: 209-106</b> Mounting carrier; for isolated mounting on DIN 35 rails	<a href="http://www.wago.com/209-106">www.wago.com/209-106</a>
--	---	--

## General accessories

	<b>Item no.: 280-404</b> Test plug adapter; 5 mm wide; for test plug 210-137 (2.3 mm Ø); suitable for 1.5 mm <sup>2</sup> - 4 mm <sup>2</sup> tbs	<a href="http://www.wago.com/280-404">www.wago.com/280-404</a>
	<b>Item no.: 280-418</b> Test plug module; modular; suitable for all WAGO 280 and 780 Series rail-mounted terminal blocks with jumper slots in the current bar	<a href="http://www.wago.com/280-418">www.wago.com/280-418</a>
	<b>Item no.: 280-419</b> Spacer module; modular; bridging commoned terminal blocks	<a href="http://www.wago.com/280-419">www.wago.com/280-419</a>
	<b>Item no.: 709-170</b> Disconnect lock; for disconnect tab used on 280/281 and 769 Series disconnect terminal blocks	<a href="http://www.wago.com/709-170">www.wago.com/709-170</a>
	<b>Item no.: 769-438</b> Pin cover; with marker slot for miniature WSB	<a href="http://www.wago.com/769-438">www.wago.com/769-438</a>
	<b>Item no.: 769-439</b> Pin cover; with marker slot for miniature WSB	<a href="http://www.wago.com/769-439">www.wago.com/769-439</a>
	<b>Item no.: 769-501</b> Start module for 1-conductor female connector; with integrated end plate; 4 mm <sup>2</sup> ; 1-pole	<a href="http://www.wago.com/769-501">www.wago.com/769-501</a>
	<b>Item no.: 769-501/000-006</b> Start module for 1-conductor female connector; 4 mm <sup>2</sup> ; 1-pole	<a href="http://www.wago.com/769-501/000-006">www.wago.com/769-501/000-006</a>
	<b>Item no.: 769-501/000-016</b> Start module for 1-conductor female connector; with integrated end plate; 4 mm <sup>2</sup> ; 1-pole	<a href="http://www.wago.com/769-501/000-016">www.wago.com/769-501/000-016</a>
	<b>Item no.: 769-502</b> Center module for 1-conductor female connector; 4 mm <sup>2</sup> ; 1-pole	<a href="http://www.wago.com/769-502">www.wago.com/769-502</a>
	<b>Item no.: 769-502/000-006</b> Center module for 1-conductor female connector; 4 mm <sup>2</sup> ; 1-pole	<a href="http://www.wago.com/769-502/000-006">www.wago.com/769-502/000-006</a>
	<b>Item no.: 769-502/000-016</b> 1-conductor center module; codable; can be commoned with miniature adjacent jumpers; 1-pole	<a href="http://www.wago.com/769-502/000-016">www.wago.com/769-502/000-016</a>

	<b>Item no.: 769-503</b> End module for 1-conductor female connector; 4 mm <sup>2</sup> ; 1-pole	<a href="http://www.wago.com/769-503">www.wago.com/769-503</a>
	<b>Item no.: 769-503/000-006</b> End module for 1-conductor female connector; 4 mm <sup>2</sup> ; 1-pole	<a href="http://www.wago.com/769-503/000-006">www.wago.com/769-503/000-006</a>
	<b>Item no.: 769-503/000-016</b> End module for 1-conductor female connector; 4 mm <sup>2</sup> ; 1-pole	<a href="http://www.wago.com/769-503/000-016">www.wago.com/769-503/000-016</a>
	<b>Item no.: 769-504</b> 2-conductor base module; with integrated end plate; codable; can be commoned with adjacent jumpers and staggered jumpers; 1-pole	<a href="http://www.wago.com/769-504">www.wago.com/769-504</a>
	<b>Item no.: 769-504/000-006</b> Start module for 2-conductor female connector; with integrated end plate; 4 mm <sup>2</sup> ; 1-pole	<a href="http://www.wago.com/769-504/000-006">www.wago.com/769-504/000-006</a>
	<b>Item no.: 769-504/000-016</b> Start module for 2-conductor female connector; 4 mm <sup>2</sup> ; 1-pole	<a href="http://www.wago.com/769-504/000-016">www.wago.com/769-504/000-016</a>
	<b>Item no.: 769-505</b> Center module for 2-conductor female connector; 4 mm <sup>2</sup> ; 1-pole	<a href="http://www.wago.com/769-505">www.wago.com/769-505</a>
	<b>Item no.: 769-505/000-006</b> Center module for 2-conductor female connector; 4 mm <sup>2</sup> ; 1-pole	<a href="http://www.wago.com/769-505/000-006">www.wago.com/769-505/000-006</a>
	<b>Item no.: 769-505/000-016</b> Center module for 2-conductor female connector; 4 mm <sup>2</sup> ; 1-pole	<a href="http://www.wago.com/769-505/000-016">www.wago.com/769-505/000-016</a>
	<b>Item no.: 769-506</b> 2-conductor end module; codable; can be commoned with adjacent jumpers and staggered jumpers; 1-pole	<a href="http://www.wago.com/769-506">www.wago.com/769-506</a>
	<b>Item no.: 769-506/000-006</b> End module for 2-conductor female connector; 4 mm <sup>2</sup> ; 1-pole	<a href="http://www.wago.com/769-506/000-006">www.wago.com/769-506/000-006</a>
	<b>Item no.: 769-506/000-016</b> End module for 2-conductor female connector; 4 mm <sup>2</sup> ; 1-pole	<a href="http://www.wago.com/769-506/000-016">www.wago.com/769-506/000-016</a>
	<b>Item no.: 769-512</b> Start module for 1-conductor female connector; angled; 4 mm <sup>2</sup> ; 1-pole	<a href="http://www.wago.com/769-512">www.wago.com/769-512</a>
	<b>Item no.: 769-512/000-006</b> Start module for 1-conductor female connector; angled; 4 mm <sup>2</sup> ; 1-pole	<a href="http://www.wago.com/769-512/000-006">www.wago.com/769-512/000-006</a>
	<b>Item no.: 769-512/000-016</b> Start module for 1-conductor female connector; angled; 4 mm <sup>2</sup> ; 1-pole	<a href="http://www.wago.com/769-512/000-016">www.wago.com/769-512/000-016</a>
	<b>Item no.: 769-513</b> Center module for 1-conductor female connector; angled; 4 mm <sup>2</sup> ; 1-pole	<a href="http://www.wago.com/769-513">www.wago.com/769-513</a>



**Item no.: 769-513/000-006**  
1-conductor center module; angled; codable; 1-pole

[www.wago.com/769-513/000-006](http://www.wago.com/769-513/000-006)



**Item no.: 769-513/000-016**  
1-conductor center module; angled; codable; 1-pole

[www.wago.com/769-513/000-016](http://www.wago.com/769-513/000-016)



**Item no.: 769-515**  
1-conductor end module; angled; codable; 1-pole

[www.wago.com/769-515](http://www.wago.com/769-515)



**Item no.: 769-515/000-006**  
1-conductor end module; angled; codable; 1-pole

[www.wago.com/769-515/000-006](http://www.wago.com/769-515/000-006)



**Item no.: 769-515/000-016**  
1-conductor end module; angled; codable; 1-pole

[www.wago.com/769-515/000-016](http://www.wago.com/769-515/000-016)

**Female plug**



**Item no.: 769-101**  
1-conductor female plug; 4 mm²; 1-pole

[www.wago.com/769-101](http://www.wago.com/769-101)



**Item no.: 769-101/000-006**  
1-conductor female plug; 4 mm²; 1-pole

[www.wago.com/769-101/000-006](http://www.wago.com/769-101/000-006)



**Item no.: 769-101/000-016**  
1-conductor female plug; 4 mm²; 1-pole

[www.wago.com/769-101/000-016](http://www.wago.com/769-101/000-016)



**Item no.: 769-101/022-000**  
1-conductor female plug; angled; 4 mm²; 1-pole

[www.wago.com/769-101/022-000](http://www.wago.com/769-101/022-000)



**Item no.: 769-101/022-016**  
1-conductor female plug; angled; 4 mm²; 1-pole

[www.wago.com/769-101/022-016](http://www.wago.com/769-101/022-016)



**Item no.: 769-102**  
1-conductor female plug; 4 mm²; 2-pole

[www.wago.com/769-102](http://www.wago.com/769-102)

**Item no.: 769-102/000-006**  
1-conductor female plug; 4 mm²; 2-pole

[www.wago.com/769-102/000-006](http://www.wago.com/769-102/000-006)

**Item no.: 769-102/000-036**  
1-conductor female plug; 4 mm²; 2-pole

[www.wago.com/769-102/000-036](http://www.wago.com/769-102/000-036)



 








**Item no.: 769-102/000-037**  
1-conductor female plug; 4 mm²; 2-pole

[www.wago.com/769-102/000-037](http://www.wago.com/769-102/000-037)



**Item no.: 769-102/022-000**  
1-conductor female plug; angled; 4 mm²; 2-pole

[www.wago.com/769-102/022-000](http://www.wago.com/769-102/022-000)

	<p><b>Item no.: 769-103</b> 1-conductor female plug; 4 mm<sup>2</sup>; 3-pole</p>	<a href="http://www.wago.com/769-103">www.wago.com/769-103</a>
	<p><b>Item no.: 769-103/000-006</b> 1-conductor female plug; 4 mm<sup>2</sup>; 3-pole</p>	<a href="http://www.wago.com/769-103/000-006">www.wago.com/769-103/000-006</a>
	<p><b>Item no.: 769-103/000-036</b> 1-conductor female plug; 4 mm<sup>2</sup>; 3-pole</p>	<a href="http://www.wago.com/769-103/000-036">www.wago.com/769-103/000-036</a>
	<p><b>Item no.: 769-103/000-037</b> 1-conductor female plug; 4 mm<sup>2</sup>; 3-pole</p>	<a href="http://www.wago.com/769-103/000-037">www.wago.com/769-103/000-037</a>
	<p><b>Item no.: 769-103/000-038</b> 1-conductor female plug; 4 mm<sup>2</sup>; 3-pole</p>	<a href="http://www.wago.com/769-103/000-038">www.wago.com/769-103/000-038</a>
	<p><b>Item no.: 769-103/000-039</b> 1-conductor female plug; 4 mm<sup>2</sup>; 3-pole</p>	<a href="http://www.wago.com/769-103/000-039">www.wago.com/769-103/000-039</a>
	<p><b>Item no.: 769-103/022-000</b> 1-conductor female plug; angled; 4 mm<sup>2</sup>; 3-pole</p>	<a href="http://www.wago.com/769-103/022-000">www.wago.com/769-103/022-000</a>
	<p><b>Item no.: 769-104</b> 1-conductor female plug; 4 mm<sup>2</sup>; 4-pole</p>	<a href="http://www.wago.com/769-104">www.wago.com/769-104</a>
	<p><b>Item no.: 769-104/000-006</b> 1-conductor female plug; 4 mm<sup>2</sup>; 4-pole</p>	<a href="http://www.wago.com/769-104/000-006">www.wago.com/769-104/000-006</a>
	<p><b>Item no.: 769-104/000-036</b> 1-conductor female plug; 4 mm<sup>2</sup>; 4-pole</p>	<a href="http://www.wago.com/769-104/000-036">www.wago.com/769-104/000-036</a>
	<p><b>Item no.: 769-104/000-037</b> 1-conductor female plug; 4 mm<sup>2</sup>; 4-pole</p>	<a href="http://www.wago.com/769-104/000-037">www.wago.com/769-104/000-037</a>
	<p><b>Item no.: 769-104/000-038</b> 1-conductor female plug; 4 mm<sup>2</sup>; 4-pole</p>	<a href="http://www.wago.com/769-104/000-038">www.wago.com/769-104/000-038</a>
	<p><b>Item no.: 769-104/000-039</b> 1-conductor female plug; 4 mm<sup>2</sup>; 4-pole</p>	<a href="http://www.wago.com/769-104/000-039">www.wago.com/769-104/000-039</a>
	<p><b>Item no.: 769-104/022-000</b> 1-conductor female plug; angled; 4 mm<sup>2</sup>; 4-pole</p>	<a href="http://www.wago.com/769-104/022-000">www.wago.com/769-104/022-000</a>
	<p><b>Item no.: 769-105</b> 1-conductor female plug; 4 mm<sup>2</sup>; 5-pole</p>	<a href="http://www.wago.com/769-105">www.wago.com/769-105</a>





**Item no.: 769-105/000-006**  
1-conductor female plug; 4 mm<sup>2</sup>; 5-pole

[www.wago.com/769-105/000-006](http://www.wago.com/769-105/000-006)



**Item no.: 769-105/000-036**  
1-conductor female plug; 4 mm<sup>2</sup>; 5-pole

[www.wago.com/769-105/000-036](http://www.wago.com/769-105/000-036)



**Item no.: 769-105/000-037**  
1-conductor female plug; 4 mm<sup>2</sup>; 5-pole

[www.wago.com/769-105/000-037](http://www.wago.com/769-105/000-037)



**Item no.: 769-105/000-038**  
1-conductor female plug; 4 mm<sup>2</sup>; 5-pole

[www.wago.com/769-105/000-038](http://www.wago.com/769-105/000-038)



**Item no.: 769-105/000-039**  
1-conductor female plug; 4 mm<sup>2</sup>; 5-pole

[www.wago.com/769-105/000-039](http://www.wago.com/769-105/000-039)



**Item no.: 769-105/022-000**  
1-conductor female plug; angled; 4 mm<sup>2</sup>; 5-pole

[www.wago.com/769-105/022-000](http://www.wago.com/769-105/022-000)

**Item no.: 769-106**  
1-conductor female plug; 4 mm<sup>2</sup>; 6-pole

[www.wago.com/769-106](http://www.wago.com/769-106)

**Item no.: 769-106/000-006**  
1-conductor female plug; 4 mm<sup>2</sup>; 6-pole

[www.wago.com/769-106/000-006](http://www.wago.com/769-106/000-006)



**Item no.: 769-106/000-036**  
1-conductor female plug; 4 mm<sup>2</sup>; 6-pole

[www.wago.com/769-106/000-036](http://www.wago.com/769-106/000-036)



**Item no.: 769-106/000-037**  
1-conductor female plug; 4 mm<sup>2</sup>; 6-pole

[www.wago.com/769-106/000-037](http://www.wago.com/769-106/000-037)



**Item no.: 769-106/000-038**  
1-conductor female plug; 4 mm<sup>2</sup>; 6-pole

[www.wago.com/769-106/000-038](http://www.wago.com/769-106/000-038)



**Item no.: 769-106/000-039**  
1-conductor female plug; 4 mm<sup>2</sup>; 6-pole

[www.wago.com/769-106/000-039](http://www.wago.com/769-106/000-039)

**Item no.: 769-106/022-000**  
1-conductor female plug; angled; 4 mm<sup>2</sup>; 6-pole

[www.wago.com/769-106/022-000](http://www.wago.com/769-106/022-000)

**Item no.: 769-107**  
1-conductor female plug; 4 mm<sup>2</sup>; 7-pole

[www.wago.com/769-107](http://www.wago.com/769-107)

**Item no.: 769-107/000-006**  
1-conductor female plug; 4 mm<sup>2</sup>; 7-pole

[www.wago.com/769-107/000-006](http://www.wago.com/769-107/000-006)



**Item no.: 769-107/000-036**  
1-conductor female plug; 4 mm<sup>2</sup>; 7-pole

[www.wago.com/769-107/000-036](http://www.wago.com/769-107/000-036)



**Item no.: 769-107/000-037**  
1-conductor female plug; 4 mm<sup>2</sup>; 7-pole

[www.wago.com/769-107/000-037](http://www.wago.com/769-107/000-037)



**Item no.: 769-107/000-038**  
1-conductor female plug; 4 mm<sup>2</sup>; 7-pole

[www.wago.com/769-107/000-038](http://www.wago.com/769-107/000-038)



**Item no.: 769-107/000-039**  
1-conductor female plug; 4 mm<sup>2</sup>; 7-pole

[www.wago.com/769-107/000-039](http://www.wago.com/769-107/000-039)

**Item no.: 769-107/022-000**  
1-conductor female plug; angled; 4 mm<sup>2</sup>; 7-pole

[www.wago.com/769-107/022-000](http://www.wago.com/769-107/022-000)

**Item no.: 769-108**  
1-conductor female plug; 4 mm<sup>2</sup>; 8-pole

[www.wago.com/769-108](http://www.wago.com/769-108)

**Item no.: 769-108/000-006**  
1-conductor female plug; 4 mm<sup>2</sup>; 8-pole

[www.wago.com/769-108/000-006](http://www.wago.com/769-108/000-006)

**Item no.: 769-108/000-036**  
1-conductor female plug; 4 mm<sup>2</sup>; 8-pole

[www.wago.com/769-108/000-036](http://www.wago.com/769-108/000-036)

**Item no.: 769-108/000-037**  
1-conductor female plug; 4 mm<sup>2</sup>; 8-pole

[www.wago.com/769-108/000-037](http://www.wago.com/769-108/000-037)

**Item no.: 769-108/000-038**  
1-conductor female plug; 4 mm<sup>2</sup>; 8-pole

[www.wago.com/769-108/000-038](http://www.wago.com/769-108/000-038)

**Item no.: 769-108/000-039**  
1-conductor female plug; 4 mm<sup>2</sup>; 8-pole

[www.wago.com/769-108/000-039](http://www.wago.com/769-108/000-039)

**Item no.: 769-108/022-000**  
1-conductor female plug; angled; 4 mm<sup>2</sup>; 8-pole

[www.wago.com/769-108/022-000](http://www.wago.com/769-108/022-000)

**Item no.: 769-109**  
1-conductor female plug; 4 mm<sup>2</sup>; 9-pole

[www.wago.com/769-109](http://www.wago.com/769-109)

**Item no.: 769-109/000-006**  
1-conductor female plug; 4 mm<sup>2</sup>; 9-pole

[www.wago.com/769-109/000-006](http://www.wago.com/769-109/000-006)



**Item no.: 769-109/000-036**  
1-conductor female plug; 4 mm<sup>2</sup>; 9-pole

[www.wago.com/769-109/000-036](http://www.wago.com/769-109/000-036)



**Item no.: 769-109/000-037**  
1-conductor female plug; 4 mm<sup>2</sup>; 9-pole

[www.wago.com/769-109/000-037](http://www.wago.com/769-109/000-037)



**Item no.: 769-109/000-038**  
1-conductor female plug; 4 mm<sup>2</sup>; 9-pole

[www.wago.com/769-109/000-038](http://www.wago.com/769-109/000-038)



**Item no.: 769-109/000-039**  
1-conductor female plug; 4 mm<sup>2</sup>; 9-pole

[www.wago.com/769-109/000-039](http://www.wago.com/769-109/000-039)

**Item no.: 769-109/022-000**  
1-conductor female plug; angled; 4 mm<sup>2</sup>; 9-pole

[www.wago.com/769-109/022-000](http://www.wago.com/769-109/022-000)

**Item no.: 769-110**  
1-conductor female plug; 4 mm<sup>2</sup>; 10-pole

[www.wago.com/769-110](http://www.wago.com/769-110)

**Item no.: 769-110/000-006**  
1-conductor female plug; 4 mm<sup>2</sup>; 10-pole

[www.wago.com/769-110/000-006](http://www.wago.com/769-110/000-006)

**Item no.: 769-110/000-036**  
1-conductor female plug; 4 mm<sup>2</sup>; 10-pole

[www.wago.com/769-110/000-036](http://www.wago.com/769-110/000-036)

**Item no.: 769-110/000-037**  
1-conductor female plug; 4 mm<sup>2</sup>; 10-pole

[www.wago.com/769-110/000-037](http://www.wago.com/769-110/000-037)

**Item no.: 769-110/000-038**  
1-conductor female plug; 4 mm<sup>2</sup>; 10-pole

[www.wago.com/769-110/000-038](http://www.wago.com/769-110/000-038)

**Item no.: 769-110/000-039**  
1-conductor female plug; 4 mm<sup>2</sup>; 10-pole

[www.wago.com/769-110/000-039](http://www.wago.com/769-110/000-039)

**Item no.: 769-110/022-000**  
1-conductor female plug; angled; 4 mm<sup>2</sup>; 10-pole

[www.wago.com/769-110/022-000](http://www.wago.com/769-110/022-000)

**Item no.: 769-111**  
1-conductor female plug; 4 mm<sup>2</sup>; 11-pole

[www.wago.com/769-111](http://www.wago.com/769-111)

**Item no.: 769-111/000-006**  
1-conductor female plug; 4 mm<sup>2</sup>; 11-pole

[www.wago.com/769-111/000-006](http://www.wago.com/769-111/000-006)

**Item no.: 769-111/000-036**  
1-conductor female plug; 4 mm<sup>2</sup>; 11-pole

[www.wago.com/769-111/000-036](http://www.wago.com/769-111/000-036)

**Item no.: 769-111/000-037**  
1-conductor female plug; 4 mm<sup>2</sup>; 11-pole

[www.wago.com/769-111/000-037](http://www.wago.com/769-111/000-037)

**Item no.: 769-111/000-038**  
1-conductor female plug; 4 mm<sup>2</sup>; 11-pole

[www.wago.com/769-111/000-038](http://www.wago.com/769-111/000-038)

**Item no.: 769-111/000-039**  
1-conductor female plug; 4 mm<sup>2</sup>; 11-pole

[www.wago.com/769-111/000-039](http://www.wago.com/769-111/000-039)

**Item no.: 769-111/022-000**  
1-conductor female plug; angled; 4 mm<sup>2</sup>; 11-pole

[www.wago.com/769-111/022-000](http://www.wago.com/769-111/022-000)

**Item no.: 769-112**  
1-conductor female plug; 4 mm<sup>2</sup>; 12-pole

[www.wago.com/769-112](http://www.wago.com/769-112)

**Item no.: 769-112/000-006**  
1-conductor female plug; 4 mm<sup>2</sup>; 12-pole

[www.wago.com/769-112/000-006](http://www.wago.com/769-112/000-006)



**Item no.: 769-112/000-036**  
1-conductor female plug; 4 mm<sup>2</sup>; 12-pole

[www.wago.com/769-112/000-036](http://www.wago.com/769-112/000-036)



**Item no.: 769-112/000-037**  
1-conductor female plug; 4 mm<sup>2</sup>; 12-pole

[www.wago.com/769-112/000-037](http://www.wago.com/769-112/000-037)



**Item no.: 769-112/000-038**  
1-conductor female plug; 4 mm<sup>2</sup>; 12-pole

[www.wago.com/769-112/000-038](http://www.wago.com/769-112/000-038)



**Item no.: 769-112/000-039**  
1-conductor female plug; 4 mm<sup>2</sup>; 12-pole

[www.wago.com/769-112/000-039](http://www.wago.com/769-112/000-039)

**Item no.: 769-112/022-000**  
1-conductor female plug; angled; 4 mm<sup>2</sup>; 12-pole

[www.wago.com/769-112/022-000](http://www.wago.com/769-112/022-000)

**Item no.: 769-113**  
1-conductor female plug; 4 mm<sup>2</sup>; 13-pole

[www.wago.com/769-113](http://www.wago.com/769-113)

**Item no.: 769-113/000-036**  
1-conductor female plug; 4 mm<sup>2</sup>; 13-pole

[www.wago.com/769-113/000-036](http://www.wago.com/769-113/000-036)

**Item no.: 769-113/000-037**  
1-conductor female plug; 4 mm<sup>2</sup>; 13-pole

[www.wago.com/769-113/000-037](http://www.wago.com/769-113/000-037)

**Item no.: 769-113/000-038**  
1-conductor female plug; 4 mm<sup>2</sup>; 13-pole

[www.wago.com/769-113/000-038](http://www.wago.com/769-113/000-038)

**Item no.: 769-113/000-039**  
1-conductor female plug; 4 mm<sup>2</sup>; 13-pole

[www.wago.com/769-113/000-039](http://www.wago.com/769-113/000-039)

**Item no.: 769-113/022-000**1-conductor female plug; angled; 4 mm<sup>2</sup>; 13-pole[www.wago.com/769-113/022-000](http://www.wago.com/769-113/022-000)**Item no.: 769-114**1-conductor female plug; 4 mm<sup>2</sup>; 14-pole[www.wago.com/769-114](http://www.wago.com/769-114)**Item no.: 769-114/000-006**1-conductor female plug; 4 mm<sup>2</sup>; 14-pole[www.wago.com/769-114/000-006](http://www.wago.com/769-114/000-006)**Item no.: 769-114/000-036**1-conductor female plug; 4 mm<sup>2</sup>; 14-pole[www.wago.com/769-114/000-036](http://www.wago.com/769-114/000-036)**Item no.: 769-114/000-037**1-conductor female plug; 4 mm<sup>2</sup>; 14-pole[www.wago.com/769-114/000-037](http://www.wago.com/769-114/000-037)**Item no.: 769-114/000-038**1-conductor female plug; 4 mm<sup>2</sup>; 14-pole[www.wago.com/769-114/000-038](http://www.wago.com/769-114/000-038)**Item no.: 769-114/000-039**1-conductor female plug; 4 mm<sup>2</sup>; 14-pole[www.wago.com/769-114/000-039](http://www.wago.com/769-114/000-039)**Item no.: 769-114/022-000**1-conductor female plug; angled; 4 mm<sup>2</sup>; 14-pole[www.wago.com/769-114/022-000](http://www.wago.com/769-114/022-000)**Item no.: 769-115**1-conductor female plug; 4 mm<sup>2</sup>; 15-pole[www.wago.com/769-115](http://www.wago.com/769-115)**Item no.: 769-115/000-036**1-conductor female plug; 4 mm<sup>2</sup>; 15-pole[www.wago.com/769-115/000-036](http://www.wago.com/769-115/000-036)**Item no.: 769-115/000-037**1-conductor female plug; 4 mm<sup>2</sup>; 15-pole[www.wago.com/769-115/000-037](http://www.wago.com/769-115/000-037)**Item no.: 769-115/000-038**1-conductor female plug; 4 mm<sup>2</sup>; 15-pole[www.wago.com/769-115/000-038](http://www.wago.com/769-115/000-038)**Item no.: 769-115/000-039**1-conductor female plug; 4 mm<sup>2</sup>; 15-pole[www.wago.com/769-115/000-039](http://www.wago.com/769-115/000-039)**Item no.: 769-115/022-000**1-conductor female plug; angled; 4 mm<sup>2</sup>; 15-pole[www.wago.com/769-115/022-000](http://www.wago.com/769-115/022-000)**Item no.: 769-121**2-conductor female connector; 4 mm<sup>2</sup>; 1-pole[www.wago.com/769-121](http://www.wago.com/769-121)



**Item no.: 769-121/000-016**  
2-conductor female connector; 4 mm<sup>2</sup>; 1-pole

[www.wago.com/769-121/000-016](http://www.wago.com/769-121/000-016)



**Item no.: 769-122**  
2-conductor female connector; 4 mm<sup>2</sup>; 2-pole

[www.wago.com/769-122](http://www.wago.com/769-122)

**Item no.: 769-123**  
2-conductor female connector; 4 mm<sup>2</sup>; 3-pole

[www.wago.com/769-123](http://www.wago.com/769-123)

**Item no.: 769-124**  
2-conductor female connector; 4 mm<sup>2</sup>; 4-pole

[www.wago.com/769-124](http://www.wago.com/769-124)



**Item no.: 769-125**  
2-conductor female connector; 4 mm<sup>2</sup>; 5-pole

[www.wago.com/769-125](http://www.wago.com/769-125)

**Item no.: 769-126**  
2-conductor female connector; 4 mm<sup>2</sup>; 6-pole

[www.wago.com/769-126](http://www.wago.com/769-126)

**Item no.: 769-127**  
2-conductor female connector; 4 mm<sup>2</sup>; 7-pole

[www.wago.com/769-127](http://www.wago.com/769-127)

**Item no.: 769-128**  
2-conductor female connector; 4 mm<sup>2</sup>; 8-pole

[www.wago.com/769-128](http://www.wago.com/769-128)

**Item no.: 769-129**  
2-conductor female connector; 4 mm<sup>2</sup>; 9-pole

[www.wago.com/769-129](http://www.wago.com/769-129)

**Item no.: 769-130**  
2-conductor female connector; 4 mm<sup>2</sup>; 10-pole

[www.wago.com/769-130](http://www.wago.com/769-130)

**Item no.: 769-131**  
2-conductor female connector; 4 mm<sup>2</sup>; 11-pole

[www.wago.com/769-131](http://www.wago.com/769-131)

**Item no.: 769-132**  
2-conductor female connector; 4 mm<sup>2</sup>; 12-pole

[www.wago.com/769-132](http://www.wago.com/769-132)

**Item no.: 769-133**  
2-conductor female connector; 4 mm<sup>2</sup>; 13-pole

[www.wago.com/769-133](http://www.wago.com/769-133)

**Item no.: 769-134**  
2-conductor female connector; 4 mm<sup>2</sup>; 14-pole

[www.wago.com/769-134](http://www.wago.com/769-134)

**Item no.: 769-135**  
2-conductor female connector; 4 mm<sup>2</sup>; 15-pole

[www.wago.com/769-135](http://www.wago.com/769-135)

#### Marking accessories



**Item no.: 2009-145**  
Mini-WSB Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type

[www.wago.com/2009-145](http://www.wago.com/2009-145)

















**Item no.: 2009-145/000-002**  
Mini-WSB Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type

[www.wago.com/2009-145/000-002](http://www.wago.com/2009-145/000-002)



**Item no.: 2009-145/000-005**  
Mini-WSB Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type

[www.wago.com/2009-145/000-005](http://www.wago.com/2009-145/000-005)

	<p><b>Item no.: 2009-145/000-006</b> Mini-WSB Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type</p>	<a href="http://www.wago.com/2009-145/000-006">www.wago.com/2009-145/000-006</a>
	<p><b>Item no.: 2009-145/000-007</b> Mini-WSB Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type</p>	<a href="http://www.wago.com/2009-145/000-007">www.wago.com/2009-145/000-007</a>
	<p><b>Item no.: 2009-145/000-012</b> Mini-WSB Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type</p>	<a href="http://www.wago.com/2009-145/000-012">www.wago.com/2009-145/000-012</a>
	<p><b>Item no.: 2009-145/000-023</b> Mini-WSB Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type</p>	<a href="http://www.wago.com/2009-145/000-023">www.wago.com/2009-145/000-023</a>
	<p><b>Item no.: 2009-145/000-024</b> Mini-WSB Inline; on reel; stretchable 5 - 5.2 mm; plain; snap-on type</p>	<a href="http://www.wago.com/2009-145/000-024">www.wago.com/2009-145/000-024</a>
	<p><b>Item no.: 248-501</b> Miniature WSB Quick marking system; plain; Marker width 5 mm; 10 strips with 10 markers per card</p>	<a href="http://www.wago.com/248-501">www.wago.com/248-501</a>
	<p><b>Item no.: 248-501/000-002</b> Mini-WSB marking card; as card; not stretchable; plain; snap-on type</p>	<a href="http://www.wago.com/248-501/000-002">www.wago.com/248-501/000-002</a>
	<p><b>Item no.: 248-501/000-005</b> Mini-WSB marking card; as card; plain; snap-on type</p>	<a href="http://www.wago.com/248-501/000-005">www.wago.com/248-501/000-005</a>
	<p><b>Item no.: 248-501/000-006</b> Mini-WSB marking card; as card; not stretchable; plain; snap-on type</p>	<a href="http://www.wago.com/248-501/000-006">www.wago.com/248-501/000-006</a>
	<p><b>Item no.: 248-501/000-007</b> Mini-WSB marking card; as card; not stretchable; plain; snap-on type</p>	<a href="http://www.wago.com/248-501/000-007">www.wago.com/248-501/000-007</a>
	<p><b>Item no.: 248-501/000-012</b> Mini-WSB marking card; as card; not stretchable; plain; snap-on type</p>	<a href="http://www.wago.com/248-501/000-012">www.wago.com/248-501/000-012</a>
	<p><b>Item no.: 248-501/000-017</b> Mini-WSB marking card; as card; not stretchable; plain; snap-on type</p>	<a href="http://www.wago.com/248-501/000-017">www.wago.com/248-501/000-017</a>
	<p><b>Item no.: 248-501/000-023</b> Mini-WSB marking card; as card; not stretchable; plain; snap-on type</p>	<a href="http://www.wago.com/248-501/000-023">www.wago.com/248-501/000-023</a>
	<p><b>Item no.: 248-501/000-024</b> Mini-WSB marking card; as card; not stretchable; plain; snap-on type</p>	<a href="http://www.wago.com/248-501/000-024">www.wago.com/248-501/000-024</a>

**Insulation stop**

	<p><b>Item no.: 769-470</b> Insulation stop; 0.08 - 0.2 mm<sup>2</sup> "s" (0.14 mm<sup>2</sup> "f-st"); 5 pieces/strip</p>	<a href="http://www.wago.com/769-470">www.wago.com/769-470</a>
--	---	--

**Item no.: 769-471**Insulation stop; 0.25 - 0.5 mm<sup>2</sup>; 5 pieces/strip[www.wago.com/769-471](http://www.wago.com/769-471)**Item no.: 769-472**Insulation stop; 0.75 - 1 mm<sup>2</sup>; 5 pieces/strip[www.wago.com/769-472](http://www.wago.com/769-472)

## ferrule

**Item no.: 216-101**Ferrule; Sleeve for 0.5 mm<sup>2</sup> / AWG 22; uninsulated; electro-tin plated[www.wago.com/216-101](http://www.wago.com/216-101)**Item no.: 216-102**Ferrule; Sleeve for 0.75 mm<sup>2</sup> / AWG 20; uninsulated; electro-tin plated[www.wago.com/216-102](http://www.wago.com/216-102)**Item no.: 216-103**Ferrule; Sleeve for 1 mm<sup>2</sup> / AWG 18; uninsulated; electro-tin plated[www.wago.com/216-103](http://www.wago.com/216-103)**Item no.: 216-104**Ferrule; Sleeve for 1.5 mm<sup>2</sup> / AWG 16; uninsulated; electro-tin plated[www.wago.com/216-104](http://www.wago.com/216-104)**Item no.: 216-201**Ferrule; Sleeve for 0.5 mm<sup>2</sup> / AWG 22; insulated; electro-tin plated[www.wago.com/216-201](http://www.wago.com/216-201)**Item no.: 216-202**Ferrule; Sleeve for 0.75 mm<sup>2</sup> / AWG 20; insulated; electro-tin plated[www.wago.com/216-202](http://www.wago.com/216-202)**Item no.: 216-203**Ferrule; Sleeve for 1 mm<sup>2</sup> / AWG 18; insulated; electro-tin plated[www.wago.com/216-203](http://www.wago.com/216-203)**Item no.: 216-204**Ferrule; Sleeve for 1.5 mm<sup>2</sup> / AWG 16; insulated; electro-tin plated[www.wago.com/216-204](http://www.wago.com/216-204)**Item no.: 216-206**Ferrule; Sleeve for 2.5 mm<sup>2</sup> / AWG 14; insulated; electro-tin plated[www.wago.com/216-206](http://www.wago.com/216-206)**Item no.: 216-301**Ferrule; Sleeve for 0.25 mm<sup>2</sup> / AWG 24; insulated; electro-tin plated[www.wago.com/216-301](http://www.wago.com/216-301)**Item no.: 216-302**Ferrule; Sleeve for 0.34 mm<sup>2</sup> / AWG 24; insulated; electro-tin plated[www.wago.com/216-302](http://www.wago.com/216-302)

## tools

**Item no.: 210-720**

Operating tool with partially insulated shaft; Type 2, blade (3.5 x 0.5) mm

[www.wago.com/210-720](http://www.wago.com/210-720)

## check

**Item no.: 210-136**

Test plug; 2 mm Ø; with 500 mm cable

[www.wago.com/210-136](http://www.wago.com/210-136)**Item no.: 210-137**

Test plug; 2.3 mm Ø; with 500 mm cable

[www.wago.com/210-137](http://www.wago.com/210-137)

## Coding





Item no.: 769-435

Coding pin; for coding of female plugs; for carrier terminal blocks / male connectors

[www.wago.com/769-435](http://www.wago.com/769-435)

## Downloads

### Documentation

#### Bid Text

769-213	Oct 18, 2017	DOC 25.1 kB	Download
---------	--------------	----------------	----------

## smartDATA

### CAD data

3D Download 769-213	URL	Download
---------------------	-----	----------

## Product family

### X-COM

[Learn more about the product family.](#)

[Show all products from the family](#)

Subject to changes.

WAGO Kontakttechnik GmbH & Co. KG

Hansastr. 27

32423 Minden

Phone: +49571 887-0 | Fax: +49571 887-169

Email: [info.de@wago.com](mailto:info.de@wago.com) | Web: [www.wago.com](http://www.wago.com)

Do you have any questions about our products?

We are always happy to take your call at +49 (571) 887-44222.