

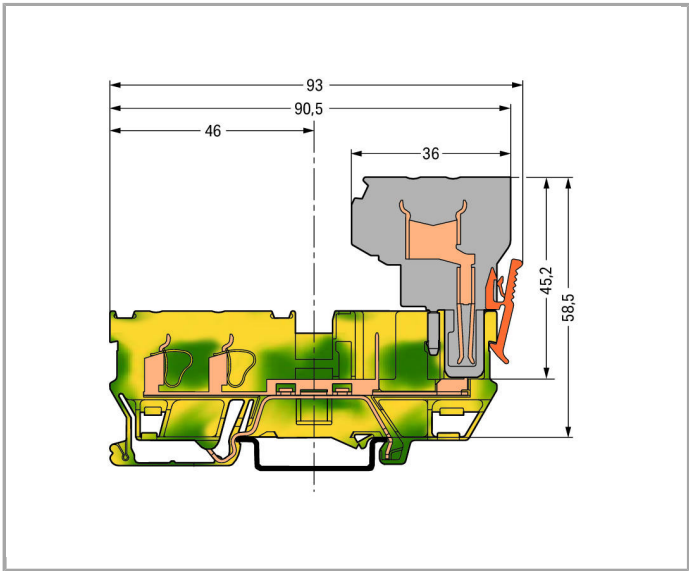


Data sheet | Item number: 769-217
2-conductor/2-pin ground carrier terminal block; for DIN-rail 35 x 15 and 35 x 7.5; 4 mm²; CAGE CLAMP®

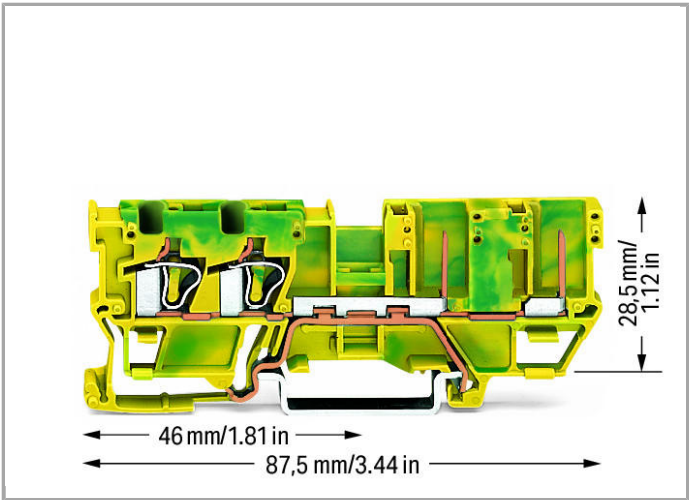

www.wago.com/769-217

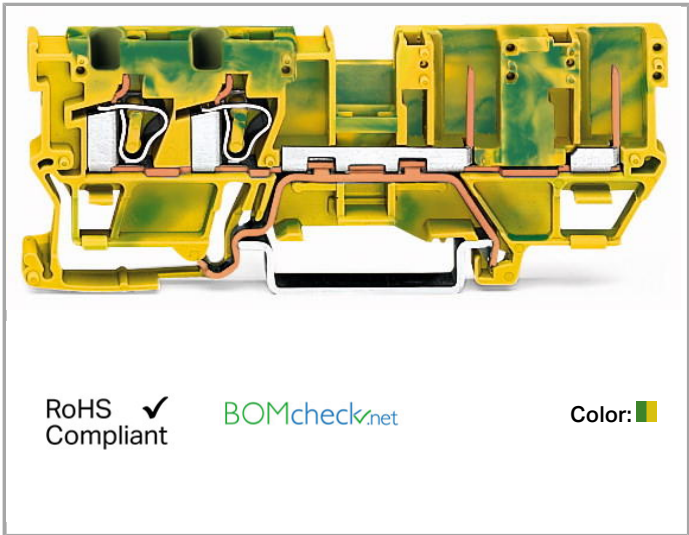

Data
Electrical data

Ratings per IEC/EN 60664-1

Legend (ratings)

(III / 3) ≙ Overvoltage category III / Pollution degree 3

Connection data

Connection technology

CAGE CLAMP®



Actuation type	Operating tool
Connectable conductor materials	Copper Aluminum
Nominal cross section	4 mm ²
Solid conductor	0.08 ... 4 mm ² / 28 ... 12 AWG
Fine-stranded conductor	0.08 ... 4 mm ² / 28 ... 12 AWG
Strip length	8 ... 9 mm / 0.31 ... 0.35 Inch
Total number of connection points	2
Total number of potentials	1
Number of levels	1
Type of wiring	Front-entry wiring

Geometrical Data

Width	5 mm / 0.197 inch
Height from upper-edge of DIN-35 rail	28.5 mm / 1.122 inch
Depth	87.5 mm / 3.445 inch

Mechanical data

Design	horizontal
Type of mounting	DIN-35 rail
Marking level	Center marking

Material Data

Color	green-yellow
Insulating material	Polyamide 66 (PA 66)
Fire load	0.17 MJ
Weight	11.278 g

Commercial data

Country of origin	DE
GTIN	4044918827799
Customs Tariff No.	85369010000
Product Group	18 (X-COM-System)

Approvals / Certificates

Country specific Approvals

Logo	Approval	Certificate name
	CCA DEKRA Certification B.V.	NTR NL-7626



CSA
DEKRA Certification B.V.

1101144



KEMA/KEUR
DEKRA Certification B.V.

2190419.01

Ship Approvals

Logo	Approval	Certificate name
	ABS American Bureau of Shipping	14-HG1293677-PDA
	BV Bureau Veritas S.A.	07436/E0 BV
	LR Lloyds Register	91/20112 (E9)

UL-Approvals

Logo	Approval	Certificate name
	UR Underwriters Laboratories Inc.	E45171
	UR Underwriters Laboratories Inc.	E45172

Compatible products

Female plug

	Item no.: 769-101 1-conductor female plug; 4 mm ² ; 1-pole	www.wago.com/769-101
	Item no.: 769-101/000-006 1-conductor female plug; 4 mm ² ; 1-pole	www.wago.com/769-101/000-006
	Item no.: 769-101/000-016 1-conductor female plug; 4 mm ² ; 1-pole	www.wago.com/769-101/000-016

**Item no.: 769-102**1-conductor female plug; 4 mm²; 2-polewww.wago.com/769-102**Item no.: 769-102/000-006**1-conductor female plug; 4 mm²; 2-polewww.wago.com/769-102/000-006**Item no.: 769-102/000-036**1-conductor female plug; 4 mm²; 2-polewww.wago.com/769-102/000-036**Item no.: 769-102/000-037**1-conductor female plug; 4 mm²; 2-polewww.wago.com/769-102/000-037**Item no.: 769-103**1-conductor female plug; 4 mm²; 3-polewww.wago.com/769-103**Item no.: 769-103/000-006**1-conductor female plug; 4 mm²; 3-polewww.wago.com/769-103/000-006**Item no.: 769-103/000-036**1-conductor female plug; 4 mm²; 3-polewww.wago.com/769-103/000-036**Item no.: 769-103/000-037**1-conductor female plug; 4 mm²; 3-polewww.wago.com/769-103/000-037**Item no.: 769-103/000-038**1-conductor female plug; 4 mm²; 3-polewww.wago.com/769-103/000-038**Item no.: 769-103/000-039**1-conductor female plug; 4 mm²; 3-polewww.wago.com/769-103/000-039**Item no.: 769-104**1-conductor female plug; 4 mm²; 4-polewww.wago.com/769-104**Item no.: 769-104/000-006**1-conductor female plug; 4 mm²; 4-polewww.wago.com/769-104/000-006**Item no.: 769-104/000-036**1-conductor female plug; 4 mm²; 4-polewww.wago.com/769-104/000-036**Item no.: 769-104/000-037**1-conductor female plug; 4 mm²; 4-polewww.wago.com/769-104/000-037**Item no.: 769-104/000-038**1-conductor female plug; 4 mm²; 4-polewww.wago.com/769-104/000-038



Item no.: 769-104/000-039
1-conductor female plug; 4 mm²; 4-pole

www.wago.com/769-104/000-039



Item no.: 769-105
1-conductor female plug; 4 mm²; 5-pole

www.wago.com/769-105



Item no.: 769-105/000-006
1-conductor female plug; 4 mm²; 5-pole

www.wago.com/769-105/000-006



Item no.: 769-105/000-036
1-conductor female plug; 4 mm²; 5-pole

www.wago.com/769-105/000-036



Item no.: 769-105/000-037
1-conductor female plug; 4 mm²; 5-pole

www.wago.com/769-105/000-037



Item no.: 769-105/000-038
1-conductor female plug; 4 mm²; 5-pole

www.wago.com/769-105/000-038



Item no.: 769-105/000-039
1-conductor female plug; 4 mm²; 5-pole

www.wago.com/769-105/000-039

Item no.: 769-106
1-conductor female plug; 4 mm²; 6-pole

www.wago.com/769-106

Item no.: 769-106/000-006
1-conductor female plug; 4 mm²; 6-pole

www.wago.com/769-106/000-006



Item no.: 769-106/000-036
1-conductor female plug; 4 mm²; 6-pole

www.wago.com/769-106/000-036



Item no.: 769-106/000-037
1-conductor female plug; 4 mm²; 6-pole

www.wago.com/769-106/000-037



Item no.: 769-106/000-038
1-conductor female plug; 4 mm²; 6-pole

www.wago.com/769-106/000-038



Item no.: 769-106/000-039
1-conductor female plug; 4 mm²; 6-pole

www.wago.com/769-106/000-039

Item no.: 769-107
1-conductor female plug; 4 mm²; 7-pole

www.wago.com/769-107

Item no.: 769-107/000-006
1-conductor female plug; 4 mm²; 7-pole

www.wago.com/769-107/000-006



Item no.: 769-107/000-036
1-conductor female plug; 4 mm²; 7-pole

www.wago.com/769-107/000-036



Item no.: 769-107/000-037
1-conductor female plug; 4 mm²; 7-pole

www.wago.com/769-107/000-037



Item no.: 769-107/000-038
1-conductor female plug; 4 mm²; 7-pole

www.wago.com/769-107/000-038



Item no.: 769-107/000-039
1-conductor female plug; 4 mm²; 7-pole

www.wago.com/769-107/000-039

Item no.: 769-108
1-conductor female plug; 4 mm²; 8-pole

www.wago.com/769-108

Item no.: 769-108/000-006
1-conductor female plug; 4 mm²; 8-pole

www.wago.com/769-108/000-006

Item no.: 769-108/000-036
1-conductor female plug; 4 mm²; 8-pole

www.wago.com/769-108/000-036

Item no.: 769-108/000-037
1-conductor female plug; 4 mm²; 8-pole

www.wago.com/769-108/000-037

Item no.: 769-108/000-038
1-conductor female plug; 4 mm²; 8-pole

www.wago.com/769-108/000-038

Item no.: 769-108/000-039
1-conductor female plug; 4 mm²; 8-pole

www.wago.com/769-108/000-039

Item no.: 769-109
1-conductor female plug; 4 mm²; 9-pole

www.wago.com/769-109

Item no.: 769-109/000-006
1-conductor female plug; 4 mm²; 9-pole

www.wago.com/769-109/000-006



Item no.: 769-109/000-036
1-conductor female plug; 4 mm²; 9-pole

www.wago.com/769-109/000-036



Item no.: 769-109/000-037
1-conductor female plug; 4 mm²; 9-pole

www.wago.com/769-109/000-037



Item no.: 769-109/000-038
1-conductor female plug; 4 mm²; 9-pole

www.wago.com/769-109/000-038



Item no.: 769-109/000-039
1-conductor female plug; 4 mm²; 9-pole

www.wago.com/769-109/000-039

Item no.: 769-110
1-conductor female plug; 4 mm²; 10-pole

www.wago.com/769-110

Item no.: 769-110/000-006
1-conductor female plug; 4 mm²; 10-pole

www.wago.com/769-110/000-006

Item no.: 769-110/000-036
1-conductor female plug; 4 mm²; 10-pole

www.wago.com/769-110/000-036

Item no.: 769-110/000-037
1-conductor female plug; 4 mm²; 10-pole

www.wago.com/769-110/000-037

Item no.: 769-110/000-038
1-conductor female plug; 4 mm²; 10-pole

www.wago.com/769-110/000-038

Item no.: 769-110/000-039
1-conductor female plug; 4 mm²; 10-pole

www.wago.com/769-110/000-039

Item no.: 769-111
1-conductor female plug; 4 mm²; 11-pole

www.wago.com/769-111

Item no.: 769-111/000-006
1-conductor female plug; 4 mm²; 11-pole

www.wago.com/769-111/000-006

Item no.: 769-111/000-036
1-conductor female plug; 4 mm²; 11-pole

www.wago.com/769-111/000-036

Item no.: 769-111/000-037
1-conductor female plug; 4 mm²; 11-pole

www.wago.com/769-111/000-037

Item no.: 769-111/000-038
1-conductor female plug; 4 mm²; 11-pole

www.wago.com/769-111/000-038

Item no.: 769-111/000-039
1-conductor female plug; 4 mm²; 11-pole

www.wago.com/769-111/000-039

Item no.: 769-112
1-conductor female plug; 4 mm²; 12-pole

www.wago.com/769-112

Item no.: 769-112/000-006
1-conductor female plug; 4 mm²; 12-pole

www.wago.com/769-112/000-006

Item no.: 769-112/000-036
1-conductor female plug; 4 mm²; 12-pole

www.wago.com/769-112/000-036



Item no.: 769-112/000-037
1-conductor female plug; 4 mm²; 12-pole

www.wago.com/769-112/000-037



Item no.: 769-112/000-038
1-conductor female plug; 4 mm²; 12-pole

www.wago.com/769-112/000-038



Item no.: 769-112/000-039
1-conductor female plug; 4 mm²; 12-pole

www.wago.com/769-112/000-039

Item no.: 769-113
1-conductor female plug; 4 mm²; 13-pole

www.wago.com/769-113

Item no.: 769-113/000-036
1-conductor female plug; 4 mm²; 13-pole

www.wago.com/769-113/000-036

Item no.: 769-113/000-037
1-conductor female plug; 4 mm²; 13-pole

www.wago.com/769-113/000-037

Item no.: 769-113/000-038
1-conductor female plug; 4 mm²; 13-pole

www.wago.com/769-113/000-038

Item no.: 769-113/000-039
1-conductor female plug; 4 mm²; 13-pole

www.wago.com/769-113/000-039

Item no.: 769-114
1-conductor female plug; 4 mm²; 14-pole

www.wago.com/769-114

Item no.: 769-114/000-006
1-conductor female plug; 4 mm²; 14-pole

www.wago.com/769-114/000-006

Item no.: 769-114/000-036
1-conductor female plug; 4 mm²; 14-pole

www.wago.com/769-114/000-036

Item no.: 769-114/000-037
1-conductor female plug; 4 mm²; 14-pole

www.wago.com/769-114/000-037

Item no.: 769-114/000-038
1-conductor female plug; 4 mm²; 14-pole

www.wago.com/769-114/000-038

Item no.: 769-114/000-039
1-conductor female plug; 4 mm²; 14-pole

www.wago.com/769-114/000-039

Item no.: 769-115
1-conductor female plug; 4 mm²; 15-pole

www.wago.com/769-115

	Item no.: 769-115/000-036 1-conductor female plug; 4 mm ² ; 15-pole	www.wago.com/769-115/000-036
	Item no.: 769-115/000-037 1-conductor female plug; 4 mm ² ; 15-pole	www.wago.com/769-115/000-037
	Item no.: 769-115/000-038 1-conductor female plug; 4 mm ² ; 15-pole	www.wago.com/769-115/000-038
	Item no.: 769-115/000-039 1-conductor female plug; 4 mm ² ; 15-pole	www.wago.com/769-115/000-039
	Item no.: 769-121 2-conductor female connector; 4 mm ² ; 1-pole	www.wago.com/769-121
	Item no.: 769-121/000-016 2-conductor female connector; 4 mm ² ; 1-pole	www.wago.com/769-121/000-016
	Item no.: 769-122 2-conductor female connector; 4 mm ² ; 2-pole	www.wago.com/769-122
	Item no.: 769-123 2-conductor female connector; 4 mm ² ; 3-pole	www.wago.com/769-123
	Item no.: 769-124 2-conductor female connector; 4 mm ² ; 4-pole	www.wago.com/769-124
	Item no.: 769-125 2-conductor female connector; 4 mm ² ; 5-pole	www.wago.com/769-125
	Item no.: 769-126 2-conductor female connector; 4 mm ² ; 6-pole	www.wago.com/769-126
	Item no.: 769-127 2-conductor female connector; 4 mm ² ; 7-pole	www.wago.com/769-127
	Item no.: 769-128 2-conductor female connector; 4 mm ² ; 8-pole	www.wago.com/769-128
	Item no.: 769-129 2-conductor female connector; 4 mm ² ; 9-pole	www.wago.com/769-129
	Item no.: 769-130 2-conductor female connector; 4 mm ² ; 10-pole	www.wago.com/769-130
	Item no.: 769-131 2-conductor female connector; 4 mm ² ; 11-pole	www.wago.com/769-131
	Item no.: 769-132 2-conductor female connector; 4 mm ² ; 12-pole	www.wago.com/769-132
	Item no.: 769-133 2-conductor female connector; 4 mm ² ; 13-pole	www.wago.com/769-133

Item no.: 769-1342-conductor female connector; 4 mm²; 14-polewww.wago.com/769-134**Item no.: 769-135**2-conductor female connector; 4 mm²; 15-polewww.wago.com/769-135**Marking accessories****Item no.: 2009-145**

Mini-WSB Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type

www.wago.com/2009-145**Item no.: 2009-145/000-002**

Mini-WSB Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type

www.wago.com/2009-145/000-002**Item no.: 2009-145/000-005**

Mini-WSB Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type

www.wago.com/2009-145/000-005**Item no.: 2009-145/000-006**

Mini-WSB Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type

www.wago.com/2009-145/000-006**Item no.: 2009-145/000-007**

Mini-WSB Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type

www.wago.com/2009-145/000-007**Item no.: 2009-145/000-012**

Mini-WSB Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type

www.wago.com/2009-145/000-012**Item no.: 2009-145/000-023**

Mini-WSB Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type

www.wago.com/2009-145/000-023**Item no.: 2009-145/000-024**

Mini-WSB Inline; on reel; stretchable 5 - 5.2 mm; plain; snap-on type

www.wago.com/2009-145/000-024**Item no.: 248-501**

Miniature WSB Quick marking system; plain; Marker width 5 mm; 10 strips with 10 markers per card

www.wago.com/248-501**Item no.: 248-501/000-002**

Mini-WSB marking card; as card; not stretchable; plain; snap-on type

www.wago.com/248-501/000-002**Item no.: 248-501/000-005**

Mini-WSB marking card; as card; plain; snap-on type

www.wago.com/248-501/000-005**Item no.: 248-501/000-006**

Mini-WSB marking card; as card; not stretchable; plain; snap-on type

www.wago.com/248-501/000-006**Item no.: 248-501/000-007**

Mini-WSB marking card; as card; not stretchable; plain; snap-on type

www.wago.com/248-501/000-007

**Item no.: 248-501/000-012**

Mini-WSB marking card; as card; not stretchable; plain; snap-on type

www.wago.com/248-501/000-012**Item no.: 248-501/000-017**

Mini-WSB marking card; as card; not stretchable; plain; snap-on type

www.wago.com/248-501/000-017**Item no.: 248-501/000-023**

Mini-WSB marking card; as card; not stretchable; plain; snap-on type

www.wago.com/248-501/000-023**Item no.: 248-501/000-024**

Mini-WSB marking card; as card; not stretchable; plain; snap-on type

www.wago.com/248-501/000-024**Protective Warning Marker****Item no.: 280-415**

Protective warning marker; with high-voltage symbol, black; for 5 terminal blocks

www.wago.com/280-415**tools****Item no.: 210-720**

Operating tool with partially insulated shaft; Type 2, blade (3.5 x 0.5) mm

www.wago.com/210-720**Insulation stop****Item no.: 769-470**Insulation stop; 0.08 - 0.2 mm² "s" (0.14 mm² "f-st"); 5 pieces/stripwww.wago.com/769-470**Item no.: 769-471**Insulation stop; 0.25 - 0.5 mm²; 5 pieces/stripwww.wago.com/769-471**Item no.: 769-472**Insulation stop; 0.75 - 1 mm²; 5 pieces/stripwww.wago.com/769-472**assembling****Item no.: 209-106**

Mounting carrier; for isolated mounting on DIN 35 rails

www.wago.com/209-106**ferrule****Item no.: 216-101**Ferrule; Sleeve for 0.5 mm² / AWG 22; uninsulated; electro-tin platedwww.wago.com/216-101**Item no.: 216-102**Ferrule; Sleeve for 0.75 mm² / AWG 20; uninsulated; electro-tin platedwww.wago.com/216-102**Item no.: 216-103**Ferrule; Sleeve for 1 mm² / AWG 18; uninsulated; electro-tin platedwww.wago.com/216-103**Item no.: 216-104**Ferrule; Sleeve for 1.5 mm² / AWG 16; uninsulated; electro-tin platedwww.wago.com/216-104**Item no.: 216-201**Ferrule; Sleeve for 0.5 mm² / AWG 22; insulated; electro-tin platedwww.wago.com/216-201



Item no.: 216-202
Ferrule; Sleeve for 0.75 mm² / AWG 20; insulated; electro-tin plated

www.wago.com/216-202



Item no.: 216-203
Ferrule; Sleeve for 1 mm² / AWG 18; insulated; electro-tin plated

www.wago.com/216-203



Item no.: 216-204
Ferrule; Sleeve for 1.5 mm² / AWG 16; insulated; electro-tin plated

www.wago.com/216-204



Item no.: 216-206
Ferrule; Sleeve for 2.5 mm² / AWG 14; insulated; electro-tin plated

www.wago.com/216-206



Item no.: 216-301
Ferrule; Sleeve for 0.25 mm² / AWG 24; insulated; electro-tin plated

www.wago.com/216-301



Item no.: 216-302
Ferrule; Sleeve for 0.34 mm² / AWG 24; insulated; electro-tin plated

www.wago.com/216-302

Coding



Item no.: 769-435
Coding pin; for coding of female plugs; for carrier terminal blocks / male connectors

www.wago.com/769-435

End plate



Item no.: 769-303
End and intermediate plate; 1.1 mm thick

www.wago.com/769-303



Item no.: 769-304
End and intermediate plate; 1.1 mm thick

www.wago.com/769-304

Jumper



Item no.: 249-123
Push-in type wire jumper; insulated; wire length 180 mm; Conductor cross section 0.75 mm²

www.wago.com/249-123



Item no.: 249-125
Push-in type wire jumper; insulated; wire length 60 mm; Conductor cross section 0.75 mm²

www.wago.com/249-125



Item no.: 249-126
Push-in type wire jumper; insulated; wire length 110 mm; Conductor cross section 0.75 mm²

www.wago.com/249-126



Item no.: 249-127
Push-in type wire jumper; insulated; wire length 250 mm; Conductor cross section 0.75 mm²

www.wago.com/249-127



Item no.: 280-402
Adjacent jumper; insulated; IN = IN terminal block

www.wago.com/280-402



Item no.: 280-409
Alternate jumper; insulated; IN = IN terminal block

www.wago.com/280-409



Item no.: 280-422
Adjacent jumper; insulated; IN = IN terminal block

www.wago.com/280-422



Item no.: 780-452
Staggered jumper; insulated; from 1 to 2; Spacing: 5 mm; suitable for 2-conductor female plugs

www.wago.com/780-452

**Item no.: 780-453**

Staggered jumper; insulated; from 1 to 3; Spacing: 5 mm; suitable for 2-conductor female plugs

www.wago.com/780-453**Item no.: 780-454**

Staggered jumper; insulated; from 1 to 4; Spacing: 5 mm; suitable for 2-conductor female plugs

www.wago.com/780-454**Item no.: 780-455**

Staggered jumper; insulated; from 1 to 5; Spacing: 5 mm; suitable for 2-conductor female plugs

www.wago.com/780-455**Item no.: 780-456**

Staggered jumper; insulated; from 1 to 6; Spacing: 5 mm; suitable for 2-conductor female plugs

www.wago.com/780-456**Item no.: 780-457**

Staggered jumper; insulated; from 1 to 7; Spacing: 5 mm; suitable for 2-conductor female plugs

www.wago.com/780-457**Item no.: 780-458**

Staggered jumper; insulated; from 1 to 8; Spacing: 5 mm; suitable for 2-conductor female plugs

www.wago.com/780-458**Carrier rail****Item no.: 210-112**

Steel carrier rail; 35 x 7.5 mm; 1 mm thick; 2 m long; slotted; according to EN 60715; "Hole width 25 mm

www.wago.com/210-112**Item no.: 210-113**

Steel carrier rail; 35 x 7.5 mm; 1 mm thick; 2 m long; unslotted; according to EN 60715

www.wago.com/210-113**Item no.: 210-114**

 
Steel carrier rail; 35 x 15 mm; 1.5 mm thick; 2 m long; unslotted; similar to EN 60715

www.wago.com/210-114**Item no.: 210-115**

Steel carrier rail; 35 x 7.5 mm; 1 mm thick; 2 m long; slotted; according to EN 60715; "Hole width 18 mm

www.wago.com/210-115**Item no.: 210-118**

Steel carrier rail; 35 x 15 mm; 2.3 mm thick; 2 m long; unslotted; according to EN 60715

www.wago.com/210-118**Item no.: 210-196**

Aluminum carrier rail; 35 x 8.2 mm; 1.6 mm thick; 2 m long; unslotted; similar to EN 60715

www.wago.com/210-196**Item no.: 210-197**

 
Steel carrier rail; 35 x 15 mm; 1.5 mm thick; 2 m long; slotted; similar to EN 60715

www.wago.com/210-197**Item no.: 210-198**

Copper carrier rail; 35 x 15 mm; 2.3 mm thick; 2 m long; unslotted; according to EN 60715

www.wago.com/210-198**Item no.: 210-504**

Steel carrier rail; 35 x 7.5 mm; 1 mm thick; 2 m long; slotted; galvanized; according to EN 60715

www.wago.com/210-504**Item no.: 210-505**

Steel carrier rail; 35 x 7.5 mm; 1 mm thick; 2 m long; unslotted; galvanized; according to EN 60715

www.wago.com/210-505**Item no.: 210-506**

Steel carrier rail; 35 x 15 mm; 1.5 mm thick; 2 m long; unslotted; galvanized; similar to EN 60715

www.wago.com/210-506**Item no.: 210-508**

Steel carrier rail; 35 x 15 mm; 1.5 mm thick; 2 m long; slotted; galvanized; similar to EN 60715

www.wago.com/210-508**General accessories**

	Item no.: 280-404 Test plug adapter; 5 mm wide; for test plug 210-137 (2.3 mm Ø); suitable for 1.5 mm² - 4 mm² tbs	www.wago.com/280-404
	Item no.: 280-418 Test plug module; modular; suitable for all WAGO 280 and 780 Series rail-mounted terminal blocks with jumper slots in the current bar	www.wago.com/280-418
	Item no.: 280-419 Spacer module; modular; bridging commoned terminal blocks	www.wago.com/280-419
	Item no.: 769-438 Pin cover; with marker slot for miniature WSB	www.wago.com/769-438
	Item no.: 769-439 Pin cover; with marker slot for miniature WSB	www.wago.com/769-439
	Item no.: 769-501 Start module for 1-conductor female connector; with integrated end plate; 4 mm²; 1-pole	www.wago.com/769-501
	Item no.: 769-501/000-006 Start module for 1-conductor female connector; 4 mm²; 1-pole	www.wago.com/769-501/000-006
	Item no.: 769-501/000-016 Start module for 1-conductor female connector; with integrated end plate; 4 mm²; 1-pole	www.wago.com/769-501/000-016
	Item no.: 769-502 Center module for 1-conductor female connector; 4 mm²; 1-pole	www.wago.com/769-502
	Item no.: 769-502/000-006 Center module for 1-conductor female connector; 4 mm²; 1-pole	www.wago.com/769-502/000-006
	Item no.: 769-502/000-016 1-conductor center module; codable; can be commoned with miniature adjacent jumpers; 1-pole	www.wago.com/769-502/000-016
	Item no.: 769-503 End module for 1-conductor female connector; 4 mm²; 1-pole	www.wago.com/769-503
	Item no.: 769-503/000-006 End module for 1-conductor female connector; 4 mm²; 1-pole	www.wago.com/769-503/000-006
	Item no.: 769-503/000-016 End module for 1-conductor female connector; 4 mm²; 1-pole	www.wago.com/769-503/000-016
	Item no.: 769-504 2-conductor base module; with integrated end plate; codable; can be commoned with adjacent jumpers and staggered jumpers; 1-pole	www.wago.com/769-504
	Item no.: 769-504/000-006 Start module for 2-conductor female connector; with integrated end plate; 4 mm²; 1-pole	www.wago.com/769-504/000-006
	Item no.: 769-504/000-016 Start module for 2-conductor female connector; 4 mm²; 1-pole	www.wago.com/769-504/000-016



Item no.: 769-505
Center module for 2-conductor female connector; 4 mm²; 1-pole

www.wago.com/769-505



Item no.: 769-505/000-006
Center module for 2-conductor female connector; 4 mm²; 1-pole

www.wago.com/769-505/000-006



Item no.: 769-505/000-016
Center module for 2-conductor female connector; 4 mm²; 1-pole

www.wago.com/769-505/000-016



Item no.: 769-506
2-conductor end module; codable; can be commoned with adjacent jumpers and staggered jumpers; 1-pole

www.wago.com/769-506



Item no.: 769-506/000-006
End module for 2-conductor female connector; 4 mm²; 1-pole

www.wago.com/769-506/000-006



Item no.: 769-506/000-016
End module for 2-conductor female connector; 4 mm²; 1-pole

www.wago.com/769-506/000-016



Item no.: 769-512
Start module for 1-conductor female connector; angled; 4 mm²; 1-pole

www.wago.com/769-512



Item no.: 769-512/000-006
Start module for 1-conductor female connector; angled; 4 mm²; 1-pole

www.wago.com/769-512/000-006



Item no.: 769-512/000-016
Start module for 1-conductor female connector; angled; 4 mm²; 1-pole

www.wago.com/769-512/000-016



Item no.: 769-513
Center module for 1-conductor female connector; angled; 4 mm²; 1-pole

www.wago.com/769-513



Item no.: 769-513/000-006
1-conductor center module; angled; codable; 1-pole

www.wago.com/769-513/000-006



Item no.: 769-513/000-016
1-conductor center module; angled; codable; 1-pole

www.wago.com/769-513/000-016



Item no.: 769-515
1-conductor end module; angled; codable; 1-pole

www.wago.com/769-515



Item no.: 769-515/000-006
1-conductor end module; angled; codable; 1-pole

www.wago.com/769-515/000-006



Item no.: 769-515/000-016
1-conductor end module; angled; codable; 1-pole

www.wago.com/769-515/000-016

check



Item no.: 210-136

Test plug; 2 mm Ø; with 500 mm cable

www.wago.com/210-136



Item no.: 210-137

Test plug; 2.3 mm Ø; with 500 mm cable

www.wago.com/210-137

Downloads

Documentation

Bid Text

769-217	Oct 18, 2017	DOC 25.6 kB	Download
---------	--------------	----------------	----------

smartDATA

CAD data

3D Download 769-217	URL	Download
---------------------	-----	----------

Product family

X-COM

[Learn more about the product family.](#)

[Show all products from the family](#)

Subject to changes.

WAGO Kontakttechnik GmbH & Co. KG

Hansastr. 27

32423 Minden

Phone: +49571 887-0 | Fax: +49571 887-169

Email: info.de@wago.com | Web: www.wago.com

Do you have any questions about our products?

We are always happy to take your call at +49 (571) 887-44222.