
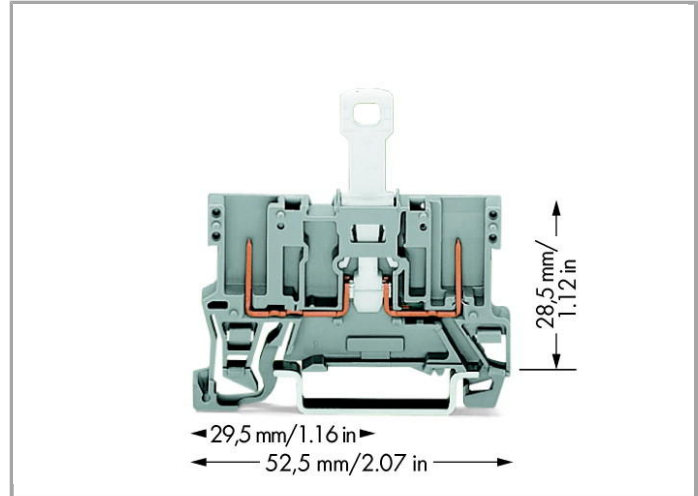


Data sheet | Item number: 769-222

2-pin disconnect carrier terminal block; for DIN-rail 35 x 15 and 35 x 7.5

www.wago.com/769-222

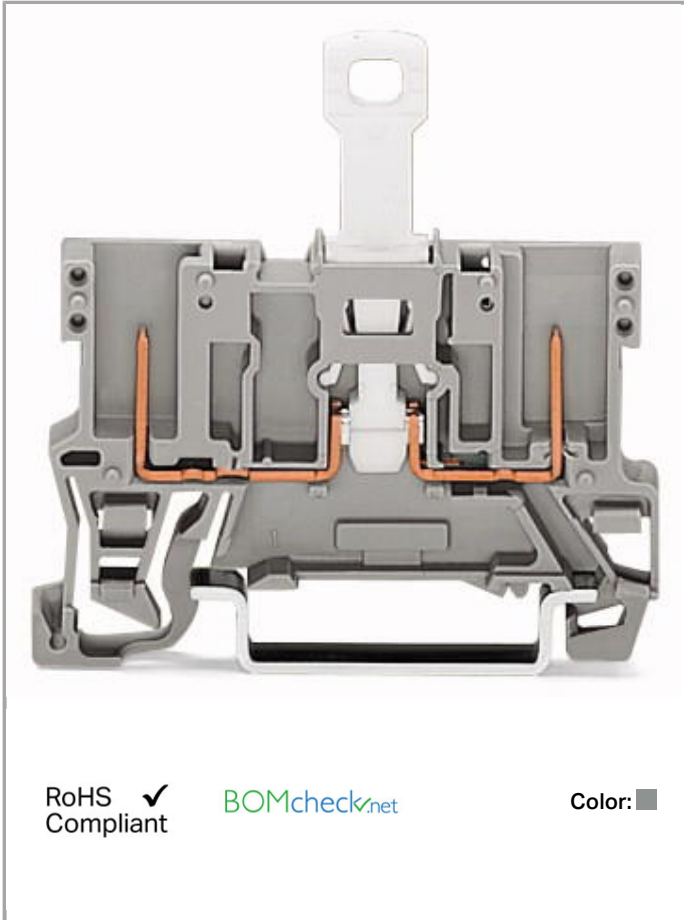

Data

Electrical data

Ratings per IEC/EN 60664-1

| | |
|---------------------------------|---|
| Rated voltage (III / 3) | 400 V |
| Rated impulse voltage (III / 3) | 6 kV |
| Rated current | 16 A |
| Legend (ratings) | (III / 3) ≙ Overvoltage category III / Pollution degree 3 |

Connection data

| | |
|----------------------------|--------------------|
| Total number of potentials | 1 |
| Number of levels | 1 |
| Type of wiring | Front-entry wiring |

Geometrical Data

| | |
|---------------------------------------|----------------------|
| Width | 5 mm / 0.197 inch |
| Height from upper-edge of DIN-35 rail | 28.5 mm / 1.122 inch |
| Depth | 52.5 mm / 2.067 inch |

Mechanical data

| | |
|------------------|----------------|
| Design | horizontal |
| Type of mounting | DIN-35 rail |
| Marking level | Center marking |

Material Data




| | |
|---------------------|----------------------|
| Color | gray |
| Insulating material | Polyamide 66 (PA 66) |
| Fire load | 0.112 MJ |
| Weight | 5.087 g |

Commercial data

| | |
|--------------------|-------------------|
| Country of origin | DE |
| GTIN | 4045454619404 |
| Customs Tariff No. | 85365080990 |
| Product Group | 18 (X-COM-System) |

Approvals / Certificates

Country specific Approvals

| Logo | Approval | Certificate name |
|--|---------------------------------------|------------------|
|  | CCA DEKRA Certification B.V. | NTR NL-7626 |
|  | CSA DEKRA Certification B.V. | 1101144 |
|  | KEMA/KEUR DEKRA Certification B.V. | 2190419.01 |

Ship Approvals

| Logo | Approval | Certificate name |
|------|------------------------------------|------------------|
| | ABS American Bureau of Shipping | 14-HG1293677-PDA |



ABS



LR
Lloyds Register







91/20112 (E9)




 






UL-Approvals

| Logo | Approval | Certificate name |
|--|--------------------------------------|------------------|
|  | UR Underwriters Laboratories Inc. | E45171 |
|  | UR Underwriters Laboratories Inc. | E45172 |

Compatible products

Female plug

| | | |
|--|---|--|
|  | Item no.: 769-101 1-conductor female plug; 4 mm ² ; 1-pole | www.wago.com/769-101 |
|  | Item no.: 769-101/000-006 1-conductor female plug; 4 mm ² ; 1-pole | www.wago.com/769-101/000-006 |
|  | Item no.: 769-101/000-016 1-conductor female plug; 4 mm ² ; 1-pole | www.wago.com/769-101/000-016 |
|  | Item no.: 769-101/022-000 1-conductor female plug; angled; 4 mm ² ; 1-pole | www.wago.com/769-101/022-000 |
|  | Item no.: 769-101/022-016 1-conductor female plug; angled; 4 mm ² ; 1-pole | www.wago.com/769-101/022-016 |
|  | Item no.: 769-102 1-conductor female plug; 4 mm ² ; 2-pole | www.wago.com/769-102 |
| | Item no.: 769-102/000-006 1-conductor female plug; 4 mm ² ; 2-pole | www.wago.com/769-102/000-006 |
| | Item no.: 769-102/000-036 1-conductor female plug; 4 mm ² ; 2-pole | www.wago.com/769-102/000-036 |

| | | |
|--|---|---|
| | <p>Item no.: 769-102/000-037 1-conductor female plug; 4 mm²; 2-pole</p> | <p>www.wago.com/769-102/000-037</p> |
|  | <p>Item no.: 769-102/022-000 1-conductor female plug; angled; 4 mm²; 2-pole</p> | <p>www.wago.com/769-102/022-000</p> |
| | <p>Item no.: 769-103 1-conductor female plug; 4 mm²; 3-pole</p> | <p>www.wago.com/769-103</p> |
| | <p>Item no.: 769-103/000-006 1-conductor female plug; 4 mm²; 3-pole</p> | <p>www.wago.com/769-103/000-006</p> |
|  | <p>Item no.: 769-103/000-036 1-conductor female plug; 4 mm²; 3-pole</p> | <p>www.wago.com/769-103/000-036</p> |
|  | <p>Item no.: 769-103/000-037 1-conductor female plug; 4 mm²; 3-pole</p> | <p>www.wago.com/769-103/000-037</p> |
|  | <p>Item no.: 769-103/000-038 1-conductor female plug; 4 mm²; 3-pole</p> | <p>www.wago.com/769-103/000-038</p> |
|  | <p>Item no.: 769-103/000-039 1-conductor female plug; 4 mm²; 3-pole</p> | <p>www.wago.com/769-103/000-039</p> |
|  | <p>Item no.: 769-103/022-000 1-conductor female plug; angled; 4 mm²; 3-pole</p> | <p>www.wago.com/769-103/022-000</p> |
| | <p>Item no.: 769-104 1-conductor female plug; 4 mm²; 4-pole</p> | <p>www.wago.com/769-104</p> |
| | <p>Item no.: 769-104/000-006 1-conductor female plug; 4 mm²; 4-pole</p> | <p>www.wago.com/769-104/000-006</p> |
|  | <p>Item no.: 769-104/000-036 1-conductor female plug; 4 mm²; 4-pole</p> | <p>www.wago.com/769-104/000-036</p> |
|  | <p>Item no.: 769-104/000-037 1-conductor female plug; 4 mm²; 4-pole</p> | <p>www.wago.com/769-104/000-037</p> |
|  | <p>Item no.: 769-104/000-038 1-conductor female plug; 4 mm²; 4-pole</p> | <p>www.wago.com/769-104/000-038</p> |
|  | <p>Item no.: 769-104/000-039 1-conductor female plug; 4 mm²; 4-pole</p> | <p>www.wago.com/769-104/000-039</p> |



Item no.: 769-104/022-000
1-conductor female plug; angled; 4 mm²; 4-pole

www.wago.com/769-104/022-000



Item no.: 769-105
1-conductor female plug; 4 mm²; 5-pole

www.wago.com/769-105



Item no.: 769-105/000-006
1-conductor female plug; 4 mm²; 5-pole

www.wago.com/769-105/000-006



Item no.: 769-105/000-036
1-conductor female plug; 4 mm²; 5-pole

www.wago.com/769-105/000-036



Item no.: 769-105/000-037
1-conductor female plug; 4 mm²; 5-pole

www.wago.com/769-105/000-037



Item no.: 769-105/000-038
1-conductor female plug; 4 mm²; 5-pole

www.wago.com/769-105/000-038



Item no.: 769-105/000-039
1-conductor female plug; 4 mm²; 5-pole

www.wago.com/769-105/000-039



Item no.: 769-105/022-000
1-conductor female plug; angled; 4 mm²; 5-pole

www.wago.com/769-105/022-000

Item no.: 769-106
1-conductor female plug; 4 mm²; 6-pole

www.wago.com/769-106

Item no.: 769-106/000-006
1-conductor female plug; 4 mm²; 6-pole

www.wago.com/769-106/000-006



Item no.: 769-106/000-036
1-conductor female plug; 4 mm²; 6-pole

www.wago.com/769-106/000-036



Item no.: 769-106/000-037
1-conductor female plug; 4 mm²; 6-pole

www.wago.com/769-106/000-037



Item no.: 769-106/000-038
1-conductor female plug; 4 mm²; 6-pole

www.wago.com/769-106/000-038



Item no.: 769-106/000-039
1-conductor female plug; 4 mm²; 6-pole

www.wago.com/769-106/000-039

Item no.: 769-106/022-000
1-conductor female plug; angled; 4 mm²; 6-pole

www.wago.com/769-106/022-000

Item no.: 769-107

1-conductor female plug; 4 mm²; 7-pole

www.wago.com/769-107

Item no.: 769-107/000-006

1-conductor female plug; 4 mm²; 7-pole

www.wago.com/769-107/000-006



Item no.: 769-107/000-036

1-conductor female plug; 4 mm²; 7-pole

www.wago.com/769-107/000-036



Item no.: 769-107/000-037

1-conductor female plug; 4 mm²; 7-pole

www.wago.com/769-107/000-037



Item no.: 769-107/000-038

1-conductor female plug; 4 mm²; 7-pole

www.wago.com/769-107/000-038



Item no.: 769-107/000-039

1-conductor female plug; 4 mm²; 7-pole

www.wago.com/769-107/000-039

Item no.: 769-107/022-000

1-conductor female plug; angled; 4 mm²; 7-pole

www.wago.com/769-107/022-000

Item no.: 769-108

1-conductor female plug; 4 mm²; 8-pole

www.wago.com/769-108

Item no.: 769-108/000-006

1-conductor female plug; 4 mm²; 8-pole

www.wago.com/769-108/000-006

Item no.: 769-108/000-036

1-conductor female plug; 4 mm²; 8-pole

www.wago.com/769-108/000-036

Item no.: 769-108/000-037

1-conductor female plug; 4 mm²; 8-pole

www.wago.com/769-108/000-037

Item no.: 769-108/000-038

1-conductor female plug; 4 mm²; 8-pole

www.wago.com/769-108/000-038

Item no.: 769-108/000-039

1-conductor female plug; 4 mm²; 8-pole

www.wago.com/769-108/000-039

Item no.: 769-108/022-000

1-conductor female plug; angled; 4 mm²; 8-pole

www.wago.com/769-108/022-000

Item no.: 769-109

1-conductor female plug; 4 mm²; 9-pole

www.wago.com/769-109

Item no.: 769-109/000-006

1-conductor female plug; 4 mm²; 9-pole

www.wago.com/769-109/000-006



Item no.: 769-109/000-036
1-conductor female plug; 4 mm²; 9-pole

www.wago.com/769-109/000-036



Item no.: 769-109/000-037
1-conductor female plug; 4 mm²; 9-pole

www.wago.com/769-109/000-037



Item no.: 769-109/000-038
1-conductor female plug; 4 mm²; 9-pole

www.wago.com/769-109/000-038



Item no.: 769-109/000-039
1-conductor female plug; 4 mm²; 9-pole

www.wago.com/769-109/000-039

Item no.: 769-109/022-000
1-conductor female plug; angled; 4 mm²; 9-pole

www.wago.com/769-109/022-000

Item no.: 769-110
1-conductor female plug; 4 mm²; 10-pole

www.wago.com/769-110

Item no.: 769-110/000-006
1-conductor female plug; 4 mm²; 10-pole

www.wago.com/769-110/000-006

Item no.: 769-110/000-036
1-conductor female plug; 4 mm²; 10-pole

www.wago.com/769-110/000-036

Item no.: 769-110/000-037
1-conductor female plug; 4 mm²; 10-pole

www.wago.com/769-110/000-037

Item no.: 769-110/000-038
1-conductor female plug; 4 mm²; 10-pole

www.wago.com/769-110/000-038

Item no.: 769-110/000-039
1-conductor female plug; 4 mm²; 10-pole

www.wago.com/769-110/000-039

Item no.: 769-110/022-000
1-conductor female plug; angled; 4 mm²; 10-pole

www.wago.com/769-110/022-000

Item no.: 769-111
1-conductor female plug; 4 mm²; 11-pole





www.wago.com/769-111

Item no.: 769-111/000-006
1-conductor female plug; 4 mm²; 11-pole

www.wago.com/769-111/000-006

Item no.: 769-111/000-036
1-conductor female plug; 4 mm²; 11-pole

www.wago.com/769-111/000-036

| | | |
|--|--|---|
| <p>Item no.: 769-111/000-037 1-conductor female plug; 4 mm²; 11-pole</p> | <p>www.wago.com/769-111/000-037</p> | |
| <p>Item no.: 769-111/000-038 1-conductor female plug; 4 mm²; 11-pole</p> | <p>www.wago.com/769-111/000-038</p> | |
| <p>Item no.: 769-111/000-039 1-conductor female plug; 4 mm²; 11-pole</p> | <p>www.wago.com/769-111/000-039</p> | |
| <p>Item no.: 769-111/022-000 1-conductor female plug; angled; 4 mm²; 11-pole</p> | <p>www.wago.com/769-111/022-000</p> | |
| <p>Item no.: 769-112 1-conductor female plug; 4 mm²; 12-pole</p> | <p>www.wago.com/769-112</p> | |
| <p>Item no.: 769-112/000-006 1-conductor female plug; 4 mm²; 12-pole</p> | <p>www.wago.com/769-112/000-006</p> | |
|  | <p>Item no.: 769-112/000-036 1-conductor female plug; 4 mm²; 12-pole</p> | <p>www.wago.com/769-112/000-036</p> |
|  | <p>Item no.: 769-112/000-037 1-conductor female plug; 4 mm²; 12-pole</p> | <p>www.wago.com/769-112/000-037</p> |
|  | <p>Item no.: 769-112/000-038 1-conductor female plug; 4 mm²; 12-pole</p> | <p>www.wago.com/769-112/000-038</p> |
|  | <p>Item no.: 769-112/000-039 1-conductor female plug; 4 mm²; 12-pole</p> | <p>www.wago.com/769-112/000-039</p> |
| <p>Item no.: 769-112/022-000 1-conductor female plug; angled; 4 mm²; 12-pole</p> | <p>www.wago.com/769-112/022-000</p> | |
| <p>Item no.: 769-113 1-conductor female plug; 4 mm²; 13-pole</p> | <p>www.wago.com/769-113</p> | |
| <p>Item no.: 769-113/000-036 1-conductor female plug; 4 mm²; 13-pole</p> | <p>www.wago.com/769-113/000-036</p> | |
| <p>Item no.: 769-113/000-037 1-conductor female plug; 4 mm²; 13-pole</p> | <p>www.wago.com/769-113/000-037</p> | |
| <p>Item no.: 769-113/000-038 1-conductor female plug; 4 mm²; 13-pole</p> | <p>www.wago.com/769-113/000-038</p> | |



Item no.: 769-113/000-039
1-conductor female plug; 4 mm²; 13-pole

www.wago.com/769-113/000-039

Item no.: 769-113/022-000
1-conductor female plug; angled; 4 mm²; 13-pole

www.wago.com/769-113/022-000

Item no.: 769-114
1-conductor female plug; 4 mm²; 14-pole

www.wago.com/769-114

Item no.: 769-114/000-006
1-conductor female plug; 4 mm²; 14-pole

www.wago.com/769-114/000-006

Item no.: 769-114/000-036
1-conductor female plug; 4 mm²; 14-pole

www.wago.com/769-114/000-036

Item no.: 769-114/000-037
1-conductor female plug; 4 mm²; 14-pole

www.wago.com/769-114/000-037

Item no.: 769-114/000-038
1-conductor female plug; 4 mm²; 14-pole

www.wago.com/769-114/000-038

Item no.: 769-114/000-039
1-conductor female plug; 4 mm²; 14-pole

www.wago.com/769-114/000-039

Item no.: 769-114/022-000
1-conductor female plug; angled; 4 mm²; 14-pole

www.wago.com/769-114/022-000

Item no.: 769-115
1-conductor female plug; 4 mm²; 15-pole

www.wago.com/769-115

Item no.: 769-115/000-036
1-conductor female plug; 4 mm²; 15-pole

www.wago.com/769-115/000-036

Item no.: 769-115/000-037
1-conductor female plug; 4 mm²; 15-pole

www.wago.com/769-115/000-037

Item no.: 769-115/000-038
1-conductor female plug; 4 mm²; 15-pole

www.wago.com/769-115/000-038

Item no.: 769-115/000-039
1-conductor female plug; 4 mm²; 15-pole

www.wago.com/769-115/000-039

Item no.: 769-115/022-000
1-conductor female plug; angled; 4 mm²; 15-pole

www.wago.com/769-115/022-000

tools

**Item no.: 210-720**

Operating tool with partially insulated shaft; Type 2, blade (3.5 x 0.5) mm

www.wago.com/210-720

assembling

**Item no.: 209-106**

Mounting carrier; for isolated mounting on DIN 35 rails

www.wago.com/209-106

End plate

**Item no.: 769-305**

End and intermediate plate; 1.1 mm thick

www.wago.com/769-305**Item no.: 769-306**

End and intermediate plate; 1.1 mm thick

www.wago.com/769-306

Carrier rail

**Item no.: 210-112**

Steel carrier rail; 35 x 7.5 mm; 1 mm thick; 2 m long; slotted; according to EN 60715; "Hole width 25 mm

www.wago.com/210-112**Item no.: 210-113**

Steel carrier rail; 35 x 7.5 mm; 1 mm thick; 2 m long; unslotted; according to EN 60715

www.wago.com/210-113**Item no.: 210-114**

Steel carrier rail; 35 x 15 mm; 1.5 mm thick; 2 m long; unslotted; similar to EN 60715

www.wago.com/210-114**Item no.: 210-115**

Steel carrier rail; 35 x 7.5 mm; 1 mm thick; 2 m long; slotted; according to EN 60715; "Hole width 18 mm

www.wago.com/210-115**Item no.: 210-118**

Steel carrier rail; 35 x 15 mm; 2.3 mm thick; 2 m long; unslotted; according to EN 60715

www.wago.com/210-118**Item no.: 210-196**

Aluminum carrier rail; 35 x 8.2 mm; 1.6 mm thick; 2 m long; unslotted; similar to EN 60715

www.wago.com/210-196**Item no.: 210-197**

Steel carrier rail; 35 x 15 mm; 1.5 mm thick; 2 m long; slotted; similar to EN 60715

www.wago.com/210-197**Item no.: 210-198**

Copper carrier rail; 35 x 15 mm; 2.3 mm thick; 2 m long; unslotted; according to EN 60715

www.wago.com/210-198**Item no.: 210-504**

Steel carrier rail; 35 x 7.5 mm; 1 mm thick; 2 m long; slotted; galvanized; according to EN 60715

www.wago.com/210-504**Item no.: 210-505**

Steel carrier rail; 35 x 7.5 mm; 1 mm thick; 2 m long; unslotted; galvanized; according to EN 60715

www.wago.com/210-505**Item no.: 210-506**

Steel carrier rail; 35 x 15 mm; 1.5 mm thick; 2 m long; unslotted; galvanized; similar to EN 60715

www.wago.com/210-506**Item no.: 210-508**

Steel carrier rail; 35 x 15 mm; 1.5 mm thick; 2 m long; slotted; galvanized; similar to EN 60715















www.wago.com/210-508

Coding

**Item no.: 769-435**

Coding pin; for coding of female plugs; for carrier terminal blocks / male connectors

www.wago.com/769-435**Marking accessories**

| | | |
|--|--|--|
|  | Item no.: 2009-145 Mini-WSB Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type | www.wago.com/2009-145 |
|  | Item no.: 2009-145/000-002 Mini-WSB Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type | www.wago.com/2009-145/000-002 |
|  | Item no.: 2009-145/000-005 Mini-WSB Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type | www.wago.com/2009-145/000-005 |
|  | Item no.: 2009-145/000-006 Mini-WSB Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type | www.wago.com/2009-145/000-006 |
|  | Item no.: 2009-145/000-007 Mini-WSB Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type | www.wago.com/2009-145/000-007 |
|  | Item no.: 2009-145/000-012 Mini-WSB Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type | www.wago.com/2009-145/000-012 |
|  | Item no.: 2009-145/000-023 Mini-WSB Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type | www.wago.com/2009-145/000-023 |
|  | Item no.: 2009-145/000-024 Mini-WSB Inline; on reel; stretchable 5 - 5.2 mm; plain; snap-on type | www.wago.com/2009-145/000-024 |
|  | Item no.: 248-501 Miniature WSB Quick marking system; plain; Marker width 5 mm; 10 strips with 10 markers per card | www.wago.com/248-501 |
|  | Item no.: 248-501/000-002 Mini-WSB marking card; as card; not stretchable; plain; snap-on type | www.wago.com/248-501/000-002 |
|  | Item no.: 248-501/000-005 Mini-WSB marking card; as card; plain; snap-on type | www.wago.com/248-501/000-005 |
|  | Item no.: 248-501/000-006 Mini-WSB marking card; as card; not stretchable; plain; snap-on type | www.wago.com/248-501/000-006 |
|  | Item no.: 248-501/000-007 Mini-WSB marking card; as card; not stretchable; plain; snap-on type | www.wago.com/248-501/000-007 |
|  | Item no.: 248-501/000-012 Mini-WSB marking card; as card; not stretchable; plain; snap-on type | www.wago.com/248-501/000-012 |



Item no.: 248-501/000-017
Mini-WSB marking card; as card; not stretchable; plain; snap-on type

www.wago.com/248-501/000-017



Item no.: 248-501/000-023
Mini-WSB marking card; as card; not stretchable; plain; snap-on type

www.wago.com/248-501/000-023



Item no.: 248-501/000-024
Mini-WSB marking card; as card; not stretchable; plain; snap-on type

www.wago.com/248-501/000-024

Jumper



Item no.: 249-123
Push-in type wire jumper; insulated; wire length 180 mm; Conductor cross section 0.75 mm²

www.wago.com/249-123



Item no.: 249-125
Push-in type wire jumper; insulated; wire length 60 mm; Conductor cross section 0.75 mm²

www.wago.com/249-125



Item no.: 249-126
Push-in type wire jumper; insulated; wire length 110 mm; Conductor cross section 0.75 mm²

www.wago.com/249-126



Item no.: 249-127
Push-in type wire jumper; insulated; wire length 250 mm; Conductor cross section 0.75 mm²

www.wago.com/249-127

check



Item no.: 210-137
Test plug; 2.3 mm Ø; with 500 mm cable

www.wago.com/210-137

General accessories



Item no.: 709-170
Disconnect lock; for disconnect tab used on 280/281 and 769 Series disconnect terminal blocks

www.wago.com/709-170



Item no.: 769-438
Pin cover; with marker slot for miniature WSB

www.wago.com/769-438



Item no.: 769-439
Pin cover; with marker slot for miniature WSB

www.wago.com/769-439



Item no.: 769-501
Start module for 1-conductor female connector; with integrated end plate; 4 mm²; 1-pole

www.wago.com/769-501



Item no.: 769-501/000-006
Start module for 1-conductor female connector; 4 mm²; 1-pole

www.wago.com/769-501/000-006


















Item no.: 769-501/000-016
Start module for 1-conductor female connector; with integrated end plate; 4 mm²; 1-pole

www.wago.com/769-501/000-016



Item no.: 769-502
Center module for 1-conductor female connector; 4 mm²; 1-pole

www.wago.com/769-502

| | | |
|--|--|--|
|  | Item no.: 769-502/000-006 Center module for 1-conductor female connector; 4 mm ² ; 1-pole | www.wago.com/769-502/000-006 |
|  | Item no.: 769-502/000-016 1-conductor center module; codable; can be commoned with miniature adjacent jumpers; 1-pole | www.wago.com/769-502/000-016 |
|  | Item no.: 769-503 End module for 1-conductor female connector; 4 mm ² ; 1-pole | www.wago.com/769-503 |
|  | Item no.: 769-503/000-006 1-conductor end module; codable; can be commoned with miniature adjacent jumpers; 1-pole | www.wago.com/769-503/000-006 |
|  | Item no.: 769-503/000-016 1-conductor end module; codable; can be commoned with miniature adjacent jumpers; 1-pole | www.wago.com/769-503/000-016 |
|  | Item no.: 769-504 2-conductor base module; with integrated end plate; codable; can be commoned with adjacent jumpers and staggered jumpers; 1-pole | www.wago.com/769-504 |
|  | Item no.: 769-504/000-006 Start module for 2-conductor female connector; with integrated end plate; 4 mm ² ; 1-pole | www.wago.com/769-504/000-006 |
|  | Item no.: 769-504/000-016 2-conductor base module; with integrated end plate; codable; can be commoned with adjacent jumpers and staggered jumpers; 1-pole | www.wago.com/769-504/000-016 |
|  | Item no.: 769-505 2-conductor center module; codable; can be commoned with adjacent jumpers and staggered jumpers; 1-pole | www.wago.com/769-505 |
|  | Item no.: 769-505/000-006 2-conductor center module; codable; can be commoned with adjacent jumpers and staggered jumpers; 1-pole | www.wago.com/769-505/000-006 |
|  | Item no.: 769-505/000-016 2-conductor center module; codable; can be commoned with adjacent jumpers and staggered jumpers; 1-pole | www.wago.com/769-505/000-016 |
|  | Item no.: 769-506 2-conductor end module; codable; can be commoned with adjacent jumpers and staggered jumpers; 1-pole | www.wago.com/769-506 |
|  | Item no.: 769-506/000-006 End module for 2-conductor female connector; 4 mm ² ; 1-pole | www.wago.com/769-506/000-006 |
|  | Item no.: 769-506/000-016 2-conductor end module; codable; can be commoned with adjacent jumpers and staggered jumpers; 1-pole | www.wago.com/769-506/000-016 |
|  | Item no.: 769-512 Start module for 1-conductor female connector; angled; 4 mm ² ; 1-pole | www.wago.com/769-512 |
| | Item no.: 769-512/000-006 1-conductor base module; angled; with integrated end plate; codable; 1-pole | www.wago.com/769-512/000-006 |



Item no.: 769-512/000-016

1-conductor base module; angled; with integrated end plate; codable; 1-pole

www.wago.com/769-512/000-016

Item no.: 769-513

Center module for 1-conductor female connector; angled; 4 mm²; 1-pole

www.wago.com/769-513

Item no.: 769-513/000-006

1-conductor center module; angled; codable; 1-pole

www.wago.com/769-513/000-006

Item no.: 769-513/000-016

1-conductor center module; angled; codable; 1-pole

www.wago.com/769-513/000-016

Item no.: 769-515

1-conductor end module; angled; codable; 1-pole

www.wago.com/769-515

Item no.: 769-515/000-006

1-conductor end module; angled; codable; 1-pole

www.wago.com/769-515/000-006

Item no.: 769-515/000-016

1-conductor end module; angled; codable; 1-pole

www.wago.com/769-515/000-016

Downloads

Documentation

Bid Text

| | | | |
|---------|--------------|----------------|----------|
| 769-222 | Oct 18, 2017 | DOC 24.6 kB | Download |
|---------|--------------|----------------|----------|

smartDATA

CAD data

| | | |
|---------------------|-----|----------|
| 3D Download 769-222 | URL | Download |
|---------------------|-----|----------|

Product family

X-COM

[Learn more about the product family.](#)

[Show all products from the family](#)



Subject to changes.

WAGO Kontakttechnik GmbH & Co. KG
Hansastr. 27
32423 Minden
Phone: +49571 887-0 | Fax: +49571 887-169
Email: info.de@wago.com | Web: www.wago.com

Do you have any questions about our products?
We are always happy to take your call at +49 (571) 887-44222.