



# Data sheet | Item number: 769-611/002-000

1-conductor male connector; clamping collar; 4 mm<sup>2</sup>; Pin spacing 5 mm; 11-pole

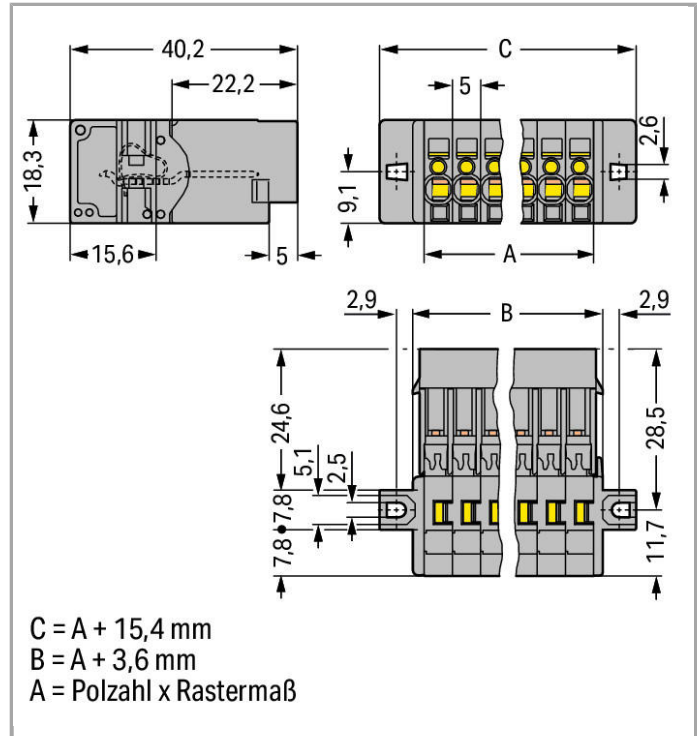

[www.wago.com/769-611/002-000](http://www.wago.com/769-611/002-000)

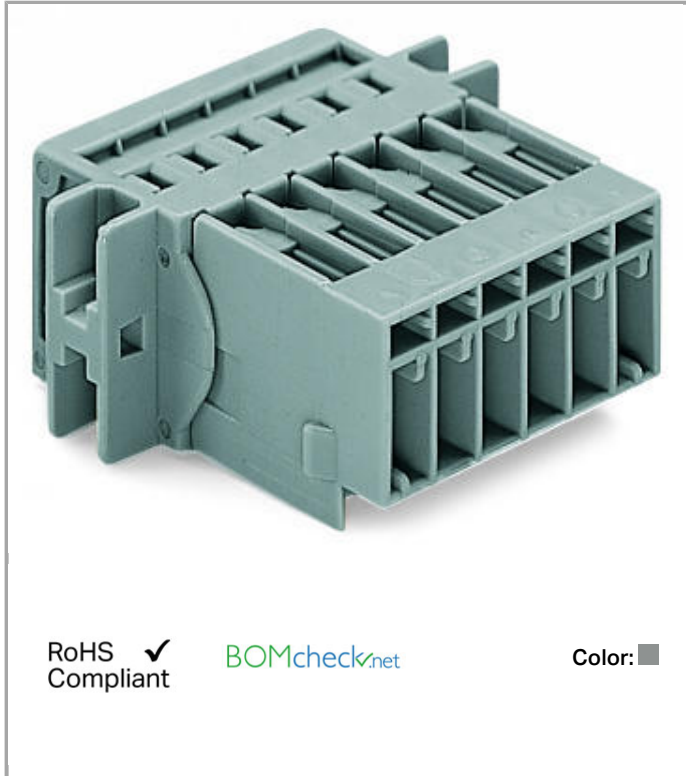

## Data

### Electrical data

### Ratings per IEC/EN 60664-1

|                                 |   |
|---------------------------------|---|
| Rated voltage (III / 3)         | 500 V   |
| Rated impulse voltage (III / 3) | 6 kV  |
| Rated current                   | 32 A  |
| Legend (ratings)                | (III / 3) ≙ Overvoltage category III / Pollution degree 3 |

### Connection data

|                                 |  |
|---------------------------------|--|
| Connection technology           | CAGE CLAMP®                                |
| Actuation type                  | Operating tool                             |
| Connectable conductor materials | Copper<br>Aluminum                         |
| Nominal cross section           | 4 mm <sup>2</sup>                          |
| Solid conductor                 | 0.08 ... 4 mm <sup>2</sup> / 28 ... 12 AWG |
| Fine-stranded conductor         | 0.08 ... 4 mm <sup>2</sup> / 28 ... 12 AWG |



|                                   |                                 |
|-----------------------------------|---------------------------------|
| Strip length                      | 8 ... 9 mm / 0.31 ... 0.35 Inch |
| No. of poles                      | 11                              |
| Total number of connection points | 11                              |
| Total number of potentials        | 11                              |
| Type of wiring                    | Front-entry wiring              |

### Geometrical Data

|                         |                      |
|-------------------------|----------------------|
| Pin spacing             | 5 mm / 0.197 inch    |
| Width                   | 58.6 mm / 2.307 inch |
| Height from the surface | 18.3 mm / 0.72 inch  |
| Depth                   | 40.2 mm / 1.583 inch |

### Mechanical data

|               |                 |
|---------------|-----------------|
| Mounting type | Mounting flange |
|---------------|-----------------|

### Plug connection

|                                    |                     |
|------------------------------------|---------------------|
| Contact type (pluggable connector) | Male connector/plug |
| Connector connection type          | for conductors      |

### Material Data


|                     |                      |
|---------------------|----------------------|
| Color               | gray                 |
| Insulating material | Polyamide 66 (PA 66) |
| Fire load           | 0.672 MJ             |
| Weight              | 32.881 g             |

### Commercial data

|                    |                   |
|--------------------|-------------------|
| Country of origin  | PL                |
| GTIN               | 4044918521673     |
| Customs Tariff No. | 85366990990       |
| Product Group      | 18 (X-COM-System) |

### Approvals / Certificates

#### Country specific Approvals

| Logo   | Approval                        | Certificate name |
|--|---------------------------------|------------------|
|  | CCA<br>DEKRA Certification B.V. | NTR NL-7626      |
|  | CSA<br>DEKRA Certification B.V. | 1101144          |





KEMA/KEUR

2190419.01











DEKRA Certification B.V.














## UL-Approvals

| Logo   | Approval                             | Certificate name |
|--|--------------------------------------|------------------|
|  | UR<br>Underwriters Laboratories Inc. | E45171           |
|  | UR<br>Underwriters Laboratories Inc. | E45172           |

## Compatible products

## Marking accessories

|  |   |  |
|--|---|--|
|  | Item no.: 2009-145<br>Mini-WSB Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type         | <a href="http://www.wago.com/2009-145">www.wago.com/2009-145</a>                 |
|  | Item no.: 2009-145/000-002<br>Mini-WSB Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type | <a href="http://www.wago.com/2009-145/000-002">www.wago.com/2009-145/000-002</a> |
|  | Item no.: 2009-145/000-005<br>Mini-WSB Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type | <a href="http://www.wago.com/2009-145/000-005">www.wago.com/2009-145/000-005</a> |
|  | Item no.: 2009-145/000-006<br>Mini-WSB Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type | <a href="http://www.wago.com/2009-145/000-006">www.wago.com/2009-145/000-006</a> |
|  | Item no.: 2009-145/000-007<br>Mini-WSB Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type | <a href="http://www.wago.com/2009-145/000-007">www.wago.com/2009-145/000-007</a> |
|  | Item no.: 2009-145/000-012<br>Mini-WSB Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type | <a href="http://www.wago.com/2009-145/000-012">www.wago.com/2009-145/000-012</a> |
|  | Item no.: 2009-145/000-023<br>Mini-WSB Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type | <a href="http://www.wago.com/2009-145/000-023">www.wago.com/2009-145/000-023</a> |
|  | Item no.: 2009-145/000-024<br>Mini-WSB Inline; on reel; stretchable 5 - 5.2 mm; plain; snap-on type                   | <a href="http://www.wago.com/2009-145/000-024">www.wago.com/2009-145/000-024</a> |

|  |  |  |
|--|--|--|
|    | <b>Item no.: 210-831</b><br>Marking strips; on reel; 2.3 mm wide; plain; Self-adhesive                                       | <a href="http://www.wago.com/210-831">www.wago.com/210-831</a>                 |
|    | <b>Item no.: 210-832</b><br>Marking strips; on reel; 3 mm wide; plain; Self-adhesive   | <a href="http://www.wago.com/210-832">www.wago.com/210-832</a>                 |
|    | <b>Item no.: 210-833</b><br>Marking strips; on reel; 6 mm wide; plain; Self-adhesive   | <a href="http://www.wago.com/210-833">www.wago.com/210-833</a>                 |
|    | <b>Item no.: 210-834</b><br>Marking strips; on reel; 5 mm wide; plain; Self-adhesive   | <a href="http://www.wago.com/210-834">www.wago.com/210-834</a>                 |
|    | <b>Item no.: 248-501</b><br>Miniature WSB Quick marking system; plain; Marker width 5 mm; 10 strips with 10 markers per card | <a href="http://www.wago.com/248-501">www.wago.com/248-501</a>                 |
|    | <b>Item no.: 248-501/000-002</b><br>Mini-WSB marking card; as card; not stretchable; plain; snap-on type                     | <a href="http://www.wago.com/248-501/000-002">www.wago.com/248-501/000-002</a> |
|    | <b>Item no.: 248-501/000-005</b><br>Mini-WSB marking card; as card; plain; snap-on type                                      | <a href="http://www.wago.com/248-501/000-005">www.wago.com/248-501/000-005</a> |
|    | <b>Item no.: 248-501/000-006</b><br>Mini-WSB marking card; as card; not stretchable; plain; snap-on type                     | <a href="http://www.wago.com/248-501/000-006">www.wago.com/248-501/000-006</a> |
|  | <b>Item no.: 248-501/000-007</b><br>Mini-WSB marking card; as card; not stretchable; plain; snap-on type                     | <a href="http://www.wago.com/248-501/000-007">www.wago.com/248-501/000-007</a> |
|  | <b>Item no.: 248-501/000-012</b><br>Mini-WSB marking card; as card; not stretchable; plain; snap-on type                     | <a href="http://www.wago.com/248-501/000-012">www.wago.com/248-501/000-012</a> |
|  | <b>Item no.: 248-501/000-017</b><br>Mini-WSB marking card; as card; not stretchable; plain; snap-on type                     | <a href="http://www.wago.com/248-501/000-017">www.wago.com/248-501/000-017</a> |
|  | <b>Item no.: 248-501/000-023</b><br>Mini-WSB marking card; as card; not stretchable; plain; snap-on type                     | <a href="http://www.wago.com/248-501/000-023">www.wago.com/248-501/000-023</a> |
|  | <b>Item no.: 248-501/000-024</b><br>Mini-WSB marking card; as card; not stretchable; plain; snap-on type                     | <a href="http://www.wago.com/248-501/000-024">www.wago.com/248-501/000-024</a> |

**Strain relief plate**

|  |   |  |
|--|---|--|
|  | <b>Item no.: 769-410</b><br>Strain relief plate | <a href="http://www.wago.com/769-410">www.wago.com/769-410</a> |
|  | <b>Item no.: 769-414</b><br>Strain relief plate | <a href="http://www.wago.com/769-414">www.wago.com/769-414</a> |

**Protective Warning Marker**



**Item no.: 280-415**  
Protective warning marker; with high-voltage symbol, black; for 5 terminal blocks

[www.wago.com/280-415](http://www.wago.com/280-415)

**tools**



**Item no.: 210-490**  
Operating tool; for female and male connectors with CAGE CLAMP® connection

[www.wago.com/210-490](http://www.wago.com/210-490)



**Item no.: 769-434**  
Push-button; loose; for female and male connectors with CAGE CLAMP® connection

[www.wago.com/769-434](http://www.wago.com/769-434)

**ferrule**



**Item no.: 216-101**  
Ferrule; Sleeve for 0.5 mm<sup>2</sup> / AWG 22; uninsulated; electro-tin plated

[www.wago.com/216-101](http://www.wago.com/216-101)



**Item no.: 216-102**  
Ferrule; Sleeve for 0.75 mm<sup>2</sup> / AWG 20; uninsulated; electro-tin plated

[www.wago.com/216-102](http://www.wago.com/216-102)



**Item no.: 216-103**  
Ferrule; Sleeve for 1 mm<sup>2</sup> / AWG 18; uninsulated; electro-tin plated

[www.wago.com/216-103](http://www.wago.com/216-103)



**Item no.: 216-104**  
Ferrule; Sleeve for 1.5 mm<sup>2</sup> / AWG 16; uninsulated; electro-tin plated

[www.wago.com/216-104](http://www.wago.com/216-104)



**Item no.: 216-201**  
Ferrule; Sleeve for 0.5 mm<sup>2</sup> / AWG 22; insulated; electro-tin plated

[www.wago.com/216-201](http://www.wago.com/216-201)



**Item no.: 216-202**  
Ferrule; Sleeve for 0.75 mm<sup>2</sup> / AWG 20; insulated; electro-tin plated

[www.wago.com/216-202](http://www.wago.com/216-202)



**Item no.: 216-203**  
Ferrule; Sleeve for 1 mm<sup>2</sup> / AWG 18; insulated; electro-tin plated

[www.wago.com/216-203](http://www.wago.com/216-203)



**Item no.: 216-204**  
Ferrule; Sleeve for 1.5 mm<sup>2</sup> / AWG 16; insulated; electro-tin plated

[www.wago.com/216-204](http://www.wago.com/216-204)



**Item no.: 216-206**  
Ferrule; Sleeve for 2.5 mm<sup>2</sup> / AWG 14; insulated; electro-tin plated

[www.wago.com/216-206](http://www.wago.com/216-206)

**Coding**



**Item no.: 769-435**  
Coding pin; for coding of female plugs; for carrier terminal blocks / male connectors

[www.wago.com/769-435](http://www.wago.com/769-435)

**Female plug**



**Item no.: 769-101**  
1-conductor female plug; 4 mm<sup>2</sup>; 1-pole

[www.wago.com/769-101](http://www.wago.com/769-101)














**Item no.: 769-101/000-016**  
1-conductor female plug; 4 mm<sup>2</sup>; 1-pole

[www.wago.com/769-101/000-016](http://www.wago.com/769-101/000-016)



**Item no.: 769-102**  
1-conductor female plug; 4 mm<sup>2</sup>; 2-pole

[www.wago.com/769-102](http://www.wago.com/769-102)

|  |   |  |
|--|---|--|
|  | <b>Item no.: 769-102/000-036</b><br>1-conductor female plug; 4 mm <sup>2</sup> ; 2-pole | <a href="http://www.wago.com/769-102/000-036">www.wago.com/769-102/000-036</a> |
|  | <b>Item no.: 769-102/000-037</b><br>1-conductor female plug; 4 mm <sup>2</sup> ; 2-pole | <a href="http://www.wago.com/769-102/000-037">www.wago.com/769-102/000-037</a> |
|  | <b>Item no.: 769-103</b><br>1-conductor female plug; 4 mm <sup>2</sup> ; 3-pole         | <a href="http://www.wago.com/769-103">www.wago.com/769-103</a>                 |
|    | <b>Item no.: 769-103/000-036</b><br>1-conductor female plug; 4 mm <sup>2</sup> ; 3-pole | <a href="http://www.wago.com/769-103/000-036">www.wago.com/769-103/000-036</a> |
|    | <b>Item no.: 769-103/000-037</b><br>1-conductor female plug; 4 mm <sup>2</sup> ; 3-pole | <a href="http://www.wago.com/769-103/000-037">www.wago.com/769-103/000-037</a> |
|    | <b>Item no.: 769-103/000-038</b><br>1-conductor female plug; 4 mm <sup>2</sup> ; 3-pole | <a href="http://www.wago.com/769-103/000-038">www.wago.com/769-103/000-038</a> |
|    | <b>Item no.: 769-103/000-039</b><br>1-conductor female plug; 4 mm <sup>2</sup> ; 3-pole | <a href="http://www.wago.com/769-103/000-039">www.wago.com/769-103/000-039</a> |
|  | <b>Item no.: 769-104</b><br>1-conductor female plug; 4 mm <sup>2</sup> ; 4-pole         | <a href="http://www.wago.com/769-104">www.wago.com/769-104</a>                 |
|  | <b>Item no.: 769-104/000-036</b><br>1-conductor female plug; 4 mm <sup>2</sup> ; 4-pole | <a href="http://www.wago.com/769-104/000-036">www.wago.com/769-104/000-036</a> |
|  | <b>Item no.: 769-104/000-037</b><br>1-conductor female plug; 4 mm <sup>2</sup> ; 4-pole | <a href="http://www.wago.com/769-104/000-037">www.wago.com/769-104/000-037</a> |
|  | <b>Item no.: 769-104/000-038</b><br>1-conductor female plug; 4 mm <sup>2</sup> ; 4-pole | <a href="http://www.wago.com/769-104/000-038">www.wago.com/769-104/000-038</a> |
|  | <b>Item no.: 769-104/000-039</b><br>1-conductor female plug; 4 mm <sup>2</sup> ; 4-pole | <a href="http://www.wago.com/769-104/000-039">www.wago.com/769-104/000-039</a> |
|  | <b>Item no.: 769-105</b><br>1-conductor female plug; 4 mm <sup>2</sup> ; 5-pole         | <a href="http://www.wago.com/769-105">www.wago.com/769-105</a>                 |
|  | <b>Item no.: 769-105/000-036</b><br>1-conductor female plug; 4 mm <sup>2</sup> ; 5-pole | <a href="http://www.wago.com/769-105/000-036">www.wago.com/769-105/000-036</a> |
|  | <b>Item no.: 769-105/000-037</b><br>1-conductor female plug; 4 mm <sup>2</sup> ; 5-pole | <a href="http://www.wago.com/769-105/000-037">www.wago.com/769-105/000-037</a> |



**Item no.: 769-105/000-038**  
1-conductor female plug; 4 mm<sup>2</sup>; 5-pole

[www.wago.com/769-105/000-038](http://www.wago.com/769-105/000-038)



**Item no.: 769-105/000-039**  
1-conductor female plug; 4 mm<sup>2</sup>; 5-pole

[www.wago.com/769-105/000-039](http://www.wago.com/769-105/000-039)

**Item no.: 769-106**  
1-conductor female plug; 4 mm<sup>2</sup>; 6-pole

[www.wago.com/769-106](http://www.wago.com/769-106)

**Item no.: 769-106/000-006**  
1-conductor female plug; 4 mm<sup>2</sup>; 6-pole

[www.wago.com/769-106/000-006](http://www.wago.com/769-106/000-006)



**Item no.: 769-106/000-036**  
1-conductor female plug; 4 mm<sup>2</sup>; 6-pole

[www.wago.com/769-106/000-036](http://www.wago.com/769-106/000-036)



**Item no.: 769-106/000-037**  
1-conductor female plug; 4 mm<sup>2</sup>; 6-pole

[www.wago.com/769-106/000-037](http://www.wago.com/769-106/000-037)



**Item no.: 769-106/000-038**  
1-conductor female plug; 4 mm<sup>2</sup>; 6-pole

[www.wago.com/769-106/000-038](http://www.wago.com/769-106/000-038)



**Item no.: 769-106/000-039**  
1-conductor female plug; 4 mm<sup>2</sup>; 6-pole

[www.wago.com/769-106/000-039](http://www.wago.com/769-106/000-039)

**Item no.: 769-107**  
1-conductor female plug; 4 mm<sup>2</sup>; 7-pole

[www.wago.com/769-107](http://www.wago.com/769-107)



**Item no.: 769-107/000-036**  
1-conductor female plug; 4 mm<sup>2</sup>; 7-pole

[www.wago.com/769-107/000-036](http://www.wago.com/769-107/000-036)



**Item no.: 769-107/000-037**  
1-conductor female plug; 4 mm<sup>2</sup>; 7-pole

[www.wago.com/769-107/000-037](http://www.wago.com/769-107/000-037)



**Item no.: 769-107/000-038**  
1-conductor female plug; 4 mm<sup>2</sup>; 7-pole

[www.wago.com/769-107/000-038](http://www.wago.com/769-107/000-038)



**Item no.: 769-107/000-039**  
1-conductor female plug; 4 mm<sup>2</sup>; 7-pole





[www.wago.com/769-107/000-039](http://www.wago.com/769-107/000-039)

**Item no.: 769-108**  
1-conductor female plug; 4 mm<sup>2</sup>; 8-pole







[www.wago.com/769-108](http://www.wago.com/769-108)

**Item no.: 769-108/000-036**  
1-conductor female plug; 4 mm<sup>2</sup>; 8-pole

[www.wago.com/769-108/000-036](http://www.wago.com/769-108/000-036)

|  |  |   |
|--|--|---|
|  | <p><b>Item no.: 769-108/000-037</b><br/>1-conductor female plug; 4 mm<sup>2</sup>; 8-pole</p>  | <p><a href="http://www.wago.com/769-108/000-037">www.wago.com/769-108/000-037</a></p> |
|  | <p><b>Item no.: 769-108/000-038</b><br/>1-conductor female plug; 4 mm<sup>2</sup>; 8-pole</p>  | <p><a href="http://www.wago.com/769-108/000-038">www.wago.com/769-108/000-038</a></p> |
|  | <p><b>Item no.: 769-108/000-039</b><br/>1-conductor female plug; 4 mm<sup>2</sup>; 8-pole</p>  | <p><a href="http://www.wago.com/769-108/000-039">www.wago.com/769-108/000-039</a></p> |
|  | <p><b>Item no.: 769-109</b><br/>1-conductor female plug; 4 mm<sup>2</sup>; 9-pole</p>          | <p><a href="http://www.wago.com/769-109">www.wago.com/769-109</a></p>                 |
|    | <p><b>Item no.: 769-109/000-036</b><br/>1-conductor female plug; 4 mm<sup>2</sup>; 9-pole</p>  | <p><a href="http://www.wago.com/769-109/000-036">www.wago.com/769-109/000-036</a></p> |
|    | <p><b>Item no.: 769-109/000-037</b><br/>1-conductor female plug; 4 mm<sup>2</sup>; 9-pole</p>  | <p><a href="http://www.wago.com/769-109/000-037">www.wago.com/769-109/000-037</a></p> |
|    | <p><b>Item no.: 769-109/000-038</b><br/>1-conductor female plug; 4 mm<sup>2</sup>; 9-pole</p>  | <p><a href="http://www.wago.com/769-109/000-038">www.wago.com/769-109/000-038</a></p> |
|  | <p><b>Item no.: 769-109/000-039</b><br/>1-conductor female plug; 4 mm<sup>2</sup>; 9-pole</p>  | <p><a href="http://www.wago.com/769-109/000-039">www.wago.com/769-109/000-039</a></p> |
|  | <p><b>Item no.: 769-110</b><br/>1-conductor female plug; 4 mm<sup>2</sup>; 10-pole</p>         | <p><a href="http://www.wago.com/769-110">www.wago.com/769-110</a></p>                 |
|  | <p><b>Item no.: 769-110/000-036</b><br/>1-conductor female plug; 4 mm<sup>2</sup>; 10-pole</p> | <p><a href="http://www.wago.com/769-110/000-036">www.wago.com/769-110/000-036</a></p> |
|  | <p><b>Item no.: 769-110/000-037</b><br/>1-conductor female plug; 4 mm<sup>2</sup>; 10-pole</p> | <p><a href="http://www.wago.com/769-110/000-037">www.wago.com/769-110/000-037</a></p> |
|  | <p><b>Item no.: 769-110/000-038</b><br/>1-conductor female plug; 4 mm<sup>2</sup>; 10-pole</p> | <p><a href="http://www.wago.com/769-110/000-038">www.wago.com/769-110/000-038</a></p> |
|  | <p><b>Item no.: 769-110/000-039</b><br/>1-conductor female plug; 4 mm<sup>2</sup>; 10-pole</p> | <p><a href="http://www.wago.com/769-110/000-039">www.wago.com/769-110/000-039</a></p> |
|  | <p><b>Item no.: 769-111</b><br/>1-conductor female plug; 4 mm<sup>2</sup>; 11-pole</p>         | <p><a href="http://www.wago.com/769-111">www.wago.com/769-111</a></p>                 |
|  | <p><b>Item no.: 769-111/000-036</b><br/>1-conductor female plug; 4 mm<sup>2</sup>; 11-pole</p> | <p><a href="http://www.wago.com/769-111/000-036">www.wago.com/769-111/000-036</a></p> |



|  |   |  |
|--|---|--|
|  | <b>Item no.: 769-111/000-037</b><br>1-conductor female plug; 4 mm <sup>2</sup> ; 11-pole                                  | <a href="http://www.wago.com/769-111/000-037">www.wago.com/769-111/000-037</a> |
|  | <b>Item no.: 769-111/000-038</b><br>1-conductor female plug; 4 mm <sup>2</sup> ; 11-pole                                  | <a href="http://www.wago.com/769-111/000-038">www.wago.com/769-111/000-038</a> |
|  | <b>Item no.: 769-111/000-039</b><br>1-conductor female plug; 4 mm <sup>2</sup> ; 11-pole                                  | <a href="http://www.wago.com/769-111/000-039">www.wago.com/769-111/000-039</a> |
|  | <b>Item no.: 769-111/021-000</b><br>1-conductor female plug; Locking lever; 4 mm <sup>2</sup> ; 11-pole                   | <a href="http://www.wago.com/769-111/021-000">www.wago.com/769-111/021-000</a> |
|    | <b>Item no.: 769-121</b><br>2-conductor female connector; 4 mm <sup>2</sup> ; 1-pole                                      | <a href="http://www.wago.com/769-121">www.wago.com/769-121</a>                 |
|    | <b>Item no.: 769-122</b><br>2-conductor female connector; 4 mm <sup>2</sup> ; 2-pole                                      | <a href="http://www.wago.com/769-122">www.wago.com/769-122</a>                 |
|  | <b>Item no.: 769-123</b><br>2-conductor female connector; 4 mm <sup>2</sup> ; 3-pole                                      | <a href="http://www.wago.com/769-123">www.wago.com/769-123</a>                 |
|  | <b>Item no.: 769-124</b><br>2-conductor female connector; 4 mm <sup>2</sup> ; 4-pole                                      | <a href="http://www.wago.com/769-124">www.wago.com/769-124</a>                 |
|  | <b>Item no.: 769-125</b><br>2-conductor female connector; 4 mm <sup>2</sup> ; 5-pole                                      | <a href="http://www.wago.com/769-125">www.wago.com/769-125</a>                 |
|  | <b>Item no.: 769-126</b><br>2-conductor female connector; 4 mm <sup>2</sup> ; 6-pole                                      | <a href="http://www.wago.com/769-126">www.wago.com/769-126</a>                 |
|  | <b>Item no.: 769-127</b><br>2-conductor female connector; 4 mm <sup>2</sup> ; 7-pole                                      | <a href="http://www.wago.com/769-127">www.wago.com/769-127</a>                 |
|  | <b>Item no.: 769-128</b><br>2-conductor female connector; 4 mm <sup>2</sup> ; 8-pole                                      | <a href="http://www.wago.com/769-128">www.wago.com/769-128</a>                 |
|  | <b>Item no.: 769-129</b><br>2-conductor female connector; 4 mm <sup>2</sup> ; 9-pole                                      | <a href="http://www.wago.com/769-129">www.wago.com/769-129</a>                 |
|  | <b>Item no.: 769-130</b><br>2-conductor female connector; 4 mm <sup>2</sup> ; 10-pole                                     | <a href="http://www.wago.com/769-130">www.wago.com/769-130</a>                 |
|  | <b>Item no.: 769-131</b><br>2-conductor female connector; 4 mm <sup>2</sup> ; 11-pole                                     | <a href="http://www.wago.com/769-131">www.wago.com/769-131</a>                 |
| <b>Insulation stop</b>   |   |  |
|  | <b>Item no.: 769-470</b><br>Insulation stop; 0.08 - 0.2 mm <sup>2</sup> "s" (0.14 mm <sup>2</sup> "f-st"); 5 pieces/strip | <a href="http://www.wago.com/769-470">www.wago.com/769-470</a>                 |
|  | <b>Item no.: 769-471</b><br>Insulation stop; 0.25 - 0.5 mm <sup>2</sup> ; 5 pieces/strip                                  | <a href="http://www.wago.com/769-471">www.wago.com/769-471</a>                 |
|  | <b>Item no.: 769-472</b><br>Insulation stop; 0.75 - 1 mm <sup>2</sup> ; 5 pieces/strip                                    | <a href="http://www.wago.com/769-472">www.wago.com/769-472</a>                 |

---

assembling



Item no.: 769-499

Fixing screw M2.5 x 16; and hexagon nut M2.5

[www.wago.com/769-499](http://www.wago.com/769-499)

---

Downloads

Documentation

Bid Text

---

|                 |              |                |          |
|-----------------|--------------|----------------|----------|
| 769-611/002-000 | Oct 18, 2017 | DOC<br>25.6 kB | Download |
|-----------------|--------------|----------------|----------|

---

smartDATA

CAD data

---

|                             |     |          |
|-----------------------------|-----|----------|
| 3D Download 769-611/002-000 | URL | Download |
|-----------------------------|-----|----------|

---

Product family

**X-COM**

[Learn more about the product family.](#)

[Show all products from the family](#)

Subject to changes.