



## Data sheet | Item number: 769-614/004-000

1-conductor male connector; Feedthrough flange; 4 mm<sup>2</sup>; Pin spacing 5 mm;  
14-pole

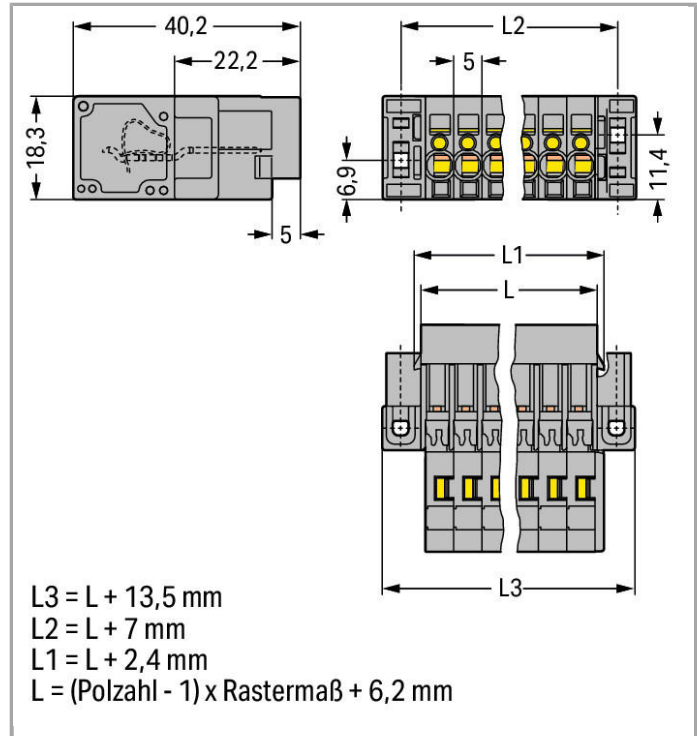

[www.wago.com/769-614/004-000](http://www.wago.com/769-614/004-000)

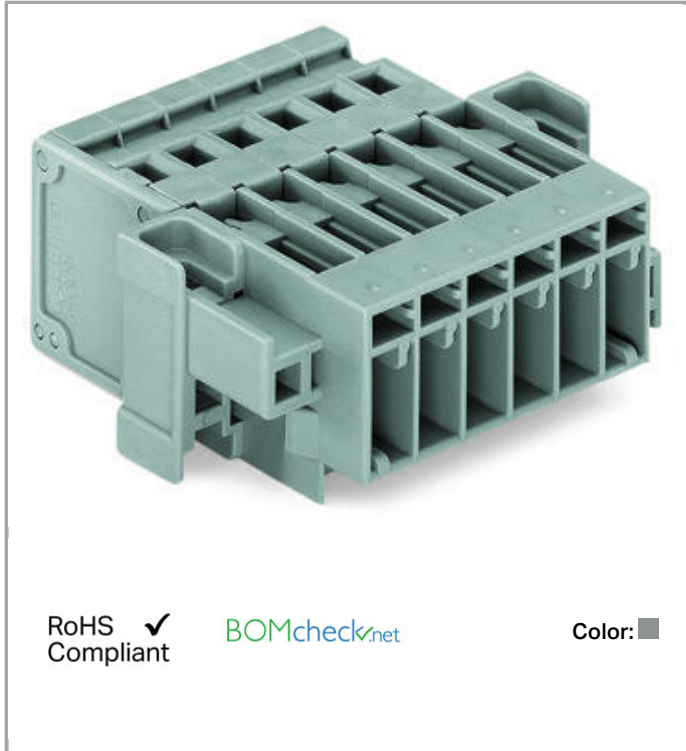

### Data

#### Electrical data

#### Ratings per IEC/EN 60664-1

Rated voltage (III / 3)	500 V
Rated impulse voltage (III / 3)	6 kV
Rated current	32 A
Legend (ratings)	(III / 3) ≙ Overvoltage category III / Pollution degree 3

#### Connection data

Connection technology	CAGE CLAMP®
Actuation type	Operating tool
Connectable conductor materials	Copper Aluminum
Nominal cross section	4 mm <sup>2</sup>
Solid conductor	0,08 ... 4 mm <sup>2</sup> / 28 ... 12 AWG
Fine-stranded conductor	0,08 ... 4 mm <sup>2</sup> / 28 ... 12 AWG



Strip length	8 ... 9 mm / 0.31 ... 0.35 Inch
No. of poles	14
Total number of connection points	14
Total number of potentials	14
Type of wiring	Front-entry wiring

### Geometrical Data

Pin spacing	5 mm / 0.197 inch
Width	84.7 mm / 3.335 inch
Height from the surface	18.3 mm / 0.72 inch
Depth	40.2 mm / 1.583 inch

### Mechanical data

Mounting type	Mounting flange
---------------	-----------------

### Plug connection

Contact type (pluggable connector)	Male connector/plug
Connector connection type	for conductors

### Material Data

Color	gray
Insulating material	Polyamide 66 (PA 66)
Fire load	0.824 MJ
Weight	40.803 g

### Commercial data

Country of origin	PL
GTIN	4044918820431
Customs Tariff No.	85366990990
Product Group	18 (X-COM-System)

### Approvals / Certificates

#### Country specific Approvals

Logo	Approval	Certificate name
	CCA DEKRA Certification B.V.	NTR NL-7626
	CSA DEKRA Certification B.V.	1101144





KEMA/KEUR

2190419.01



DEKRA Certification B.V.

## UL-Approvals



Logo	Approval	Certificate name
	UR Underwriters Laboratories Inc.	E45172
	UR Underwriters Laboratories Inc.	E45171

## Compatible products

## Strain relief plate













	Item no.: 769-410 Strain relief plate	<a href="http://www.wago.com/769-410">www.wago.com/769-410</a>
	Item no.: 769-414 Strain relief plate	<a href="http://www.wago.com/769-414">www.wago.com/769-414</a>

## tools

	Item no.: 210-490 Operating tool; for female and male connectors with CAGE CLAMP® connection	<a href="http://www.wago.com/210-490">www.wago.com/210-490</a>
	Item no.: 769-434 Push-button; loose; for female and male connectors with CAGE CLAMP® connection	<a href="http://www.wago.com/769-434">www.wago.com/769-434</a>

## Female plug

	Item no.: 769-101 1-conductor female plug; 4 mm <sup>2</sup> ; 1-pole	<a href="http://www.wago.com/769-101">www.wago.com/769-101</a>
	Item no.: 769-101/000-016 1-conductor female plug; 4 mm <sup>2</sup> ; 1-pole	<a href="http://www.wago.com/769-101/000-016">www.wago.com/769-101/000-016</a>
	Item no.: 769-102 1-conductor female plug; 4 mm <sup>2</sup> ; 2-pole	<a href="http://www.wago.com/769-102">www.wago.com/769-102</a>
	Item no.: 769-102/000-036 1-conductor female plug; 4 mm <sup>2</sup> ; 2-pole	<a href="http://www.wago.com/769-102/000-036">www.wago.com/769-102/000-036</a>

	<p><b>Item no.: 769-102/000-037</b> 1-conductor female plug; 4 mm<sup>2</sup>; 2-pole</p>	<p><a href="http://www.wago.com/769-102/000-037">www.wago.com/769-102/000-037</a></p>
	<p><b>Item no.: 769-103</b> 1-conductor female plug; 4 mm<sup>2</sup>; 3-pole</p>	<p><a href="http://www.wago.com/769-103">www.wago.com/769-103</a></p>
	<p><b>Item no.: 769-103/000-036</b> 1-conductor female plug; 4 mm<sup>2</sup>; 3-pole</p>	<p><a href="http://www.wago.com/769-103/000-036">www.wago.com/769-103/000-036</a></p>
	<p><b>Item no.: 769-103/000-037</b> 1-conductor female plug; 4 mm<sup>2</sup>; 3-pole</p>	<p><a href="http://www.wago.com/769-103/000-037">www.wago.com/769-103/000-037</a></p>
	<p><b>Item no.: 769-103/000-038</b> 1-conductor female plug; 4 mm<sup>2</sup>; 3-pole</p>	<p><a href="http://www.wago.com/769-103/000-038">www.wago.com/769-103/000-038</a></p>
	<p><b>Item no.: 769-103/000-039</b> 1-conductor female plug; 4 mm<sup>2</sup>; 3-pole</p>	<p><a href="http://www.wago.com/769-103/000-039">www.wago.com/769-103/000-039</a></p>
	<p><b>Item no.: 769-104</b> 1-conductor female plug; 4 mm<sup>2</sup>; 4-pole</p>	<p><a href="http://www.wago.com/769-104">www.wago.com/769-104</a></p>
	<p><b>Item no.: 769-104/000-036</b> 1-conductor female plug; 4 mm<sup>2</sup>; 4-pole</p>	<p><a href="http://www.wago.com/769-104/000-036">www.wago.com/769-104/000-036</a></p>
	<p><b>Item no.: 769-104/000-037</b> 1-conductor female plug; 4 mm<sup>2</sup>; 4-pole</p>	<p><a href="http://www.wago.com/769-104/000-037">www.wago.com/769-104/000-037</a></p>
	<p><b>Item no.: 769-104/000-038</b> 1-conductor female plug; 4 mm<sup>2</sup>; 4-pole</p>	<p><a href="http://www.wago.com/769-104/000-038">www.wago.com/769-104/000-038</a></p>
	<p><b>Item no.: 769-104/000-039</b> 1-conductor female plug; 4 mm<sup>2</sup>; 4-pole</p>	<p><a href="http://www.wago.com/769-104/000-039">www.wago.com/769-104/000-039</a></p>
	<p><b>Item no.: 769-105</b> 1-conductor female plug; 4 mm<sup>2</sup>; 5-pole</p>	<p><a href="http://www.wago.com/769-105">www.wago.com/769-105</a></p>
	<p><b>Item no.: 769-105/000-036</b> 1-conductor female plug; 4 mm<sup>2</sup>; 5-pole</p>	<p><a href="http://www.wago.com/769-105/000-036">www.wago.com/769-105/000-036</a></p>
	<p><b>Item no.: 769-105/000-037</b> 1-conductor female plug; 4 mm<sup>2</sup>; 5-pole</p>	<p><a href="http://www.wago.com/769-105/000-037">www.wago.com/769-105/000-037</a></p>
	<p><b>Item no.: 769-105/000-038</b> 1-conductor female plug; 4 mm<sup>2</sup>; 5-pole</p>	<p><a href="http://www.wago.com/769-105/000-038">www.wago.com/769-105/000-038</a></p>



**Item no.: 769-105/000-039**  
1-conductor female plug; 4 mm<sup>2</sup>; 5-pole

[www.wago.com/769-105/000-039](http://www.wago.com/769-105/000-039)

**Item no.: 769-106**  
1-conductor female plug; 4 mm<sup>2</sup>; 6-pole

[www.wago.com/769-106](http://www.wago.com/769-106)

**Item no.: 769-106/000-006**  
1-conductor female plug; 4 mm<sup>2</sup>; 6-pole

[www.wago.com/769-106/000-006](http://www.wago.com/769-106/000-006)



**Item no.: 769-106/000-036**  
1-conductor female plug; 4 mm<sup>2</sup>; 6-pole

[www.wago.com/769-106/000-036](http://www.wago.com/769-106/000-036)



**Item no.: 769-106/000-037**  
1-conductor female plug; 4 mm<sup>2</sup>; 6-pole

[www.wago.com/769-106/000-037](http://www.wago.com/769-106/000-037)



**Item no.: 769-106/000-038**  
1-conductor female plug; 4 mm<sup>2</sup>; 6-pole

[www.wago.com/769-106/000-038](http://www.wago.com/769-106/000-038)



**Item no.: 769-106/000-039**  
1-conductor female plug; 4 mm<sup>2</sup>; 6-pole

[www.wago.com/769-106/000-039](http://www.wago.com/769-106/000-039)

**Item no.: 769-107**  
1-conductor female plug; 4 mm<sup>2</sup>; 7-pole

[www.wago.com/769-107](http://www.wago.com/769-107)



**Item no.: 769-107/000-036**  
1-conductor female plug; 4 mm<sup>2</sup>; 7-pole

[www.wago.com/769-107/000-036](http://www.wago.com/769-107/000-036)



**Item no.: 769-107/000-037**  
1-conductor female plug; 4 mm<sup>2</sup>; 7-pole

[www.wago.com/769-107/000-037](http://www.wago.com/769-107/000-037)



**Item no.: 769-107/000-038**  
1-conductor female plug; 4 mm<sup>2</sup>; 7-pole

[www.wago.com/769-107/000-038](http://www.wago.com/769-107/000-038)



**Item no.: 769-107/000-039**  
1-conductor female plug; 4 mm<sup>2</sup>; 7-pole

[www.wago.com/769-107/000-039](http://www.wago.com/769-107/000-039)

**Item no.: 769-108**  
1-conductor female plug; 4 mm<sup>2</sup>; 8-pole





[www.wago.com/769-108](http://www.wago.com/769-108)





**Item no.: 769-108/000-036**  
1-conductor female plug; 4 mm<sup>2</sup>; 8-pole




[www.wago.com/769-108/000-036](http://www.wago.com/769-108/000-036)

**Item no.: 769-108/000-037**  
1-conductor female plug; 4 mm<sup>2</sup>; 8-pole


[www.wago.com/769-108/000-037](http://www.wago.com/769-108/000-037)

	<p><b>Item no.: 769-108/000-038</b> 1-conductor female plug; 4 mm<sup>2</sup>; 8-pole</p>	<p><a href="http://www.wago.com/769-108/000-038">www.wago.com/769-108/000-038</a></p>
	<p><b>Item no.: 769-108/000-039</b> 1-conductor female plug; 4 mm<sup>2</sup>; 8-pole</p>	<p><a href="http://www.wago.com/769-108/000-039">www.wago.com/769-108/000-039</a></p>
	<p><b>Item no.: 769-109</b> 1-conductor female plug; 4 mm<sup>2</sup>; 9-pole</p>	<p><a href="http://www.wago.com/769-109">www.wago.com/769-109</a></p>
	<p><b>Item no.: 769-109/000-036</b> 1-conductor female plug; 4 mm<sup>2</sup>; 9-pole</p>	<p><a href="http://www.wago.com/769-109/000-036">www.wago.com/769-109/000-036</a></p>
	<p><b>Item no.: 769-109/000-037</b> 1-conductor female plug; 4 mm<sup>2</sup>; 9-pole</p>	<p><a href="http://www.wago.com/769-109/000-037">www.wago.com/769-109/000-037</a></p>
	<p><b>Item no.: 769-109/000-038</b> 1-conductor female plug; 4 mm<sup>2</sup>; 9-pole</p>	<p><a href="http://www.wago.com/769-109/000-038">www.wago.com/769-109/000-038</a></p>
	<p><b>Item no.: 769-109/000-039</b> 1-conductor female plug; 4 mm<sup>2</sup>; 9-pole</p>	<p><a href="http://www.wago.com/769-109/000-039">www.wago.com/769-109/000-039</a></p>
	<p><b>Item no.: 769-110</b> 1-conductor female plug; 4 mm<sup>2</sup>; 10-pole</p>	<p><a href="http://www.wago.com/769-110">www.wago.com/769-110</a></p>
	<p><b>Item no.: 769-110/000-036</b> 1-conductor female plug; 4 mm<sup>2</sup>; 10-pole</p>	<p><a href="http://www.wago.com/769-110/000-036">www.wago.com/769-110/000-036</a></p>
	<p><b>Item no.: 769-110/000-037</b> 1-conductor female plug; 4 mm<sup>2</sup>; 10-pole</p>	<p><a href="http://www.wago.com/769-110/000-037">www.wago.com/769-110/000-037</a></p>
	<p><b>Item no.: 769-110/000-038</b> 1-conductor female plug; 4 mm<sup>2</sup>; 10-pole</p>	<p><a href="http://www.wago.com/769-110/000-038">www.wago.com/769-110/000-038</a></p>
	<p><b>Item no.: 769-110/000-039</b> 1-conductor female plug; 4 mm<sup>2</sup>; 10-pole</p>	<p><a href="http://www.wago.com/769-110/000-039">www.wago.com/769-110/000-039</a></p>
	<p><b>Item no.: 769-111</b> 1-conductor female plug; 4 mm<sup>2</sup>; 11-pole</p>	<p><a href="http://www.wago.com/769-111">www.wago.com/769-111</a></p>
	<p><b>Item no.: 769-111/000-036</b> 1-conductor female plug; 4 mm<sup>2</sup>; 11-pole</p>	<p><a href="http://www.wago.com/769-111/000-036">www.wago.com/769-111/000-036</a></p>
	<p><b>Item no.: 769-111/000-037</b> 1-conductor female plug; 4 mm<sup>2</sup>; 11-pole</p>	<p><a href="http://www.wago.com/769-111/000-037">www.wago.com/769-111/000-037</a></p>

	<p><b>Item no.: 769-111/000-038</b> 1-conductor female plug; 4 mm<sup>2</sup>; 11-pole</p>	<p><a href="http://www.wago.com/769-111/000-038">www.wago.com/769-111/000-038</a></p>
	<p><b>Item no.: 769-111/000-039</b> 1-conductor female plug; 4 mm<sup>2</sup>; 11-pole</p>	<p><a href="http://www.wago.com/769-111/000-039">www.wago.com/769-111/000-039</a></p>
	<p><b>Item no.: 769-112</b> 1-conductor female plug; 4 mm<sup>2</sup>; 12-pole</p>	<p><a href="http://www.wago.com/769-112">www.wago.com/769-112</a></p>
	<p><b>Item no.: 769-112/000-036</b> 1-conductor female plug; 4 mm<sup>2</sup>; 12-pole</p>	<p><a href="http://www.wago.com/769-112/000-036">www.wago.com/769-112/000-036</a></p>
	<p><b>Item no.: 769-112/000-037</b> 1-conductor female plug; 4 mm<sup>2</sup>; 12-pole</p>	<p><a href="http://www.wago.com/769-112/000-037">www.wago.com/769-112/000-037</a></p>
	<p><b>Item no.: 769-112/000-038</b> 1-conductor female plug; 4 mm<sup>2</sup>; 12-pole</p>	<p><a href="http://www.wago.com/769-112/000-038">www.wago.com/769-112/000-038</a></p>
	<p><b>Item no.: 769-112/000-039</b> 1-conductor female plug; 4 mm<sup>2</sup>; 12-pole</p>	<p><a href="http://www.wago.com/769-112/000-039">www.wago.com/769-112/000-039</a></p>
	<p><b>Item no.: 769-113</b> 1-conductor female plug; 4 mm<sup>2</sup>; 13-pole</p>	<p><a href="http://www.wago.com/769-113">www.wago.com/769-113</a></p>
	<p><b>Item no.: 769-113/000-036</b> 1-conductor female plug; 4 mm<sup>2</sup>; 13-pole</p>	<p><a href="http://www.wago.com/769-113/000-036">www.wago.com/769-113/000-036</a></p>
	<p><b>Item no.: 769-113/000-037</b> 1-conductor female plug; 4 mm<sup>2</sup>; 13-pole</p>	<p><a href="http://www.wago.com/769-113/000-037">www.wago.com/769-113/000-037</a></p>
	<p><b>Item no.: 769-113/000-038</b> 1-conductor female plug; 4 mm<sup>2</sup>; 13-pole</p>	<p><a href="http://www.wago.com/769-113/000-038">www.wago.com/769-113/000-038</a></p>
	<p><b>Item no.: 769-113/000-039</b> 1-conductor female plug; 4 mm<sup>2</sup>; 13-pole</p>	<p><a href="http://www.wago.com/769-113/000-039">www.wago.com/769-113/000-039</a></p>
	<p><b>Item no.: 769-114</b> 1-conductor female plug; 4 mm<sup>2</sup>; 14-pole</p>	<p><a href="http://www.wago.com/769-114">www.wago.com/769-114</a></p>
	<p><b>Item no.: 769-114/000-036</b> 1-conductor female plug; 4 mm<sup>2</sup>; 14-pole</p>	<p><a href="http://www.wago.com/769-114/000-036">www.wago.com/769-114/000-036</a></p>
	<p><b>Item no.: 769-114/000-037</b> 1-conductor female plug; 4 mm<sup>2</sup>; 14-pole</p>	<p><a href="http://www.wago.com/769-114/000-037">www.wago.com/769-114/000-037</a></p>

	<b>Item no.: 769-114/000-038</b> 1-conductor female plug; 4 mm <sup>2</sup> ; 14-pole	<a href="http://www.wago.com/769-114/000-038">www.wago.com/769-114/000-038</a>
	<b>Item no.: 769-114/000-039</b> 1-conductor female plug; 4 mm <sup>2</sup> ; 14-pole	<a href="http://www.wago.com/769-114/000-039">www.wago.com/769-114/000-039</a>
	<b>Item no.: 769-114/021-000</b> 1-conductor female plug; Locking lever; 4 mm <sup>2</sup> ; 14-pole	<a href="http://www.wago.com/769-114/021-000">www.wago.com/769-114/021-000</a>
	<b>Item no.: 769-121</b> 2-conductor female connector; 4 mm <sup>2</sup> ; 1-pole	<a href="http://www.wago.com/769-121">www.wago.com/769-121</a>
	<b>Item no.: 769-122</b> 2-conductor female connector; 4 mm <sup>2</sup> ; 2-pole	<a href="http://www.wago.com/769-122">www.wago.com/769-122</a>
	<b>Item no.: 769-123</b> 2-conductor female connector; 4 mm <sup>2</sup> ; 3-pole	<a href="http://www.wago.com/769-123">www.wago.com/769-123</a>
	<b>Item no.: 769-124</b> 2-conductor female connector; 4 mm <sup>2</sup> ; 4-pole	<a href="http://www.wago.com/769-124">www.wago.com/769-124</a>
	<b>Item no.: 769-125</b> 2-conductor female connector; 4 mm <sup>2</sup> ; 5-pole	<a href="http://www.wago.com/769-125">www.wago.com/769-125</a>
	<b>Item no.: 769-126</b> 2-conductor female connector; 4 mm <sup>2</sup> ; 6-pole	<a href="http://www.wago.com/769-126">www.wago.com/769-126</a>
	<b>Item no.: 769-127</b> 2-conductor female connector; 4 mm <sup>2</sup> ; 7-pole	<a href="http://www.wago.com/769-127">www.wago.com/769-127</a>
	<b>Item no.: 769-128</b> 2-conductor female connector; 4 mm <sup>2</sup> ; 8-pole	<a href="http://www.wago.com/769-128">www.wago.com/769-128</a>
	<b>Item no.: 769-129</b> 2-conductor female connector; 4 mm <sup>2</sup> ; 9-pole	<a href="http://www.wago.com/769-129">www.wago.com/769-129</a>
	<b>Item no.: 769-130</b> 2-conductor female connector; 4 mm <sup>2</sup> ; 10-pole	<a href="http://www.wago.com/769-130">www.wago.com/769-130</a>
	<b>Item no.: 769-131</b> 2-conductor female connector; 4 mm <sup>2</sup> ; 11-pole	<a href="http://www.wago.com/769-131">www.wago.com/769-131</a>
	<b>Item no.: 769-132</b> 2-conductor female connector; 4 mm <sup>2</sup> ; 12-pole	<a href="http://www.wago.com/769-132">www.wago.com/769-132</a>
	<b>Item no.: 769-133</b> 2-conductor female connector; 4 mm <sup>2</sup> ; 13-pole	<a href="http://www.wago.com/769-133">www.wago.com/769-133</a>
	<b>Item no.: 769-134</b> 2-conductor female connector; 4 mm <sup>2</sup> ; 14-pole	<a href="http://www.wago.com/769-134">www.wago.com/769-134</a>

**Protective Warning Marker**

	<b>Item no.: 280-415</b> Protective warning marker; with high-voltage symbol, black; for 5 terminal blocks	<a href="http://www.wago.com/280-415">www.wago.com/280-415</a>
--	---	--



## Coding

**Item no.: 769-435**

Coding pin; for coding of female plugs; for carrier terminal blocks / male connectors

[www.wago.com/769-435](http://www.wago.com/769-435)

## Marking accessories

**Item no.: 2009-145**

Mini-WSB Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type

[www.wago.com/2009-145](http://www.wago.com/2009-145)**Item no.: 2009-145/000-002**

Mini-WSB Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type

[www.wago.com/2009-145/000-002](http://www.wago.com/2009-145/000-002)**Item no.: 2009-145/000-005**

Mini-WSB Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type

[www.wago.com/2009-145/000-005](http://www.wago.com/2009-145/000-005)**Item no.: 2009-145/000-006**

Mini-WSB Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type

[www.wago.com/2009-145/000-006](http://www.wago.com/2009-145/000-006)**Item no.: 2009-145/000-007**

Mini-WSB Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type

[www.wago.com/2009-145/000-007](http://www.wago.com/2009-145/000-007)**Item no.: 2009-145/000-012**

Mini-WSB Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type

[www.wago.com/2009-145/000-012](http://www.wago.com/2009-145/000-012)**Item no.: 2009-145/000-023**

Mini-WSB Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type

[www.wago.com/2009-145/000-023](http://www.wago.com/2009-145/000-023)**Item no.: 2009-145/000-024**

Mini-WSB Inline; on reel; stretchable 5 - 5.2 mm; plain; snap-on type

[www.wago.com/2009-145/000-024](http://www.wago.com/2009-145/000-024)**Item no.: 210-831**

Marking strips; on reel; 2.3 mm wide; plain; Self-adhesive

[www.wago.com/210-831](http://www.wago.com/210-831)**Item no.: 210-832**

Marking strips; on reel; 3 mm wide; plain; Self-adhesive

[www.wago.com/210-832](http://www.wago.com/210-832)**Item no.: 210-833**

Marking strips; on reel; 6 mm wide; plain; Self-adhesive

[www.wago.com/210-833](http://www.wago.com/210-833)**Item no.: 210-834**

Marking strips; on reel; 5 mm wide; plain; Self-adhesive

[www.wago.com/210-834](http://www.wago.com/210-834)**Item no.: 248-501**

Miniature WSB Quick marking system; plain; Marker width 5 mm; 10 strips with 10 markers per card

[www.wago.com/248-501](http://www.wago.com/248-501)**Item no.: 248-501/000-002**

Mini-WSB marking card; as card; not stretchable; plain; snap-on type

[www.wago.com/248-501/000-002](http://www.wago.com/248-501/000-002)



**Item no.: 248-501/000-005**  
Mini-WSB marking card; as card; plain; snap-on type

[www.wago.com/248-501/000-005](http://www.wago.com/248-501/000-005)



**Item no.: 248-501/000-006**  
Mini-WSB marking card; as card; not stretchable; plain; snap-on type

[www.wago.com/248-501/000-006](http://www.wago.com/248-501/000-006)



**Item no.: 248-501/000-007**  
Mini-WSB marking card; as card; not stretchable; plain; snap-on type

[www.wago.com/248-501/000-007](http://www.wago.com/248-501/000-007)



**Item no.: 248-501/000-012**  
Mini-WSB marking card; as card; not stretchable; plain; snap-on type

[www.wago.com/248-501/000-012](http://www.wago.com/248-501/000-012)



**Item no.: 248-501/000-017**  
Mini-WSB marking card; as card; not stretchable; plain; snap-on type

[www.wago.com/248-501/000-017](http://www.wago.com/248-501/000-017)



**Item no.: 248-501/000-023**  
Mini-WSB marking card; as card; not stretchable; plain; snap-on type

[www.wago.com/248-501/000-023](http://www.wago.com/248-501/000-023)



**Item no.: 248-501/000-024**  
Mini-WSB marking card; as card; not stretchable; plain; snap-on type

[www.wago.com/248-501/000-024](http://www.wago.com/248-501/000-024)

#### ferrule



**Item no.: 216-101**  
Ferrule; Sleeve for 0.5 mm<sup>2</sup> / AWG 22; uninsulated; electro-tin plated

[www.wago.com/216-101](http://www.wago.com/216-101)



**Item no.: 216-102**  
Ferrule; Sleeve for 0.75 mm<sup>2</sup> / AWG 20; uninsulated; electro-tin plated

[www.wago.com/216-102](http://www.wago.com/216-102)



**Item no.: 216-103**  
Ferrule; Sleeve for 1 mm<sup>2</sup> / AWG 18; uninsulated; electro-tin plated

[www.wago.com/216-103](http://www.wago.com/216-103)



**Item no.: 216-104**  
Ferrule; Sleeve for 1.5 mm<sup>2</sup> / AWG 16; uninsulated; electro-tin plated

[www.wago.com/216-104](http://www.wago.com/216-104)



**Item no.: 216-201**  
Ferrule; Sleeve for 0.5 mm<sup>2</sup> / AWG 22; insulated; electro-tin plated

[www.wago.com/216-201](http://www.wago.com/216-201)



**Item no.: 216-202**  
Ferrule; Sleeve for 0.75 mm<sup>2</sup> / AWG 20; insulated; electro-tin plated

[www.wago.com/216-202](http://www.wago.com/216-202)



**Item no.: 216-203**  
Ferrule; Sleeve for 1 mm<sup>2</sup> / AWG 18; insulated; electro-tin plated

[www.wago.com/216-203](http://www.wago.com/216-203)



**Item no.: 216-204**  
Ferrule; Sleeve for 1.5 mm<sup>2</sup> / AWG 16; insulated; electro-tin plated

[www.wago.com/216-204](http://www.wago.com/216-204)



**Item no.: 216-206**  
Ferrule; Sleeve for 2.5 mm<sup>2</sup> / AWG 14; insulated; electro-tin plated

[www.wago.com/216-206](http://www.wago.com/216-206)

#### Insulation stop



**Item no.: 769-470**  
Insulation stop; 0.08 - 0.2 mm<sup>2</sup> "s" (0.14 mm<sup>2</sup> "f-st"); 5 pieces/strip

[www.wago.com/769-470](http://www.wago.com/769-470)



**Item no.: 769-471**  
Insulation stop; 0.25 - 0.5 mm<sup>2</sup>; 5 pieces/strip

[www.wago.com/769-471](http://www.wago.com/769-471)



**Item no.: 769-472**  
Insulation stop; 0.75 - 1 mm<sup>2</sup>; 5 pieces/strip

[www.wago.com/769-472](http://www.wago.com/769-472)

## Downloads

### Documentation

#### Bid Text

769-614/004-000	Oct 18, 2017	DOC 25.6 kB	Download
-----------------	--------------	----------------	----------

## smartDATA

### CAD data

3D Download 769-614/004-000	URL	Download
-----------------------------	-----	----------

## Product family

### X-COM

[Learn more about the product family.](#)

[Show all products from the family](#)

Subject to changes.

WAGO Kontakttechnik GmbH & Co. KG  
Hansastr. 27  
32423 Minden  
Phone: +49571 887-0 | Fax: +49571 887-169  
Email: [info.de@wago.com](mailto:info.de@wago.com) | Web: [www.wago.com](http://www.wago.com)

Do you have any questions about our products?  
We are always happy to take your call at +49 (571) 887-44222.