
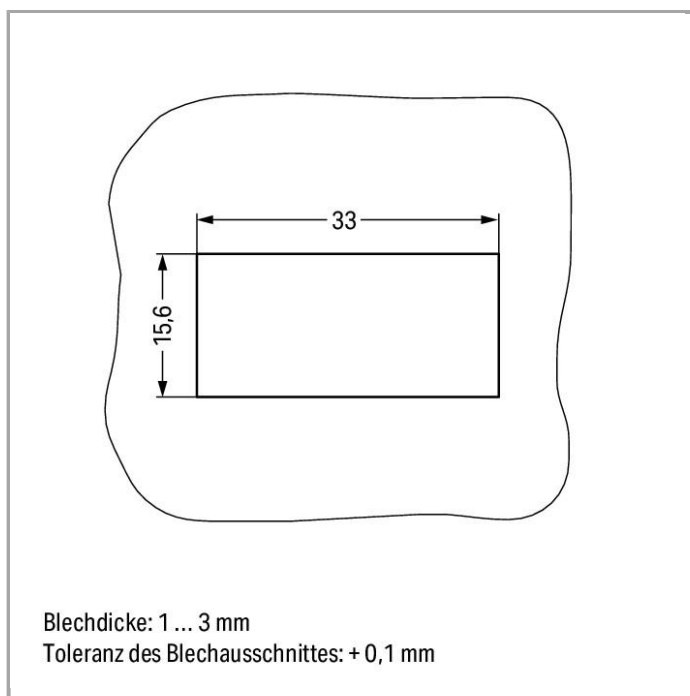
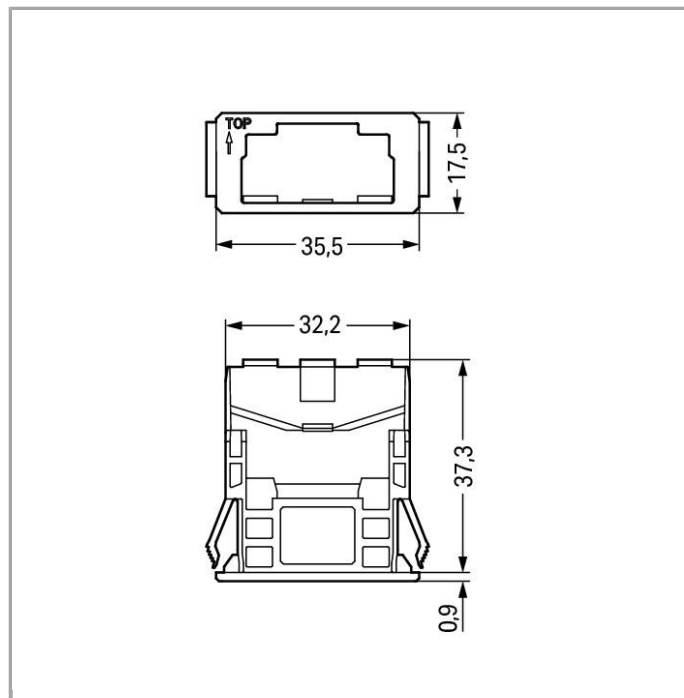


Data sheet | Item number: 770-318

Snap-in frame; for 3-pole sockets and plugs; 3-pole

www.wago.com/770-318

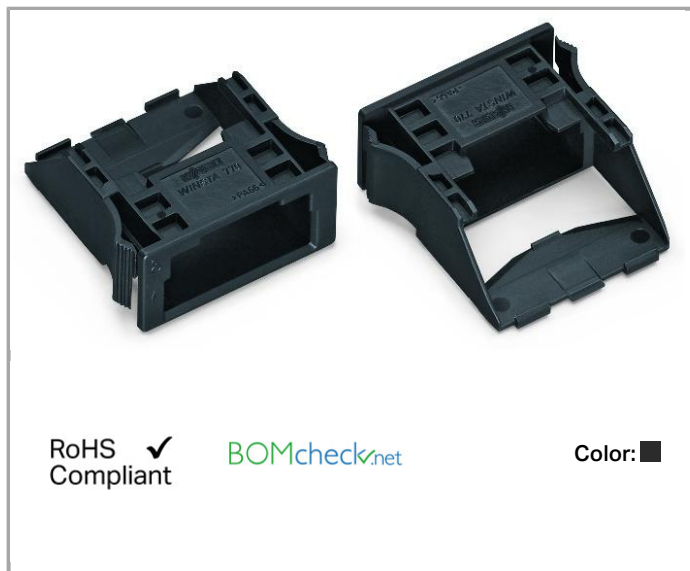

Data

Electrical data

Ratings per IEC/EN 60664-1

Legend (ratings)

(III / 3) ≙ Overvoltage category III / Pollution degree 3

Geometrical Data

Width	35.5 mm / 1.398 inch
Height	17.5 mm / 0.689 inch
Depth	38.75 mm / 1.526 inch

Mechanical data

Gehäuseblechstärke	1 ... 3 mm / 0.039 ... 0.118 inch
Mounting type	Snap-in
Degree of protection	IP20

Material Data

Color	black
Insulating material	Polyamide 66 (PA 66)
Flammability class per UL94	V0
Fire load	0.098 MJ
Weight	3.26 g

Environmental Requirements

Surrounding air (operating) temperature	-35 ... 85 °C
---	---------------

Commercial data

Packaging type	bag
Country of origin	DE
GTIN	4045454777548
Customs Tariff No.	39269097900
Product Group	20 (WINSTA)

Compatible products

Locking lever



Item no.: 770-140

Locking lever; for sockets; for manual operation

www.wago.com/770-140

Downloads

Documentation

Bid Text



770-318	Feb 1, 2016	DOC	Download
WINSTA MIDI 3-polig		23.6 kB	

smartDATA

CAD data

3D Download 770-318	URL	Download
---------------------	-----	----------

Subject to changes.