

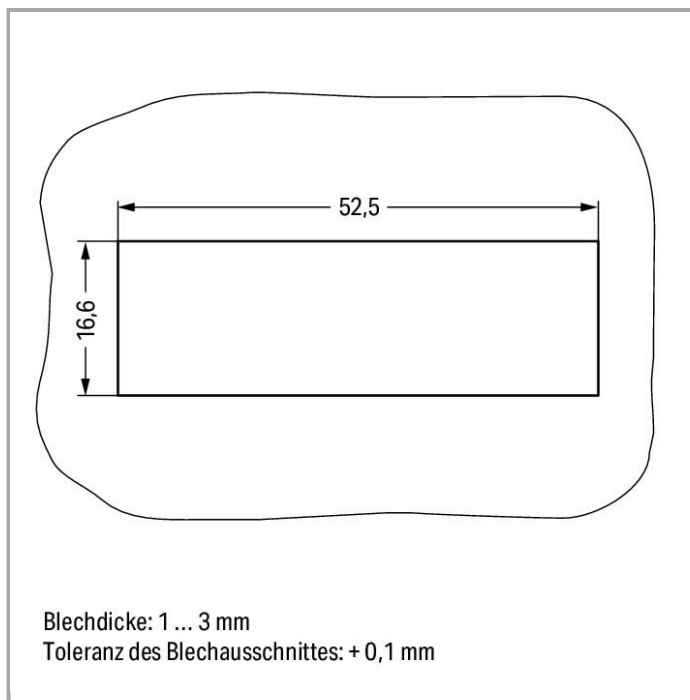


Data sheet | Item number: 770-320

Snap-in frame; 5-pole; for 1 - 3 mm plate thickness; suitable for coding A / I / P / Q

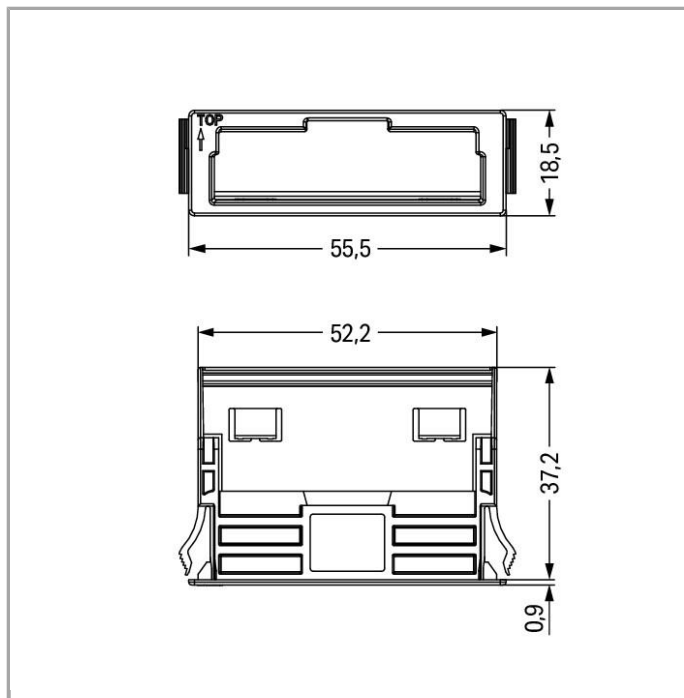

www.wago.com/770-320

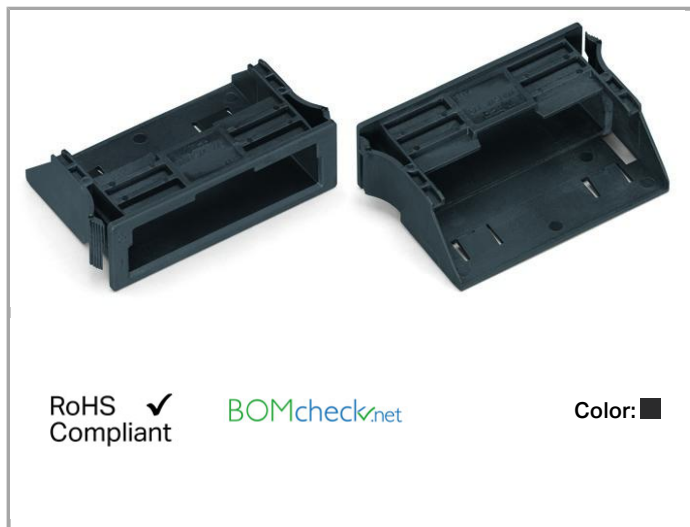

Data

Electrical data

Ratings per IEC/EN 60664-1

Legend (ratings)

(III / 3) $\hat{=}$ Overvoltage category III / Pollution degree 3

Geometrical Data

Width	55.5 mm / 2.185 inch
Height	18.5 mm / 0.728 inch
Depth	37.5 mm / 1.476 inch

Mechanical data

Gehäuseblechstärke	1 ... 3 mm / 0.039 ... 0.118 inch
Mounting type	Snap-in
Degree of protection	IP20

Material Data

Color	black
Insulating material	Polyamide 66 (PA 66)
Flammability class per UL94	V0
Fire load	0.167 MJ
Weight	5.58 g

Environmental Requirements

Surrounding air (operating) temperature	-35 ... 85 °C
---	---------------

Commercial data

Packaging type	bag
Country of origin	DE
GTIN	4045454997205
Customs Tariff No.	39269097900
Product Group	20 (WINSTA)

Approvals / Certificates

Ship Approvals

Logo	Approval	Certificate name
	LR Lloyds Register	02/20050 (E6)

Compatible products

Locking lever



Item no.: 770-140

Locking lever; for sockets; for manual operation

www.wago.com/770-140

Downloads

Documentation

Bid Text

770-320	Jan 21, 2016	DOC	Download
WINSTA MIDI 5-polig		24.1 kB	

smartDATA

CAD data

3D Download 770-320	URL	Download
---------------------	-----	----------

Subject to changes.

WAGO Kontakttechnik GmbH & Co. KG

Hansastr. 27

32423 Minden

Phone: +49571 887-0 | Fax: +49571 887-169

Email: info.de@wago.com | Web: www.wago.com

Do you have any questions about our products?

We are always happy to take your call at +49 (571) 887-44222.