
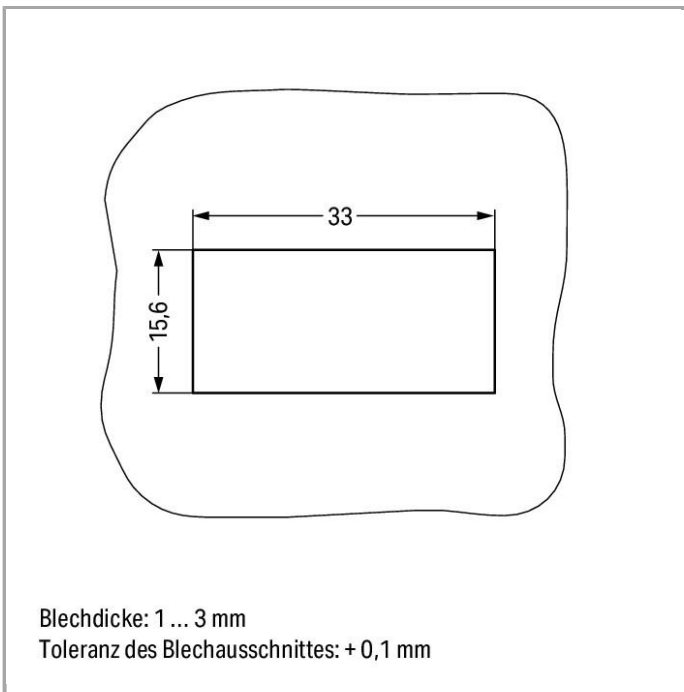
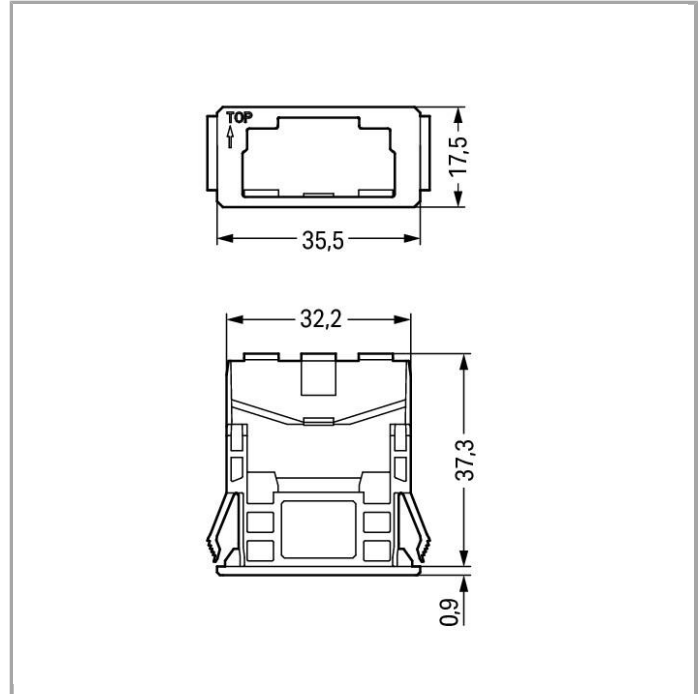


Data sheet | Item number: 770-338

Snap-in frame; for 3-pole sockets and plugs; 3-pole

www.wago.com/770-338

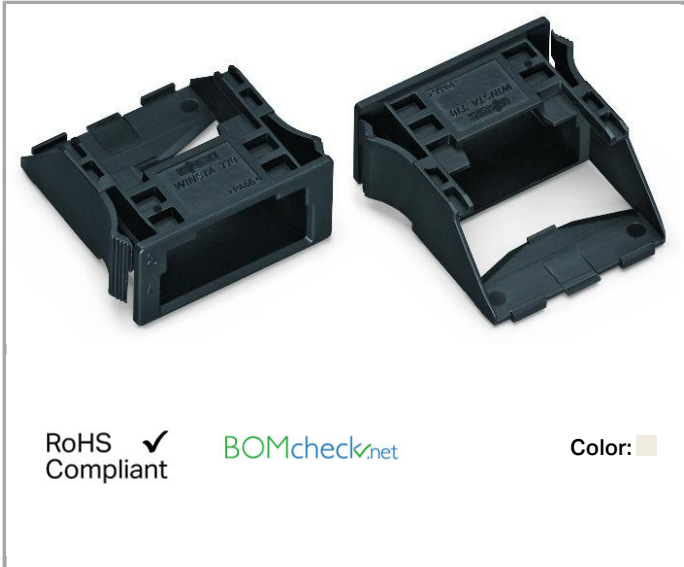

Data

Electrical data

Ratings per IEC/EN 60664-1

Legend (ratings)

(III / 3) $\hat{=}$ Overvoltage category III / Pollution degree 3

Geometrical Data

| | |
|--------|-----------------------|
| Width | 35.5 mm / 1.398 inch |
| Height | 17.5 mm / 0.689 inch |
| Depth | 38.75 mm / 1.526 inch |

Mechanical data

| | |
|----------------------|-----------------------------------|
| Gehäuseblechstärke | 1 ... 3 mm / 0.039 ... 0.118 inch |
| Mounting type | Snap-in |
| Degree of protection | IP20 |

Material Data

| | |
|-----------------------------|----------------------|
| Color | white |
| Insulating material | Polyamide 66 (PA 66) |
| Flammability class per UL94 | V0 |
| Fire load | 0.098 MJ |
| Weight | 3.26 g |

Environmental Requirements

| | |
|---|---------------|
| Surrounding air (operating) temperature | -35 ... 85 °C |
|---|---------------|

Commercial data

| | |
|--------------------|---------------|
| Country of origin | DE |
| GTIN | 4045454997212 |
| Customs Tariff No. | 39269097900 |
| Product Group | 20 (WINSTA) |

Approvals / Certificates

Ship Approvals

| Logo | Approval | Certificate name |
|--|-----------------------|------------------|
|  | LR Lloyds Register | 02/20050 (E6) |

Compatible products

Locking lever



Item no.: 770-140

Locking lever; for sockets; for manual operation

www.wago.com/770-140

Downloads

Documentation

Bid Text

| | | | |
|---------------------|-------------|---------|----------|
| 770-338 | Feb 1, 2016 | DOC | Download |
| WINSTA MIDI 3-polig | | 23.6 kB | |

smartDATA

CAD data

| | | |
|---------------------|-----|----------|
| 3D Download 770-338 | URL | Download |
|---------------------|-----|----------|

Subject to changes.