


## Data sheet | Item number: 870-127

1-conductor/1-pin double deck receptacle terminal block; Ground conductor /through terminal block; PE/L; for DIN-rail 35 x 15 and 35 x 7.5; 2.5 mm<sup>2</sup>; CAGE CLAMP®

[www.wago.com/870-127](http://www.wago.com/870-127)

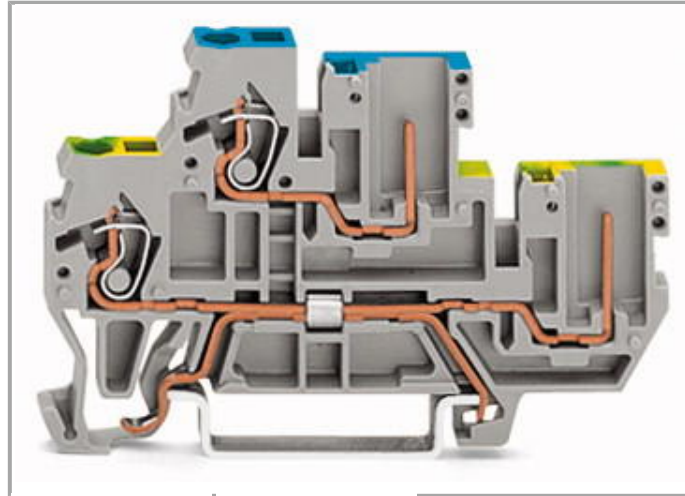

RoHS  
Compliant ✓

BOMcheck.net

Color: ■

### Data

#### Electrical data

#### Ratings per IEC/EN 60664-1

Rated voltage (III / 3)	500 V
Rated impulse voltage (III / 3)	6 kV
Rated current	16 A
Legend (ratings)	(III / 3) ≙ Overvoltage category III / Pollution degree 3

#### Connection data

Connection technology	CAGE CLAMP®
Actuation type	Operating tool
Connectable conductor materials	Copper Aluminum
Solid conductor	0.08 ... 2.5 mm <sup>2</sup> / 28 ... 12 AWG
Fine-stranded conductor	0.08 ... 4 mm <sup>2</sup> / 28 ... 12 AWG
Strip length	6 ... 7 mm / 0.24 ... 0.28 Inch
Total number of connection points	2
Total number of potentials	2

Number of levels	2
Type of wiring	Front-entry wiring

### Geometrical Data

Width	5 mm / 0.197 inch
Height from upper-edge of DIN-35 rail	40 mm / 1.575 inch
Depth	70 mm / 2.756 inch

### Mechanical data

Design	horizontal
Type of mounting	DIN-35 rail
Potential marking	PE/L
Marking level	Side marking

### Material Data



Color	gray
Fire load	0.163 MJ
Weight	10.591 g

### Commercial data

Country of origin	DE
GTIN	4045454225360
Customs Tariff No.	85369010000

### Approvals / Certificates

#### Country specific Approvals

Logo	Approval	Certificate name
	CCA DEKRA Certification B.V.	NTR NL 7468
	CCA DEKRA Certification B.V.	2189801.01

#### Ship Approvals


Logo	Approval	Certificate name
	ABS American Bureau of Shipping	14-HG1293677-PDA



LR  
Lloyds Register




91/20112 (E9)

### UL-Approvals

Logo	Approval	Certificate name
	<b>cURus</b> UL International Germany GmbH	E45172
















### Compatible products

#### Insulation stop

	<b>Item no.: 280-470</b> Insulation stop; 0.08 - 0.2 mm <sup>2</sup> "s" (0.14 mm <sup>2</sup> "f-st"); 5 pieces/strip	<a href="http://www.wago.com/280-470">www.wago.com/280-470</a>
	<b>Item no.: 280-471</b> Insulation stop; 0.25 - 0.5 mm <sup>2</sup> ; 5 pieces/strip	<a href="http://www.wago.com/280-471">www.wago.com/280-471</a>
	<b>Item no.: 280-472</b> Insulation stop; 0.75 - 1 mm <sup>2</sup> ; 5 pieces/strip	<a href="http://www.wago.com/280-472">www.wago.com/280-472</a>

#### Marking accessories

	<b>Item no.: 2009-115</b> WMB-Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type	<a href="http://www.wago.com/2009-115">www.wago.com/2009-115</a>
	<b>Item no.: 2009-115/000-002</b> WMB-Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type	<a href="http://www.wago.com/2009-115/000-002">www.wago.com/2009-115/000-002</a>
	<b>Item no.: 2009-115/000-006</b> WMB-Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type	<a href="http://www.wago.com/2009-115/000-006">www.wago.com/2009-115/000-006</a>
	<b>Item no.: 2009-115/000-007</b> WMB-Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type	<a href="http://www.wago.com/2009-115/000-007">www.wago.com/2009-115/000-007</a>
	<b>Item no.: 2009-115/000-012</b> WMB-Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type	<a href="http://www.wago.com/2009-115/000-012">www.wago.com/2009-115/000-012</a>
	<b>Item no.: 2009-115/000-017</b> WMB-Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type	<a href="http://www.wago.com/2009-115/000-017">www.wago.com/2009-115/000-017</a>
	<b>Item no.: 2009-115/000-023</b> WMB-Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type	<a href="http://www.wago.com/2009-115/000-023">www.wago.com/2009-115/000-023</a>

	<p><b>Item no.: 2009-115/000-024</b>                  WMB-Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type</p>	<a href="http://www.wago.com/2009-115/000-024">www.wago.com/2009-115/000-024</a>
	<p><b>Item no.: 2009-145</b>                  Mini-WSB Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type</p>	<a href="http://www.wago.com/2009-145">www.wago.com/2009-145</a>
	<p><b>Item no.: 2009-145/000-002</b>                  Mini-WSB Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type</p>	<a href="http://www.wago.com/2009-145/000-002">www.wago.com/2009-145/000-002</a>
	<p><b>Item no.: 2009-145/000-005</b>                  Mini-WSB Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type</p>	<a href="http://www.wago.com/2009-145/000-005">www.wago.com/2009-145/000-005</a>
	<p><b>Item no.: 2009-145/000-006</b>                  Mini-WSB Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type</p>	<a href="http://www.wago.com/2009-145/000-006">www.wago.com/2009-145/000-006</a>
	<p><b>Item no.: 2009-145/000-007</b>                  Mini-WSB Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type</p>	<a href="http://www.wago.com/2009-145/000-007">www.wago.com/2009-145/000-007</a>
	<p><b>Item no.: 2009-145/000-012</b>                  Mini-WSB Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type</p>	<a href="http://www.wago.com/2009-145/000-012">www.wago.com/2009-145/000-012</a>
	<p><b>Item no.: 2009-145/000-023</b>                  Mini-WSB Inline; for smartPRINTER; on reel; stretchable 5 - 5.2 mm; plain; snap-on type</p>	<a href="http://www.wago.com/2009-145/000-023">www.wago.com/2009-145/000-023</a>
	<p><b>Item no.: 2009-145/000-024</b>                  Mini-WSB Inline; on reel; stretchable 5 - 5.2 mm; plain; snap-on type</p>	<a href="http://www.wago.com/2009-145/000-024">www.wago.com/2009-145/000-024</a>
	<p><b>Item no.: 2009-198</b>                  Adaptor</p>	<a href="http://www.wago.com/2009-198">www.wago.com/2009-198</a>
	<p><b>Item no.: 248-501</b>                  Miniature WSB Quick marking system; plain; Marker width 5 mm; 10 strips with 10 markers per card</p>	<a href="http://www.wago.com/248-501">www.wago.com/248-501</a>
	<p><b>Item no.: 248-501/000-002</b>                  Mini-WSB marking card; as card; not stretchable; plain; snap-on type</p>	<a href="http://www.wago.com/248-501/000-002">www.wago.com/248-501/000-002</a>
	<p><b>Item no.: 248-501/000-005</b>                  Mini-WSB marking card; as card; plain; snap-on type</p>	<a href="http://www.wago.com/248-501/000-005">www.wago.com/248-501/000-005</a>
	<p><b>Item no.: 248-501/000-006</b>                  Mini-WSB marking card; as card; not stretchable; plain; snap-on type</p>	<a href="http://www.wago.com/248-501/000-006">www.wago.com/248-501/000-006</a>
	<p><b>Item no.: 248-501/000-007</b>                  Mini-WSB marking card; as card; not stretchable; plain; snap-on type</p>	<a href="http://www.wago.com/248-501/000-007">www.wago.com/248-501/000-007</a>



**Item no.: 248-501/000-012**  
Mini-WSB marking card; as card; not stretchable; plain; snap-on type

[www.wago.com/248-501/000-012](http://www.wago.com/248-501/000-012)



**Item no.: 248-501/000-017**  
Mini-WSB marking card; as card; not stretchable; plain; snap-on type

[www.wago.com/248-501/000-017](http://www.wago.com/248-501/000-017)



**Item no.: 248-501/000-023**  
Mini-WSB marking card; as card; not stretchable; plain; snap-on type

[www.wago.com/248-501/000-023](http://www.wago.com/248-501/000-023)



**Item no.: 248-501/000-024**  
Mini-WSB marking card; as card; not stretchable; plain; snap-on type

[www.wago.com/248-501/000-024](http://www.wago.com/248-501/000-024)



**Item no.: 793-501**  
WMB marking card; as card; not stretchable; plain; snap-on type

[www.wago.com/793-501](http://www.wago.com/793-501)



**Item no.: 793-501/000-002**  
WMB marking card; as card; not stretchable; plain; snap-on type

[www.wago.com/793-501/000-002](http://www.wago.com/793-501/000-002)



**Item no.: 793-501/000-005**  
WMB marking card; as card; not stretchable; plain; snap-on type

[www.wago.com/793-501/000-005](http://www.wago.com/793-501/000-005)



**Item no.: 793-501/000-006**  
WMB marking card; as card; not stretchable; plain; snap-on type

[www.wago.com/793-501/000-006](http://www.wago.com/793-501/000-006)



**Item no.: 793-501/000-007**  
WMB marking card; as card; not stretchable; plain; snap-on type

[www.wago.com/793-501/000-007](http://www.wago.com/793-501/000-007)



**Item no.: 793-501/000-012**  
WMB marking card; as card; not stretchable; plain; snap-on type

[www.wago.com/793-501/000-012](http://www.wago.com/793-501/000-012)



**Item no.: 793-501/000-017**  
WMB marking card; as card; not stretchable; plain; snap-on type

[www.wago.com/793-501/000-017](http://www.wago.com/793-501/000-017)



**Item no.: 793-501/000-023**  
WMB marking card; as card; not stretchable; plain; snap-on type

[www.wago.com/793-501/000-023](http://www.wago.com/793-501/000-023)



**Item no.: 793-501/000-024**  
WMB marking card; as card; not stretchable; plain; snap-on type

[www.wago.com/793-501/000-024](http://www.wago.com/793-501/000-024)



**Item no.: 793-5501**  
WMB marking card; as card; for terminal block width 5 - 17.5 mm; stretchable 5 - 5.2 mm; plain; snap-on type

[www.wago.com/793-5501](http://www.wago.com/793-5501)



**Item no.: 793-5501/000-002**  
WMB marking card; as card; for terminal block width 5 - 17.5 mm; stretchable 5 - 5.2 mm; plain; snap-on type

[www.wago.com/793-5501/000-002](http://www.wago.com/793-5501/000-002)



**Item no.: 793-5501/000-005**  
WMB marking card; as card; stretchable 5 - 5.2 mm; plain; snap-on type

[www.wago.com/793-5501/000-005](http://www.wago.com/793-5501/000-005)



**Item no.: 793-5501/000-006**  
WMB marking card; as card; stretchable 5 - 5.2 mm; plain; snap-on type

[www.wago.com/793-5501/000-006](http://www.wago.com/793-5501/000-006)



**Item no.: 793-5501/000-007**  
WMB marking card; as card; stretchable 5 - 5.2 mm; plain; snap-on type

[www.wago.com/793-5501/000-007](http://www.wago.com/793-5501/000-007)



**Item no.: 793-5501/000-012**  
WMB marking card; as card; stretchable 5 - 5.2 mm; plain; snap-on type

[www.wago.com/793-5501/000-012](http://www.wago.com/793-5501/000-012)



**Item no.: 793-5501/000-017**  
WMB marking card; as card; stretchable 5 - 5.2 mm; plain; snap-on type

[www.wago.com/793-5501/000-017](http://www.wago.com/793-5501/000-017)



**Item no.: 793-5501/000-023**  
WMB marking card; as card; stretchable 5 - 5.2 mm; plain; snap-on type

[www.wago.com/793-5501/000-023](http://www.wago.com/793-5501/000-023)



**Item no.: 793-5501/000-024**  
WMB marking card; as card; stretchable 5 - 5.2 mm; plain; snap-on type

[www.wago.com/793-5501/000-024](http://www.wago.com/793-5501/000-024)

#### Carrier rail



**Item no.: 210-112**  
Steel carrier rail; 35 x 7.5 mm; 1 mm thick; 2 m long; slotted; according to EN 60715; "Hole width 25 mm

[www.wago.com/210-112](http://www.wago.com/210-112)



**Item no.: 210-113**  
Steel carrier rail; 35 x 7.5 mm; 1 mm thick; 2 m long; unslotted; according to EN 60715

[www.wago.com/210-113](http://www.wago.com/210-113)



**Item no.: 210-114**  
Steel carrier rail; 35 x 15 mm; 1.5 mm thick; 2 m long; unslotted; similar to EN 60715

[www.wago.com/210-114](http://www.wago.com/210-114)



**Item no.: 210-115**  
Steel carrier rail; 35 x 7.5 mm; 1 mm thick; 2 m long; slotted; according to EN 60715; "Hole width 18 mm

[www.wago.com/210-115](http://www.wago.com/210-115)



**Item no.: 210-118**  
Steel carrier rail; 35 x 15 mm; 2.3 mm thick; 2 m long; unslotted; according to EN 60715

[www.wago.com/210-118](http://www.wago.com/210-118)



**Item no.: 210-196**  
Aluminum carrier rail; 35 x 8.2 mm; 1.6 mm thick; 2 m long; unslotted; similar to EN 60715

[www.wago.com/210-196](http://www.wago.com/210-196)



**Item no.: 210-197**  
Steel carrier rail; 35 x 15 mm; 1.5 mm thick; 2 m long; slotted; similar to EN 60715

[www.wago.com/210-197](http://www.wago.com/210-197)



**Item no.: 210-198**  
Copper carrier rail; 35 x 15 mm; 2.3 mm thick; 2 m long; unslotted; according to EN 60715

[www.wago.com/210-198](http://www.wago.com/210-198)



**Item no.: 210-504**  
Steel carrier rail; 35 x 7.5 mm; 1 mm thick; 2 m long; slotted; galvanized; according to EN 60715

[www.wago.com/210-504](http://www.wago.com/210-504)

**Item no.: 210-505**



Steel carrier rail; 35 x 7.5 mm; 1 mm thick; 2 m long; unslotted; galvanized; according to EN 60715

[www.wago.com/210-505](http://www.wago.com/210-505)



**Item no.: 210-506**

Steel carrier rail; 35 x 15 mm; 1.5 mm thick; 2 m long; unslotted; galvanized; similar to EN 60715

[www.wago.com/210-506](http://www.wago.com/210-506)



**Item no.: 210-508**

Steel carrier rail; 35 x 15 mm; 1.5 mm thick; 2 m long; slotted; galvanized; similar to EN 60715

[www.wago.com/210-508](http://www.wago.com/210-508)

### Protective Warning Marker



**Item no.: 280-405**

Protective warning marker; with high-voltage symbol, black; for 5 terminal blocks

[www.wago.com/280-405](http://www.wago.com/280-405)

### Jumper



**Item no.: 210-103**

Wire commoning chain; insulated; 50 connections

[www.wago.com/210-103](http://www.wago.com/210-103)



**Item no.: 709-110**

Wire commoning chain; insulated; 4 connections; 3 x 110 mm

[www.wago.com/709-110](http://www.wago.com/709-110)



**Item no.: 709-111**

Wire commoning chain; insulated; 3 connections; 2 x 120 mm

[www.wago.com/709-111](http://www.wago.com/709-111)



**Item no.: 709-112**

Wire commoning chain; insulated; 3 connections; 2 x 170 mm

[www.wago.com/709-112](http://www.wago.com/709-112)



**Item no.: 870-402**

Push-in type jumper bar; insulated; 2-way; Nominal current 18 A

[www.wago.com/870-402](http://www.wago.com/870-402)



**Item no.: 870-403**

Push-in type jumper bar; insulated; 3-way; Nominal current 18 A

[www.wago.com/870-403](http://www.wago.com/870-403)



**Item no.: 870-404**

Push-in type jumper bar; insulated; 4-way; Nominal current 18 A

[www.wago.com/870-404](http://www.wago.com/870-404)



**Item no.: 870-405**

Push-in type jumper bar; insulated; 5-way; Nominal current 18 A

[www.wago.com/870-405](http://www.wago.com/870-405)



**Item no.: 870-405/011-000**

Ready-made push-in type jumper bar; insulated; 3-way (1-3-5); Nominal current 18 A

[www.wago.com/870-405/011-000](http://www.wago.com/870-405/011-000)



**Item no.: 870-406**

Push-in type jumper bar; insulated; 6-way; Nominal current 18 A

[www.wago.com/870-406](http://www.wago.com/870-406)



**Item no.: 870-407**

Push-in type jumper bar; insulated; 7-way; Nominal current 18 A

[www.wago.com/870-407](http://www.wago.com/870-407)



**Item no.: 870-407/011-000**

Ready-made push-in type jumper bar; insulated; 3-way (1-3-5); Nominal current 18 A

[www.wago.com/870-407/011-000](http://www.wago.com/870-407/011-000)



**Item no.: 870-408**

Push-in type jumper bar; insulated; 8-way; Nominal current 18 A



















[www.wago.com/870-408](http://www.wago.com/870-408)



**Item no.: 870-409**

Push-in type jumper bar; insulated; 9-way; Nominal current 18 A

[www.wago.com/870-409](http://www.wago.com/870-409)

	<b>Item no.: 870-409/011-000</b> Ready-made push-in type jumper bar; insulated; 3-way (1-3-5); Nominal current 18 A	<a href="http://www.wago.com/870-409/011-000">www.wago.com/870-409/011-000</a>
	<b>Item no.: 870-410</b> Push-in type jumper bar; insulated; 10-way; Nominal current 18 A	<a href="http://www.wago.com/870-410">www.wago.com/870-410</a>
	<b>Item no.: 870-433</b> Push-in type jumper bar; insulated; from 1 to 3; Nominal current 18 A	<a href="http://www.wago.com/870-433">www.wago.com/870-433</a>
	<b>Item no.: 870-434</b> Push-in type jumper bar; insulated; from 1 to 4; Nominal current 18 A	<a href="http://www.wago.com/870-434">www.wago.com/870-434</a>
	<b>Item no.: 870-435</b> Push-in type jumper bar; insulated; from 1 to 5; Nominal current 18 A	<a href="http://www.wago.com/870-435">www.wago.com/870-435</a>
	<b>Item no.: 870-440</b> Push-in type jumper bar; insulated; from 1 to 10; Nominal current 18 A	<a href="http://www.wago.com/870-440">www.wago.com/870-440</a>
<b>ferrule</b>		
	<b>Item no.: 216-121</b> Ferrule; Sleeve for 0.5 mm <sup>2</sup> / AWG 22; uninsulated; electro-tin plated	<a href="http://www.wago.com/216-121">www.wago.com/216-121</a>
	<b>Item no.: 216-122</b> Ferrule; Sleeve for 0.75 mm <sup>2</sup> / AWG 20; uninsulated; electro-tin plated	<a href="http://www.wago.com/216-122">www.wago.com/216-122</a>
	<b>Item no.: 216-123</b> Ferrule; Sleeve for 1 mm <sup>2</sup> / AWG 18; uninsulated; electro-tin plated	<a href="http://www.wago.com/216-123">www.wago.com/216-123</a>
	<b>Item no.: 216-124</b> Ferrule; Sleeve for 1.5 mm <sup>2</sup> / AWG 16; uninsulated; electro-tin plated	<a href="http://www.wago.com/216-124">www.wago.com/216-124</a>
	<b>Item no.: 216-131</b> Ferrule; Sleeve for 0.25 mm <sup>2</sup> / AWG 24; uninsulated; electro-tin plated	<a href="http://www.wago.com/216-131">www.wago.com/216-131</a>
	<b>Item no.: 216-132</b> Ferrule; Sleeve for 0.34 mm <sup>2</sup> / AWG 24; uninsulated; electro-tin plated	<a href="http://www.wago.com/216-132">www.wago.com/216-132</a>
	<b>Item no.: 216-221</b> Ferrule; Sleeve for 0.5 mm <sup>2</sup> / AWG 22; insulated; electro-tin plated	<a href="http://www.wago.com/216-221">www.wago.com/216-221</a>
	<b>Item no.: 216-222</b> Ferrule; Sleeve for 0.75 mm <sup>2</sup> / AWG 20; insulated; electro-tin plated	<a href="http://www.wago.com/216-222">www.wago.com/216-222</a>
	<b>Item no.: 216-223</b> Ferrule; Sleeve for 1 mm <sup>2</sup> / AWG 18; insulated; electro-tin plated	<a href="http://www.wago.com/216-223">www.wago.com/216-223</a>
	<b>Item no.: 216-224</b> Ferrule; Sleeve for 1.5 mm <sup>2</sup> / AWG 16; insulated; electro-tin plated	<a href="http://www.wago.com/216-224">www.wago.com/216-224</a>
	<b>Item no.: 216-321</b> Ferrule; Sleeve for 0.25 mm <sup>2</sup> / AWG 24; insulated; electro-tin plated	<a href="http://www.wago.com/216-321">www.wago.com/216-321</a>
	<b>Item no.: 216-322</b> Ferrule; Sleeve for 0.34 mm <sup>2</sup> / AWG 24; insulated; electro-tin plated	<a href="http://www.wago.com/216-322">www.wago.com/216-322</a>

**End plate**





**Item no.: 870-118**  
End and intermediate plate; 1 mm thick

[www.wago.com/870-118](http://www.wago.com/870-118)



**Item no.: 870-119**  
End and intermediate plate; 1 mm thick

[www.wago.com/870-119](http://www.wago.com/870-119)

#### tools



**Item no.: 210-720**  
Operating tool with partially insulated shaft; Type 2, blade (3.5 x 0.5) mm

[www.wago.com/210-720](http://www.wago.com/210-720)

#### Female plug



**Item no.: 769-101**  
1-conductor female plug; 4 mm<sup>2</sup>; 1-pole

[www.wago.com/769-101](http://www.wago.com/769-101)



**Item no.: 769-101/000-006**  
1-conductor female plug; 4 mm<sup>2</sup>; 1-pole

[www.wago.com/769-101/000-006](http://www.wago.com/769-101/000-006)



**Item no.: 769-101/000-016**  
1-conductor female plug; 4 mm<sup>2</sup>; 1-pole

[www.wago.com/769-101/000-016](http://www.wago.com/769-101/000-016)



**Item no.: 769-101/022-000**  
1-conductor female plug; angled; 4 mm<sup>2</sup>; 1-pole

[www.wago.com/769-101/022-000](http://www.wago.com/769-101/022-000)



**Item no.: 769-101/022-016**  
1-conductor female plug; angled; 4 mm<sup>2</sup>; 1-pole

[www.wago.com/769-101/022-016](http://www.wago.com/769-101/022-016)



**Item no.: 769-102**  
1-conductor female plug; 4 mm<sup>2</sup>; 2-pole

[www.wago.com/769-102](http://www.wago.com/769-102)

**Item no.: 769-102/000-006**  
1-conductor female plug; 4 mm<sup>2</sup>; 2-pole

[www.wago.com/769-102/000-006](http://www.wago.com/769-102/000-006)

**Item no.: 769-102/000-036**  
1-conductor female plug; 4 mm<sup>2</sup>; 2-pole

[www.wago.com/769-102/000-036](http://www.wago.com/769-102/000-036)

**Item no.: 769-102/000-037**  
1-conductor female plug; 4 mm<sup>2</sup>; 2-pole

[www.wago.com/769-102/000-037](http://www.wago.com/769-102/000-037)



**Item no.: 769-102/022-000**  
1-conductor female plug; angled; 4 mm<sup>2</sup>; 2-pole

[www.wago.com/769-102/022-000](http://www.wago.com/769-102/022-000)

**Item no.: 769-103**  
1-conductor female plug; 4 mm<sup>2</sup>; 3-pole

[www.wago.com/769-103](http://www.wago.com/769-103)

**Item no.: 769-103/000-006**  
1-conductor female plug; 4 mm<sup>2</sup>; 3-pole

[www.wago.com/769-103/000-006](http://www.wago.com/769-103/000-006)



**Item no.: 769-103/000-036**  
1-conductor female plug; 4 mm<sup>2</sup>; 3-pole

[www.wago.com/769-103/000-036](http://www.wago.com/769-103/000-036)



**Item no.: 769-103/000-037**  
1-conductor female plug; 4 mm<sup>2</sup>; 3-pole

[www.wago.com/769-103/000-037](http://www.wago.com/769-103/000-037)



**Item no.: 769-103/000-038**  
1-conductor female plug; 4 mm<sup>2</sup>; 3-pole

[www.wago.com/769-103/000-038](http://www.wago.com/769-103/000-038)



**Item no.: 769-103/000-039**  
1-conductor female plug; 4 mm<sup>2</sup>; 3-pole

[www.wago.com/769-103/000-039](http://www.wago.com/769-103/000-039)



**Item no.: 769-103/022-000**  
1-conductor female plug; angled; 4 mm<sup>2</sup>; 3-pole

[www.wago.com/769-103/022-000](http://www.wago.com/769-103/022-000)

**Item no.: 769-104**  
1-conductor female plug; 4 mm<sup>2</sup>; 4-pole

[www.wago.com/769-104](http://www.wago.com/769-104)

**Item no.: 769-104/000-006**  
1-conductor female plug; 4 mm<sup>2</sup>; 4-pole

[www.wago.com/769-104/000-006](http://www.wago.com/769-104/000-006)



**Item no.: 769-104/000-036**  
1-conductor female plug; 4 mm<sup>2</sup>; 4-pole

[www.wago.com/769-104/000-036](http://www.wago.com/769-104/000-036)



**Item no.: 769-104/000-037**  
1-conductor female plug; 4 mm<sup>2</sup>; 4-pole

[www.wago.com/769-104/000-037](http://www.wago.com/769-104/000-037)



**Item no.: 769-104/000-038**  
1-conductor female plug; 4 mm<sup>2</sup>; 4-pole

[www.wago.com/769-104/000-038](http://www.wago.com/769-104/000-038)



**Item no.: 769-104/000-039**  
1-conductor female plug; 4 mm<sup>2</sup>; 4-pole

[www.wago.com/769-104/000-039](http://www.wago.com/769-104/000-039)



**Item no.: 769-104/022-000**  
1-conductor female plug; angled; 4 mm<sup>2</sup>; 4-pole

[www.wago.com/769-104/022-000](http://www.wago.com/769-104/022-000)



**Item no.: 769-105**  
1-conductor female plug; 4 mm<sup>2</sup>; 5-pole

[www.wago.com/769-105](http://www.wago.com/769-105)



**Item no.: 769-105/000-006**  
1-conductor female plug; 4 mm<sup>2</sup>; 5-pole

[www.wago.com/769-105/000-006](http://www.wago.com/769-105/000-006)



**Item no.: 769-105/000-036**  
1-conductor female plug; 4 mm<sup>2</sup>; 5-pole

[www.wago.com/769-105/000-036](http://www.wago.com/769-105/000-036)

**Item no.: 769-105/000-037**1-conductor female plug; 4 mm<sup>2</sup>; 5-pole[www.wago.com/769-105/000-037](http://www.wago.com/769-105/000-037)**Item no.: 769-105/000-038**1-conductor female plug; 4 mm<sup>2</sup>; 5-pole[www.wago.com/769-105/000-038](http://www.wago.com/769-105/000-038)**Item no.: 769-105/000-039**1-conductor female plug; 4 mm<sup>2</sup>; 5-pole[www.wago.com/769-105/000-039](http://www.wago.com/769-105/000-039)**Item no.: 769-105/022-000**1-conductor female plug; angled; 4 mm<sup>2</sup>; 5-pole[www.wago.com/769-105/022-000](http://www.wago.com/769-105/022-000)**Item no.: 769-106**1-conductor female plug; 4 mm<sup>2</sup>; 6-pole[www.wago.com/769-106](http://www.wago.com/769-106)**Item no.: 769-106/000-006**1-conductor female plug; 4 mm<sup>2</sup>; 6-pole[www.wago.com/769-106/000-006](http://www.wago.com/769-106/000-006)**Item no.: 769-106/000-036**1-conductor female plug; 4 mm<sup>2</sup>; 6-pole[www.wago.com/769-106/000-036](http://www.wago.com/769-106/000-036)**Item no.: 769-106/000-037**1-conductor female plug; 4 mm<sup>2</sup>; 6-pole[www.wago.com/769-106/000-037](http://www.wago.com/769-106/000-037)**Item no.: 769-106/000-038**1-conductor female plug; 4 mm<sup>2</sup>; 6-pole[www.wago.com/769-106/000-038](http://www.wago.com/769-106/000-038)**Item no.: 769-106/000-039**1-conductor female plug; 4 mm<sup>2</sup>; 6-pole[www.wago.com/769-106/000-039](http://www.wago.com/769-106/000-039)**Item no.: 769-106/022-000**1-conductor female plug; angled; 4 mm<sup>2</sup>; 6-pole[www.wago.com/769-106/022-000](http://www.wago.com/769-106/022-000)**Item no.: 769-107**1-conductor female plug; 4 mm<sup>2</sup>; 7-pole[www.wago.com/769-107](http://www.wago.com/769-107)**Item no.: 769-107/000-006**1-conductor female plug; 4 mm<sup>2</sup>; 7-pole[www.wago.com/769-107/000-006](http://www.wago.com/769-107/000-006)**Item no.: 769-107/000-036**1-conductor female plug; 4 mm<sup>2</sup>; 7-pole[www.wago.com/769-107/000-036](http://www.wago.com/769-107/000-036)**Item no.: 769-107/000-037**1-conductor female plug; 4 mm<sup>2</sup>; 7-pole[www.wago.com/769-107/000-037](http://www.wago.com/769-107/000-037)



**Item no.: 769-107/000-038**

1-conductor female plug; 4 mm<sup>2</sup>; 7-pole

[www.wago.com/769-107/000-038](http://www.wago.com/769-107/000-038)



**Item no.: 769-107/000-039**

1-conductor female plug; 4 mm<sup>2</sup>; 7-pole

[www.wago.com/769-107/000-039](http://www.wago.com/769-107/000-039)

**Item no.: 769-107/022-000**

1-conductor female plug; angled; 4 mm<sup>2</sup>; 7-pole

[www.wago.com/769-107/022-000](http://www.wago.com/769-107/022-000)

**Item no.: 769-108**

1-conductor female plug; 4 mm<sup>2</sup>; 8-pole

[www.wago.com/769-108](http://www.wago.com/769-108)

**Item no.: 769-108/000-006**

1-conductor female plug; 4 mm<sup>2</sup>; 8-pole

[www.wago.com/769-108/000-006](http://www.wago.com/769-108/000-006)

**Item no.: 769-108/000-036**

1-conductor female plug; 4 mm<sup>2</sup>; 8-pole

[www.wago.com/769-108/000-036](http://www.wago.com/769-108/000-036)

**Item no.: 769-108/000-037**

1-conductor female plug; 4 mm<sup>2</sup>; 8-pole

[www.wago.com/769-108/000-037](http://www.wago.com/769-108/000-037)

**Item no.: 769-108/000-038**

1-conductor female plug; 4 mm<sup>2</sup>; 8-pole

[www.wago.com/769-108/000-038](http://www.wago.com/769-108/000-038)

**Item no.: 769-108/000-039**

1-conductor female plug; 4 mm<sup>2</sup>; 8-pole

[www.wago.com/769-108/000-039](http://www.wago.com/769-108/000-039)

**Item no.: 769-108/022-000**

1-conductor female plug; angled; 4 mm<sup>2</sup>; 8-pole

[www.wago.com/769-108/022-000](http://www.wago.com/769-108/022-000)

**Item no.: 769-109**

1-conductor female plug; 4 mm<sup>2</sup>; 9-pole

[www.wago.com/769-109](http://www.wago.com/769-109)

**Item no.: 769-109/000-006**

1-conductor female plug; 4 mm<sup>2</sup>; 9-pole

[www.wago.com/769-109/000-006](http://www.wago.com/769-109/000-006)



**Item no.: 769-109/000-036**

1-conductor female plug; 4 mm<sup>2</sup>; 9-pole

[www.wago.com/769-109/000-036](http://www.wago.com/769-109/000-036)



**Item no.: 769-109/000-037**

1-conductor female plug; 4 mm<sup>2</sup>; 9-pole

[www.wago.com/769-109/000-037](http://www.wago.com/769-109/000-037)







**Item no.: 769-109/000-038**

1-conductor female plug; 4 mm<sup>2</sup>; 9-pole

[www.wago.com/769-109/000-038](http://www.wago.com/769-109/000-038)

**Item no.: 769-109/000-039**1-conductor female plug; 4 mm<sup>2</sup>; 9-pole[www.wago.com/769-109/000-039](http://www.wago.com/769-109/000-039)**Item no.: 769-109/022-000**1-conductor female plug; angled; 4 mm<sup>2</sup>; 9-pole[www.wago.com/769-109/022-000](http://www.wago.com/769-109/022-000)**Item no.: 769-110**1-conductor female plug; 4 mm<sup>2</sup>; 10-pole[www.wago.com/769-110](http://www.wago.com/769-110)**Item no.: 769-110/000-006**1-conductor female plug; 4 mm<sup>2</sup>; 10-pole[www.wago.com/769-110/000-006](http://www.wago.com/769-110/000-006)**Item no.: 769-110/000-036**1-conductor female plug; 4 mm<sup>2</sup>; 10-pole[www.wago.com/769-110/000-036](http://www.wago.com/769-110/000-036)**Item no.: 769-110/000-037**1-conductor female plug; 4 mm<sup>2</sup>; 10-pole[www.wago.com/769-110/000-037](http://www.wago.com/769-110/000-037)**Item no.: 769-110/000-038**1-conductor female plug; 4 mm<sup>2</sup>; 10-pole[www.wago.com/769-110/000-038](http://www.wago.com/769-110/000-038)**Item no.: 769-110/000-039**1-conductor female plug; 4 mm<sup>2</sup>; 10-pole[www.wago.com/769-110/000-039](http://www.wago.com/769-110/000-039)**Item no.: 769-110/022-000**1-conductor female plug; angled; 4 mm<sup>2</sup>; 10-pole[www.wago.com/769-110/022-000](http://www.wago.com/769-110/022-000)**Item no.: 769-111**1-conductor female plug; 4 mm<sup>2</sup>; 11-pole[www.wago.com/769-111](http://www.wago.com/769-111)**Item no.: 769-111/000-006**1-conductor female plug; 4 mm<sup>2</sup>; 11-pole[www.wago.com/769-111/000-006](http://www.wago.com/769-111/000-006)**Item no.: 769-111/000-036**1-conductor female plug; 4 mm<sup>2</sup>; 11-pole[www.wago.com/769-111/000-036](http://www.wago.com/769-111/000-036)**Item no.: 769-111/000-037**1-conductor female plug; 4 mm<sup>2</sup>; 11-pole[www.wago.com/769-111/000-037](http://www.wago.com/769-111/000-037)**Item no.: 769-111/000-038**1-conductor female plug; 4 mm<sup>2</sup>; 11-pole[www.wago.com/769-111/000-038](http://www.wago.com/769-111/000-038)**Item no.: 769-111/000-039**1-conductor female plug; 4 mm<sup>2</sup>; 11-pole[www.wago.com/769-111/000-039](http://www.wago.com/769-111/000-039)

	<b>Item no.: 769-111/022-000</b> 1-conductor female plug; angled; 4 mm <sup>2</sup> ; 11-pole	<a href="http://www.wago.com/769-111/022-000">www.wago.com/769-111/022-000</a>
	<b>Item no.: 769-112</b> 1-conductor female plug; 4 mm <sup>2</sup> ; 12-pole	<a href="http://www.wago.com/769-112">www.wago.com/769-112</a>
	<b>Item no.: 769-112/000-006</b> 1-conductor female plug; 4 mm <sup>2</sup> ; 12-pole	<a href="http://www.wago.com/769-112/000-006">www.wago.com/769-112/000-006</a>
	<b>Item no.: 769-112/000-036</b> 1-conductor female plug; 4 mm <sup>2</sup> ; 12-pole	<a href="http://www.wago.com/769-112/000-036">www.wago.com/769-112/000-036</a>
	<b>Item no.: 769-112/000-037</b> 1-conductor female plug; 4 mm <sup>2</sup> ; 12-pole	<a href="http://www.wago.com/769-112/000-037">www.wago.com/769-112/000-037</a>
	<b>Item no.: 769-112/000-038</b> 1-conductor female plug; 4 mm <sup>2</sup> ; 12-pole	<a href="http://www.wago.com/769-112/000-038">www.wago.com/769-112/000-038</a>
	<b>Item no.: 769-112/000-039</b> 1-conductor female plug; 4 mm <sup>2</sup> ; 12-pole	<a href="http://www.wago.com/769-112/000-039">www.wago.com/769-112/000-039</a>
	<b>Item no.: 769-112/022-000</b> 1-conductor female plug; angled; 4 mm <sup>2</sup> ; 12-pole	<a href="http://www.wago.com/769-112/022-000">www.wago.com/769-112/022-000</a>
	<b>Item no.: 769-113</b> 1-conductor female plug; 4 mm <sup>2</sup> ; 13-pole	<a href="http://www.wago.com/769-113">www.wago.com/769-113</a>
	<b>Item no.: 769-113/000-036</b> 1-conductor female plug; 4 mm <sup>2</sup> ; 13-pole	<a href="http://www.wago.com/769-113/000-036">www.wago.com/769-113/000-036</a>
	<b>Item no.: 769-113/000-037</b> 1-conductor female plug; 4 mm <sup>2</sup> ; 13-pole	<a href="http://www.wago.com/769-113/000-037">www.wago.com/769-113/000-037</a>
	<b>Item no.: 769-113/000-038</b> 1-conductor female plug; 4 mm <sup>2</sup> ; 13-pole	<a href="http://www.wago.com/769-113/000-038">www.wago.com/769-113/000-038</a>
	<b>Item no.: 769-113/000-039</b> 1-conductor female plug; 4 mm <sup>2</sup> ; 13-pole	<a href="http://www.wago.com/769-113/000-039">www.wago.com/769-113/000-039</a>
	<b>Item no.: 769-113/022-000</b> 1-conductor female plug; angled; 4 mm <sup>2</sup> ; 13-pole	<a href="http://www.wago.com/769-113/022-000">www.wago.com/769-113/022-000</a>
	<b>Item no.: 769-114</b> 1-conductor female plug; 4 mm <sup>2</sup> ; 14-pole	<a href="http://www.wago.com/769-114">www.wago.com/769-114</a>
	<b>Item no.: 769-114/000-006</b> 1-conductor female plug; 4 mm <sup>2</sup> ; 14-pole	<a href="http://www.wago.com/769-114/000-006">www.wago.com/769-114/000-006</a>

<b>Item no.: 769-114/000-036</b> 1-conductor female plug; 4 mm <sup>2</sup> ; 14-pole	<a href="http://www.wago.com/769-114/000-036">www.wago.com/769-114/000-036</a>
<b>Item no.: 769-114/000-037</b> 1-conductor female plug; 4 mm <sup>2</sup> ; 14-pole	<a href="http://www.wago.com/769-114/000-037">www.wago.com/769-114/000-037</a>
<b>Item no.: 769-114/000-038</b> 1-conductor female plug; 4 mm <sup>2</sup> ; 14-pole	<a href="http://www.wago.com/769-114/000-038">www.wago.com/769-114/000-038</a>
<b>Item no.: 769-114/000-039</b> 1-conductor female plug; 4 mm <sup>2</sup> ; 14-pole	<a href="http://www.wago.com/769-114/000-039">www.wago.com/769-114/000-039</a>
<b>Item no.: 769-114/022-000</b> 1-conductor female plug; angled; 4 mm <sup>2</sup> ; 14-pole	<a href="http://www.wago.com/769-114/022-000">www.wago.com/769-114/022-000</a>
<b>Item no.: 769-115</b> 1-conductor female plug; 4 mm <sup>2</sup> ; 15-pole	<a href="http://www.wago.com/769-115">www.wago.com/769-115</a>
<b>Item no.: 769-115/000-036</b> 1-conductor female plug; 4 mm <sup>2</sup> ; 15-pole	<a href="http://www.wago.com/769-115/000-036">www.wago.com/769-115/000-036</a>
<b>Item no.: 769-115/000-037</b> 1-conductor female plug; 4 mm <sup>2</sup> ; 15-pole	<a href="http://www.wago.com/769-115/000-037">www.wago.com/769-115/000-037</a>
<b>Item no.: 769-115/000-038</b> 1-conductor female plug; 4 mm <sup>2</sup> ; 15-pole	<a href="http://www.wago.com/769-115/000-038">www.wago.com/769-115/000-038</a>
<b>Item no.: 769-115/000-039</b> 1-conductor female plug; 4 mm <sup>2</sup> ; 15-pole	<a href="http://www.wago.com/769-115/000-039">www.wago.com/769-115/000-039</a>
<b>Item no.: 769-115/022-000</b> 1-conductor female plug; angled; 4 mm <sup>2</sup> ; 15-pole	<a href="http://www.wago.com/769-115/022-000">www.wago.com/769-115/022-000</a>

#### Coding



**Item no.: 769-435**  
Coding pin; for coding of female plugs; for carrier terminal blocks / male connectors

[www.wago.com/769-435](http://www.wago.com/769-435)

















#### assembling













**Item no.: 209-106**  
Mounting carrier; for isolated mounting on DIN 35 rails

[www.wago.com/209-106](http://www.wago.com/209-106)

#### General accessories

	<b>Item no.: 769-438</b> Pin cover; with marker slot for miniature WSB	<a href="http://www.wago.com/769-438">www.wago.com/769-438</a>
	<b>Item no.: 769-439</b> Pin cover; with marker slot for miniature WSB	<a href="http://www.wago.com/769-439">www.wago.com/769-439</a>
	<b>Item no.: 769-501</b> Start module for 1-conductor female connector; with integrated end plate; 4 mm <sup>2</sup> ; 1-pole	<a href="http://www.wago.com/769-501">www.wago.com/769-501</a>
	<b>Item no.: 769-501/000-006</b> Start module for 1-conductor female connector; 4 mm <sup>2</sup> ; 1-pole	<a href="http://www.wago.com/769-501/000-006">www.wago.com/769-501/000-006</a>
	<b>Item no.: 769-501/000-016</b> Start module for 1-conductor female connector; with integrated end plate; 4 mm <sup>2</sup> ; 1-pole	<a href="http://www.wago.com/769-501/000-016">www.wago.com/769-501/000-016</a>
	<b>Item no.: 769-502</b> Center module for 1-conductor female connector; 4 mm <sup>2</sup> ; 1-pole	<a href="http://www.wago.com/769-502">www.wago.com/769-502</a>
	<b>Item no.: 769-502/000-006</b> Center module for 1-conductor female connector; 4 mm <sup>2</sup> ; 1-pole	<a href="http://www.wago.com/769-502/000-006">www.wago.com/769-502/000-006</a>
	<b>Item no.: 769-502/000-016</b> 1-conductor center module; codable; can be commoned with miniature adjacent jumpers; 1-pole	<a href="http://www.wago.com/769-502/000-016">www.wago.com/769-502/000-016</a>
	<b>Item no.: 769-503</b> End module for 1-conductor female connector; 4 mm <sup>2</sup> ; 1-pole	<a href="http://www.wago.com/769-503">www.wago.com/769-503</a>
	<b>Item no.: 769-503/000-006</b> End module for 1-conductor female connector; 4 mm <sup>2</sup> ; 1-pole	<a href="http://www.wago.com/769-503/000-006">www.wago.com/769-503/000-006</a>
	<b>Item no.: 769-503/000-016</b> End module for 1-conductor female connector; 4 mm <sup>2</sup> ; 1-pole	<a href="http://www.wago.com/769-503/000-016">www.wago.com/769-503/000-016</a>
	<b>Item no.: 769-512</b> Start module for 1-conductor female connector; angled; 4 mm <sup>2</sup> ; 1-pole	<a href="http://www.wago.com/769-512">www.wago.com/769-512</a>
	<b>Item no.: 769-512/000-006</b> Start module for 1-conductor female connector; angled; 4 mm <sup>2</sup> ; 1-pole	<a href="http://www.wago.com/769-512/000-006">www.wago.com/769-512/000-006</a>
	<b>Item no.: 769-512/000-016</b> Start module for 1-conductor female connector; angled; 4 mm <sup>2</sup> ; 1-pole	<a href="http://www.wago.com/769-512/000-016">www.wago.com/769-512/000-016</a>
	<b>Item no.: 769-513</b> Center module for 1-conductor female connector; angled; 4 mm <sup>2</sup> ; 1-pole	<a href="http://www.wago.com/769-513">www.wago.com/769-513</a>
	<b>Item no.: 769-513/000-006</b> 1-conductor center module; angled; codable; 1-pole	<a href="http://www.wago.com/769-513/000-006">www.wago.com/769-513/000-006</a>



	<p><b>Item no.: 769-513/000-016</b>                  1-conductor center module; angled; codable; 1-pole</p>	<a href="http://www.wago.com/769-513/000-016">www.wago.com/769-513/000-016</a>
	<p><b>Item no.: 769-515</b>                  1-conductor end module; angled; codable; 1-pole</p>	<a href="http://www.wago.com/769-515">www.wago.com/769-515</a>
	<p><b>Item no.: 769-515/000-006</b>                  1-conductor end module; angled; codable; 1-pole</p>	<a href="http://www.wago.com/769-515/000-006">www.wago.com/769-515/000-006</a>
	<p><b>Item no.: 769-515/000-016</b>                  1-conductor end module; angled; codable; 1-pole</p>	<a href="http://www.wago.com/769-515/000-016">www.wago.com/769-515/000-016</a>
	<p><b>Item no.: 870-182</b>                  Adaptor</p>	<a href="http://www.wago.com/870-182">www.wago.com/870-182</a>
	<p><b>Item no.: 870-183</b>                  Adaptor</p>	<a href="http://www.wago.com/870-183">www.wago.com/870-183</a>
	<p><b>Item no.: 870-184</b>                  Adaptor</p>	<a href="http://www.wago.com/870-184">www.wago.com/870-184</a>
	<p><b>Item no.: 870-425</b>                  Tap-off module; with anti-rotation protection; modular; suitable for 870 Series terminal blocks with jumper slots in the current bar</p>	<a href="http://www.wago.com/870-425">www.wago.com/870-425</a>
	<p><b>Item no.: 870-426</b>                  Tap-off module; modular; suitable for 870 Series terminal blocks with jumper slots in the current bar</p>	<a href="http://www.wago.com/870-426">www.wago.com/870-426</a>
	<p><b>Item no.: 870-427</b>                  Spacer module; modular; bridging commoned terminal blocks</p>	<a href="http://www.wago.com/870-427">www.wago.com/870-427</a>

**Downloads**

**Documentation**

**Bid Text**

870-127	Oct 19, 2017	DOC 25.6 kB	Download
---------	--------------	----------------	----------

**smartDATA**

**CAD data**

3D Download 870-127	URL	Download
---------------------	-----	----------



## Product family

### X-COM

[Learn more about the product family.](#)

[Show all products from the family](#)

Subject to changes.

---

WAGO Kontakttechnik GmbH & Co. KG

Hansastr. 27

32423 Minden

Phone: +49571 887-0 | Fax: +49571 887-169

Email: [info.de@wago.com](mailto:info.de@wago.com) | Web: [www.wago.com](http://www.wago.com)

Do you have any questions about our products?

We are always happy to take your call at +49 (571) 887-44222.