


Data sheet | Item number: 890-502

Strain relief housing; 2-pole; with locking clip; for 1 cable; 3.8 ... 8.2 mm; 30 mm



www.wago.com/890-502

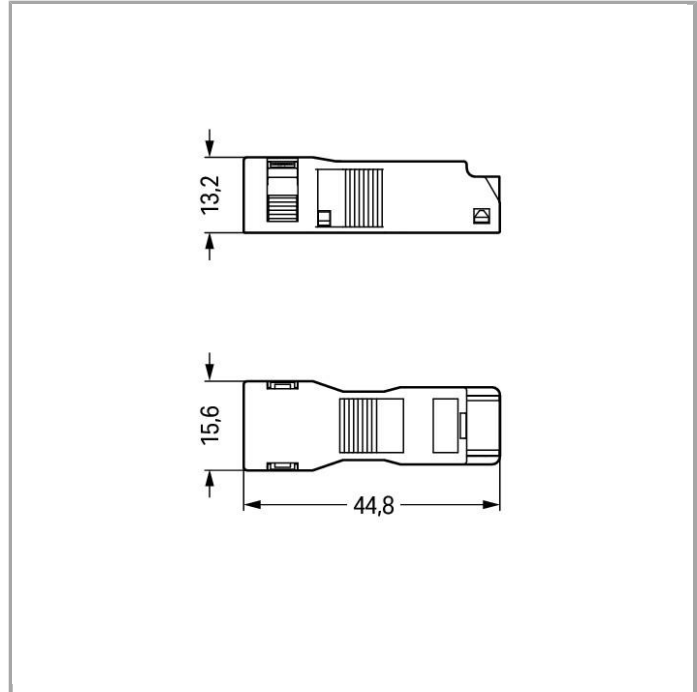

Data

Connection data

No. of poles	2
Connectable sheathed cable diameter	3.8 ... 8.2 mm
Abmantelllänge	32 mm

Geometrical Data

Width	15.6 mm / 0.614 inch
Height	13.2 mm / 0.52 inch
Depth	44.8 mm / 1.764 inch

Mechanical data

Degree of protection	IP20
----------------------	------

Material Data

Color	black
Insulating material	Polyamide 66 (PA 66)
Flammability class per UL94	V0



Fire load	0.088 MJ
Weight	2.944 g

Environmental Requirements

Surrounding air (operating) temperature	-35 ... 85 °C
---	---------------

Commercial data

Country of origin	DE
GTIN	4045454233310
Customs Tariff No.	85389099990
Product Group	20 (WINSTA)

Approvals / Certificates**UL-Approvals**

Logo	Approval	Certificate name
	UL UL International Germany GmbH	E45171

Downloads**Documentation****Bid Text**

890-502	Sep 19, 2016	DOC	Download
WINSTA MINI 2-polig		23.6 kB	

smartDATA**CAD data**

3D Download 890-502	URL	Download
---------------------	-----	----------

Subject to changes.