



Data sheet | Item number: 890-504

Strain relief housing; 4-pole; with locking clip; for 1 cable; 6.5 ... 10.5 mm; 45 mm

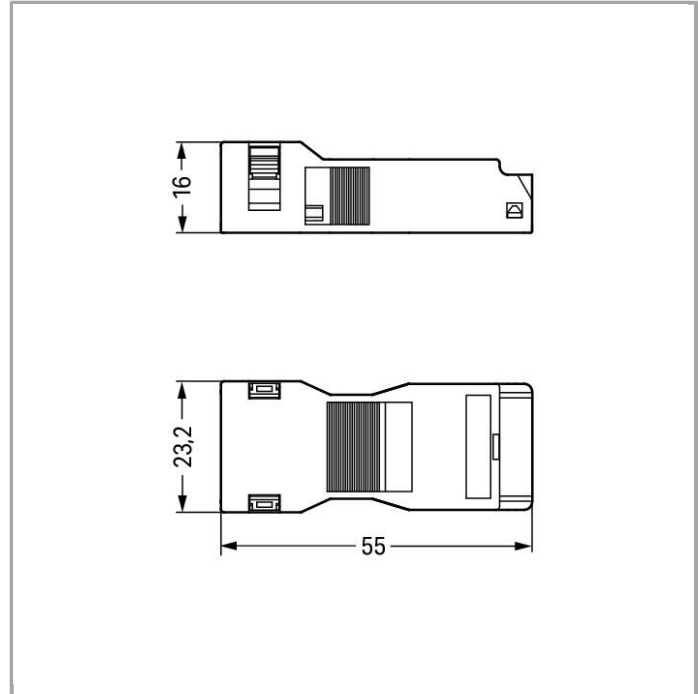

www.wago.com/890-504

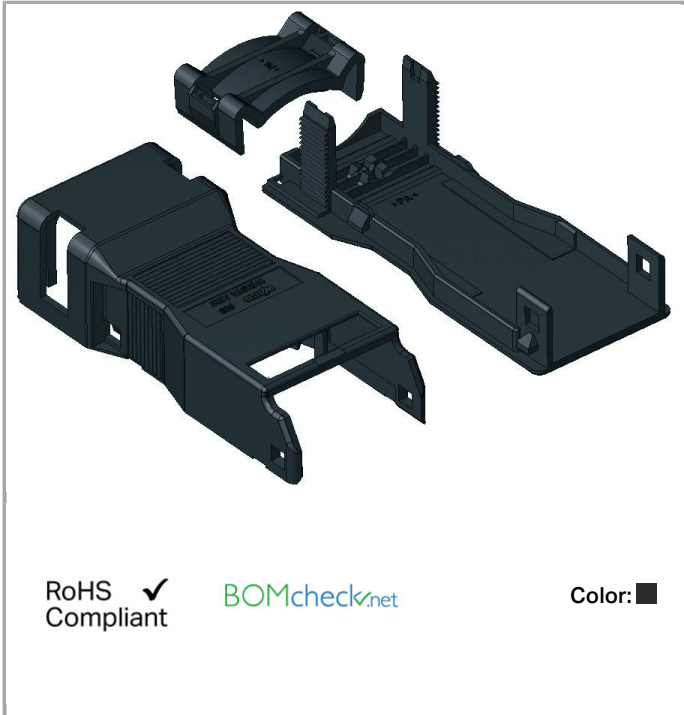

RoHS Compliant

BOMcheck.net

Color:

Data

Connection data

No. of poles	4
Connectable sheathed cable diameter	6.5 ... 10.5 mm
Abmantellänge	45 mm

Geometrical Data

Width	23.2 mm / 0.913 inch
Height	16 mm / 0.63 inch
Depth	55 mm / 2.165 inch

Mechanical data

Degree of protection	IP20
----------------------	------

Material Data

Color	black
Insulating material	Polyamide 66 (PA 66)
Flammability class per UL94	V0



Fire load	0.173 MJ
Weight	5.78 g

Environmental Requirements

Surrounding air (operating) temperature	-35 ... 85 °C
---	---------------

Commercial data

Country of origin	DE
GTIN	4045454233334
Customs Tariff No.	85389099990
Product Group	20 (WINSTA)

Downloads

Documentation

Bid Text

890-504	Mar 15, 2016	DOC	Download
WINSTA MINI 4-polig		24.1 kB	

smartDATA

CAD data

3D Download 890-504	URL	Download
---------------------	-----	----------

Subject to changes.