

## Data sheet | Item number: 890-512

Strain relief housing; 2-pole; with locking clip; for 1 cable; 3.8 ... 8.2 mm; 30 mm




[www.wago.com/890-512](http://www.wago.com/890-512)



RoHS  Compliant

BOMcheck.net

Color:

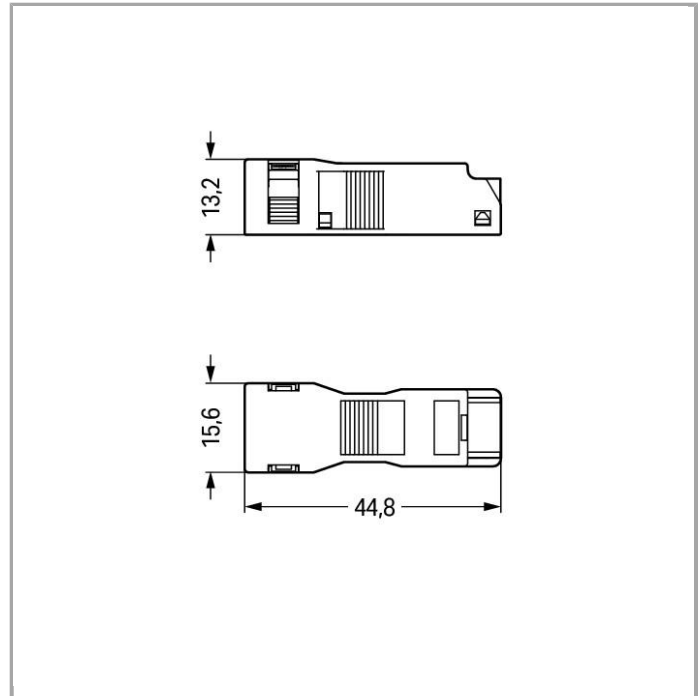

### Data

#### Connection data

No. of poles	2
Connectable sheathed cable diameter	3.8 ... 8.2 mm
Abmantelllänge	32 mm

#### Geometrical Data

Width	15.6 mm / 0.614 inch
Height	13.2 mm / 0.52 inch
Depth	44.8 mm / 1.764 inch

#### Mechanical data

Degree of protection	IP20
----------------------	------

#### Material Data

Color	white
Insulating material	Polyamide 66 (PA 66)
Flammability class per UL94	V0



Fire load	0.088 MJ
Weight	2.94 g

**Environmental Requirements**

Surrounding air (operating) temperature	-35 ... 85 °C
---	---------------

**Commercial data**

Country of origin	DE
GTIN	4045454233358
Customs Tariff No.	85389099990
Product Group	20 (WINSTA)

**Approvals / Certificates****UL-Approvals**

Logo	Approval	Certificate name
	UL UL International Germany GmbH	E45171

**Downloads****Documentation****Bid Text**

890-512	Sep 19, 2016	DOC	Download
WINSTA MINI 2-polig		24.1 kB	

**smartDATA****CAD data**

3D Download 890-512	URL	Download
---------------------	-----	----------

Subject to changes.