


Data sheet | Item number: 893-122

Tap-off module; 2-pole; for plug connectors and distributors WINSTA® knx; 1
Nm tightening torque; with screw-type connection



www.wago.com/893-122

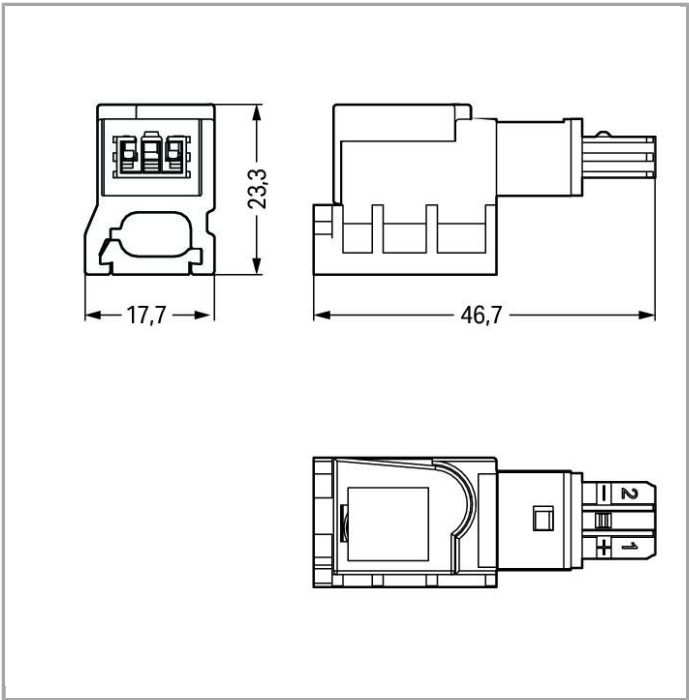

Data
Electrical data

Ratings per IEC/EN 60664-1

Rated voltage (III / 3)	50 V
Rated impulse voltage (III / 3)	0.8 kV
Rated current	3 A
Legend (ratings)	(III / 3) ≙ Overvoltage category III / Pollution degree 3

Connection data

Connection technology	IDC
Actuation type	Operating tool



No. of poles	2
--------------	---

Geometrical Data

Width	17.7 mm / 0.697 inch
Height	23.3 mm / 0.917 inch
Depth	46.7 mm / 1.839 inch

Mechanical data

Mating force of a plug-in connection	approx. 30–70N (depending on number of poles)
Unmating force of a plug-in connection	when unlocked: approx. 15–20N
Marking	1+ 2-
Degree of protection	IP20
Potential marking	1+ 2-

Plug connection

Mismating protection	Yes
----------------------	-----

Material Data

Color	green
Insulating material	Polyamide 66 (PA 66)
Flammability class per UL94	V0
Reaction to fire class per EN 50575	E _{ca}
Contact material	Copper or copper alloy, surface-treated
Weight	14 g

Environmental Requirements

Surrounding air (operating) temperature	-35 ... 85 °C
---	---------------

Commercial data

Country of origin	CH
GTIN	4045454267407
Customs Tariff No.	85366990990
Product Group	20 (WINSTA)

Compatible products**wiring and connectors**

Item no.: 897-121

Flat cable; PVC insulated; 2 x 1.5 mm²www.wago.com/897-121



Item no.: 897-122
Flat cable; halogen-free; 2 x 1.5 mm²

www.wago.com/897-122

Downloads
Documentation
Bid Text

893-122	Sep 22, 2016	DOC	Download
WINSTA® IDC		24.1 kB	

Subject to changes.