


Base Plates • overall dimensions same as pallets DIN 55 201

1000.800

Product Description

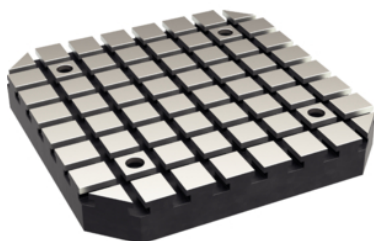

Material


- Steel, case-hardened, ground

More information

Notes

Special types on request.

Drawing

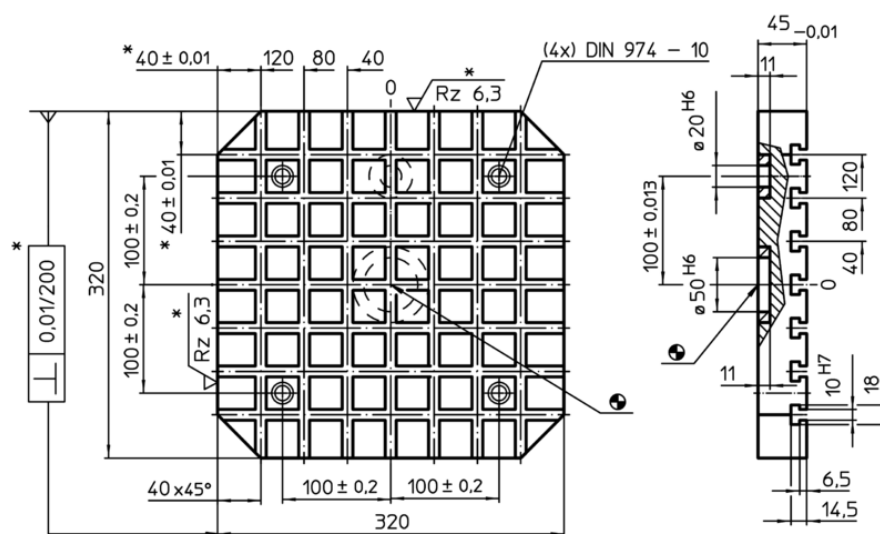

* These tolerances are valid only for the exterior stop types.
Slot spacing $40 \pm 0,01$.

Order information

System	Dimensions										y [mm]	Number of T-slots	[kg]	Art. No.
	a	b ₁	b ₂	b ₃	c	d	l ₁	l ₂	l ₃	y				
V40	100	320	100	40	40	20	320	100	40	10	10	7 x 7	24,5	1000.800

Application example

